

BRYANT®

Quick Selection Guide

Manual Motor Controllers / Disconnects

TECH·SPEC®

Toggle Switch AC Motor Controllers / Disconnects


Part Number	Description	Amperage	Phase	Poles	Wired	Price
<u>30002D</u>	Switch only, 30A, 2-pole, 15 HP @ 600 VAC - Standard Toggle	30	1	2	Back and Side	\$40.50
<u>30003D</u>	Switch only, 30A, 3-pole, 20 HP @ 600 VAC - Standard Toggle	30	3	3	Back and Side	\$85.00
<u>4002*</u>	Switch only, 40A, 2-pole, 5 HP @ 600 VAC - Standard Toggle	40	1	2	Side	\$41.50
<u>40002D</u>	Switch only, 40A, 2-pole, 15 HP @ 600 VAC - Standard Toggle	40	1	2	Side	\$71.00
<u>40003D</u>	Switch only, 40A, 3-pole, 20 HP @ 600 VAC - Standard Toggle	40	3	3	Side	\$115.00
<u>60002D</u>	Switch only, 60A, 2-pole, 20 HP @ 600 VAC - Standard Toggle	60	1	2	Back	\$124.00
<u>60003D</u>	Switch only, 60A, 3-pole, 30 HP @ 600 VAC - Standard Toggle	60	3	3	Back	\$152.00

*Motor controller only ("Not suitable as disconnect")

Toggle Switch AC Motor Controller Accessories

Part Number	Description	Price
<u>30003FG</u>	Finger guards; red; for use with 30A and 40A Switches (Set of 2)	\$11.00
<u>30100</u>	NEMA 1 enclosure without switch, use with 30002D and 30003D	\$25.50

**Example
Back and Side
Wired**

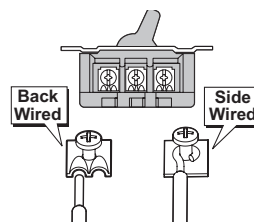

Enclosed Toggle Switch AC Motor Controllers / Disconnects

Part Number	Description	Included Switch	Amperage	Phase	Poles	Enclosure	Price
<u>30102D</u>	Enclosed, 30A, 2-pole, NEMA 1	30002D Standard Toggle	30	1	2	NEMA 1Metal	\$52.00
<u>30103D</u>	Enclosed, 30A, 3-pole, NEMA 1	30003D Standard Toggle	30	3	3		\$114.00
<u>30302D</u>	Enclosed, 30A, 2-pole, Aluminum	30002D Standard Toggle	30	1	2	NEMA 3RMetal	\$78.00
<u>30303D</u>	Enclosed, 30A, 3-pole, Aluminum	30003D Standard Toggle	30	3	3		\$139.00
<u>30322D*</u>	Enclosed, 30A, 2-pole, Plastic	30002DS Short Toggle	30	1	2	NEMA 3R Thermoplastic	\$90.00
<u>30323D*</u>	Enclosed, 30A, 3-pole, Plastic	30003DS Short Toggle	30	3	3		\$96.00
<u>60302D*</u>	Enclosed, 60A, 2-pole, Aluminum	60002FWD Standard Toggle	60	1	2	NEMA 3R Metal	\$181.00
<u>60303D*</u>	Enclosed, 60A, 3-pole, Aluminum	60003FWD Standard Toggle	60	3	3		\$211.00

*Switch is not available as a separate item

NEMA 4X Enclosed Rotary Switch AC Motor Controllers / Disconnects

Part Number	Description	Included Switch	Amperage	Phase	Poles	Enclosure	Price
<u>664X33D*</u>	Enclosed, 30A, 3-pole, NEMA 4X	66033D Rotary	30	3	3	NEMA 4X Thermoplastic	\$189.00
<u>664X63D*</u>	Enclosed, 60A, 3-pole, NEMA 4X	66033D Rotary	60	3	3		\$237.00

*Switch is not available as a separate item

NEMA 4X Enclosed Rotary Switch AC Motor Controller Accessories

Part Number	Description	Price
<u>30003FG</u>	Finger Guards; red; for use with 30A and 40A Switches (Set of 2)	\$11.00
<u>660AC*</u>	SPDT Auxiliary contact NO / NC; includes one contact for use with push-on terminals; use with 664X33D and 664X63D	\$27.00
<u>6610MK</u>	Rotary handle replacement kit, use with 664X33D and 664X63D. (Nema 1 rating) Must use gasket replacement kit 664XWP for NEMA 4X rating.	\$22.00
<u>664XWP</u>	NEMA 4X enclosure gasket replacement kit; includes 4 seals, neoprene bushing and 3 o-rings; use with 664X33D and 664X63D	\$14.00
<u>664XFT</u>	NEMA 4X enclosure mounting feet	\$13.00
<u>6603N</u>	NEMA 4X enclosure neutral buss connector	\$63.00

*660AC Terminal is a quick connect terminal #250