

NEMA 12 and 13 Large Continuous Hinge Wall-Mount



Application

Designed to house electrical controls, terminals, instruments and components. Provides protection from dust, dirt, oil, and water.

Construction

- Bodies and doors fabricated from 14-gauge steel
- Continuously-welded seams ground smooth
- Doors are sealed with poured-in-place polyurethane gasket
- External screw clamps on door
- Continuously hinged door removable by pulling hinge pin
- Collar studs provided for mounting optional subpanels
- External mounting feet
- Grounding provisions provided
- Uses WABN4JIC clamp

Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces



Listings

- UL 50, 12 and 13 [UL Files E6924]
- NEMA/EEMAC 12 and 13
- JIC EL-1-71



Note: Do NOT use NPxxxxC subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures. For example: Subpanel NP1612C will not fit enclosure.WA161206FM (NP1612 is the correct subpanel). Only use NPxxxx subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures.

Dimensions

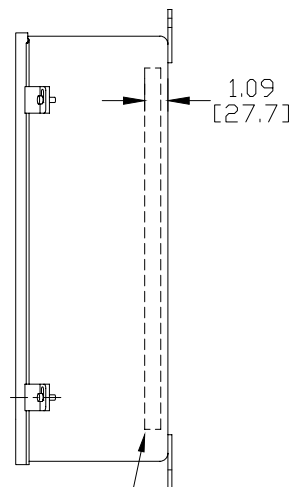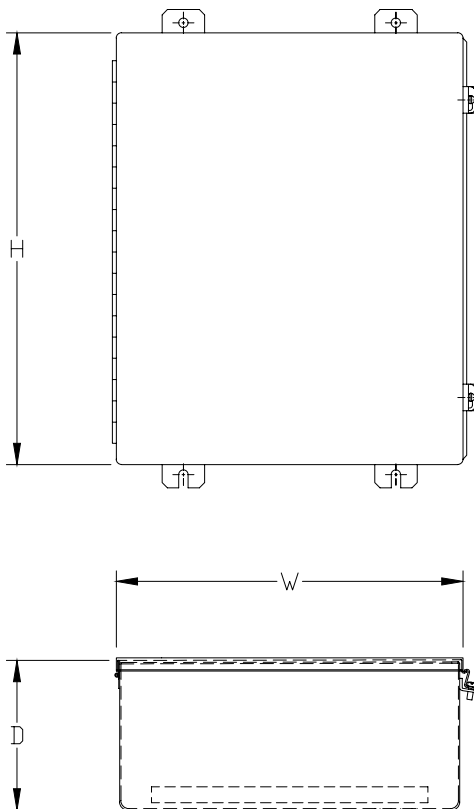

SUBPANEL
(ORDER
SEPARATELY)

NOTES:

1. IF H = 36" OR MORE,
SCREW CLAMP QTY IS 3.

NEMA 12 and 13 Large Continuous Hinge Wall-Mount



NEMA 12 and 13 Large Continuous Hinge Wall-Mount				
Part Number	Price	Enclosure SizeHxWxD	Painted Steel Subpanel	Stainless Steel Subpanel
<u>B201607CH</u>	\$401.00	20.31 x 16.50 x 7.24 [516 x 419 x 184]	<u>NP2016</u>	<u>NP2016SS</u>
<u>B201609CH</u>	\$429.00	20.31 x 16.50 x 9.24 [516 x 419 x 235]	<u>NP2016</u>	<u>NP2016SS</u>
<u>B202007CH</u>	\$444.00	20.31 x 20.50 x 7.24 [516 x 521 x 184]	<u>NP2020</u>	<u>NP2020SS</u>
<u>B202009CH</u>	\$476.00	20.31 x 20.50 x 9.24 [516 x 521 x 235]	<u>NP2020</u>	<u>NP2020SS</u>
<u>B242007CH</u>	\$487.00	24.31 x 20.50 x 7.24 [617 x 521 x 184]	<u>NP2420</u>	<u>NP2420SS</u>
<u>B242009CH</u>	\$521.00	24.31 x 20.50 x 9.24 [617 x 521 x 235]	<u>NP2420</u>	<u>NP2420SS</u>
<u>B242407CH</u>	\$536.00	24.31 x 24.50 x 7.24 [617 x 622 x 184]	<u>NP2424</u>	<u>NP2424SS</u>
<u>B242409CH</u>	\$574.00	24.31 x 24.50 x 9.24 [617 x 622 x 235]	<u>NP2424</u>	<u>NP2424SS</u>
<u>B242411CH</u>	\$647.00	24.31 x 24.50 x 11.24 [617 x 622 x 285]	<u>NP2424</u>	<u>NP2424SS</u>
<u>B302007CH</u>	\$551.00	30.31 x 20.50 x 7.24 [770 x 521 x 184]	<u>NP3020</u>	<u>NP3020SS</u>
<u>B302009CH</u>	\$591.00	30.31 x 20.50 x 9.24 [770 x 521 x 235]	<u>NP3020</u>	<u>NP3020SS</u>
<u>B302409CH</u>	\$653.00	30.31 x 24.50 x 9.24 [770 x 622 x 235]	<u>NP3024</u>	<u>NP3024SS</u>
<u>B302413CH</u>	\$745.00	30.31 x 24.50 x 13.24 [770 x 622 x 336]	<u>NP3024</u>	<u>NP3024SS</u>
<u>B362407CH</u>	\$764.00	36.31 x 24.50 x 7.24 [922 x 622 x 184]	<u>NP3624</u>	<u>NP3624SS</u>
<u>B362409CH</u>	\$798.00	36.31 x 24.50 x 9.24 [922 x 622 x 235]	<u>NP3624</u>	<u>NP3624SS</u>
<u>B362411CH</u>	\$833.00	36.31 x 24.50 x 11.24 [922 x 622 x 285]	<u>NP3624</u>	<u>NP3624SS</u>
<u>B363009CH</u>	\$875.00	36.31 x 30.50 x 9.24 [922 x 775 x 235]	<u>NP3630</u>	<u>NP3630SS</u>
<u>B363013CH</u>	\$949.00	36.31 x 30.50 x 13.24 [922 x 775 x 336]	<u>NP3630</u>	<u>NP3630SS</u>
<u>B423609CH</u>	\$1,096.00	42.31 x 36.50 x 9.24 [1075 x 927 x 235]	<u>NP4236</u>	<u>NP4236SS</u>
<u>B483611CH</u>	\$1,189.00	48.31 x 36.50 x 11.24 [1227 x 927 x 285]	<u>NP4836</u>	<u>NP4836SS</u>
Notes: Subpanels must be ordered separately. Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawings.				

Enclosure Subpanels




Subpanels for NEMA 1, 12, 4 and 4X Wall-Mount Enclosures and WC9 NEMA 12 Operator Consoles

- 12-gauge steel (perforated subpanels are 14-gauge)
- Subpanels with any side over 17 in [432 mm] have 0.25 in [6mm] flange on all sides
- Painted steel and perforated subpanels white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint) Panels listed fit the following enclosures:
- NEMA 1 large (N1C, 42 in [1067 mm] width and wider)
- NEMA 12 single door wall-mount (N12)
- NEMA 12 two-door wall-mount (WA_WF)
- NEMA 12 single door flush wall-mount (WA_FM)
- NEMA 4 (N4) and 4X (SSN) single door wall-mount
- NEMA 12 operator consoles (WC9)
- NEMA 12 Wall Disconnect (SDN12_PL and ABN12)
- NEMA 4 and 4X Wall-Mount Disconnect (SSN4 and SSN4X)



Note: Use NPxxxx subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures only. Do NOT use NPxxxx subpanels in N412 Ultimate Series enclosures with a C in the suffix.

Dimensions

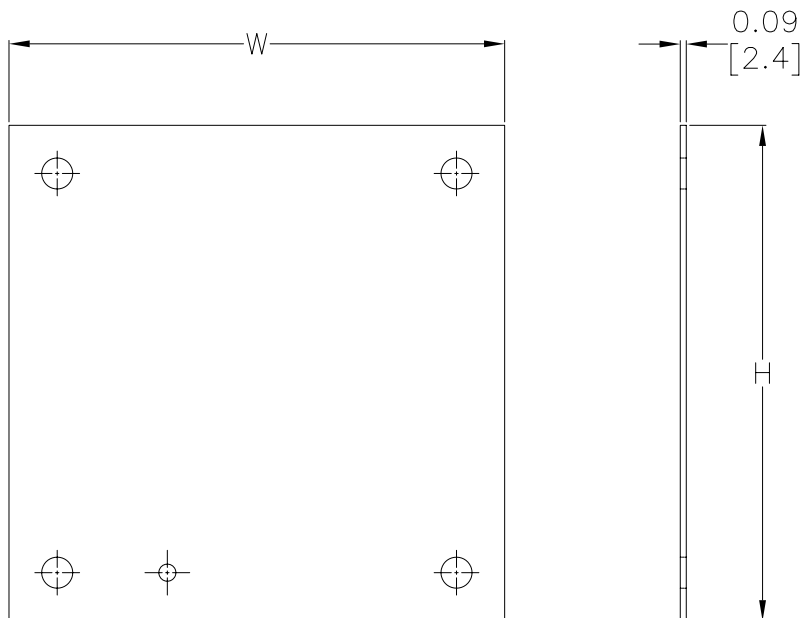

NOTE:
SUBPANELS LARGER THAN
20 X 20 HAVE (2) 0.31"
GROUND HOLES.

Note: Perforated panels have 0.13in [3 mm] diameter holes at 0.25 in [6 mm] spacing.

Enclosure Subpanels



Subpanels for NEMA 1, 12, 4 and 4X Wall-Mount Enclosures and WC9 NEMA 12 Operator Consoles

<i>Painted Steel</i>	<i>Price</i>	<i>Galvanized</i>	<i>Price</i>	<i>304 Stainless Steel</i>	<i>Price</i>	<i>Nominal Enclosure Size HxW</i>	<i>Subpanel Size AxB</i>
<u>NP1212</u>	\$19.50	—	—	—	—	12 x 12	9.00 x 9.00 [229 x 229]
<u>NP1224</u>	\$48.00	—	—	—	—	24 x 12	9.00 x 21.00 [229 x 533]
<u>NP1612</u>	\$34.50	—	—	<u>NP1612SS</u>	\$80.00	12 x 16 16 x 12	13.00 x 9.00 [330 x 229]
<u>NP1616</u>	\$42.50	—	—	<u>NP1616SS</u>	\$97.00	16 x 16	13.00 x 13.00 [330 x 330]
<u>NP2012</u>	\$40.00	—	—	—	—	20 x 12	17.00 x 9.00 [432 x 229]
<u>NP2016</u>	\$51.00	—	—	<u>NP2016SS</u>	\$117.00	20 x 16	17.00 x 13.00 [432 x 330]
<u>NP2020</u>	\$61.00	—	—	<u>NP2020SS</u>	\$151.00	20 x 20	17.00 x 17.00 [432 x 432]
<u>NP2416</u>	\$59.00	—	—	<u>NP2416SS</u>	\$145.00	24 x 16	21.00 x 13.00 [533 x 330]
<u>NP2420</u>	\$79.00	—	—	<u>NP2420SS</u>	\$183.00	24 x 20	21.00 x 17.00 [533 x 432]
<u>NP2424</u>	\$91.00	—	—	<u>NP2424SS</u>	\$213.00	24 x 24	21.00 x 21.00 [533 x 533]
<u>NP3016</u>	\$78.00	—	—	—	—	30 x 16	27.00 x 13.00 [686 x 330]
<u>NP3020</u>	\$95.00	—	—	<u>NP3020SS</u>	\$245.00	30 x 20	27.00 x 17.00 [686 x 432]
<u>NP3024</u>	\$110.00	—	—	<u>NP3024SS</u>	\$258.00	24 x 30 30 x 24	27.00 x 21.00 [686 x 533]
<u>NP3030</u>	\$155.00	—	—	<u>NP3030SS</u>	\$414.00	30 x 30	27.00 x 27.00 [686 x 686]
<u>NP3624</u>	\$132.00	—	—	<u>NP3624SS</u>	\$353.00	36 x 24	33.00 x 21.00 [838 x 533]
<u>NP3630</u>	\$175.00	—	—	<u>NP3630SS</u>	\$405.00	30 x 36 36 x 30	33.00 x 27.00 [838 x 686]
<u>NP3636</u>	\$206.00	—	—	<u>NP3636SS</u>	\$489.00	36 x 36	33.00 x 33.00 [838 x 838]
<u>NP4024</u>	\$158.00	—	—	—	—	40 x 24	37.00 x 21.00 [940 x 533]
<u>NP4224</u>	\$151.00	—	—	—	—	42 x 24	39.00 x 21.00 [991 x 533]
<u>NP4230</u>	\$201.00	—	—	<u>NP4230SS</u>	\$515.00	42 x 30	39.00 x 27.00 [991 x 686]
<u>NP4236</u>	\$236.00	—	—	<u>NP4236SS</u>	\$618.00	42 x 36	39.00 x 33.00 [991 x 838]
<u>NP4824</u>	\$171.00	—	—	—	—	48 x 24	45.00 x 21.00 [1143 x 533]
<u>NP4830</u>	\$225.00	—	—	—	—	48 x 30	45.00 x 27.00 [1143 x 686]
<u>NP4836</u>	\$267.00	—	—	<u>NP4836SS</u>	\$669.00	48 x 36	45.00 x 33.00 [1143 x 838]
<u>NP6030</u>	\$276.00	—	—	—	—	60 x 30	57.00 x 27.00 [1448 x 686]
<u>NP6036</u>	\$328.00	—	—	<u>NP6036SS</u>	\$883.00	60 x 36	57.00 x 33.00 [1448 x 838]
<u>NP7230</u>	\$318.00	<u>NP7230G</u>	\$344.00	—	—	72 x 30	69.00 x 27.00 [1753 x 686]
<u>NP7236</u>	\$389.00	<u>NP7236G</u>	\$422.00	—	—	72 x 36	69.00 x 33.00 [1753 x 838]

Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.

Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table.