

# 30mm Pushbutton Extra-Deep Wall-Mount



## Applications

Designed to hold 30mm [1.18 in] oil-tight pushbuttons, switches and pilot lights. Provides protection from dirt, dust, oil and water. Extra deep design accommodates additional contact blocks for pushbuttons.



## Construction

- Bodies and doors fabricated from 14-gauge steel
- Closed-cell oil-resistant neoprene gasket
- Continuously-welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Enclosures with 2 or more holes have internal detachable hinges to hold cover open during wiring, yet permit quick removal
- Grounding provisions provided

## Finish

- Painted Steel: ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Stainless steel: #3 intermediate polished finish

## Listings

- UL 508, 4, 12 and 13 (stainless steel enclosures also 4X) [UL File E64791]
- NEMA/EEMAC 4, 12 and 13 (stainless steel enclosures also 4X)



### Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1-10 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

### 30mm Pushbutton Extra-Deep Wall-Mount Painted Steel

Painted Steel	Price	Enclosure Size HxWxD	# Holes	Drawing Link
<a href="#">PBXD1</a>	\$94.00	4.32 x 4.38 x 5.14 [110 x 111 x 131]	1	<a href="#">PDF</a>
<a href="#">PBXD2</a>	\$137.00	6.31 x 4.38 x 5.14 [160 x 111 x 131]	2	<a href="#">PDF</a>
<a href="#">PBXD3</a>	\$122.00	8.26 x 4.38 x 5.14 [210 x 111 x 131]	3	<a href="#">PDF</a>
<a href="#">PBXD4S</a>	\$138.00	7.57 x 6.63 x 5.14 [192 x 168 x 131]	4	<a href="#">PDF</a>
<a href="#">PBXD4</a>	\$147.00	10.31 x 4.38 x 5.14 [262 x 111 x 131]	4	<a href="#">PDF</a>
<a href="#">PBXD6</a>	\$158.00	9.82 x 6.63 x 5.14 [249 x 168 x 131]	6	<a href="#">PDF</a>
<a href="#">PBXD9</a>	\$181.00	9.82 x 8.88 x 5.14 [249 x 226 x 131]	9	<a href="#">PDF</a>
<a href="#">PBXD10</a>	\$197.00	14.32 x 6.63 x 5.14 [364 x 168 x 131]	10	<a href="#">PDF</a>
<a href="#">PBXD12</a>	\$207.00	12.07 x 8.88 x 5.14 [307 x 226 x 131]	12	<a href="#">PDF</a>
<a href="#">PBXD16</a>	\$232.00	12.07 x 11.13 x 5.14 [307 x 283 x 131]	16	<a href="#">PDF</a>
<a href="#">PBXD16V</a>	\$256.00	21.07 x 6.63 x 5.14 [535 x 168 x 131]	16	<a href="#">PDF</a>
<a href="#">PBXD20</a>	\$260.00	14.32 x 11.13 x 5.14 [364 x 283 x 131]	20	<a href="#">PDF</a>
<a href="#">PBXD25</a>	\$293.00	14.32 x 13.38 x 5.14 [364 x 340 x 131]	25	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

### 30mm Pushbutton Extra-Deep Wall-Mount Stainless Steel


Stainless Steel	Price	Enclosure Size HxWxD	# Holes	Drawing Link
<a href="#">PBXD1SS</a>	\$181.00	4.25 x 4.34 x 5.01 [108 x 110 x 127]	1	<a href="#">PDF</a>
<a href="#">PBXD2SS</a>	\$218.00	6.25 x 4.34 x 5.01 [159 x 110 x 127]	2	<a href="#">PDF</a>
<a href="#">PBXD4SS</a>	\$284.00	10.25 x 4.34 x 5.01 [260 x 110 x 127]	4	<a href="#">PDF</a>
<a href="#">PBXD3SS</a>	\$365.00	8.25 x 4.34 x 5.01 [210 x 110 x 127]	3	<a href="#">PDF</a>
<a href="#">PBXD16SS</a>	\$649.00	12.00 x 11.09 x 5.01 [305 x 282 x 127]	16	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# 30mm Pushbutton Extra-Deep Wall-Mount



## Dimensions

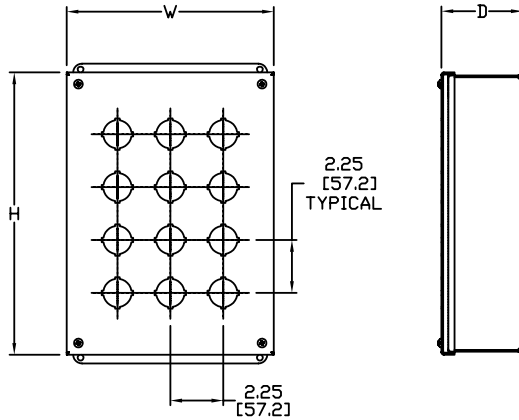

### PBXD HOLE ARRANGEMENTS

