

# 30mm Pushbutton Extra-Deep Wall-Mount



## Applications

Designed to hold 30mm [1.18 in] oil-tight pushbuttons, switches and pilot lights. Provides protection from dirt, dust, oil and water. Extra deep design accommodates additional contact blocks for pushbuttons.



## Construction

- Bodies and doors fabricated from 14-gauge steel
- Closed-cell oil-resistant neoprene gasket
- Continuously-welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Enclosures with 2 or more holes have internal detachable hinges to hold cover open during wiring, yet permit quick removal
- Grounding provisions provided

## Finish

- Painted Steel: ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Stainless steel: #3 intermediate polished finish

## Listings

- UL 508, 4, 12 and 13 (stainless steel enclosures also 4X) [UL File E64791]
- NEMA/EEMAC 4, 12 and 13 (stainless steel enclosures also 4X)



### 30mm Pushbutton Extra-Deep Wall-Mount Painted Steel

| Painted Steel           | Price    | Enclosure Size HxWxD                   | # Holes | Drawing Link        |
|-------------------------|----------|----------------------------------------|---------|---------------------|
| <a href="#">PBXD1</a>   | \$94.00  | 4.32 x 4.38 x 5.14 [110 x 111 x 131]   | 1       | <a href="#">PDF</a> |
| <a href="#">PBXD2</a>   | \$137.00 | 6.31 x 4.38 x 5.14 [160 x 111 x 131]   | 2       | <a href="#">PDF</a> |
| <a href="#">PBXD3</a>   | \$122.00 | 8.26 x 4.38 x 5.14 [210 x 111 x 131]   | 3       | <a href="#">PDF</a> |
| <a href="#">PBXD4S</a>  | \$138.00 | 7.57 x 6.63 x 5.14 [192 x 168 x 131]   | 4       | <a href="#">PDF</a> |
| <a href="#">PBXD4</a>   | \$147.00 | 10.31 x 4.38 x 5.14 [262 x 111 x 131]  | 4       | <a href="#">PDF</a> |
| <a href="#">PBXD6</a>   | \$158.00 | 9.82 x 6.63 x 5.14 [249 x 168 x 131]   | 6       | <a href="#">PDF</a> |
| <a href="#">PBXD9</a>   | \$181.00 | 9.82 x 8.88 x 5.14 [249 x 226 x 131]   | 9       | <a href="#">PDF</a> |
| <a href="#">PBXD10</a>  | \$197.00 | 14.32 x 6.63 x 5.14 [364 x 168 x 131]  | 10      | <a href="#">PDF</a> |
| <a href="#">PBXD12</a>  | \$207.00 | 12.07 x 8.88 x 5.14 [307 x 226 x 131]  | 12      | <a href="#">PDF</a> |
| <a href="#">PBXD16</a>  | \$232.00 | 12.07 x 11.13 x 5.14 [307 x 283 x 131] | 16      | <a href="#">PDF</a> |
| <a href="#">PBXD16V</a> | \$256.00 | 21.07 x 6.63 x 5.14 [535 x 168 x 131]  | 16      | <a href="#">PDF</a> |
| <a href="#">PBXD20</a>  | \$260.00 | 14.32 x 11.13 x 5.14 [364 x 283 x 131] | 20      | <a href="#">PDF</a> |
| <a href="#">PBXD25</a>  | \$293.00 | 14.32 x 13.38 x 5.14 [364 x 340 x 131] | 25      | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

### 30mm Pushbutton Extra-Deep Wall-Mount Stainless Steel


| Stainless Steel          | Price    | Enclosure Size HxWxD                   | # Holes | Drawing Link        |
|--------------------------|----------|----------------------------------------|---------|---------------------|
| <a href="#">PBXD1SS</a>  | \$181.00 | 4.25 x 4.34 x 5.01 [108 x 110 x 127]   | 1       | <a href="#">PDF</a> |
| <a href="#">PBXD2SS</a>  | \$218.00 | 6.25 x 4.34 x 5.01 [159 x 110 x 127]   | 2       | <a href="#">PDF</a> |
| <a href="#">PBXD4SS</a>  | \$284.00 | 10.25 x 4.34 x 5.01 [260 x 110 x 127]  | 4       | <a href="#">PDF</a> |
| <a href="#">PBXD3SS</a>  | \$365.00 | 8.25 x 4.34 x 5.01 [210 x 110 x 127]   | 3       | <a href="#">PDF</a> |
| <a href="#">PBXD16SS</a> | \$649.00 | 12.00 x 11.09 x 5.01 [305 x 282 x 127] | 16      | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].



# 30mm Pushbutton Extra-Deep Wall-Mount



## Dimensions

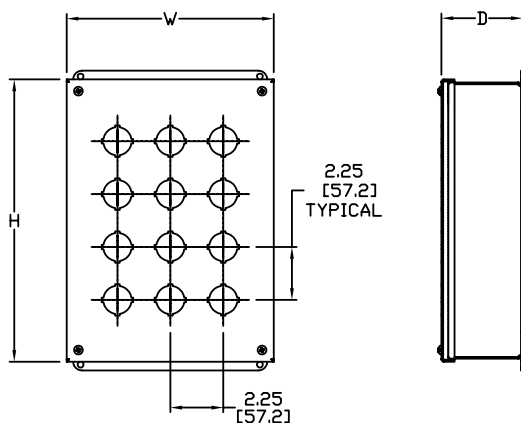

### PBXD HOLE ARRANGEMENTS

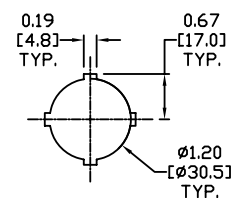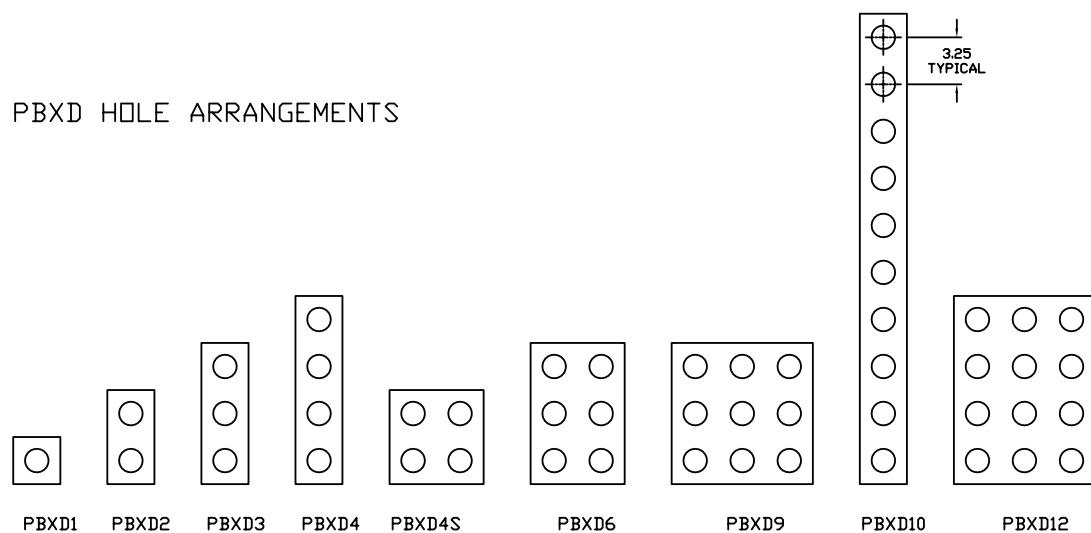

STANDARD 4-WAY  
PUSHBUTTON

