

# 30mm Pushbutton NEMA 12 and 13 Operator Consolelet



## Applications

Designed for use where slanted control surfaces are wanted. Enclosures may be mounted in a variety of ways to meet specific requirements. Receives standard 30mm [1.18 in] oil-tight pushbuttons, switches and pilot lights. Provides protection from dirt, dust, oil, and water.



## Construction

- Fabricated from 14-gauge steel
- Closed-cell oil- resistant neoprene gasket
- Continuously-welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Enclosures with 2 or more rows of holes have internal detachable hinges to hold cover open during wiring, yet permit quick removal
- Grounding provisions provided

## Finish

- ANSI 61 gray polyester powder inside and out over phosphatized surfaces

## Listings

- UL 508 12 and 13 [UL File E64791]
- NEMA/EEMAC 12 and 13




| 30mm Pushbutton NEMA 12 and 13 Operator Consolelet |          |         |                                         |
|----------------------------------------------------|----------|---------|-----------------------------------------|
| Part Number                                        | Price    | # Holes | Enclosure Size HxWxD                    |
| <a href="#">WPBA1</a>                              | \$101.00 | 1       | 3.77 x 3.59 x 4.88 [96 x 91 x 124]      |
| <a href="#">WPBA2</a>                              | \$118.00 | 2       | 3.77 x 5.84 x 4.88 [96 x 148 x 124]     |
| <a href="#">WPBA3</a>                              | \$134.00 | 3       | 3.77 x 8.09 x 4.88 [96 x 205 x 124]     |
| <a href="#">WPBA4</a>                              | \$151.00 | 4       | 3.77 x 10.34 x 4.88 [96 x 263 x 124]    |
| <a href="#">WPBA4S</a>                             | \$169.00 | 4       | 7.52 x 6.59 x 6.76 [191 x 167 x 172]    |
| <a href="#">WPBA6</a>                              | \$196.00 | 6       | 7.52 x 8.84 x 6.76 [191 x 225 x 172]    |
| <a href="#">WPBA8</a>                              | \$222.00 | 8       | 7.52 x 11.09 x 6.76 [191 x 282 x 172]   |
| <a href="#">WPBA9</a>                              | \$232.00 | 9       | 9.77 x 8.84 x 7.88 [248 x 225 x 200]    |
| <a href="#">WPBA10</a>                             | \$246.00 | 10      | 7.52 x 13.34 x 6.76 [191 x 339 x 172]   |
| <a href="#">WPBA12</a>                             | \$269.00 | 12      | 7.52 x 15.59 x 6.76 [191 x 396 x 172]   |
| <a href="#">WPBA12S</a>                            | \$258.00 | 12      | 12.02 x 8.84 x 9.01 [305 x 225 x 229]   |
| <a href="#">WPBA16</a>                             | \$288.00 | 16      | 7.52 x 20.09 x 6.76 [191 x 510 x 172]   |
| <a href="#">WPBA16S</a>                            | \$333.00 | 16      | 12.02 x 11.09 x 9.01 [305 x 282 x 229]  |
| <a href="#">WPBA20</a>                             | \$332.00 | 20      | 12.02 x 13.34 x 9.01 [305 x 339 x 229]  |
| <a href="#">WPBA25</a>                             | \$378.00 | 25      | 14.27 x 13.34 x 10.13 [362 x 339 x 257] |
| <a href="#">WPBA30</a>                             | \$412.00 | 30      | 14.27 x 15.59 x 10.13 [362 x 396 x 257] |
| Note: Dimensions in inches [millimeters].          |          |         |                                         |

# 30mm Pushbutton NEMA 12 and 13 Operator Consolelet



## Dimensions

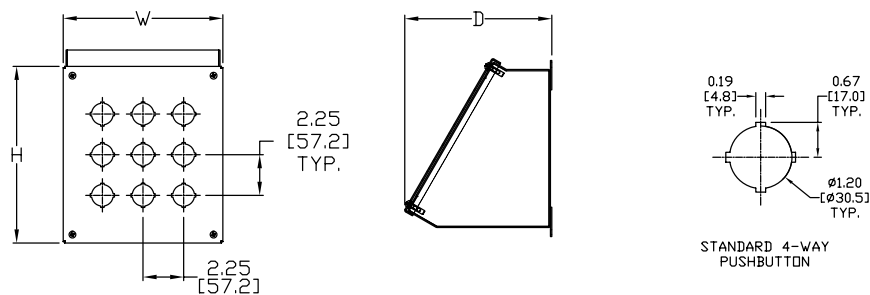

### WPBA HOLE ARRANGEMENTS

