

30mm Pushbutton NEMA 12 and 13 Operator Consolelet



Applications

Designed for use where slanted control surfaces are wanted. Enclosures may be mounted in a variety of ways to meet specific requirements. Receives standard 30mm [1.18 in] oil-tight pushbuttons, switches and pilot lights. Provides protection from dirt, dust, oil, and water.



Construction

- Fabricated from 14-gauge steel
- Closed-cell oil- resistant neoprene gasket
- Continuously-welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Enclosures with 2 or more rows of holes have internal detachable hinges to hold cover open during wiring, yet permit quick removal
- Grounding provisions provided

Finish

- ANSI 61 gray polyester powder inside and out over phosphatized surfaces

Listings

- UL 508 12 and 13 [UL File E64791]
- NEMA/EEMAC 12 and 13




30mm Pushbutton NEMA 12 and 13 Operator Consolelet			
Part Number	Price	# Holes	Enclosure Size HxWxD
<u>WPBA1</u>	\$100.00	1	3.77 x 3.59 x 4.88 [96 x 91 x 124]
<u>WPBA2</u>	\$116.00	2	3.77 x 5.84 x 4.88 [96 x 148 x 124]
<u>WPBA3</u>	\$132.00	3	3.77 x 8.09 x 4.88 [96 x 205 x 124]
<u>WPBA4</u>	\$148.00	4	3.77 x 10.34 x 4.88 [96 x 263 x 124]
<u>WPBA4S</u>	\$167.00	4	7.52 x 6.59 x 6.76 [191 x 167 x 172]
<u>WPBA6</u>	\$193.00	6	7.52 x 8.84 x 6.76 [191 x 225 x 172]
<u>WPBA8</u>	\$219.00	8	7.52 x 11.09 x 6.76 [191 x 282 x 172]
<u>WPBA9</u>	\$229.00	9	9.77 x 8.84 x 7.88 [248 x 225 x 200]
<u>WPBA10</u>	\$243.00	10	7.52 x 13.34 x 6.76 [191 x 339 x 172]
<u>WPBA12</u>	\$265.00	12	7.52 x 15.59 x 6.76 [191 x 396 x 172]
<u>WPBA12S</u>	\$254.00	12	12.02 x 8.84 x 9.01 [305 x 225 x 229]
<u>WPBA16</u>	\$284.00	16	7.52 x 20.09 x 6.76 [191 x 510 x 172]
<u>WPBA16S</u>	\$328.00	16	12.02 x 11.09 x 9.01 [305 x 282 x 229]
<u>WPBA20</u>	\$327.00	20	12.02 x 13.34 x 9.01 [305 x 339 x 229]
<u>WPBA25</u>	\$372.00	25	14.27 x 13.34 x 10.13 [362 x 339 x 257]
<u>WPBA30</u>	\$406.00	30	14.27 x 15.59 x 10.13 [362 x 396 x 257]
Note: Dimensions in inches [millimeters].			

30mm Pushbutton NEMA 12 and 13 Operator Consolelet



Dimensions

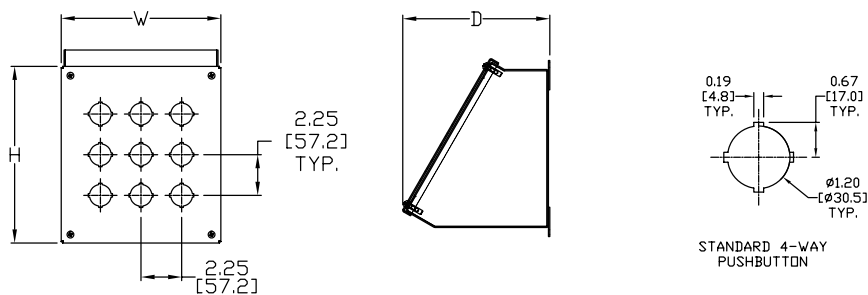


WPBA HOLE ARRANGEMENTS



WPBA1

WPBA2

 
WPBA3




WPBA4



 
WPBA4S




WPBA6

 


WPBA8

 


WPBA9

 


WPBA10

 


WPBA12

 


WPBA12S

 


WPBA16

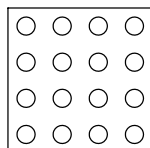


WPBA16S

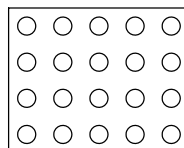

WPBA20

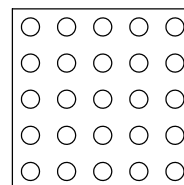

WPBA25

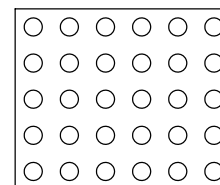

WPBA30