

# NEMA 12 and 13 Single-Door Wall-Mount



## Applications

Designed to house electrical and electronic controls, instruments, components and associated wiring. Hinged doors provide easy access. Designed for indoor use in protecting components from dust, dirt, oil and water.



## Construction

- Bodies and doors fabricated from 14-gauge steel
- Continuously plasma welded seams
- Rolled lip on three sides of door and all sides of enclosure opening is provided to exclude liquids and contaminants
- Quick and easy-to-operate door clamps provided
- Doors removable by pulling heavy gauge continuous hinge pin
- Hasp and staple for padlocking
- Doors are sealed with poured-in-place polyurethane gasket
- Collar studs provided for mounting optional subpanels
- External mounting feet
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Uses WAN12RA clamp

## Finish

- ANSI-61 gray polyester powder light texture inside and outside over phosphatized surfaces

## Listings

- UL 508 12 and 13 [UL file E64791]
- Meets NEMA/EEMAC 12 and 13 requirements
- JIC EL-1-71



Note: Do NOT use NPxxxxC subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures. For example: Subpanel NP1612C will not fit enclosure.WA161206FM (NP1612 is the correct subpanel). Only use NPxxxx subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures.

## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## NEMA 12 and 13 Single-Door Wall-Mount

| Part Number               | Price    | Enclosure SizeHxWxD                     | No. of Clamps | Painted Steel Subpanel | Stainless Steel Subpanel |
|---------------------------|----------|---|---------------|------------------------|--------------------------|
| <a href="#">N12122406</a> | \$398.00 | 12.00 x 24.00 x 7.03 [305 x 610 x 179]  | 2             | <a href="#">NP1224</a> | —                        |
| <a href="#">N12122408</a> | \$420.00 | 12.00 x 24.00 x 9.03 [305 x 610 x 229]  | 2             | <a href="#">NP1224</a> | —                        |
| <a href="#">N12161206</a> | \$343.00 | 16.00 x 12.00 x 7.03 [406 x 305 x 179]  | 2             | <a href="#">NP1612</a> | <a href="#">NP1612SS</a> |
| <a href="#">N12161208</a> | \$360.00 | 16.00 x 12.00 x 9.03 [406 x 305 x 229]  | 2             | <a href="#">NP1612</a> | <a href="#">NP1612SS</a> |
| <a href="#">N12161210</a> | \$388.00 | 16.00 x 12.00 x 11.03 [406 x 305 x 280] | 2             | <a href="#">NP1612</a> | <a href="#">NP1612SS</a> |
| <a href="#">N12161606</a> | \$380.00 | 16.00 x 16.00 x 7.03 [406 x 406 x 179]  | 2             | <a href="#">NP1616</a> | <a href="#">NP1616SS</a> |
| <a href="#">N12161608</a> | \$400.00 | 16.00 x 16.00 x 9.03 [406 x 406 x 229]  | 2             | <a href="#">NP1616</a> | <a href="#">NP1616SS</a> |
| <a href="#">N12162006</a> | \$408.00 | 16.00 x 20.00 x 7.03 [406 x 508 x 179]  | 2             | <a href="#">NP2016</a> | <a href="#">NP2016SS</a> |
| <a href="#">N12162008</a> | \$430.00 | 16.00 x 20.00 x 9.03 [406 x 508 x 229]  | 2             | <a href="#">NP2016</a> | <a href="#">NP2016SS</a> |
| <a href="#">N12201206</a> | \$375.00 | 20.00 x 12.00 x 7.03 [508 x 305 x 179]  | 2             | <a href="#">NP2012</a> | —                        |
| <a href="#">N12201208</a> | \$395.00 | 20.00 x 12.00 x 9.03 [508 x 305 x 229]  | 2             | <a href="#">NP2012</a> | —                        |
| <a href="#">N12201606</a> | \$396.00 | 20.00 x 16.00 x 7.03 [508 x 406 x 179]  | 2             | <a href="#">NP2016</a> | <a href="#">NP2016SS</a> |
| <a href="#">N12201608</a> | \$430.00 | 20.00 x 16.00 x 9.03 [508 x 406 x 229]  | 2             | <a href="#">NP2016</a> | <a href="#">NP2016SS</a> |
| <a href="#">N12201610</a> | \$444.00 | 20.00 x 16.00 x 11.03 [508 x 406 x 280] | 2             | <a href="#">NP2016</a> | <a href="#">NP2016SS</a> |
| <a href="#">N12201612</a> | \$474.00 | 20.00 x 16.00 x 13.03 [508 x 406 x 331] | 2             | <a href="#">NP2016</a> | <a href="#">NP2016SS</a> |
| <a href="#">N12202006</a> | \$440.00 | 20.00 x 20.00 x 7.03 [508 x 508 x 179]  | 2             | <a href="#">NP2020</a> | <a href="#">NP2020SS</a> |

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

Table continued on next page

# NEMA 12 and 13 Single-Door Wall-Mount



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

Table continued from previous page

| NEMA 12 and 13 Single-Door Wall-Mount |          |   |               |                        |                          |
|---------------------------------------|----------|---|---------------|------------------------|--------------------------|
| Part Number                           | Price    | Enclosure SizeHxWxD                     | No. of Clamps | Painted Steel Subpanel | Stainless Steel Subpanel |
| <a href="#">N12202008</a>             | \$451.00 | 20.00 x 20.00 x 9.03 [508 x 508 x 229]  | 2             | <a href="#">NP2020</a> | <a href="#">NP2020SS</a> |
| <a href="#">N12202010</a>             | \$481.00 | 20.00 x 20.00 x 11.03 [508 x 508 x 280] | 2             | <a href="#">NP2020</a> | <a href="#">NP2020SS</a> |
| <a href="#">N12202406</a>             | \$472.00 | 20.00 x 24.00 x 7.03 [508 x 610 x 179]  | 2             | <a href="#">NP2420</a> | <a href="#">NP2420SS</a> |
| <a href="#">N12202408</a>             | \$485.00 | 20.00 x 24.00 x 9.03 [508 x 610 x 229]  | 2             | <a href="#">NP2420</a> | <a href="#">NP2420SS</a> |
| <a href="#">N12241206</a>             | \$398.00 | 24.00 x 12.00 x 7.03 [610 x 305 x 179]  | 2             | <a href="#">NP1224</a> | —                        |
| <a href="#">N12241208</a>             | \$420.00 | 24.00 x 12.00 x 9.03 [610 x 305 x 229]  | 2             | <a href="#">NP1224</a> | —                        |
| <a href="#">N12241210</a>             | \$442.00 | 24.00 x 12.00 x 11.03 [610 x 305 x 280] | 2             | <a href="#">NP1224</a> | —                        |
| <a href="#">N12241606</a>             | \$435.00 | 24.00 x 16.00 x 7.03 [610 x 406 x 179]  | 2             | <a href="#">NP2416</a> | <a href="#">NP2416SS</a> |
| <a href="#">N12241608</a>             | \$447.00 | 24.00 x 16.00 x 9.03 [610 x 406 x 229]  | 2             | <a href="#">NP2416</a> | <a href="#">NP2416SS</a> |
| <a href="#">N12242006</a>             | \$472.00 | 24.00 x 20.00 x 7.03 [610 x 508 x 179]  | 2             | <a href="#">NP2420</a> | <a href="#">NP2420SS</a> |
| <a href="#">N12242008</a>             | \$485.00 | 24.00 x 20.00 x 9.03 [610 x 508 x 229]  | 2             | <a href="#">NP2420</a> | <a href="#">NP2420SS</a> |
| <a href="#">N12242010</a>             | \$512.00 | 24.00 x 20.00 x 11.03 [610 x 508 x 280] | 2             | <a href="#">NP2420</a> | <a href="#">NP2420SS</a> |
| <a href="#">N12242012</a>             | \$554.00 | 24.00 x 20.00 x 13.03 [610 x 508 x 331] | 2             | <a href="#">NP2420</a> | <a href="#">NP2420SS</a> |
| <a href="#">N12242016</a>             | \$592.00 | 24.00 x 20.00 x 17.03 [610 x 508 x 433] | 2             | <a href="#">NP2420</a> | <a href="#">NP2420SS</a> |
| <a href="#">N12242406</a>             | \$495.00 | 24.00 x 24.00 x 7.03 [610 x 610 x 179]  | 2             | <a href="#">NP2424</a> | <a href="#">NP2424SS</a> |
| <a href="#">N12242408</a>             | \$524.00 | 24.00 x 24.00 x 9.03 [610 x 610 x 229]  | 2             | <a href="#">NP2424</a> | <a href="#">NP2424SS</a> |
| <a href="#">N12242410</a>             | \$568.00 | 24.00 x 24.00 x 11.03 [610 x 610 x 280] | 2             | <a href="#">NP2424</a> | <a href="#">NP2424SS</a> |
| <a href="#">N12242412</a>             | \$581.00 | 24.00 x 24.00 x 13.03 [610 x 610 x 331] | 2             | <a href="#">NP2424</a> | <a href="#">NP2424SS</a> |
| <a href="#">N12242416</a>             | \$640.00 | 24.00 x 24.00 x 17.03 [610 x 610 x 433] | 2             | <a href="#">NP2424</a> | <a href="#">NP2424SS</a> |
| <a href="#">N12243008</a>             | \$581.00 | 24.00 x 30.00 x 9.03 [610 x 762 x 229]  | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12301606</a>             | \$476.00 | 30.00 x 16.00 x 7.03 [762 x 406 x 179]  | 2             | <a href="#">NP3016</a> | —                        |
| <a href="#">N12302006</a>             | \$506.00 | 30.00 x 20.00 x 7.03 [762 x 508 x 179]  | 2             | <a href="#">NP3020</a> | <a href="#">NP3020SS</a> |
| <a href="#">N12302008</a>             | \$551.00 | 30.00 x 20.00 x 9.03 [762 x 508 x 229]  | 2             | <a href="#">NP3020</a> | <a href="#">NP3020SS</a> |
| <a href="#">N12302010</a>             | \$577.00 | 30.00 x 20.00 x 11.03 [762 x 508 x 280] | 2             | <a href="#">NP3020</a> | <a href="#">NP3020SS</a> |
| <a href="#">N12302406</a>             | \$565.00 | 30.00 x 24.00 x 7.03 [762 x 610 x 179]  | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12302408</a>             | \$581.00 | 30.00 x 24.00 x 9.03 [762 x 610 x 229]  | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12302410</a>             | \$609.00 | 30.00 x 24.00 x 11.03 [762 x 610 x 280] | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12302412</a>             | \$646.00 | 30.00 x 24.00 x 13.03 [762 x 610 x 331] | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12302416</a>             | \$719.00 | 30.00 x 24.00 x 17.03 [762 x 610 x 433] | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12302420</a>             | \$799.00 | 30.00 x 24.00 x 21.03 [762 x 610 x 534] | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12302424</a>             | \$866.00 | 30.00 x 24.00 x 25.03 [762 x 610 x 636] | 2             | <a href="#">NP3024</a> | <a href="#">NP3024SS</a> |
| <a href="#">N12303008</a>             | \$650.00 | 30.00 x 30.00 x 9.03 [762 x 762 x 229]  | 2             | <a href="#">NP3030</a> | <a href="#">NP3030SS</a> |
| <a href="#">N12303012</a>             | \$722.00 | 30.00 x 30.00 x 13.03 [762 x 762 x 331] | 2             | <a href="#">NP3030</a> | <a href="#">NP3030SS</a> |

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

Table continued on next page

# NEMA 12 and 13 Single-Door Wall-Mount



| Shipping Schedule |            |            |             |             |
|-------------------|------------|------------|-------------|-------------|
| Same day          | 1 - 5 days | 1 - 7 days | 1 - 15 days | 1 - 20 days |

Color indicates shipping lead time in business days.

Table continued from previous page




| NEMA 12 and 13 Single-Door Wall-Mount |            |  |               |                        |                          |                           |
|---------------------------------------|------------|--|---------------|------------------------|--------------------------|---------------------------|
| Part Number                           | Price      | Enclosure SizeHxWxD                      | No. of Clamps | Painted Steel Subpanel | Stainless Steel Subpanel | Galvanized Steel Subpanel |
| <a href="#">N12303608</a>             | \$719.00   | 30.00 x 36.00 x 9.03 [762 x 914 x 229]   | 2             | <a href="#">NP3630</a> | <a href="#">NP3630SS</a> | —                         |
| <a href="#">N12362406</a>             | \$604.00   | 36.00 x 24.00 x 7.03 [914 x 610 x 179]   | 2             | <a href="#">NP3624</a> | <a href="#">NP3624SS</a> | —                         |
| <a href="#">N12362408</a>             | \$639.00   | 36.00 x 24.00 x 9.03 [914 x 610 x 229]   | 2             | <a href="#">NP3624</a> | <a href="#">NP3624SS</a> | —                         |
| <a href="#">N12362410</a>             | \$675.00   | 36.00 x 24.00 x 11.03 [914 x 610 x 280]  | 2             | <a href="#">NP3624</a> | <a href="#">NP3624SS</a> | —                         |
| <a href="#">N12362412</a>             | \$719.00   | 36.00 x 24.00 x 13.03 [914 x 610 x 331]  | 2             | <a href="#">NP3624</a> | <a href="#">NP3624SS</a> | —                         |
| <a href="#">N12363006</a>             | \$698.00   | 36.00 x 30.00 x 7.03 [914 x 762 x 179]   | 2             | <a href="#">NP3630</a> | <a href="#">NP3630SS</a> | —                         |
| <a href="#">N12363008</a>             | \$719.00   | 36.00 x 30.00 x 9.03 [914 x 762 x 229]   | 2             | <a href="#">NP3630</a> | <a href="#">NP3630SS</a> | —                         |
| <a href="#">N12363010</a>             | \$758.00   | 36.00 x 30.00 x 11.03 [914 x 762 x 280]  | 2             | <a href="#">NP3630</a> | <a href="#">NP3630SS</a> | —                         |
| <a href="#">N12363012</a>             | \$806.00   | 36.00 x 30.00 x 13.03 [914 x 762 x 331]  | 2             | <a href="#">NP3630</a> | <a href="#">NP3630SS</a> | —                         |
| <a href="#">N12363016</a>             | \$897.00   | 36.00 x 30.00 x 17.03 [914 x 762 x 433]  | 2             | <a href="#">NP3630</a> | <a href="#">NP3630SS</a> | —                         |
| <a href="#">N12363020</a>             | \$992.00   | 36.00 x 30.00 x 21.03 [914 x 762 x 534]  | 2             | <a href="#">NP3630</a> | <a href="#">NP3630SS</a> | —                         |
| <a href="#">N12363608</a>             | \$806.00   | 36.00 x 36.00 x 9.03 [914 x 914 x 229]   | 2             | <a href="#">NP3636</a> | <a href="#">NP3636SS</a> | —                         |
| <a href="#">N12363612</a>             | \$902.00   | 36.00 x 36.00 x 13.03 [914 x 914 x 331]  | 2             | <a href="#">NP3636</a> | <a href="#">NP3636SS</a> | —                         |
| <a href="#">N12422408</a>             | \$711.00   | 42.00 x 24.00 x 9.03 [1067 x 610 x 229]  | 3             | <a href="#">NP4224</a> | —                        | —                         |
| <a href="#">N12423008</a>             | \$803.00   | 42.00 x 30.00 x 9.03 [1067 x 762 x 229]  | 3             | <a href="#">NP4230</a> | <a href="#">NP4230SS</a> | —                         |
| <a href="#">N12423010</a>             | \$854.00   | 42.00 x 30.00 x 11.03 [1067 x 762 x 280] | 3             | <a href="#">NP4230</a> | <a href="#">NP4230SS</a> | —                         |
| <a href="#">N12423012</a>             | \$899.00   | 42.00 x 30.00 x 13.03 [1067 x 762 x 331] | 3             | <a href="#">NP4230</a> | <a href="#">NP4230SS</a> | —                         |
| <a href="#">N12423608</a>             | \$896.00   | 42.00 x 36.00 x 9.03 [1067 x 914 x 229]  | 3             | <a href="#">NP4236</a> | <a href="#">NP4236SS</a> | —                         |
| <a href="#">N12423610</a>             | \$950.00   | 42.00 x 36.00 x 11.03 [1067 x 914 x 280] | 3             | <a href="#">NP4236</a> | <a href="#">NP4236SS</a> | —                         |
| <a href="#">N12423612</a>             | \$1,008.00 | 42.00 x 36.00 x 13.03 [1067 x 914 x 331] | 3             | <a href="#">NP4236</a> | <a href="#">NP4236SS</a> | —                         |
| <a href="#">N12423616</a>             | \$1,096.00 | 42.00 x 36.00 x 17.03 [1067 x 914 x 433] | 3             | <a href="#">NP4236</a> | <a href="#">NP4236SS</a> | —                         |
| <a href="#">N12482408</a>             | \$776.00   | 48.00 x 24.00 x 9.03 [1219 x 610 x 229]  | 3             | <a href="#">NP4824</a> | —                        | —                         |
| <a href="#">N12483008</a>             | \$880.00   | 48.00 x 30.00 x 9.03 [1219 x 762 x 229]  | 3             | <a href="#">NP4830</a> | —                        | —                         |
| <a href="#">N12483010</a>             | \$929.00   | 48.00 x 30.00 x 11.03 [1219 x 762 x 280] | 3             | <a href="#">NP4830</a> | —                        | —                         |
| <a href="#">N12483608</a>             | \$993.00   | 48.00 x 36.00 x 9.03 [1219 x 914 x 229]  | 3             | <a href="#">NP4836</a> | <a href="#">NP4836SS</a> | —                         |
| <a href="#">N12483610</a>             | \$1,027.00 | 48.00 x 36.00 x 11.03 [1219 x 914 x 280] | 3             | <a href="#">NP4836</a> | <a href="#">NP4836SS</a> | —                         |
| <a href="#">N12483612</a>             | \$1,058.00 | 48.00 x 36.00 x 13.03 [1219 x 914 x 331] | 3             | <a href="#">NP4836</a> | <a href="#">NP4836SS</a> | —                         |
| <a href="#">N12483616</a>             | \$1,159.00 | 48.00 x 36.00 x 17.03 [1219 x 914 x 433] | 3             | <a href="#">NP4836</a> | <a href="#">NP4836SS</a> | —                         |
| <a href="#">N12483620</a>             | \$1,359.00 | 48.00 x 36.00 x 21.03 [1219 x 914 x 534] | 3             | <a href="#">NP4836</a> | <a href="#">NP4836SS</a> | —                         |
| <a href="#">N12603608</a>             | \$1,148.00 | 60.00 x 36.00 x 9.03 [1524 x 914 x 229]  | 3             | <a href="#">NP6036</a> | <a href="#">NP6036SS</a> | —                         |
| <a href="#">N12603610</a>             | \$1,174.00 | 60.00 x 36.00 x 11.03 [1524 x 914 x 280] | 3             | <a href="#">NP6036</a> | <a href="#">NP6036SS</a> | —                         |
| <a href="#">N12603612</a>             | \$1,231.00 | 60.00 x 36.00 x 13.03 [1524 x 914 x 331] | 3             | <a href="#">NP6036</a> | <a href="#">NP6036SS</a> | —                         |
| <a href="#">N12603616</a>             | \$1,387.00 | 60.00 x 36.00 x 17.03 [1524 x 914 x 433] | 3             | <a href="#">NP6036</a> | <a href="#">NP6036SS</a> | —                         |
| <a href="#">N12603620</a>             | \$1,546.00 | 60.00 x 36.00 x 21.03 [1524 x 914 x 534] | 3             | <a href="#">NP6036</a> | <a href="#">NP6036SS</a> | —                         |
| <a href="#">N12723016</a>             | \$1,524.00 | 72.00 x 30.00 x 17.03 [1829 x 762 x 433] | 4             | <a href="#">NP7230</a> | —                        | <a href="#">NP7230G</a>   |
| <a href="#">N12723612</a>             | \$1,538.00 | 72.00 x 36.00 x 13.03 [1829 x 914 x 331] | 4             | <a href="#">NP7236</a> | —                        | <a href="#">NP7236G</a>   |

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

# NEMA 12 and 13 Single-Door Wall-Mount



## Dimensions

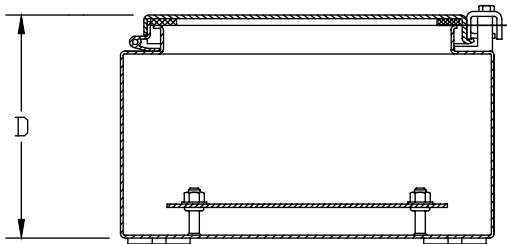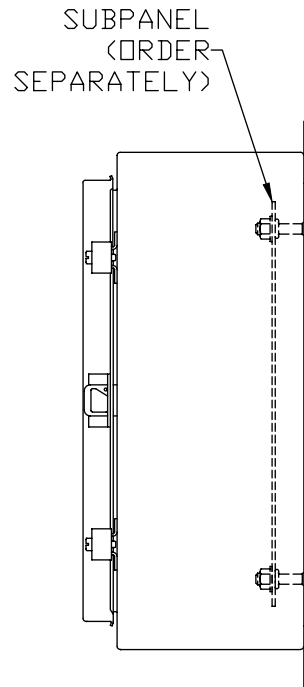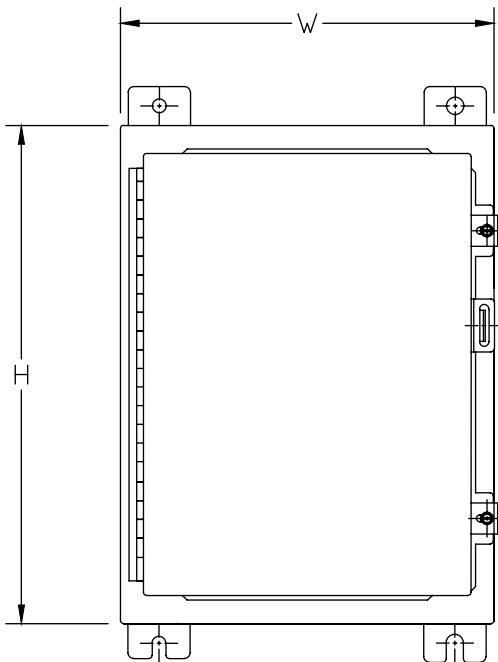

### NOTES:

1. THE NUMBER OF DOOR CLAMPS IS DEPENDANT ON THE SIZE OF THE ENCLOSURE.

# Enclosure Subpanels




## Subpanels for NEMA 1, 12, 4 and 4X Wall-Mount Enclosures and WC9 NEMA 12 Operator Consoles

- 12-gauge steel (perforated subpanels are 14-gauge)
- Subpanels with any side over 17 in [432 mm] have 0.25 in [6mm] flange on all sides
- Painted steel and perforated subpanels white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint) Panels listed fit the following enclosures:
- NEMA 1 large (N1C, 42 in [1067 mm] width and wider)
- NEMA 12 single door wall-mount (N12)
- NEMA 12 two-door wall-mount (WA\_WF)
- NEMA 12 single door flush wall-mount (WA\_FM)
- NEMA 4 (N4) and 4X (SSN) single door wall-mount
- NEMA 12 operator consoles (WC9)
- NEMA 12 Wall Disconnect (SDN12\_PL and ABN12)
- NEMA 4 and 4X Wall-Mount Disconnect (SSN4 and SSN4X)



Note: Use NPxxxx subpanels in NEMA 1, NEMA 4 and 4X, and NEMA 12 enclosures only. Do NOT use NPxxxx subpanels in N412 Ultimate Series enclosures with a C in the suffix.

## Dimensions

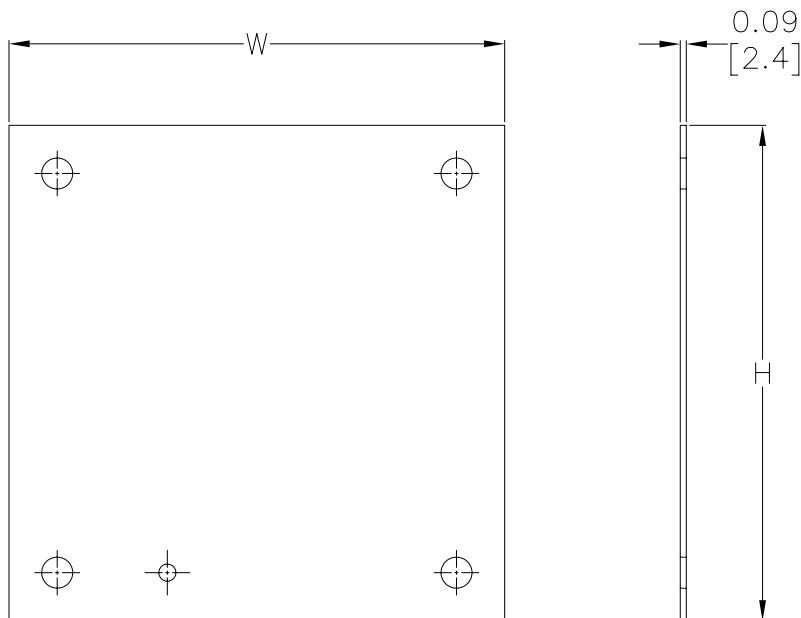

NOTE:  
SUBPANELS LARGER THAN  
20 X 20 HAVE (2) 0.31"  
GROUND HOLES.

Note: Perforated panels have 0.13in [3 mm] diameter holes at 0.25 in [6 mm] spacing.

# Enclosure Subpanels



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Subpanels for NEMA 1, 12, 4 and 4X Wall-Mount Enclosures and WC9 NEMA 12 Operator Consoles

| Painted Steel          | Price    | Galvanized              | Price    | 304 Stainless Steel      | Price    | Nominal Enclosure Size HxW | Subpanel Size AxB          |
|------------------------|----------|-------------------------|----------|--------------------------|----------|----------------------------|----------------------------|
| <a href="#">NP1212</a> | \$18.50  | -                       | -        | —                        | —        | 12 x 12                    | 9.00 x 9.00 [229 x 229]    |
| <a href="#">NP1224</a> | \$45.50  | -                       | -        | —                        | —        | 24 x 12                    | 9.00 x 21.00 [229 x 533]   |
| <a href="#">NP1612</a> | \$33.00  | -                       | -        | <a href="#">NP1612SS</a> | \$87.00  | 12 x 16<br>16 x 12         | 13.00 x 9.00 [330 x 229]   |
| <a href="#">NP1616</a> | \$40.50  | -                       | -        | <a href="#">NP1616SS</a> | \$106.00 | 16 x 16                    | 13.00 x 13.00 [330 x 330]  |
| <a href="#">NP2012</a> | \$38.00  | -                       | -        | —                        | —        | 20 x 12                    | 17.00 x 9.00 [432 x 229]   |
| <a href="#">NP2016</a> | \$48.00  | -                       | -        | <a href="#">NP2016SS</a> | \$128.00 | 20 x 16                    | 17.00 x 13.00 [432 x 330]  |
| <a href="#">NP2020</a> | \$58.00  | -                       | -        | <a href="#">NP2020SS</a> | \$165.00 | 20 x 20                    | 17.00 x 17.00 [432 x 432]  |
| <a href="#">NP2416</a> | \$56.00  | -                       | -        | <a href="#">NP2416SS</a> | \$159.00 | 24 x 16                    | 21.00 x 13.00 [533 x 330]  |
| <a href="#">NP2420</a> | \$75.00  | -                       | -        | <a href="#">NP2420SS</a> | \$200.00 | 24 x 20                    | 21.00 x 17.00 [533 x 432]  |
| <a href="#">NP2424</a> | \$86.00  | -                       | -        | <a href="#">NP2424SS</a> | \$233.00 | 24 x 24                    | 21.00 x 21.00 [533 x 533]  |
| <a href="#">NP3016</a> | \$75.00  | -                       | -        | —                        | —        | 30 x 16                    | 27.00 x 13.00 [686 x 330]  |
| <a href="#">NP3020</a> | \$90.00  | -                       | -        | <a href="#">NP3020SS</a> | \$268.00 | 30 x 20                    | 27.00 x 17.00 [686 x 432]  |
| <a href="#">NP3024</a> | \$105.00 | -                       | -        | <a href="#">NP3024SS</a> | \$283.00 | 24 x 30<br>30 x 24         | 27.00 x 21.00 [686 x 533]  |
| <a href="#">NP3030</a> | \$147.00 | -                       | -        | <a href="#">NP3030SS</a> | \$452.00 | 30 x 30                    | 27.00 x 27.00 [686 x 686]  |
| <a href="#">NP3624</a> | \$125.00 | -                       | -        | <a href="#">NP3624SS</a> | \$386.00 | 36 x 24                    | 33.00 x 21.00 [838 x 533]  |
| <a href="#">NP3630</a> | \$167.00 | -                       | -        | <a href="#">NP3630SS</a> | \$443.00 | 30 x 36<br>36 x 30         | 33.00 x 27.00 [838 x 686]  |
| <a href="#">NP3636</a> | \$196.00 | -                       | -        | <a href="#">NP3636SS</a> | \$535.00 | 36 x 36                    | 33.00 x 33.00 [838 x 838]  |
| <a href="#">NP4024</a> | \$151.00 | -                       | -        | —                        | —        | 40 x 24                    | 37.00 x 21.00 [940 x 533]  |
| <a href="#">NP4224</a> | \$144.00 | -                       | -        | —                        | —        | 42 x 24                    | 39.00 x 21.00 [991 x 533]  |
| <a href="#">NP4230</a> | \$191.00 | -                       | -        | <a href="#">NP4230SS</a> | \$563.00 | 42 x 30                    | 39.00 x 27.00 [991 x 686]  |
| <a href="#">NP4236</a> | \$225.00 | -                       | -        | <a href="#">NP4236SS</a> | \$676.00 | 42 x 36                    | 39.00 x 33.00 [991 x 838]  |
| <a href="#">NP4824</a> | \$163.00 | -                       | -        | —                        | —        | 48 x 24                    | 45.00 x 21.00 [1143 x 533] |
| <a href="#">NP4830</a> | \$215.00 | -                       | -        | —                        | —        | 48 x 30                    | 45.00 x 27.00 [1143 x 686] |
| <a href="#">NP4836</a> | \$254.00 | -                       | -        | <a href="#">NP4836SS</a> | \$731.00 | 48 x 36                    | 45.00 x 33.00 [1143 x 838] |
| <a href="#">NP6030</a> | \$263.00 | -                       | -        | —                        | —        | 60 x 30                    | 57.00 x 27.00 [1448 x 686] |
| <a href="#">NP6036</a> | \$313.00 | -                       | -        | <a href="#">NP6036SS</a> | \$965.00 | 60 x 36                    | 57.00 x 33.00 [1448 x 838] |
| <a href="#">NP7230</a> | \$302.00 | <a href="#">NP7230G</a> | \$327.00 | —                        | —        | 72 x 30                    | 69.00 x 27.00 [1753 x 686] |
| <a href="#">NP7236</a> | \$371.00 | <a href="#">NP7236G</a> | \$402.00 | —                        | —        | 72 x 36                    | 69.00 x 33.00 [1753 x 838] |

Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.

Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table.