

WC12 NEMA 12 and 13 Operator Consoles



Applications

Designed to hold electrical and electronic controls and instruments. Pushbuttons, pilot lights, meters, switches, etc. can be mounted on sloping control surfaces. Interior components can be mounted on subpanel and terminal straps. Heavy-duty construction provides protection from dirt, dust, oil and water.

Construction

Base

- Bodies and doors fabricated from 14-gauge steel
- Seams are continuously-welded and ground smooth
- 3-point keylocking handle is provided on front main door
- Double overlapping doors are provided on two-door consoles
- Main hinged doors are flush
- Large sloping control panels are hinged along bottom edge
- Control panels have captivated screws threaded into sealed wells
- Door stops provided to hold control panel open
- Closed-cell neoprene gasket
- Removable subpanel is included with console
- Grounding provisions provided
- Studs are welded to inside of console for mounting subpanel
- An inclined body rail is welded to each side of 24 in [610 mm] wide and 36 in [914 mm] wide consoles for support of terminal straps
- Uses WAL2 series handles and WAL2KEY replacement key

Top

- Fabricated from 14-gauge steel
- Top has a sloped front surface
- Four holes are provided for mounting to body
- Seams are continuously-welded and ground smooth
- Instrument and access panels have captivated screws which thread into sealed wells
- Closed-cell neoprene gasket
- Instrument panels and access panels are removable

Writing desk

- Fabricated from 14-gauge steel
- Seams are continuously-welded and ground smooth
- Desks are removable and attach easily to console front

Finish

- ANSI 61 gray polyester powder inside and out over phosphatized surfaces
- Included painted steel subpanel is white polyester powder over phosphatized surfaces

Listings

- UL 508 12 and 13 [UL File E64791]
- NEMA/EEMAC 12 and 13



Shipping Schedule

Same day | 1 - 5 days | 1 - 7 days | 1-10 days | 1 - 15 days | 1 - 20 days

Color indicates shipping lead time in business days.

WC12 NEMA 12 and 13 Operator Consoles

Console Base	Price	Console Base HxWxD	Subpanel Size	Console Top	Price	Writing Desk	Price
WC1224B(Single Door)	\$2,774.00	36.13 x 24.13 x 24.06 [918 x 613 x 611]	32.00 x 18.00 [813 x 457]	-	-	-	-
WC12B (Single Door)	\$3,194.00	36.13 x 36.13 x 24.06 [918 x 918 x 611]	32.00 x 30.00 [813 x 762]	WC12T	\$934.00	WC12W	\$327.00
WC1248BD(Double Door)	\$3,872.00	36.13 x 48.13 x 24.06 [918 x 1223 x 611]	32.00 x 42.00 [813 x 1067]	-	-	-	-

Notes: Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawings.

Subpanels included.


Tops, writing desk, etc. must be ordered separately.

WC12 NEMA 12 and 13 Operator Consoles



Dimensions

in mm

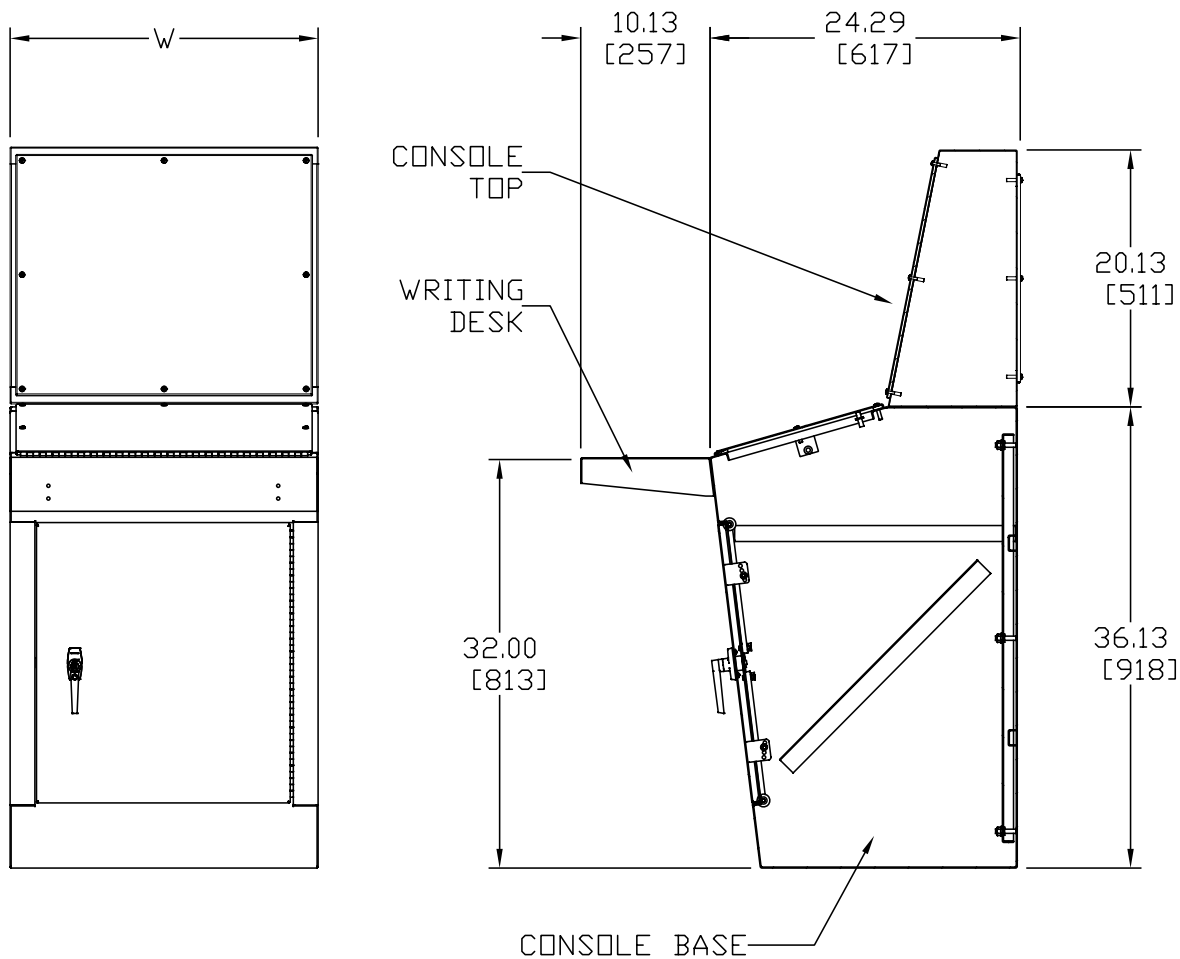

NOTES:

1. ACCESS DOORS OPEN 180 DEGREES.
2. 3-POINT KEY LOCKING HANDLES ARE PROVIDED ON MAIN DOORS
3. WRITING DESK IS PROVIDED WITH MOUNTING HARDWARE.
4. 48" WIDE CONSOLE HAS TWO DOORS.

Enclosure Accessories – Mounting Feet and Casters

Mounting Feet for Ultimate Series Enclosures



Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Mounting Feet	Price	Description	Wt. [lb]
<u>N412MFK</u>	\$26.50	Wiegmann mounting feet kit, plated finish. For use on NEMA 412 Ultimate series enclosures. Includes (4) mounting feet, mounting hardware and sealing washers.	4
<u>N412MFKSS</u>	\$77.00	Wiegmann mounting feet kit, 304 stainless steel. For use on NEMA 412 Ultimate series enclosures. Includes (4) mounting feet, mounting hardware and sealing washers.	4



N412MFK



N412MFKSS

Enclosure Accessories – Locks and Latches

Latch Kits for Single Door NEMA 3R, NEMA 4, and NEMA 12 Enclosures



Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Latch Kits for Single Door NEMA 3R and NEMA 12 Enclosures			
Padlock Style	Price	Wt. [lb]	Description
WAL1C	\$193.00	3.8	Wiegmann enclosure latch kit, 3-point. For use on NEMA 12 enclosures where height is 36, 42 or 48 inches.
WAL1D	\$192.00	4.8	Wiegmann enclosure latch kit, 3-point. For use on NEMA 12 enclosures where height is 60 or 72 inches.

Enclosures

The locks and lock kits on this page are used with the following enclosure series: CTDD

- WA_WF

Enclosure series example:

Enclosure part number WA364812WF = WA_WF series



WAL2A



WAL1A

Enclosure Accessories – Fasteners and Miscellaneous

Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1-10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.					



Print pockets

Print Pockets	Price	Description	Wt. [lb]
WAPPL0606	\$19.00	6.0in [152mm]x6.0in [152mm] plastic print pocket can be placed anywhere within enclosure using 2-way adhesive tape flanges. Color: white	0.5
WAPPL0810	\$30.50	8"x10" plastic print pocket can be placed anywhere within enclosure using 2-way adhesive tape flanges. Color: white	



WAPPL0810

Touch-up paint



WAGSE

Touch-Up Paint	Price	Description	Wt. [lb]
WAGSE	\$23.50	ANSI-61 gray satin enamel in 12 oz. spray can. Use on existing enclosure and subpanel finishes.	1.5