

# Subpanels and Swing-out Panels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures



| Subpanels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures |                                  |                                   |                                  |                                   |
|-------------------------------------------------------------------------|----------------------------------|-----------------------------------|----------------------------------|-----------------------------------|
| Enclosures                                                              | Full Height Subpanels            |                                   | Half Height Subpanels            |                                   |
|                                                                         | Painted Steel                    | Galvanized                        | Painted Steel                    | Galvanized                        |
| <a href="#"><u>WRD602418FS4</u></a>                                     | <a href="#"><u>WA60P24F1</u></a> | —                                 | <a href="#"><u>WA60P24F2</u></a> | —                                 |
| <a href="#"><u>WRD603624FS4</u></a>                                     | <a href="#"><u>WA60P36F1</u></a> | <a href="#"><u>WA60P36F1G</u></a> | <a href="#"><u>WA60P36F2</u></a> | <a href="#"><u>WA60P36F2G</u></a> |
| <a href="#"><u>WRD722418FS4</u></a>                                     | <a href="#"><u>WA72P24F1</u></a> | <a href="#"><u>WA72P24F1G</u></a> | —                                | —                                 |
| <a href="#"><u>WRD723018FS4</u></a>                                     | <a href="#"><u>WA72P30F1</u></a> | <a href="#"><u>WA72P30F1G</u></a> | —                                | —                                 |
| <a href="#"><u>WRD723618FS4</u></a>                                     | <a href="#"><u>WA72P36F1</u></a> | <a href="#"><u>WA72P36F1G</u></a> | —                                | —                                 |
| <a href="#"><u>WRD723630FS4</u></a>                                     | <a href="#"><u>WA72P36F1</u></a> | <a href="#"><u>WA72P36F1G</u></a> | —                                | —                                 |
| <a href="#"><u>WRD723636FS4</u></a>                                     | <a href="#"><u>WA72P36F1</u></a> | <a href="#"><u>WA72P36F1G</u></a> | —                                | —                                 |
| <a href="#"><u>WRD903620FS4</u></a>                                     | <a href="#"><u>WA90P36F1</u></a> | <a href="#"><u>WA90P36F1G</u></a> | —                                | —                                 |
| <a href="#"><u>WRD903636FS4</u></a>                                     | <a href="#"><u>WA90P36F1</u></a> | <a href="#"><u>WA90P36F1G</u></a> | —                                | —                                 |


# Subpanels and Swing-out Panels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures



## Side-Mount Panels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures

| Enclosures                          | Side-Mount Panels                |                                  |
|-------------------------------------|----------------------------------|----------------------------------|
|                                     | Painted Steel                    |                                  |
| <u><a href="#">WRD722418FS4</a></u> | <u><a href="#">WA72SMP14</a></u> |                                  |
| <u><a href="#">WRD723018FS4</a></u> | <u><a href="#">WA72SMP14</a></u> |                                  |
| <u><a href="#">WRD723618FS4</a></u> | <u><a href="#">WA72SMP14</a></u> |                                  |
| <u><a href="#">WRD723630FS4</a></u> | <u><a href="#">WA72SMP14</a></u> | <u><a href="#">WA72SMP20</a></u> |
| <u><a href="#">WRD723636FS4</a></u> | <u><a href="#">WA72SMP14</a></u> | <u><a href="#">WA72SMP20</a></u> |

# WA-F1/F2 Panels for Single-Door Freestanding Enclosures

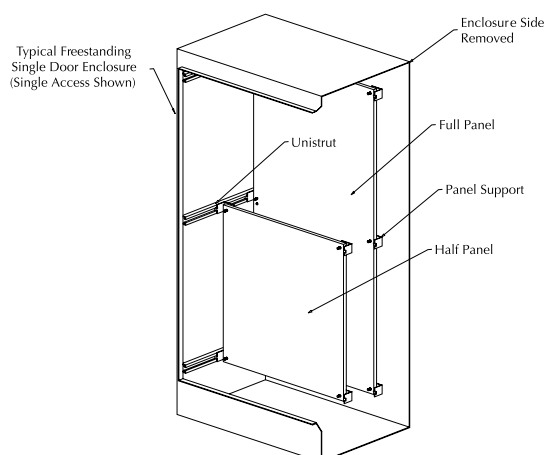

## Description

- Panels for single-door single-access and single-door dual-access, freestanding NEMA 12, and freestanding NEMA 4 enclosures
- Can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories

| Painted Steel                    | Price    | Galvanized                        | Price    | Steel Gauge | Panel Size HxW             | Subpanel Type |
|----------------------------------|----------|-----------------------------------|----------|-------------|----------------------------|---------------|
| <a href="#"><u>WA60P24F1</u></a> | \$342.00 | —                                 | —        | 12          | 48.00 x 20.00 [1219 x 508] | Full          |
| <a href="#"><u>WA60P24F2</u></a> | \$246.00 | —                                 | —        | 10          | 24.88 x 20.00 [632 x 508]  | Half          |
| <a href="#"><u>WA60P36F1</u></a> | \$441.00 | <a href="#"><u>WA60P36F1G</u></a> | \$441.00 | 12          | 48.00 x 32.00 [1219 x 813] | Full          |
| <a href="#"><u>WA60P36F2</u></a> | \$278.00 | <a href="#"><u>WA60P36F2G</u></a> | \$278.00 | 12          | 24.88 x 32.00 [632 x 813]  | Half          |
| <a href="#"><u>WA72P24F1</u></a> | \$383.00 | <a href="#"><u>WA72P24F1G</u></a> | \$383.00 | 12          | 60.00 x 20.00 [1524 x 508] | Full          |
| <a href="#"><u>WA72P30F1</u></a> | \$445.00 | <a href="#"><u>WA72P30F1G</u></a> | \$482.00 | 12          | 60.00 x 26.00 [1524 x 660] | Full          |
| <a href="#"><u>WA72P36F1</u></a> | \$507.00 | <a href="#"><u>WA72P36F1G</u></a> | \$507.00 | 12          | 60.00 x 32.00 [1524 x 813] | Full          |
| <a href="#"><u>WA90P24F1</u></a> | \$445.00 | <a href="#"><u>WA90P24F1G</u></a> | \$445.00 | 12          | 78.00 x 20.00 [1981 x 508] | Full          |
| <a href="#"><u>WA90P36F1</u></a> | \$607.00 | <a href="#"><u>WA90P36F1G</u></a> | \$607.00 | 12          | 78.00 x 32.00 [1981 x 813] | Full          |


Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.


If used in a two-door enclosure, a center panel support must be ordered.

Suffix F1= full panel, F2 = half panel

## Dimensions

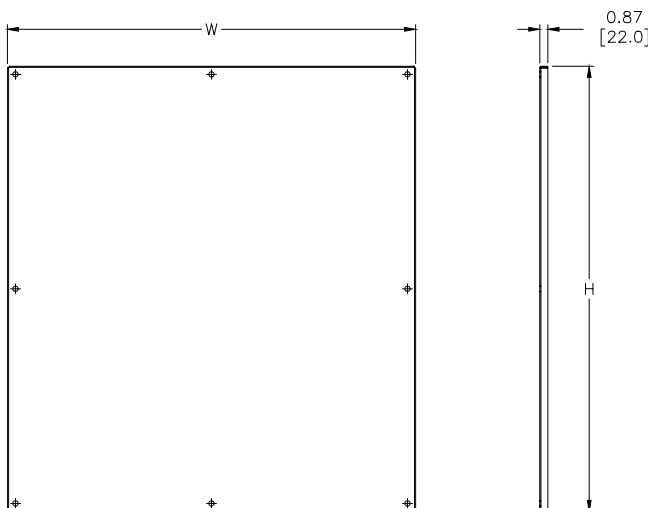

# WA-SMP Series Side-Mount Panels for Freestanding Enclosures

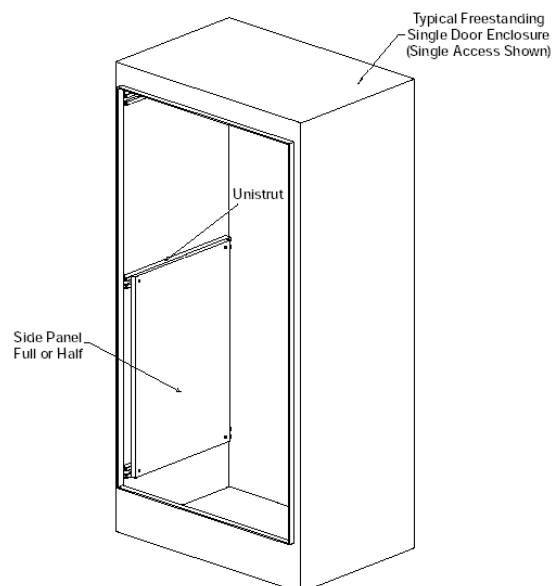

## Description

- Panels for freestanding NEMA 4 and freestanding NEMA 12 enclosures
- Panels are fabricated from 12-gauge steel
- They provide extra mounting space on the sides of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels attach securely to mounting channels

| Painted Steel    | Price    | Panel Size AxB             |
|------------------|----------|----------------------------|
| <b>WA72SMP14</b> | \$236.00 | 60.00 x 14.00 [1524 x 356] |
| <b>WA72SMP20</b> | \$288.00 | 60.00 x 20.00 [1524 x 508] |

Note: Dimensions in inches [millimeters].

## Dimensions

