

Subpanels and Swing-out Panels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures



Subpanels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures				
Enclosures	Full Height Subpanels		Half Height Subpanels	
	Painted Steel	Galvanized	Painted Steel	Galvanized
<u>WRD602418FS4</u>	<u>WA60P24F1</u>	—	<u>WA60P24F2</u>	—
<u>WRD603624FS4</u>	<u>WA60P36F1</u>	<u>WA60P36F1G</u>	<u>WA60P36F2</u>	<u>WA60P36F2G</u>
<u>WRD722418FS4</u>	<u>WA72P24F1</u>	<u>WA72P24F1G</u>	—	—
<u>WRD723018FS4</u>	<u>WA72P30F1</u>	<u>WA72P30F1G</u>	—	—
<u>WRD723618FS4</u>	<u>WA72P36F1</u>	<u>WA72P36F1G</u>	—	—
<u>WRD723630FS4</u>	<u>WA72P36F1</u>	<u>WA72P36F1G</u>	—	—
<u>WRD723636FS4</u>	<u>WA72P36F1</u>	<u>WA72P36F1G</u>	—	—
<u>WRD903620FS4</u>	<u>WA90P36F1</u>	<u>WA90P36F1G</u>	—	—
<u>WRD903636FS4</u>	<u>WA90P36F1</u>	<u>WA90P36F1G</u>	—	—


Subpanels and Swing-out Panels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures



Side-Mount Panels for NEMA 3, 3R, 4, and 12 Freestanding Single-Door Enclosures

Enclosures	Side-Mount Panels	
	Painted Steel	
<u>WRD722418FS4</u>	<u>WA72SMP14</u>	
<u>WRD723018FS4</u>	<u>WA72SMP14</u>	
<u>WRD723618FS4</u>	<u>WA72SMP14</u>	
<u>WRD723630FS4</u>	<u>WA72SMP14</u>	<u>WA72SMP20</u>
<u>WRD723636FS4</u>	<u>WA72SMP14</u>	<u>WA72SMP20</u>

WA-F1/F2 Panels for Single-Door Freestanding Enclosures

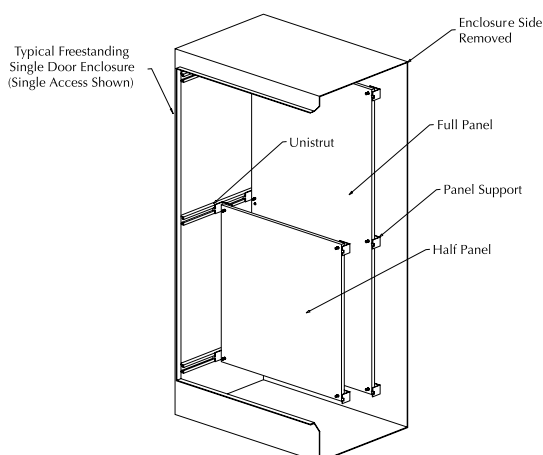

Description

- Panels for single-door single-access and single-door dual-access, freestanding NEMA 12, and freestanding NEMA 4 enclosures
- Can be positioned anywhere along horizontal depth-wise mounting channels
- Half-height panels can be located in the upper or lower portion of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- May be used in two-door enclosures along with other freestanding accessories

Painted Steel	Price	Galvanized	Price	Steel Gauge	Panel Size HxW	Subpanel Type
<u>WA60P24F1</u>	\$359.00	—	—	12	48.00 x 20.00 [1219 x 508]	Full
<u>WA60P24F2</u>	\$259.00	—	—	10	24.88 x 20.00 [632 x 508]	Half
<u>WA60P36F1</u>	\$463.00	<u>WA60P36F1G</u>	\$463.00	12	48.00 x 32.00 [1219 x 813]	Full
<u>WA60P36F2</u>	\$292.00	<u>WA60P36F2G</u>	\$292.00	12	24.88 x 32.00 [632 x 813]	Half
<u>WA72P24F1</u>	\$402.00	<u>WA72P24F1G</u>	\$402.00	12	60.00 x 20.00 [1524 x 508]	Full
<u>WA72P30F1</u>	\$468.00	<u>WA72P30F1G</u>	\$506.00	12	60.00 x 26.00 [1524 x 660]	Full
<u>WA72P36F1</u>	\$533.00	<u>WA72P36F1G</u>	\$533.00	12	60.00 x 32.00 [1524 x 813]	Full
<u>WA90P24F1</u>	\$468.00	<u>WA90P24F1G</u>	\$468.00	12	78.00 x 20.00 [1981 x 508]	Full
<u>WA90P36F1</u>	\$637.00	<u>WA90P36F1G</u>	\$637.00	12	78.00 x 32.00 [1981 x 813]	Full


Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.


If used in a two-door enclosure, a center panel support must be ordered.

Suffix F1= full panel, F2 = half panel

Dimensions

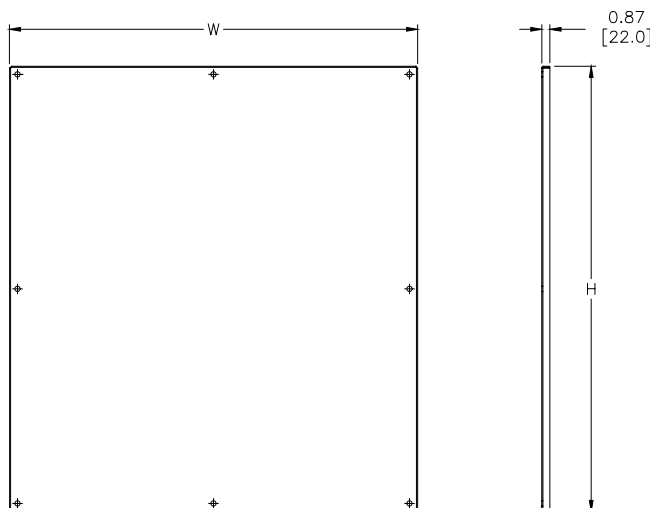

WA-SMP Series Side-Mount Panels for Freestanding Enclosures

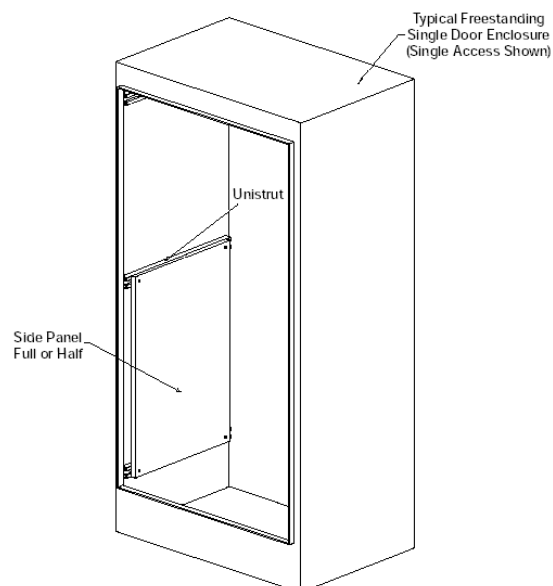

Description

- Panels for freestanding NEMA 4 and freestanding NEMA 12 enclosures
- Panels are fabricated from 12-gauge steel
- They provide extra mounting space on the sides of the enclosure
- Mounting hardware is furnished with each panel
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels attach securely to mounting channels

Painted Steel	Price	Panel Size AxB
WA72SMP14	\$248.00	60.00 x 14.00 [1524 x 356]
WA72SMP20	\$303.00	60.00 x 20.00 [1524 x 508]

Note: Dimensions in inches [millimeters].

Dimensions

