


# Ultimate Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount with Removable Gland Plate

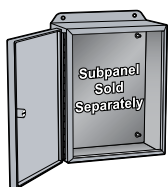

N412121206CGP



## Applications

Designed to house and protect electrical and electronic components from harsh, dirty environments. Features a removable gland plate on the bottom of the enclosure. The fully gasketed plate can be removed for easy drilling and hole tapping without disturbing the integrity of the enclosure. For use in installations where dust, dirt, water or other contaminants are present. Streamlined styling, flush latching, and an attractive, durable finish complement any high-tech electronic equipment. Removable, interchangeable doors feature concealed hinges. 1/4-turn semi-flush latch holds door securely closed.

## Construction

- Bodies, doors and gland plates fabricated from carbon steel
- Polyurethane poured-in-place gasket
- Collar studs provided for mounting optional subpanels
- Grounding provisions provided
- Continuous welded seams
- Concealed hinges
- Optional subpanels must be ordered separately
- Mounting holes in rear of enclosure body
- 1/4-turn semi-flush latch
- Uses N41214 series latches

## Finish

- ANSI 61 gray light-textured polyester powder coat, interior and exterior

## Listings

- cULus File E64791
- UL 508A 3R, 4, 12, and 13
- Meets NEMA/EEMAC 3R, 4, 12, and 13 requirements
- N412MFK mounting feet are required to maintain UL external mounting requirements

Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)



## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1-10 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Ultimate Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount with Removable Gland Plate

Part Number	Price	Enclosure Size HxWxD	Painted Steel Subpanel	304 Stainless Steel	Swing-Out Panel
<a href="#">N412121206CGP</a>	\$477.00	12.20 x 12.00 x 6.92 [310 x 305 x 176]	<a href="#">NP1212C</a>	—	<a href="#">HFWNSP1212C</a>
<a href="#">N412161206CGP</a>	\$509.00	16.20 x 12.00 x 6.92 [411 x 305 x 176]	<a href="#">NP1612C</a>	<a href="#">NP1612SSC</a>	<a href="#">HFWNSP1612C</a>
<a href="#">N412161606CGP</a>	\$548.00	16.20 x 16.00 x 6.92 [411 x 406 x 176]	<a href="#">NP1616C</a>	<a href="#">NP1616SSC</a>	<a href="#">HFWNSP1616C</a>
<a href="#">N412161608CGP</a>	\$577.00	16.20 x 16.00 x 8.92 [411 x 406 x 227]	<a href="#">NP1616C</a>	<a href="#">NP1616SSC</a>	<a href="#">HFWNSP1616C</a>
<a href="#">N412201606CGP</a>	\$588.00	20.20 x 16.00 x 6.92 [513 x 406 x 176]	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">HFWNSP2016C</a>
<a href="#">N412201608CGP</a>	\$619.00	20.20 x 16.00 x 8.92 [513 x 406 x 227]	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">HFWNSP2016C</a>
<a href="#">N412202008CGP</a>	\$670.00	20.20 x 20.00 x 8.92 [513 x 508 x 227]	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">HFWNSP2020C</a>
<a href="#">N412242408CGP</a>	\$831.00	24.20 x 24.00 x 8.92 [615 x 610 x 227]	<a href="#">NP2424C</a>	<a href="#">NP2424SSC</a>	<a href="#">HFWNSP2424C</a>
<a href="#">N412242410CGP</a>	\$808.00	24.20 x 24.00 x 10.92 [615 x 610 x 277]	<a href="#">NP2424C</a>	<a href="#">NP2424SSC</a>	<a href="#">HFWNSP2424C</a>
<a href="#">N412242412CGP</a>	\$863.00	24.20 x 24.00 x 12.92 [615 x 610 x 328]	<a href="#">NP2424C</a>	<a href="#">NP2424SSC</a>	<a href="#">HFWNSP2424C</a>
<a href="#">N412302408CGP</a>	\$863.00	30.20 x 24.00 x 8.92 [767 x 610 x 227]	<a href="#">NP2424C</a>	<a href="#">NP3024SSC</a>	<a href="#">HFWNSP3024C</a>
<a href="#">N412302410CGP</a>	\$897.00	30.20 x 24.00 x 10.92 [767 x 610 x 277]	<a href="#">NP3024C</a>	<a href="#">NP3024SSC</a>	<a href="#">HFWNSP3024C</a>
<a href="#">N412302412CGP</a>	\$959.00	30.20 x 24.00 x 12.92 [767 x 610 x 328]	<a href="#">NP3024C</a>	<a href="#">NP3024SSC</a>	<a href="#">HFWNSP3024C</a>
<a href="#">N412362408CGP</a>	\$973.00	36.20 x 24.00 x 8.92 [919 x 610 x 227]	<a href="#">NP3024C</a>	<a href="#">NP3624SSC</a>	<a href="#">HFWNSP3624C</a>
<a href="#">N412362410CGP</a>	\$996.00	36.20 x 24.00 x 10.92 [919 x 610 x 277]	<a href="#">NP3624C</a>	<a href="#">NP3624SSC</a>	<a href="#">HFWNSP3624C</a>
<a href="#">N412362412CGP</a>	\$1,086.00	36.20 x 24.00 x 12.92 [919 x 610 x 328]	<a href="#">NP3624C</a>	<a href="#">NP3624SSC</a>	<a href="#">HFWNSP3624C</a>
<a href="#">N412363012CGP</a>	\$1,215.00	36.20 x 30.00 x 12.92 [919 x 762 x 328]	<a href="#">NP3630C</a>	<a href="#">NP3630SSC</a>	<a href="#">HFWNSP3630C</a>
<a href="#">N412363612CGP</a>	\$1,312.00	36.20 x 36.00 x 12.92 [919 x 914 x 328]	<a href="#">NP3636C</a>	<a href="#">NP3636SSC</a>	<a href="#">HFWNSP3636C</a>

Notes: Subpanels must be ordered separately.

Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawings.

[www.automationdirect.com](http://www.automationdirect.com)

# Ultimate Series NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount with Removable Gland Plate



## Dimensions

