

# Ultimate Series NEMA 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



## Applications

The Wiegmann N412-SS stainless steel series, with its streamlined design, is a perfect fit for mounting electrical or high-tech electronic equipment in a variety of indoor and outdoor settings. It is typically used in the following areas where corrosion-resistant protection is needed: food processing plants, pharmaceutical manufacturing facilities, petrochemical plants, pulp and paper processing, and waste water treatment facilities.



## Construction

- Bodies and doors fabricated from 14- or 16-gauge type 304 or 316L stainless steel
- Doors are sealed with poured-in-place polyurethane gasket
- Concealed hinges
- Increased tub openings to accommodate larger size (optional) subpanels
- Collar studs for mounting optional subpanels
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Swing-out panel kits WAJCDFK and WANADFK will not work with these enclosures
- Doors are interchangeable and easily removable (open to 90° to remove door)
- 1/4 turn, semi-flush oil-tight latches supplied to hold door securely closed
- Mounting holes in rear of enclosure
- Optional N412MFKSS mounting foot kit is required to maintain the NEMA 4, 4X, 12, and 13 ratings
- Mounting foot kit must be ordered separately
- Uses N41214\_SS series latches

## Finish

- All exterior surfaces have a smooth-grained finish
- Painted steel subpanels are painted white polyester powder over phosphatized surfaces
- Galvanized and stainless subpanels are a conductive finish (unpainted)

## Listings

- UL 508, 4, 4X, 12, and 13 [UL file E64791]
- Meets NEMA/EEMAC 4, 4X, 12, and 13 requirements
- Wall mounting brackets required to maintain UL/CSA external mounting requirements



Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)

Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1-10 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.					

Ultimate Series NEMA 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount								
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Swing-Out Panel
<a href="#">N412121206SSC</a>	\$558.00	—	—	12.00 x 12.00 x 6.92 [305 x 305 x 176]	16	<a href="#">NP1212C</a>	—	<a href="#">HFWNSP1212C</a>
<a href="#">N412161206SSC</a>	\$612.00	—	—	16.00 x 12.00 x 6.92 [406 x 305 x 176]	16	<a href="#">NP1612C</a>	<a href="#">NP1612SSC</a>	<a href="#">HFWNSP1612C</a>
<a href="#">N412161208SSC</a>	\$646.00	—	—	16.00 x 12.00 x 8.92 [406 x 305 x 227]	16	<a href="#">NP1612C</a>	<a href="#">NP1612SSC</a>	<a href="#">HFWNSP1612C</a>
<a href="#">N412161210SSC</a>	\$691.00	<a href="#">N412161210SSAC</a>	\$1,294.00	16.00 x 12.00 x 10.92 [406 x 305 x 277]	16	<a href="#">NP1612C</a>	<a href="#">NP1612SSC</a>	<a href="#">HFWNSP1612C</a>
<a href="#">N412161606SSC</a>	\$678.00	—	—	16.00 x 16.00 x 6.92 [406 x 406 x 176]	16	<a href="#">NP1616C</a>	<a href="#">NP1616SSC</a>	<a href="#">HFWNSP1616C</a>
<a href="#">N412161608SSC</a>	\$735.00	—	—	16.00 x 16.00 x 8.92 [406 x 406 x 227]	16	<a href="#">NP1616C</a>	<a href="#">NP1616SSC</a>	<a href="#">HFWNSP1616C</a>
<a href="#">N412161610SSC</a>	\$780.00	—	—	16.00 x 16.00 x 10.92 [406 x 406 x 277]	16	<a href="#">NP1616C</a>	<a href="#">NP1616SSC</a>	<a href="#">HFWNSP1616C</a>
<a href="#">N412162008SSC</a>	\$807.00	<a href="#">N412162008SSAC</a>	\$1,489.00	16.00 x 20.00 x 8.92 [406 x 508 x 227]	16	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">HFWNSP1620C</a>
<a href="#">N412162010SSC</a>	\$907.00	—	—	16.00 x 20.00 x 10.92 [406 x 508 x 277]	16	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">HFWNSP1620C</a>
<a href="#">N412201606SSC</a>	\$766.00	—	—	20.00 x 16.00 x 6.92 [508 x 406 x 176]	16	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">HFWNSP2016C</a>

Notes: Subpanels must be ordered separately.  
 Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.

Table continued on next page

# Ultimate Series NEMA 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Shipping Schedule					
Same day	1 - 5 days	1 - 7 days	1-10 days	1 - 15 days	1 - 20 days

Color indicates shipping lead time in business days.

Table continued from previous page

Ultimate Series NEMA 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount								
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Swing-Out Panel
<a href="#">N412201608SSC</a>	\$814.00	-	-	20.00 x 16.00 x 8.92 [508 x 406 x 227]	16	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">HFWNSP2016C</a>
<a href="#">N412201610SSC</a>	\$830.00	-	-	20.00 x 16.00 x 10.92 [508 x 406 x 277]	16	<a href="#">NP2016C</a>	<a href="#">NP2016SSC</a>	<a href="#">HFWNSP2016C</a>
<a href="#">N412202006SSC</a>	\$846.00	-	-	20.00 x 20.00 x 6.92 [508 x 508 x 176]	16	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">HFWNSP2020C</a>
<a href="#">N412202008SSC</a>	\$883.00	-	-	20.00 x 20.00 x 8.92 [508 x 508 x 227]	16	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">HFWNSP2020C</a>
<a href="#">N412202010SSC</a>	\$927.00	-	-	20.00 x 20.00 x 10.92 [508 x 508 x 277]	16	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">HFWNSP2020C</a>
<a href="#">N412202012SSC</a>	\$1,006.00	-	-	20.00 x 20.00 x 12.92 [508 x 508 x 328]	16	<a href="#">NP2020C</a>	<a href="#">NP2020SSC</a>	<a href="#">HFWNSP2020C</a>
<a href="#">N412241608SSC</a>	\$870.00	-	-	24.00 x 16.00 x 8.92 [610 x 406 x 227]	16	<a href="#">NP2416C</a>	<a href="#">NP2416SSC</a>	<a href="#">HFWNSP2416C</a>
<a href="#">N412241610SSC</a>	\$914.00	-	-	24.00 x 16.00 x 10.92 [610 x 406 x 277]	16	<a href="#">NP2416C</a>	<a href="#">NP2416SSC</a>	<a href="#">HFWNSP2416C</a>
<a href="#">N412242008SSC</a>	\$966.00	<a href="#">N412242008SSAC</a>	\$1,638.00	24.00 x 20.00 x 8.92 [610 x 508 x 227]	16	<a href="#">NP2420C</a>	<a href="#">NP2420SSC</a>	<a href="#">HFWNSP2420C</a>
<a href="#">N412242010SSC</a>	\$1,015.00	-	-	24.00 x 20.00 x 10.92 [610 x 508 x 277]	16	<a href="#">NP2420C</a>	<a href="#">NP2420SSC</a>	<a href="#">HFWNSP2420C</a>
<a href="#">N412242408SSC</a>	\$1,063.00	-	-	24.00 x 24.00 x 8.92 [610 x 610 x 227]	14	<a href="#">NP2424C</a>	<a href="#">NP2424SSC</a>	<a href="#">HFWNSP2424C</a>
<a href="#">N412242410SSC</a>	\$1,149.00	<a href="#">N412242410SSAC</a>	\$1,881.00	24.00 x 24.00 x 10.92 [610 x 610 x 277]	14	<a href="#">NP2424C</a>	<a href="#">NP2424SSC</a>	<a href="#">HFWNSP2424C</a>
<a href="#">N412242412SSC</a>	\$1,185.00	<a href="#">N412242412SSAC</a>	\$2,235.00	24.00 x 24.00 x 12.92 [610 x 610 x 328]	14	<a href="#">NP2424C</a>	<a href="#">NP2424SSC</a>	<a href="#">HFWNSP2424C</a>
<a href="#">N412302408SSC</a>	\$1,209.00	<a href="#">N412302408SSAC</a>	\$2,244.00	30.00 x 24.00 x 8.92 [762 x 610 x 227]	14	<a href="#">NP3024C</a>	<a href="#">NP3024SSC</a>	<a href="#">HFWNSP3024C</a>
<a href="#">N412302410SSC</a>	\$1,293.00	-	-	30.00 x 24.00 x 10.92 [762 x 610 x 277]	14	<a href="#">NP3024C</a>	<a href="#">NP3024SSC</a>	<a href="#">HFWNSP3024C</a>
<a href="#">N412302412SSC</a>	\$1,358.00	-	-	30.00 x 24.00 x 12.92 [762 x 610 x 328]	14	<a href="#">NP3024C</a>	<a href="#">NP3024SSC</a>	<a href="#">HFWNSP3024C</a>
<a href="#">N412303008SSC</a>	\$1,420.00	-	-	30.00 x 30.00 x 8.92 [762 x 762 x 227]	14	<a href="#">NP3030C</a>	<a href="#">NP3030SSC</a>	<a href="#">HFWNSP3030C</a>
<a href="#">N412303010SSC</a>	\$1,492.00	<a href="#">N412303010SSAC</a>	\$2,620.00	30.00 x 30.00 x 10.92 [762 x 762 x 277]	14	<a href="#">NP3030C</a>	<a href="#">NP3030SSC</a>	<a href="#">HFWNSP3030C</a>
<a href="#">N412362408SSC</a>	\$1,477.00	-	-	36.00 x 24.00 x 8.92 [914 x 610 x 227]	14	<a href="#">NP3624C</a>	<a href="#">NP3624SSC</a>	<a href="#">HFWNSP3624C</a>
<a href="#">N412362410SSC</a>	\$1,461.00	-	-	36.00 x 24.00 x 10.92 [914 x 610 x 277]	14	<a href="#">NP3624C</a>	<a href="#">NP3624SSC</a>	<a href="#">HFWNSP3624C</a>
<a href="#">N412362412SSC</a>	\$1,515.00	-	-	36.00 x 24.00 x 12.92 [914 x 610 x 328]	14	<a href="#">NP3624C</a>	<a href="#">NP3624SSC</a>	<a href="#">HFWNSP3624C</a>
<a href="#">N412363008SSC</a>	\$1,694.00	-	-	36.00 x 30.00 x 8.92 [914 x 762 x 227]	14	<a href="#">NP3630C</a>	<a href="#">NP3630SSC</a>	<a href="#">HFWNSP3630C</a>
<a href="#">N412363010SSC</a>	\$1,903.00	-	-	36.00 x 30.00 x 10.92 [914 x 762 x 277]	14	<a href="#">NP3630C</a>	<a href="#">NP3630SSC</a>	<a href="#">HFWNSP3630C</a>
<a href="#">N412363012SSC</a>	\$1,811.00	-	-	36.00 x 30.00 x 12.92 [914 x 762 x 328]	14	<a href="#">NP3630C</a>	<a href="#">NP3630SSC</a>	<a href="#">HFWNSP3630C</a>

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

Table continued on next page

# Ultimate Series NEMA 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount




Shipping Schedule				
Same day	1 - 5 days	1 - 7 days	1 - 15 days	1 - 20 days
Color indicates shipping lead time in business days.				

Table continued from previous page

Ultimate Series NEMA 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount								
304 Stainless Steel	Price	316L Stainless Steel	Price	Enclosure Size HxWxD	Steel Gauge	Painted Steel Subpanel	Stainless Steel Subpanel	Swing-Out Panel
<a href="#">N412363610SSC</a>	\$1,828.00	-	-	36.00 x 36.00 x 10.92 [914 x 914 x 277]	14	<a href="#">NP3636C</a>	<a href="#">NP3636SSC</a>	<a href="#">HFWNSP3636C</a>
<a href="#">N412363612SSC</a>	\$1,966.00	<a href="#">N412363612SSAC</a>	\$3,632.00	36.00 x 36.00 x 12.92 [914 x 914 x 328]	14	<a href="#">NP3636C</a>	<a href="#">NP3636SSC</a>	<a href="#">HFWNSP3636C</a>
<a href="#">N412423610SSC</a>	\$2,050.00	-	-	42.00 x 36.00 x 10.92 [1067 x 914 x 277]	14	<a href="#">NP4236C</a>	<a href="#">NP4236SSC</a>	-
<a href="#">N412423612SSC</a>	\$2,181.00	-	-	42.00 x 36.00 x 12.92 [1067 x 914 x 328]	14	<a href="#">NP4236C</a>	<a href="#">NP4236SSC</a>	-
<a href="#">N412483610SSC</a>	\$2,438.00	-	-	48.00 x 36.00 x 10.92 [1219 x 914 x 277]	14	<a href="#">NP4836C</a>	<a href="#">NP4836SSC</a>	-
<a href="#">N412483612SSC</a>	\$2,445.00	-	-	48.00 x 36.00 x 12.92 [1219 x 914 x 328]	14	<a href="#">NP4836C</a>	<a href="#">NP4836SSC</a>	-
<a href="#">N412603610SSC</a>	\$2,865.00	-	-	60.00 x 36.00 x 10.92 [1524 x 914 x 277]	14	<a href="#">NP6036C</a>	<a href="#">NP6036SSC</a>	-
<a href="#">N412603612SSC</a>	\$3,080.00	-	-	60.00 x 36.00 x 12.92 [1524 x 914 x 328]	14	<a href="#">NP6036C</a>	<a href="#">NP6036SSC</a>	-

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

## Dimensions

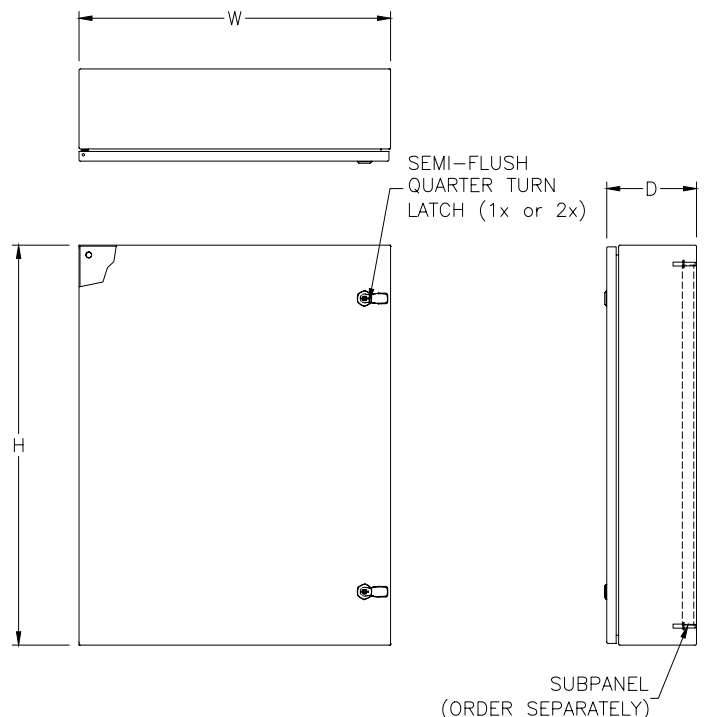

Notes: Enclosures include a 3-point latch when H=40 in [1016 mm] or more.  
Two hinges are provided when H<36 in [914 mm].  
Three hinges are provided when H=36 in [914 mm] or greater.  
Four hinges are provided when H=48 in [1219 mm] or greater.  
Enclosures smaller than 24 in [610 mm] have one latch.

# Enclosure Subpanels





## Subpanels for Ultimate Series Wall-Mount Enclosures

- 12-gauge steel
- Subpanels with dimensions 30 x 30 in [ 762 x 762 mm] and larger are flanged on all sides. Smaller subpanels are flanged on two sides
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Panels listed fit all styles of N412 Ultimate Series wall-mount enclosures, including slope top and disconnect enclosures

Note: NPxxxxC subpanels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Subpanel NP1212C will not fit enclosures N412121206 or N412121206SS.



## Dimensions

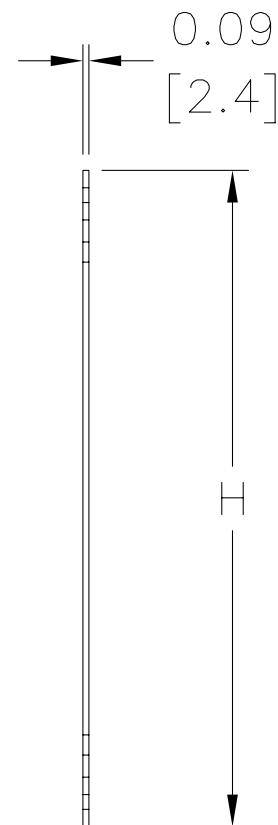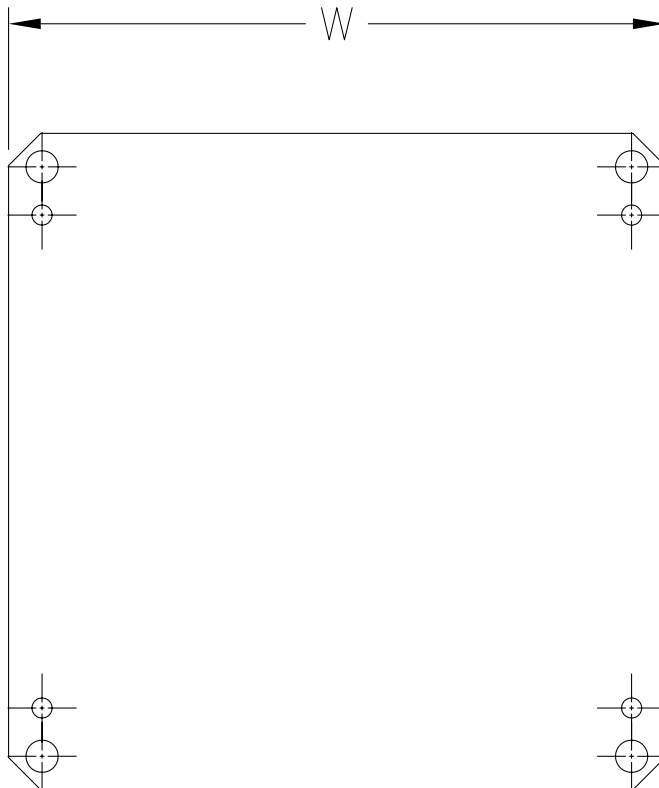

# Enclosure Subpanels



## Subpanels for Ultimate Series Wall-Mount Enclosures

### Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

### Subpanels for Ultimate Series Wall-Mount Enclosures


Painted Steel	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW*	Subpanel Size HxW
<a href="#">NP1212C</a>	\$15.50	—	—	12 x 12	10.20 x 10.20 [259 x 259]
<a href="#">NP1612C</a>	\$16.75	<a href="#">NP1612SSC</a>	\$87.00	16 x 12	14.20 x 10.20 [361 x 259]
<a href="#">NP1616C</a>	\$40.50	<a href="#">NP1616SSC</a>	\$106.00	16 x 16	14.20 x 14.20 [361 x 361]
<a href="#">NP2016C</a>	\$48.00	<a href="#">NP2016SSC</a>	\$128.00	16 x 20 20 x 16	18.20 x 14.20 [462 x 361]
<a href="#">NP2020C</a>	\$58.00	<a href="#">NP2020SSC</a>	\$165.00	20 x 20	18.20 x 18.20 [462 x 462]
<a href="#">NP2416C</a>	\$56.00	<a href="#">NP2416SSC</a>	\$159.00	24 x 16	22.20 x 14.20 [564 x 361]
<a href="#">NP2420C</a>	\$56.00	<a href="#">NP2420SSC</a>	\$200.00	24 x 20	22.20 x 18.20 [564 x 462]
<a href="#">NP2424C</a>	\$86.00	<a href="#">NP2424SSC</a>	\$233.00	24 x 24	22.20 x 22.20 [564 x 564]
<a href="#">NP3020C</a>	\$90.00	—	—	30 x 20	28.20 x 18.20 [716 x 462]
<a href="#">NP3024C</a>	\$105.00	<a href="#">NP3024SSC</a>	\$306.00	30 x 24	28.20 x 22.20 [716 x 564]
<a href="#">NP3030C</a>	\$147.00	<a href="#">NP3030SSC</a>	\$418.00	30 x 30	28.20 x 28.20 [716 x 716]
<a href="#">NP3624C</a>	\$125.00	<a href="#">NP3624SSC</a>	\$357.00	24 x 36 36 x 24	34.20 x 22.20 [869 x 564]
<a href="#">NP3630C</a>	\$167.00	<a href="#">NP3630SSC</a>	\$443.00	36 x 30	34.20 x 28.20 [869 x 716]
<a href="#">NP3636C</a>	\$196.00	<a href="#">NP3636SSC</a>	\$535.00	36 x 36	34.20 x 34.20 [869 x 869]
<a href="#">NP4224C</a>	\$244.00	—	—	24 x 42	40.20 x 22.20 [1021 x 564]
<a href="#">NP4024C</a>	\$151.00	—	—	40 x 24	38.20 x 22.20 [970 x 564]
<a href="#">NP4242C</a>	\$418.00	—	—	42 x 42	40.20 x 40.20 [1021 x 1021]
<a href="#">NP4230C</a>	\$225.00	—	—	30 x 42 42 x 32	40.20 x 28.20 [1021 x 716]
<a href="#">NP4236C</a>	\$225.00	<a href="#">NP4236SSC</a>	\$676.00	36 x 42 42 x 36	40.20 x 34.20 [1021 x 869]
<a href="#">NP4824C</a>	\$163.00	—	—	24 x 48 48 x 24	46.20 x 22.20 [1173 x 564]
<a href="#">NP4830C</a>	\$336.00	—	—	30 x 48	46.20 x 28.20 [1173 x 716]
<a href="#">NP4842C</a>	\$562.00	—	—	42 x 48	46.20 x 40.20 [1173 x 1021]
<a href="#">NP4836C</a>	\$254.00	<a href="#">NP4836SSC</a>	\$676.00	36 x 48 48 x 36	46.20 x 34.20 [1173 x 869]
<a href="#">NP4848C</a>	\$625.00	—	—	48 x 48	46.20 x 46.20 [1173 x 1173]
<a href="#">NP6030C</a>	\$446.00	—	—	30 x 60	58.20 x 28.20 [1478 x 716]
<a href="#">NP6036C</a>	\$313.00	<a href="#">NP6036SSC</a>	\$965.00	36 x 30 60 x 36	58.20 x 34.20 [1478 x 869]
<a href="#">NP6042C</a>	\$627.00	—	—	42 x 60	58.20 x 40.20 [1478 x 1021]

Notes: Dimensions in inches [millimeters].

Letters in table correspond to letters on dimensional drawing.

Disconnect enclosures will be up to 2 in [51 mm] wider than width dimensions in this table.

# Swing-Out Panels for Ultimate Series Enclosures

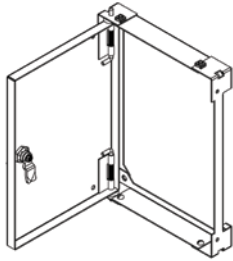

**For N412 Ultimate Series Wall-Mount Enclosures except N412-1PTC, -3PTC, -SS1PTC, -SS3PTC, -SSA1PTC, and -SSA3PTC**

- Maximum swing 107°
- Convenient access to sub enclosure is provided via 1/4 turn pull-tab
- On solid doors, the clearance from the swing panel face to the interior door face is 1.25in [31.8mm] on window doors (when the door is closed)
- The kit includes the swing panel, brackets and hardware necessary for a tub flange install. Swing out panels meet 1 with enclosure door open
- Painted steel subpanels are painted white polyester powder over phosphated surfaces
- Fabricated from 14-gauge steel
- Mounting hardware is furnished with each panel

Note: HFWNSPxxxxC swing-out panels will not fit in older NEMA 4/12 enclosures (purchased prior to 3-23-05) that do not have a C suffix. For example: Swing-out panel HFWNSP1212C will not fit enclosures N41212126 or N412121206SS.

## Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

## Swing-Out Panels for Ultimate Series Enclosures

Part Number	Price	Panel Size CxE	Overall Dimensions HxW	Enclosure Nominal Size
<a href="#">HFWNSP1212C</a>	\$128.00	9.75 x 9.75 [248 x 248]	10.50 x 10.62 [267 x 270]	12 x 12
<a href="#">HFWNSP1612C</a>	\$133.00	13.75 x 9.75 [349 x 248]	14.50 x 10.62 [368 x 270]	16 x 12
<a href="#">HFWNSP1616C</a>	\$140.00	13.75 x 13.75 [349 x 349]	14.50 x 14.62 [368 x 37]	16 x 16
<a href="#">HFWNSP1620C</a>	\$160.00	13.75 x 17.75 [349 x 451]	14.50 x 18.62 [368 x 473]	16 x 20
<a href="#">HFWNSP2016C</a>	\$147.00	17.75 x 13.75 [451 x 349]	18.50 x 14.62 [470 x 371]	20 x 16
<a href="#">HFWNSP2020C</a>	\$156.00	17.75 x 17.75 [451 x 451]	18.50 x 18.62 [470 x 473]	20 x 20
<a href="#">HFWNSP2024C</a>	\$179.00	17.75 x 21.75 [451 x 552]	18.50 x 22.62 [470 x 575]	20 x 24
<a href="#">HFWNSP2416C</a>	\$167.00	21.75 x 13.75 [552 x 349]	22.50 x 14.62 [572 x 371]	24 x 16
<a href="#">HFWNSP2420C</a>	\$165.00	21.75 x 17.75 [552 x 451]	22.50 x 18.62 [572 x 473]	24 x 20
<a href="#">HFWNSP2424C</a>	\$176.00	21.75 x 21.75 [552 x 552]	22.50 x 22.62 [572 x 575]	24 x 24
<a href="#">HFWNSP3020C</a>	\$194.00	27.75 x 17.75 [705 x 451]	28.50 x 18.62 [724 x 473]	30 x 20
<a href="#">HFWNSP3024C</a>	\$192.00	27.75 x 21.75 [705 x 552]	28.50 x 22.62 [724 x 575]	30 x 24
<a href="#">HFWNSP3030C</a>	\$212.00	27.75 x 27.75 [705 x 705]	28.50 x 28.62 [724 x 727]	30 x 30
<a href="#">HFWNSP3624C</a>	\$208.00	33.75 x 21.75 [857 x 552]	34.50 x 22.62 [876 x 575]	36 x 24
<a href="#">HFWNSP3630C</a>	\$232.00	33.75 x 27.75 [857 x 705]	34.50 x 28.62 [876 x 727]	36 x 30
<a href="#">HFWNSP3636C</a>	\$256.00	33.75 x 33.75 [857 x 857]	34.50 x 34.62 [876 x 879]	36 x 36

Notes: Dimensions in inches [millimeters].  
 Letters in table correspond to letters on dimensional drawings.  
 If used in a two-door enclosure, a center panel support must be ordered.

## Dimensions

