

# 22mm Pushbutton NEMA 4, 4X, 12, and 13 Stainless Steel Wall-Mount



PBGX2SS

## Applications

Designed to hold all standard 22mm brands of miniature oil-tight pushbuttons, switches and pilot lights. Provide protection from dirt, dust, oil and water.

## Construction

- Fabricated from 304 or 316 stainless steel
- Closed-cell oil-resistant neoprene gasket
- Continuously-welded seams ground smooth
- External mounting feet, top and bottom of enclosure
- Captivated cover screws thread into sealed wells
- Standard "4-way" miniature pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights
- Enclosures with 6 or more holes have internal detachable hinges to hold cover open during wiring, yet permit quick removal
- Grounding provisions provided

## Finish

- Smooth-grained finish

## Listings

- UL 508A, Type 4, 4X, 12, 13 [File E64791]
- NEMA Type 4, 4X, 12, and 13
- cULus Certified Type 4, 4X, 12, and 13
- IEC 60529, IP66



## 22mm Pushbutton NEMA 4, 4X, 12, and 13 Wall-Mount


304 Stainless Steel	Price	316 Stainless Steel	Price	# Holes	Size HxWxD	Drawing Link
<a href="#"><u>PBGX1SS</u></a>	\$272.00	<a href="#"><u>PBGX1SSA</u></a>	\$544.00	1	3.56 x 3.06 x 3.83 [90 x 78 x 97]	<a href="#"><u>PDF</u></a>
<a href="#"><u>PBGX2SS</u></a>	\$309.00	<a href="#"><u>PBGX2SSA</u></a>	\$618.00	2	5.44 x 3.06 x 3.83 [138 x 78 x 97]	<a href="#"><u>PDF</u></a>
<a href="#"><u>PBGX3SS</u></a>	\$349.00	<a href="#"><u>PBGX3SSA</u></a>	\$698.00	3	7.31 x 3.06 x 3.83 [186 x 78 x 97]	<a href="#"><u>PDF</u></a>
<a href="#"><u>PBGX4SS</u></a>	\$462.00	<a href="#"><u>PBGX4SSA</u></a>	\$924.00	4	9.19 x 3.06 x 3.83 [233 x 78 x 97]	<a href="#"><u>PDF</u></a>
<a href="#"><u>PBGX6SS</u></a>	\$582.00	<a href="#"><u>PBGX6SSA</u></a>	\$1,164.00	6	8.81 x 5.31 x 4.58 [224 x 135 x 116]	<a href="#"><u>PDF</u></a>

Note: Dimensions in inches [millimeters].

# 22mm Pushbutton NEMA 4, 4X, 12, and 13 Stainless Steel Wall-Mount



## Dimensions

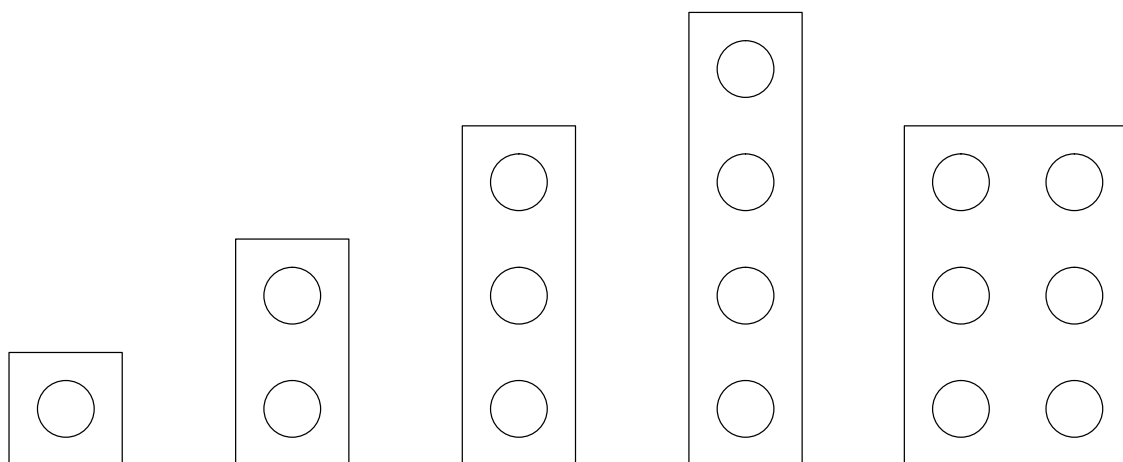

PBGX1SS

PBGX2SS

PBGX3SS

PBGX4SS

PBGX6SS