

NEMA 4, 4X, and 12 Stainless Steel Single-Door Wall-Mount with 1/4-Turn Latch



Application

Provides unmatched protection for housing electrical components in highly corrosive environments. This enclosure is used for indoor and outdoor settings that are frequently wet or have constant exposure to water, other liquids, or contaminants.

Construction

- Fabricated from 16-gauge type 304 or 316L stainless steel
- Continuously-welded seams ground smooth
- Closed-cell oil-resistant neoprene gasket
- External mounting feet
- Weldnuts are provided for mounting optional subpanels securely
- Continuous hinge cover with a 1/4-turn semi-flush oil-tight latch
- Door removed by pulling stainless steel continuous hinge pin
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Uses N41214 series latches (requires reuse of existing latch cam)

Finish

- Cover and outside of enclosure have a #3 intermediate polished finish

Listings

- UL 50 Listed 4, 4X, and 12 [UL file E6924 and E470978]
- Meets NEMA/EEMAC 4, 4X, and 12



Note: For current listings, please see www.automationdirect.com

NEMA 4, 4X, and 12 Stainless Steel Single-Door Wall-Mount 1/4-Turn Latch


304Stainless Steel	Price	Enclosure Size HxWxD	Painted Steel Subpanel	Stainless Steel Subpanel
BN4060604CHQTSS	\$259.00	6.31 x 6.31 x 4.75 [160 x 160 x 121]	P0606	P0606SS
BN4080604CHQTSS	\$301.00	8.31 x 6.31 x 4.75 [211 x 160 x 121]	P0806	P0806SS
BN4100804CHQTSS	\$328.00	10.31 x 8.31 x 4.75 [262 x 211 x 121]	P1008	P1008SS
BN4100806CHQTSS	\$370.00	10.31 x 8.31 x 6.75 [262 x 211 x 171]	P1008	P1008SS
BN4121006CHQTSS	\$492.00	12.31 x 10.31 x 6.75 [313 x 262 x 171]	P1210	P1210SS
BN4121008CHQTSS	\$558.00	12.31 x 10.31 x 8.75 [313 x 262 x 222]	P1210	P1210SS
BN4121010CHQTSS	\$602.00	12.31 x 10.31 x 10.75 [313 x 262 x 273]	P1210	P1210SS
BN4121206CHQTSS	\$534.00	12.31 x 12.31 x 6.75 [313 x 313 x 171]	P1212	P1212SS
BN4121208CHQTSS	\$577.00	12.31 x 12.31 x 8.75 [313 x 313 x 222]	P1212	P1212SS
BN4121210CHQTSS	\$618.00	12.31 x 12.31 x 10.75 [313 x 313 x 273]	P1212	P1212SS
BN4141206CHQTSS	\$560.00	14.31 x 12.31 x 6.75 [363 x 313 x 171]	P1412	P1412SS
BN4141208CHQTSS	\$608.00	14.31 x 12.31 x 8.75 [363 x 313 x 222]	P1412	P1412SS
BN4161406CHQTSS	\$624.00	16.31 x 14.31 x 6.75 [414 x 363 x 171]	P1614	P1614SS
BN4161408CHQTSS	\$633.00	16.31 x 14.31 x 8.75 [414 x 363 x 222]	P1614	P1614SS

Notes: Subpanels must be ordered separately.
Dimensions in inches [millimeters].
Letters in table correspond to letters on dimensional drawings.

NEMA 4, 4X, and 12 Stainless Steel Single-Door Wall-Mount with 1/4-Turn Latch



Dimensions

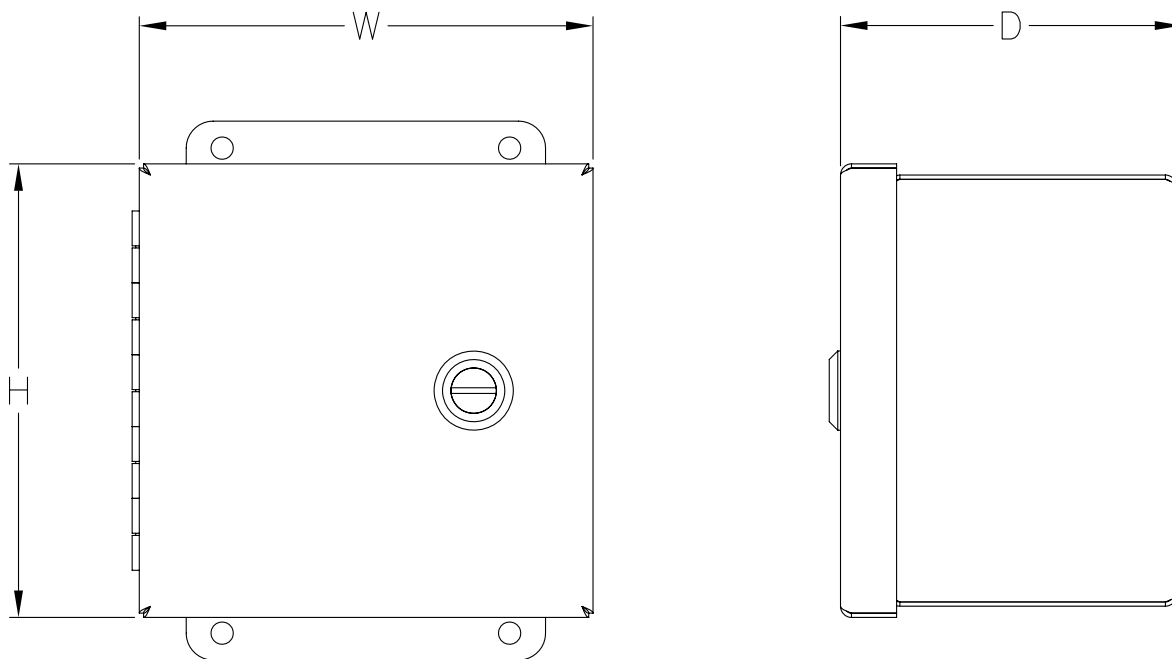

Enclosure Subpanels



Subpanels

Subpanels are not included with most enclosures and must be purchased separately.

The specifications table for each enclosure family list the part number of the subpanel that goes with each enclosure.

Subpanels for Small NEMA 12 (B) and NEMA 4 (BN4) Enclosures

- 14-gauge (painted, stainless, and galvanized)
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels fit the following enclosures: B, B_CH, BN4, BN4_CH, BN4_CHQT, BN4_SS, BN4_CHSS, BN4_CHSSA, BN4_CHQTSS, BN4_CHQTSSA ("_" refers to dimensions).



Subpanels for B and BN4 Enclosures					
Painted Steel	Price	304 Stainless Steel	Price	Nominal Enclosure Size HxW	Subpanel Size AxB
<u>P0604</u>	\$5.00	<u>P0604SS</u>	\$16.75	6 x 4	4.88 x 2.88 [124 x 73]
<u>P0606</u>	\$6.00	<u>P0606SS</u>	\$20.50	6 x 6	4.88 x 4.88 [124 x 124]
<u>P0806</u>	\$6.75	<u>P0806SS</u>	\$24.50	8 x 6	6.88 x 4.88 [175 x 124]
<u>P0808</u>	\$8.00	—	—	8 x 8	6.88 x 6.88 [175 x 175]
<u>P1008</u>	\$8.75	<u>P1008SS</u>	\$35.50	10 x 8	8.88 x 6.88 [226 x 175]
<u>P1010</u>	\$11.00	—	—	10 x 10	8.88 x 8.88 [226 x 226]
<u>P1206</u>	\$8.75	—	—	12 x 6	10.88 x 4.88 [276 x 124]
<u>P1210</u>	\$12.75	<u>P1210SS</u>	\$50.00	12 x 10	10.88 x 8.88 [276 x 226]
<u>P1212</u>	\$15.00	<u>P1212SS</u>	\$58.00	12 x 12	10.88 x 10.88 [276 x 276]
<u>P1408</u>	\$12.00	—	—	14 x 8	12.88 x 6.88 [327 x 175]
<u>P1412</u>	\$16.50	<u>P1412SS</u>	\$67.00	14 x 12	12.88 x 10.88 [327 x 276]
<u>P1610</u>	\$16.25	—	—	16 x 10	14.88 x 8.88 [378 x 226]
<u>P1614</u>	\$22.00	<u>P1614SS</u>	\$88.00	16 x 14	14.88 x 12.88 [378 x 327]
Notes: Dimensions in inches [millimeters]. Letters in table correspond to letters on dimensional drawing.					

Dimensions

