

# NEMA 4, 4X, and 12 Stainless Steel Single-Door Wall-Mount with 1/4-Turn Latch



## Application

Provides unmatched protection for housing electrical components in highly corrosive environments. This enclosure is used for indoor and outdoor settings that are frequently wet or have constant exposure to water, other liquids, or contaminants.

## Construction

- Fabricated from 16-gauge type 304 or 316L stainless steel
- Continuously-welded seams ground smooth
- Closed-cell oil-resistant neoprene gasket
- External mounting feet
- Weldnuts are provided for mounting optional subpanels securely
- Continuous hinge cover with a 1/4-turn semi-flush oil-tight latch
- Door removed by pulling stainless steel continuous hinge pin
- Grounding provisions provided
- Optional subpanels must be ordered separately
- Uses N41214 series latches (requires reuse of existing latch cam)

## Finish

- Cover and outside of enclosure have a #3 intermediate polished finish

## Listings

- UL 50 Listed 4, 4X, and 12 [UL file E6924 and E470978]
- Meets NEMA/EEMAC 4, 4X, and 12



Note: For current listings, please see [www.automationdirect.com](http://www.automationdirect.com)

## NEMA 4, 4X, and 12 Stainless Steel Single-Door Wall-Mount 1/4-Turn Latch


| 304Stainless Steel              | Price    | Enclosure Size HxWxD                    | Painted Steel Subpanel | Stainless Steel Subpanel |
|---------------------------------|----------|-----------------------------------------|------------------------|--------------------------|
| <a href="#">BN4060604CHQTSS</a> | \$204.00 | 6.31 x 6.31 x 4.75 [160 x 160 x 121]    | <a href="#">P0606</a>  | <a href="#">P0606SS</a>  |
| <a href="#">BN4080604CHQTSS</a> | \$237.00 | 8.31 x 6.31 x 4.75 [211 x 160 x 121]    | <a href="#">P0806</a>  | <a href="#">P0806SS</a>  |
| <a href="#">BN4100804CHQTSS</a> | \$258.00 | 10.31 x 8.31 x 4.75 [262 x 211 x 121]   | <a href="#">P1008</a>  | <a href="#">P1008SS</a>  |
| <a href="#">BN4100806CHQTSS</a> | \$292.00 | 10.31 x 8.31 x 6.75 [262 x 211 x 171]   | <a href="#">P1008</a>  | <a href="#">P1008SS</a>  |
| <a href="#">BN4121006CHQTSS</a> | \$388.00 | 12.31 x 10.31 x 6.75 [313 x 262 x 171]  | <a href="#">P1210</a>  | <a href="#">P1210SS</a>  |
| <a href="#">BN4121008CHQTSS</a> | \$440.00 | 12.31 x 10.31 x 8.75 [313 x 262 x 222]  | <a href="#">P1210</a>  | <a href="#">P1210SS</a>  |
| <a href="#">BN4121010CHQTSS</a> | \$475.00 | 12.31 x 10.31 x 10.75 [313 x 262 x 273] | <a href="#">P1210</a>  | <a href="#">P1210SS</a>  |
| <a href="#">BN4121206CHQTSS</a> | \$421.00 | 12.31 x 12.31 x 6.75 [313 x 313 x 171]  | <a href="#">P1212</a>  | <a href="#">P1212SS</a>  |
| <a href="#">BN4121208CHQTSS</a> | \$455.00 | 12.31 x 12.31 x 8.75 [313 x 313 x 222]  | <a href="#">P1212</a>  | <a href="#">P1212SS</a>  |
| <a href="#">BN4121210CHQTSS</a> | \$487.00 | 12.31 x 12.31 x 10.75 [313 x 313 x 273] | <a href="#">P1212</a>  | <a href="#">P1212SS</a>  |
| <a href="#">BN4141206CHQTSS</a> | \$441.00 | 14.31 x 12.31 x 6.75 [363 x 313 x 171]  | <a href="#">P1412</a>  | <a href="#">P1412SS</a>  |
| <a href="#">BN4141208CHQTSS</a> | \$479.00 | 14.31 x 12.31 x 8.75 [363 x 313 x 222]  | <a href="#">P1412</a>  | <a href="#">P1412SS</a>  |
| <a href="#">BN4161406CHQTSS</a> | \$492.00 | 16.31 x 14.31 x 6.75 [414 x 363 x 171]  | <a href="#">P1614</a>  | <a href="#">P1614SS</a>  |
| <a href="#">BN4161408CHQTSS</a> | \$499.00 | 16.31 x 14.31 x 8.75 [414 x 363 x 222]  | <a href="#">P1614</a>  | <a href="#">P1614SS</a>  |

Notes: Subpanels must be ordered separately.  
Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawings.

# NEMA 4, 4X, and 12 Stainless Steel Single-Door Wall-Mount with 1/4-Turn Latch



## Dimensions

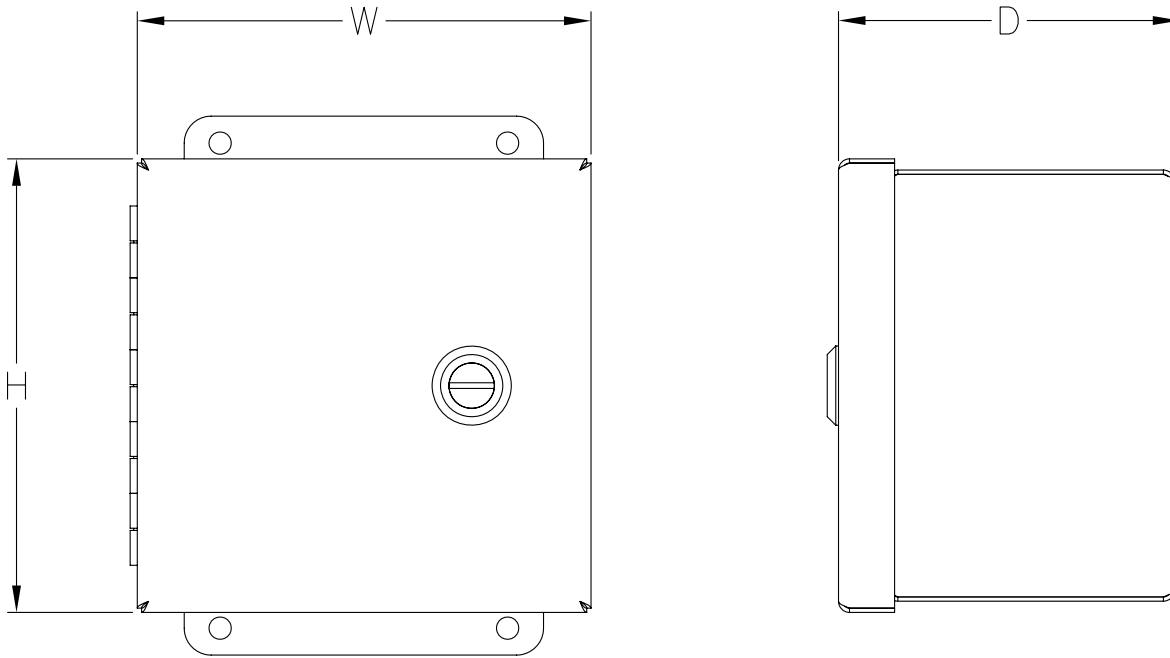

# Enclosure Subpanels



## Subpanels

Subpanels are not included with most enclosures and must be purchased separately.

The specifications table for each enclosure family list the part number of the subpanel that goes with each enclosure.

## Subpanels for Small NEMA 12 (B) and NEMA 4 (BN4) Enclosures

- 14-gauge (painted, stainless, and galvanized)
- Painted steel subpanels are white polyester powder over phosphatized surfaces
- Galvanized subpanels have a conductive finish (no paint)
- Subpanels fit the following enclosures: B, B\_CH, BN4, BN4\_CH, BN4\_CHQT, BN4\_SS, BN4\_CHSS, BN4\_CHSSA, BN4\_CHQTSS, BN4\_CHQTSSA ("\_" refers to dimensions).



| Subpanels for B and BN4 Enclosures |         |                     |         |                            |                           |
|------------------------------------|---------|---------------------|---------|----------------------------|---------------------------|
| Painted Steel                      | Price   | 304 Stainless Steel | Price   | Nominal Enclosure Size HxW | Subpanel Size AxB         |
| <b>P0604</b>                       | \$5.25  | <b>P0604SS</b>      | \$15.25 | 6 x 4                      | 4.88 x 2.88 [124 x 73]    |
| <b>P0606</b>                       | \$6.25  | <b>P0606SS</b>      | \$19.00 | 6 x 6                      | 4.88 x 4.88 [124 x 124]   |
| <b>P0806</b>                       | \$7.25  | <b>P0806SS</b>      | \$22.50 | 8 x 6                      | 6.88 x 4.88 [175 x 124]   |
| <b>P0808</b>                       | \$8.50  | —                   | —       | 8 x 8                      | 6.88 x 6.88 [175 x 175]   |
| <b>P1008</b>                       | \$9.25  | <b>P1008SS</b>      | \$32.50 | 10 x 8                     | 8.88 x 6.88 [226 x 175]   |
| <b>P1010</b>                       | \$11.50 | —                   | —       | 10 x 10                    | 8.88 x 8.88 [226 x 226]   |
| <b>P1206</b>                       | \$9.25  | —                   | —       | 12 x 6                     | 10.88 x 4.88 [276 x 124]  |
| <b>P1210</b>                       | \$13.25 | <b>P1210SS</b>      | \$45.50 | 12 x 10                    | 10.88 x 8.88 [276 x 226]  |
| <b>P1212</b>                       | \$15.50 | <b>P1212SS</b>      | \$53.00 | 12 x 12                    | 10.88 x 10.88 [276 x 276] |
| <b>P1408</b>                       | \$12.75 | —                   | —       | 14 x 8                     | 12.88 x 6.88 [327 x 175]  |
| <b>P1412</b>                       | \$17.50 | <b>P1412SS</b>      | \$61.00 | 14 x 12                    | 12.88 x 10.88 [327 x 276] |
| <b>P1610</b>                       | \$17.00 | —                   | —       | 16 x 10                    | 14.88 x 8.88 [378 x 226]  |
| <b>P1614</b>                       | \$23.00 | <b>P1614SS</b>      | \$80.00 | 16 x 14                    | 14.88 x 12.88 [378 x 327] |

Notes: Dimensions in inches [millimeters].  
Letters in table correspond to letters on dimensional drawing.

## Dimensions

