



# Reinforced Polyurethane Hose



NITRA™ reinforced polyurethane (PUR) hose features a sturdy polyester braid between the polyurethane inner and outer layers. Contamination of air systems caused by rubber hose breakdown is significantly reduced by using NITRA PUR hose. CBL2 and CBL3 hoses have one rigid and one swivel fitting and are specified by inside diameter. CBL5 and CBL6 hoses have one Male and one Female industrial interchange quick disconnect fitting.

## Features

- 1/4" and 3/8" inside diameters (25 and 50 foot package lengths available)
- Clear blue color
- Lighter weight compared to rubber hose
- Strong, flexible and kink resistant
- Made in USA

## Reinforced Polyurethane Hose Specifications

<b>Working Pressure (psi) @ 68°F</b>			210		<b>Temp. Range</b>		-40°F to +155°F (-40°C to +68°C)		
<b>Burst Pressure (psi) @ 68°F</b>			630		<b>Hardness</b>		Shore A 85		
<b>Part Number</b>	<b>Price</b>	<b>Hose I.D. (in)</b>	<b>Hose O.D. (in)</b>	<b>Wall Thickness (in)</b>	<b>Fittings</b>	<b>Min. Bend Radius</b>	<b>PKG Length</b>	<b>Package Weight (lbs)</b>	
<a href="#"><b>HBP14-25CBL2</b></a>	\$40.50	1/4	3/8	0.06	1/4 in MNPT	1.00"	25 ft	1.15	
<a href="#"><b>HBP14-50CBL2</b></a>	\$57.00						50 ft	2.00	
<a href="#"><b>HBP38-25CBL2</b></a>	\$44.50	3/8	9/16	0.09	1/4 in MNPT	1.63"	25 ft	2.50	
<a href="#"><b>HBP38-50CBL2</b></a>	\$70.00						50 ft	4.25	
<a href="#"><b>HBP38-25CBL3</b></a>	\$46.50				3/8 in MNPT		25 ft	2.50	
<a href="#"><b>HBP38-50CBL3</b></a>	\$75.00						50 ft	4.50	

## Dimensions

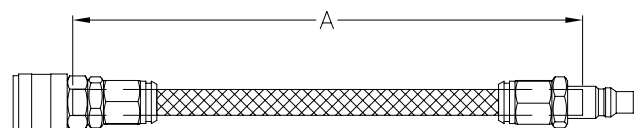
 


TABLE 1

PART NUMBER	DIM A (OVERALL LENGTH)
HBP14-25CBL2	25'
HBP14-50CBL2	50'
HBP38-25CBL2	25'
HBP38-50CBL2	50'
HBP38-25CBL3	25'
HBP38-50CBL3	50'

TABLE 1

PART NUMBER	DIM A (OVERALL LENGTH)
HBP14-25CBL5	25'
HBP14-50CBL5	50'
HBP38-25CBL6	25'
HBP38-50CBL6	50'