



Pneumatic Nickel-Plated Bleed Valve Fittings

Nickel-Plated Bleed Valves

These bleed valves offer an easy solution to releasing trapped or excess air pressure from a pneumatic system. Simply press the button to exhaust air pressure.

Features

- Release 100 in³ in 4 seconds
- Durable construction
- Available with standard pipe thread and 10-32 thread
- Operating pressure: 0 to 125 psi
- Made in USA



NITRA™ Pneumatic Nickel-Plated Bleed Valve Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<u>GBV10N</u>	\$13.50	NITRA pneumatic threaded fitting, bleed valve, nickel-plated brass body, nickel-plated brass threads, (1) #10-32 male threaded connection(s).	1	0.01
<u>GBV18N</u>	\$12.50	NITRA pneumatic threaded fitting, bleed valve, nickel-plated brass body, nickel-plated brass threads, (1) 1/8in male NPT connection(s).	1	0.05
<u>GBV14N</u>	\$13.50	NITRA pneumatic threaded fitting, bleed valve, nickel-plated brass body, nickel-plated brass threads, (1) 1/4in male NPT connection(s).	1	0.10



Part No. **GBV10N**




Part No. **GBV18N**




Part No. **GBV14N**

Dimensions


inches [mm]

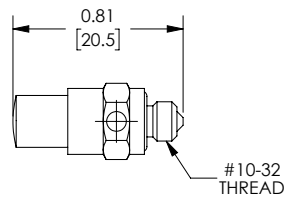

Part No. **GBV10N**

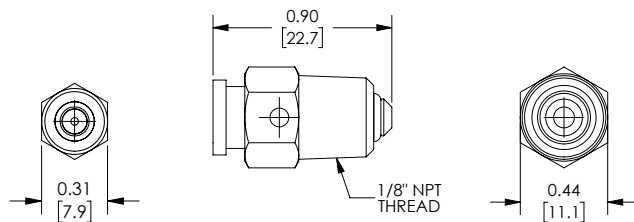

Part No. **GBV18N**

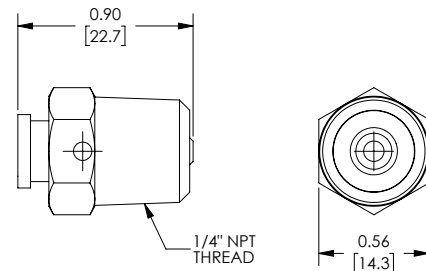

Part No. **GBV14N**

See our website www.AutomationDirect.com for complete Engineering drawings.