



# Nickel-Plated Brass Push-to-Connect Fittings

Part No. [ME532-10N-B](#)

**NITRA** pneumatic push-to-connect male elbow fittings with rotating nickel-plated brass body, nickel-plated brass threads, stainless steel tube gripping claws and pre-applied Teflon thread sealant (#10-32, M5 and G threads have O-ring instead of thread sealant). For use with flexible tubing. Five fittings per package.

- Performs well in harsh duty or washdown applications
- Working Pressure 0 to 300 psi
- Working Temperature 0 to 175°F (-17.8 to 79.4°C)

NITRA™ Nickel-Plated Brass Male Elbow					
Imperial Tube and Threads					
Part No.	Size	Price	Drawing Link	Qty. per pack	Weight (lb)
<a href="#">ME532-10N-B</a>	(1) #10-32 male UNF x (1) 5/32in (4mm) push-to-connect	\$17.50	<a href="#">PDF</a>	5	0.19
<a href="#">ME532-18N-B</a>	(1) 1/8in male NPT x (1) 5/32in (4mm) push-to-connect	\$17.00	<a href="#">PDF</a>	5	0.22
<a href="#">ME532-14N-B</a>	(1) 1/4in male NPT x (1) 5/32in (4mm) push-to-connect	\$20.50	<a href="#">PDF</a>	5	0.25
<a href="#">ME14-10N-B</a>	(1) #10-32 male UNF x (1) 1/4in push-to-connect	\$18.00	<a href="#">PDF</a>	5	0.22
<a href="#">ME14-18N-B</a>	(1) 1/8in male NPT x (1) 1/4in push-to-connect	\$17.00	<a href="#">PDF</a>	5	0.24
<a href="#">ME14-14N-B</a>	(1) 1/4in male NPT x (1) 1/4in push-to-connect	\$19.00	<a href="#">PDF</a>	5	0.28
<a href="#">ME14-38N-B</a>	(1) R3/8 male BSPT x (1) 1/4in push-to-connect	\$24.50	<a href="#">PDF</a>	5	0.35
<a href="#">ME516-18N-B</a>	(1) 1/8in male NPT x (1) 5/16in (8mm) push-to-connect	\$19.00	<a href="#">PDF</a>	5	0.27
<a href="#">ME516-14N-B</a>	(1) 1/4in male NPT x (1) 5/16in (8mm) push-to-connect	\$20.50	<a href="#">PDF</a>	5	0.3
<a href="#">ME38-18N-B</a>	(1) 1/8in male NPT x (1) 3/8in push-to-connect	\$26.00	<a href="#">PDF</a>	5	0.44
<a href="#">ME38-14N-B</a>	(1) 1/4in male NPT x (1) 3/8in push-to-connect	\$27.00	<a href="#">PDF</a>	5	0.46
<a href="#">ME38-38N-B</a>	(1) 3/8in male NPT x (1) 3/8in push-to-connect	\$28.50	<a href="#">PDF</a>	5	0.48
<a href="#">ME38-12N-B</a>	(1) 1/2in male NPT x (1) 3/8in push-to-connect	\$33.00	<a href="#">PDF</a>	5	0.67
<a href="#">ME12-14N-B</a>	(1) 1/4in male NPT x (1) 1/2in push-to-connect	\$34.50	<a href="#">PDF</a>	5	0.72
<a href="#">ME12-38N-B</a>	(1) R3/8 male BSPT x (1) 1/2in push-to-connect	\$35.50	<a href="#">PDF</a>	5	0.74
<a href="#">ME12-12N-B</a>	(1) 1/2in male NPT x (1) 1/2in push-to-connect	\$39.50	<a href="#">PDF</a>	5	0.82
Hybrid Imperial to Metric R Threads (BSPT)					
<a href="#">ME14-18R-B</a>	(1) R1/8 male BSPT x (1) 1/4in push-to-connect	\$17.00	<a href="#">PDF</a>	5	0.23
<a href="#">ME14-14R-B</a>	(1) R1/4 male BSPT x (1) 1/4in push-to-connect	\$19.00	<a href="#">PDF</a>	5	0.28
<a href="#">ME38-14R-B</a>	(1) R1/4 male BSPT x (1) 3/8in push-to-connect	\$27.00	<a href="#">PDF</a>	5	0.43
<a href="#">ME38-38R-B</a>	(1) R3/8 male BSPT x (1) 3/8in push-to-connect	\$28.50	<a href="#">PDF</a>	5	0.49
<a href="#">ME12-14R-B</a>	(1) R1/4 male BSPT x (1) 1/2in push-to-connect	\$34.50	<a href="#">PDF</a>	5	0.65
<a href="#">ME12-38R-B</a>	(1) R3/8 male BSPT x (1) 1/2in push-to-connect	\$35.50	<a href="#">PDF</a>	5	0.68
Hybrid Imperial to Metric G Threads (BSPP)					
<a href="#">ME14-18G-B</a>	(1) G1/8 male BSPP x (1) 1/4in push-to-connect	\$17.00	<a href="#">PDF</a>	5	0.24
<a href="#">ME14-14G-B</a>	(1) G1/4 male BSPP x (1) 1/4in push-to-connect	\$19.00	<a href="#">PDF</a>	5	0.29
<a href="#">ME38-14G-B</a>	(1) G1/4 male BSPP x (1) 3/8in push-to-connect	\$27.00	<a href="#">PDF</a>	5	0.42
<a href="#">ME38-38G-B</a>	(1) G3/8 male BSPP x (1) 3/8in push-to-connect	\$28.50	<a href="#">PDF</a>	5	0.46
<a href="#">ME38-12G-B</a>	(1) G1/2 male BSPP x (1) 3/8in push-to-connect	\$33.00	<a href="#">PDF</a>	5	0.56
<a href="#">ME12-38G-B</a>	(1) G3/8 male BSPP x (1) 1/2in push-to-connect	\$35.50	<a href="#">PDF</a>	5	0.64
<a href="#">ME12-12G-B</a>	(1) G1/2 male BSPP x (1) 1/2in push-to-connect	\$39.50	<a href="#">PDF</a>	5	0.72



# Nickel-Plated Brass Push-to-Connect Fittings

<b>NITRA™ Nickel-Plated Brass Male Elbow Continued</b>					
<i>Hybrid Metric Tube to Imperial</i>					
<b>Part No.</b>	<b>Size</b>	<b>Price</b>	<b>Drawing Link</b>	<b>Qty. per pack</b>	<b>Weight (lb)</b>
<a href="#"><u>ME4M-M5-B</u></a>	(1) M5 x 0.8 male ISO x (1) 5/32in (4mm) push-to-connect	\$17.00	<a href="#"><u>PDF</u></a>	5	0.19
<a href="#"><u>ME6M-M5-B</u></a>	(1) M5 x 0.8 male ISO x (1) 6mm push-to-connect	\$17.50	<a href="#"><u>PDF</u></a>	5	0.21
<a href="#"><u>ME6M-18N-B</u></a>	(1) 1/8in male NPT x (1) 6mm push-to-connect	\$17.00	<a href="#"><u>PDF</u></a>	5	0.24
<a href="#"><u>ME6M-14N-B</u></a>	(1) 1/4in male NPT x (1) 6mm push-to-connect	\$19.00	<a href="#"><u>PDF</u></a>	5	0.28
<i>Metric Tube to Metric R Threads (BSPT)</i>					
<a href="#"><u>ME4M-18R-B</u></a>	(1) R1/8 male BSPT x (1) 5/32in (4mm) push-to-connect	\$16.00	<a href="#"><u>PDF</u></a>	5	0.21
<a href="#"><u>ME4M-14R-B</u></a>	(1) R1/4 male BSPT x (1) 5/32in (4mm) push-to-connect	\$18.00	<a href="#"><u>PDF</u></a>	5	0.25
<a href="#"><u>ME6M-18R-B</u></a>	(1) R1/8 male BSPT x (1) 6mm push-to-connect	\$17.00	<a href="#"><u>PDF</u></a>	5	0.23
<a href="#"><u>ME6M-14R-B</u></a>	(1) R1/4 male BSPT x (1) 6mm push-to-connect	\$18.00	<a href="#"><u>PDF</u></a>	5	0.27
<a href="#"><u>ME8M-18R-B</u></a>	(1) R1/8 male BSPT x (1) 5/16in (8mm) push-to-connect	\$18.00	<a href="#"><u>PDF</u></a>	5	0.25
<a href="#"><u>ME8M-14R-B</u></a>	(1) R1/4 male BSPT x (1) 5/16in (8mm) push-to-connect	\$20.00	<a href="#"><u>PDF</u></a>	5	0.3
<a href="#"><u>ME10M-18R-B</u></a>	(1) R1/8 male BSPT x (1) 10mm push-to-connect	\$23.00	<a href="#"><u>PDF</u></a>	5	0.4
<a href="#"><u>ME10M-14R-B</u></a>	(1) R1/4 male BSPT x (1) 10mm push-to-connect	\$24.00	<a href="#"><u>PDF</u></a>	5	0.42
<a href="#"><u>ME10M-38R-B</u></a>	(1) R3/8 male BSPT x (1) 10mm push-to-connect	\$27.00	<a href="#"><u>PDF</u></a>	5	0.48
<i>Metric Tube to Metric G Threads (BSPP)</i>					
<a href="#"><u>ME4M-18G-B</u></a>	(1) G1/8 male BSPP x (1) 5/32in (4mm) push-to-connect	\$17.00	<a href="#"><u>PDF</u></a>	5	0.21
<a href="#"><u>ME6M-18G-B</u></a>	(1) G1/8 male BSPP x (1) 6mm push-to-connect	\$16.00	<a href="#"><u>PDF</u></a>	5	0.24
<a href="#"><u>ME6M-14G-B</u></a>	(1) G1/4 male BSPP x (1) 6mm push-to-connect	\$18.00	<a href="#"><u>PDF</u></a>	5	0.29
<a href="#"><u>ME8M-18G-B</u></a>	(1) G1/8 male BSPP x (1) 5/16in (8mm) push-to-connect	\$18.00	<a href="#"><u>PDF</u></a>	5	0.26
<a href="#"><u>ME8M-14G-B</u></a>	(1) G1/4 male BSPP x (1) 5/16in (8mm) push-to-connect	\$21.00	<a href="#"><u>PDF</u></a>	5	0.31




# Nickel-Plated Brass Push-to-Connect Fittings


**NITRA** nickel-plated brass push-to-connect fittings are an excellent choice for many industrial applications. They have an attractive, easily maintained finish and have a higher pressure and temperature rating when compared to resin fittings.

## Features

- Large selection of fitting configurations
- Inch and metric sizes available
- Hybrid Inch to metric conversion fittings available
- NPT, BSPT (R) and BSPP (G) threads available
- Nickel-plated brass bodies, threads and release rings
- Threaded elbow and tee bodies can be rotated after installation
- For use with air and water
- Working pressure 0 to 300 psi
- Working Temperature 0 to 175°F (-17.8 to 79.4°C)

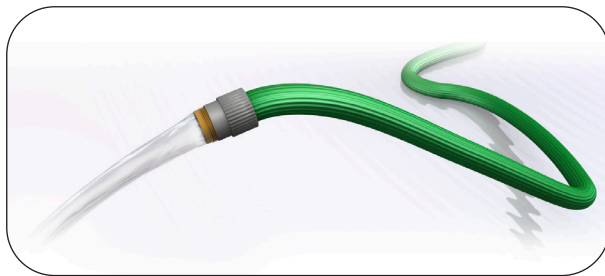

**Ideal for washdown and harsh environments**

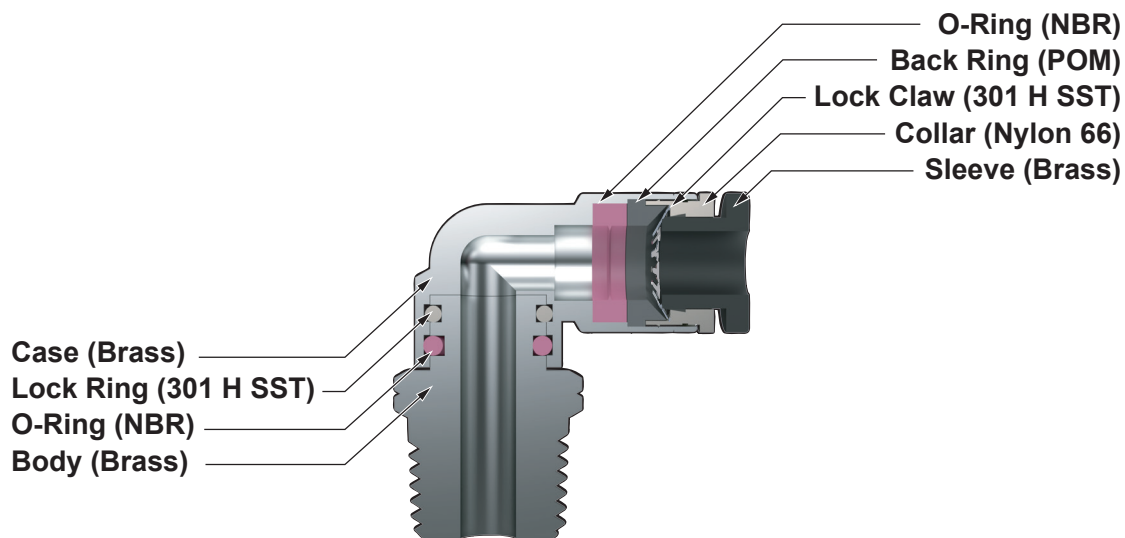

*Fitting Cut-away Diagram*