



# Nickel-Plated Brass Push-to-Connect Fittings

Part No. [US532-B](#)

**NITRA** pneumatic push-to-connect union straight fittings with nickel-plated brass body and stainless steel tube gripping claws. For use with flexible tubing. Five fittings per package.

- Performs well in harsh duty or washdown applications
- Working Pressure 0 to 300 psi
- Working Temperature 0 to 175°F (-17.8 to 79.4°C)

NITRA™ Nickel-Plated Brass Union Straight					
Imperial Tube					
Part No.	Size	Price	Drawing Link	Qty. per pack	Weight (lb)
<a href="#">US532-B</a>	(1) 5/32in (4mm) push-to-connect to (1) 5/32in (4mm) push-to-connect	\$12.50	<a href="#">PDF</a>	5	0.09
<a href="#">US14-B</a>	(1) 1/4in push-to-connect to (1) 1/4in push-to-connect	\$14.50	<a href="#">PDF</a>	5	0.14
<a href="#">US38-B</a>	(1) 3/8in push-to-connect to (1) 3/8in push-to-connect	\$21.50	<a href="#">PDF</a>	5	0.26
<a href="#">US12-B</a>	(1) 1/2in push-to-connect to (1) 1/2in push-to-connect	\$25.50	<a href="#">PDF</a>	5	0.4
Metric Tube					
<a href="#">US6M-B</a>	(1) 6mm push-to-connect to (1) 6mm push-to-connect	\$14.00	<a href="#">PDF</a>	5	0.14
<a href="#">US8M-B</a>	(1) 5/16in (8mm) push-to-connect to (1) 5/16in (8mm) push-to-connect	\$17.50	<a href="#">PDF</a>	5	0.18
<a href="#">US10M-B</a>	(1) 10mm push-to-connect to (1) 10mm push-to-connect	\$19.00	<a href="#">PDF</a>	5	0.25

Part No. [UR14-532-B](#)

**NITRA** pneumatic push-to-connect union straight reducer fittings with nickel-plated brass body and stainless steel tube gripping claws. For use with flexible tubing. Five fittings per package.

- Performs well in harsh duty or washdown applications
- Working Pressure 0 to 300 psi
- Working Temperature 0 to 175°F (-17.8 to 79.4°C)

NITRA™ Nickel-Plated Brass Union Straight Reducer					
Imperial Tube					
Part No.	Size	Price	Drawing Link	Qty. per pack	Weight (lb)
<a href="#">UR14-532-B</a>	(1) 1/4in push-to-connect x (1) 5/32in (4mm) push-to-connect	\$15.00	<a href="#">PDF</a>	5	0.11
<a href="#">UR516-14-B</a>	(1) 5/16in (8mm) push-to-connect x (1) 1/4in push-to-connect	\$21.50	<a href="#">PDF</a>	5	0.18
<a href="#">UR38-516-B</a>	(1) 3/8in push-to-connect x (1) 5/16in (8mm) push-to-connect	\$26.00	<a href="#">PDF</a>	5	0.23
<a href="#">UR38-14-B</a>	(1) 3/8in push-to-connect x (1) 1/4in push-to-connect	\$26.00	<a href="#">PDF</a>	5	0.21
Hybrid Imperial to Metric Tube					
<a href="#">UR14-6M-B</a>	(1) 1/4in push-to-connect x (1) 6mm push-to-connect	\$15.00	<a href="#">PDF</a>	5	0.15
<a href="#">UR38-6M-B</a>	(1) 3/8in push-to-connect x (1) 6mm push-to-connect	\$26.00	<a href="#">PDF</a>	5	0.22
<a href="#">UR38-10M-B</a>	(1) 10mm push-to-connect x (1) 3/8in push-to-connect	\$26.50	<a href="#">PDF</a>	5	0.25
Metric Tube					
<a href="#">UR6M-4M-B</a>	(1) 6mm push-to-connect x (1) 5/32in (4mm) push-to-connect	\$15.00	<a href="#">PDF</a>	5	0.12
<a href="#">UR8M-6M-B</a>	(1) 5/16in (8mm) push-to-connect x (1) 6mm push-to-connect	\$21.50	<a href="#">PDF</a>	5	0.16




# Nickel-Plated Brass Push-to-Connect Fittings


**NITRA** nickel-plated brass push-to-connect fittings are an excellent choice for many industrial applications. They have an attractive, easily maintained finish and have a higher pressure and temperature rating when compared to resin fittings.

## Features

- Large selection of fitting configurations
- Inch and metric sizes available
- Hybrid Inch to metric conversion fittings available
- NPT, BSPT (R) and BSPP (G) threads available
- Nickel-plated brass bodies, threads and release rings
- Threaded elbow and tee bodies can be rotated after installation
- For use with air and water
- Working pressure 0 to 300 psi
- Working Temperature 0 to 175°F (-17.8 to 79.4°C)

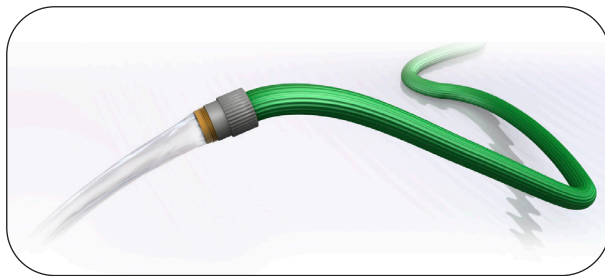

**Ideal for washdown and harsh environments**

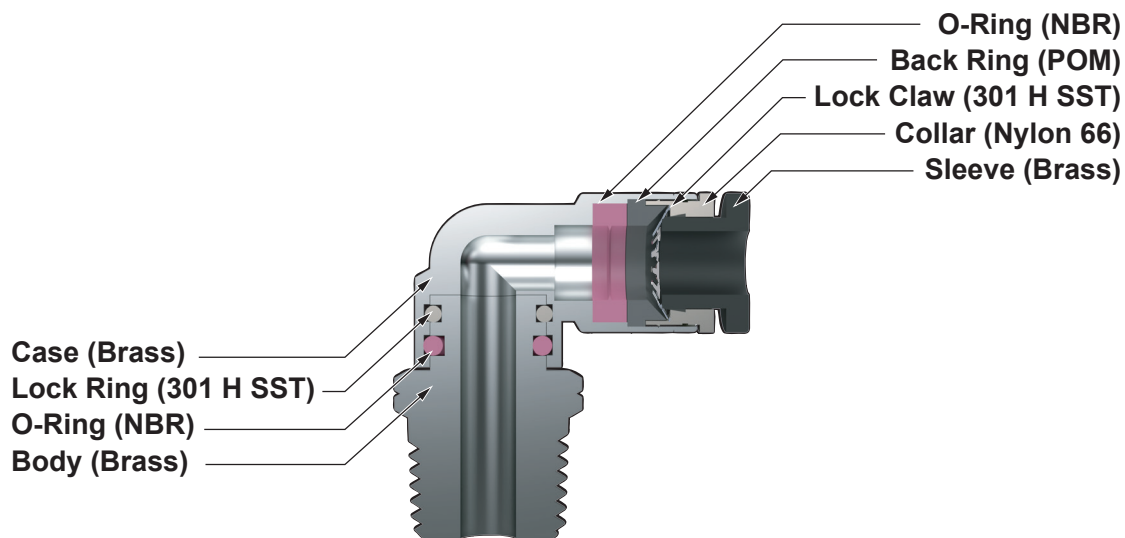

*Fitting Cut-away Diagram*