




Quick-Disconnect Swivel Fittings

Features

- Two independent-rotation points allow a full 360° circular rotation and 45° angled rotation for better swivel action vs. traditional swivel fittings
- Prevents kinking of and strain on the supply line
- Lightweight, streamlined design
- Chrome-plated steel construction for long service life
- Thread sealant supplied on all male fittings
- Maximum pressure of 145 psi

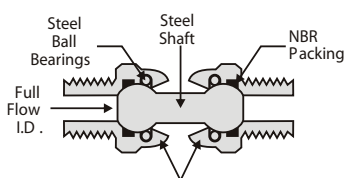

Two Independent Rotation Points



45° Swivel Design

**HS14F-14M**

NITRA™ 1/4 in. NPT Swivel Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<u>HS14F-14M</u>	\$40.00	Swivel fitting, chrome plated steel, 1/4 inch female NPT and 1/4 inch male NPT threaded connections	1	0.2

**HSP38-14M-S**

NITRA™ Quick-Disconnect Plug to NPT Swivel Fittings				
Part No.	Price	Description	Parts Per Pkg	Weight (lbs)
<u>HSP14-14M-S</u>	\$43.00	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch industrial interchange plug and 1/4 inch male NPT threaded connection	1	0.2
<u>HSP38-14M-S</u>	\$43.00	Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 1/4 inch male NPT threaded connection	1	0.2
<u>HSP38-38M-S</u>	\$48.00	Quick-disconnect swivel fitting, chrome plated steel, 3/8 inch industrial interchange plug and 3/8 inch male NPT threaded connection	1	0.2
<u>HSP14-14M-T</u>	\$48.00	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch ARO 210 plug and 1/4 inch male NPT threaded connection	1	0.1
<u>HSP14-14M-U</u>	\$48.00	Quick-disconnect swivel fitting, chrome plated steel, 1/4 inch Truflate plug and 1/4 inch male NPT threaded connection	1	0.1