



# 1/4" NPT Stainless Steel Manifolds



MRS-2CB

### NITRA stainless steel manifolds


- 303 Stainless Steel
- Maximum input pressure of 3500 psi
- Made in the USA



NITRA 1/4" NPT Stainless Steel Manifolds					
Part No.	Description	A	Parts Per Pkg	Weight (lbs)	Price
<b>MRS-2CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 2 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	1.75 [44.5]	1	0.4	\$81.00
<b>MRS-3CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 3 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	2.50 [63.0]	1	0.5	\$89.00
<b>MRS-4CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 4 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	3.25 [82.6]	1	0.7	\$97.00
<b>MRS-5CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 5 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	4.00 [101.6]	1	0.9	\$102.00
<b>MRS-6CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 6 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	4.75 [120.7]	1	1.1	\$106.00
<b>MRS-7CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 7 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	5.50 [139.7]	1	1.2	\$114.00
<b>MRS-8CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 8 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	6.25 [158.8]	1	1.4	\$120.00
<b>MRS-9CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 9 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	7.00 [177.8]	1	1.6	\$129.00
<b>MRS-10CB</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 10 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing.	7.75 [196.9]	1	1.7	\$139.00

## Dimensions

inches [mm]

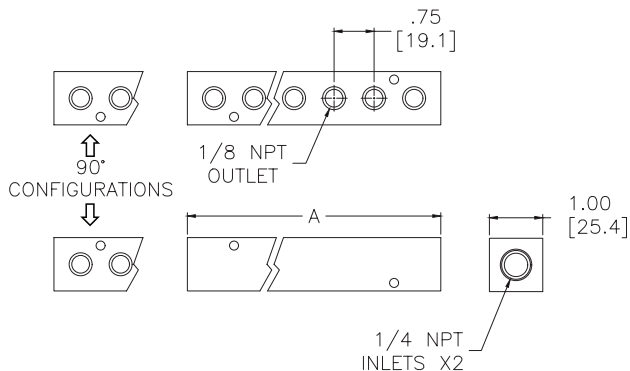

See our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete Engineering drawings.



# 3/8" NPT Stainless Steel Manifolds



MRS-2DC

### NITRA stainless steel manifolds


- 303 Stainless Steel
- Maximum input pressure of 3500 psi
- Made in the USA



NITRA 3/8" NPT Stainless Steel Manifolds					
Part No.	Description	A	Parts Per Pkg	Weight (lbs)	Price
<b>MRS-2DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 2 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	2.13 [54.1]	1	0.7	\$97.00
<b>MRS-3DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 3 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	3.00 [76.2]	1	1.0	\$105.00
<b>MRS-4DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 4 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	3.88 [98.6]	1	1.3	\$115.00
<b>MRS-5DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 5 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	4.75 [120.7]	1	1.6	\$126.00
<b>MRS-6DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 6 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	5.63 [143.0]	1	1.9	\$139.00
<b>MRS-7DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 7 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	6.50 [165.1]	1	2.2	\$150.00
<b>MRS-8DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 8 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	7.38 [187.5]	1	2.5	\$163.00
<b>MRS-9DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 9 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	8.25 [209.6]	1	2.8	\$176.00
<b>MRS-10DC</b>	NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 10 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing.	9.13 [231.9]	1	3.1	\$189.00

## Dimensions

inches [mm]

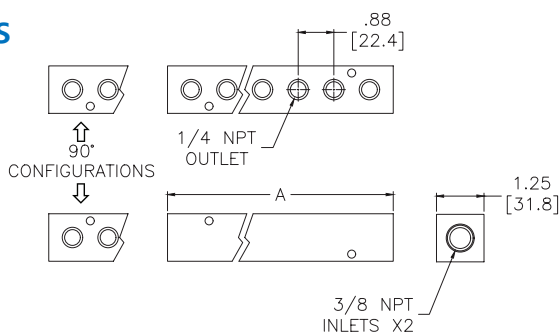

See our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete Engineering drawings.