



1/4" NPT Stainless Steel Manifolds

**MRS-2CB****NITRA** stainless steel manifolds

- 303 Stainless Steel
- Maximum input pressure of 3500 psi
- Made in the USA

**STAINLESS
STEEL**




NITRA 1/4" NPT Stainless Steel Manifolds

| Part No. | Description | A | Parts Per Pkg | Weight (lbs) | Price |
|------------------------|--|--------------|---------------|--------------|----------|
| <u>MRS-2CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 2 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 1.75 [44.5] | 1 | 0.4 | \$85.00 |
| <u>MRS-3CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 3 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 2.50 [63.0] | 1 | 0.5 | \$93.00 |
| <u>MRS-4CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 4 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 3.25 [82.6] | 1 | 0.7 | \$102.00 |
| <u>MRS-5CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 5 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 4.00 [101.6] | 1 | 0.9 | \$107.00 |
| <u>MRS-6CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 6 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 4.75 [120.7] | 1 | 1.1 | \$111.00 |
| <u>MRS-7CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 7 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 5.50 [139.7] | 1 | 1.2 | \$119.00 |
| <u>MRS-8CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 8 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 6.25 [158.8] | 1 | 1.4 | \$126.00 |
| <u>MRS-9CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 9 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 7.00 [177.8] | 1 | 1.6 | \$135.00 |
| <u>MRS-10CB</u> | NITRA pneumatic manifold, stainless steel, rectangular, (2) 1/4 inch female NPT inlet port(s), 10 stations, (1) 1/8 inch female NPT outlet port(s) per station, standard hole spacing. | 7.75 [196.9] | 1 | 1.7 | \$146.00 |

Dimensions

inches [mm]

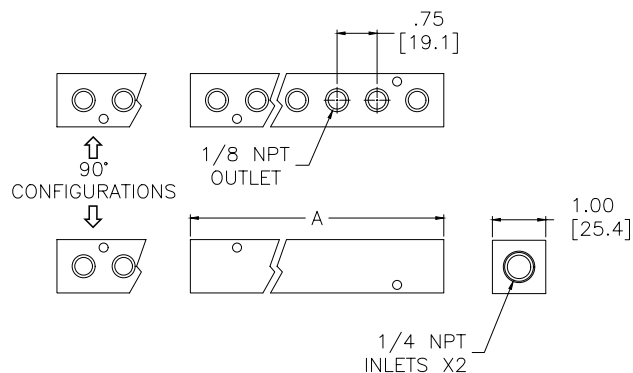

See our website www.AutomationDirect.com for complete Engineering drawings.



3/8" NPT Stainless Steel Manifolds

**MRS-2DC**

NITRA stainless steel manifolds


- 303 Stainless Steel
- Maximum input pressure of 3500 psi
- Made in the USA



| NITRA 3/8" NPT Stainless Steel Manifolds | | | | | |
|--|--|--------------|---------------|--------------|----------|
| Part No. | Description | A | Parts Per Pkg | Weight (lbs) | Price |
| MRS-2DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 2 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 2.13 [54.1] | 1 | 0.7 | \$102.00 |
| MRS-3DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 3 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 3.00 [76.2] | 1 | 1.0 | \$110.00 |
| MRS-4DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 4 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 3.88 [98.6] | 1 | 1.3 | \$120.00 |
| MRS-5DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 5 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 4.75 [120.7] | 1 | 1.6 | \$132.00 |
| MRS-6DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 6 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 5.63 [143.0] | 1 | 1.9 | \$146.00 |
| MRS-7DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 7 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 6.50 [165.1] | 1 | 2.2 | \$157.00 |
| MRS-8DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 8 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 7.38 [187.5] | 1 | 2.5 | \$171.00 |
| MRS-9DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 9 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 8.25 [209.6] | 1 | 2.8 | \$184.00 |
| MRS-10DC | NITRA pneumatic manifold, stainless steel, rectangular, (2) 3/8 inch female NPT inlet port(s), 10 stations, (1) 1/4 inch female NPT outlet port(s) per station, standard hole spacing. | 9.13 [231.9] | 1 | 3.1 | \$198.00 |

Dimensions

inches [mm]

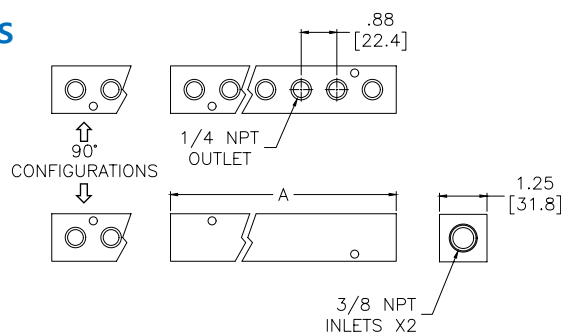

See our website www.AutomationDirect.com for complete Engineering drawings.