


OPT Series Color Sensors



- Capable of evaluating up to 3 colors simultaneously
- Single lens optics allows this sensor to have a small spot diameter and large working range
- Reflex mode operation
- 3 switching outputs
- IP68


Wiring Diagram

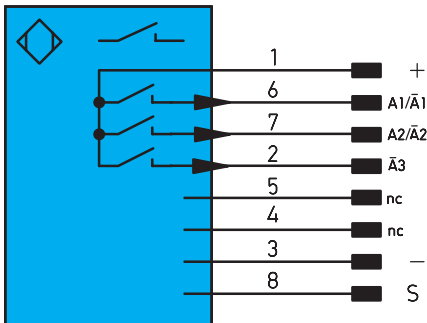

Legend	
+	Supply Voltage +
-	Supply Voltage 0V
A1/Ā1	Switching output 1 (N.O./N.C.)
A2/Ā2	Switching output 2 (N.O./N.C.)
Ā3	Input (analog or digital)/switching output (N.C.)
S	Shielding

Connectors

8-Pin M12 connector

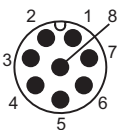


OPT2023 Specifications

Part Number	OPT2023
Price	\$372.00
Working range	30 to 40mm
Working distance	35mm
Light source	White light
Service Life (T = +25°C)	100,000h
Max. ambient light	10,000 Lux
Spot diameter	3mm
Operating voltage	10 to 30VDC
No load supply current	< 80mA
Switching frequency	1.8 kHz
Response time	~ (1000/1.8) μs x filter
Temperature range	-25 to 60°C [-13 to 140°F]
Switching outputs	3 NPN/PNP
Switching output voltage drop	1.5 V
Operating (load) current	100mA
Short circuit protection	yes
Reverse polarity protection	yes
Overload protection	yes
Digital inputs	2
Protection class	III
Setting method	Teach-In
Housing material	Plastic
Degree of protection	IP68
Connection	8-pin M12
Operating mode	Selectable light-on/dark-on
Approvals	CE, RoHS, cULus,

Note: To obtain the most current agency approval information, see the Agency Compliance & Certifications Checklist section on the specific part number's web page.

Dimensions

mm [inches]

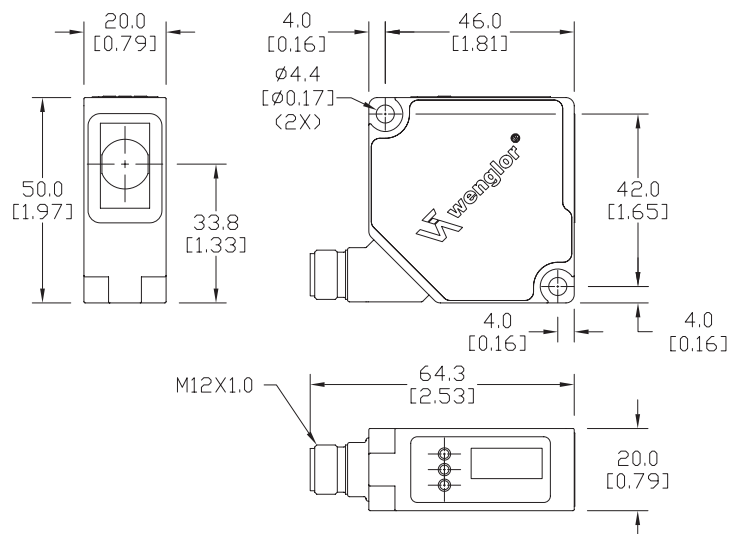

See our website: www.AutomationDirect.com for complete Engineering drawings.

Accessories for OPT Series 50x50mm Photoelectric Sensors

Right-angle Brackets

Mounting bracket, right-angle, nickel-plated steel or 304 stainless steel.
For use with OPT series 50x50mm photoelectric sensors.

Accessories for OPT Series 50x50mm Photoelectric Sensors				
Part Number	Price	Description	Drawing Link	Weight [lb]
<u>OPT2031</u>	\$7.00	Wenglor mounting bracket, right-angle, nickel-plated brass. For use with OPT series 50x50mm photoelectric sensors.	<u>PDF</u>	0.24
<u>OPT2038</u>	\$11.00	Wenglor mounting bracket, right-angle, vertical and horizontal adjustment, 304 stainless steel. For use with OPT series 50x50mm photoelectric sensors.	<u>PDF</u>	0.19



[OPT2031](#)



[OPT2038](#)

Accessories for OPT Series 50x50mm Photoelectric Sensors

Right-angle Swivel Mounting Systems

Mounting bracket, right-angle swivel, 360 degree vertical and horizontal adjustment, 12mm rod mount. For use with OPT series 50x50mm photoelectric sensors. Available in all stainless steel or with an aluminum head with a stainless steel mounting plate.

Accessories for OPT Series 50x50mm Photoelectric Sensors						
Part Number	Price	Description	Mounting Head	Mounting Plate	Drawing Link	Weight [lb]
<u>OPT2122</u>	\$11.50	Wenglor mounting bracket, right-angle swivel, 360 degree vertical and horizontal adjustment, aluminum, 12mm rod mount. For use with OPT series 50x50mm photoelectric sensors.	Aluminum	304 Stainless Steel	<u>PDF</u>	0.19
<u>OPT2123</u>	\$21.00	Wenglor mounting bracket, right-angle swivel, 360 degree vertical and horizontal adjustment, 304 stainless steel, 12mm rod mount. For use with OPT series 50x50mm photoelectric sensors.	304 Stainless Steel	304 Stainless Steel	<u>PDF</u>	0.31

NOTE:

304 Stainless steel mounting rods sold separately: [OPT2109](#) (200mm length), [OPT2110](#) (300mm length), and [OPT2111](#) [500mm length].



[OPT2122,](#)
[OPT2123](#)

Mounting Rods and Brackets

Mounting Rods

304 Stainless steel rods for mounting swivel brackets [OPT2112](#) - [OPT2127](#). Available in three lengths: 200mm, 300mm, and 500mm. 12mm diameter.

Mounting Rods for OPT2112-2127 Swivel Mounting Brackets				
Part Number	Price	Description	Drawing Link	Weight lb (g)
OPT2109	\$13.00	Wenglor mounting rod, 12mm diameter, 200mm length, 304 stainless steel.	PDF	0.41 [185.97]
OPT2110	\$16.00	Wenglor mounting rod, 12mm diameter, 300mm length, 304 stainless steel.	PDF	0.60 [272.16]
OPT2111	\$21.00	Wenglor mounting rod, 12mm diameter, 500mm length, 304 stainless steel.	PDF	0.98 [444.52]



Right-angle Mounting Bracket

Mounting bracket, right-angle, nickel-plated brass. For use with 12mm mounting rods [OPT2109](#), [OPT2110](#) & [OPT2111](#).

Right-angle Mounting Brackets for 12mm Sensors				
Part Number	Price	Description	Drawing Link	Weight lb [g]
OPT2108	\$16.00	Wenglor mounting bracket, right-angle, nickel-plated brass. For use with 12mm mounting rods OPT2109, OPT2110 & OPT2111.	PDF	0.07 [31.8]

