

proSense® Octal Sockets

Features

- Mounts on 35mm DIN rail
- Screw clamp wire termination



70169-D



70170-D




750-2C-SKT

| Octal Sockets for Relays | | | | | |
|----------------------------|--------|--|-----|---------|---------------------|
| Part Number | Price | Description | Qty | Wt (lb) | Drawing Links |
| 70169-D | \$5.25 | Macromatic relay socket, 8-pin, 35mm DIN rail or panel mount. For use with ProSense octal relays. | 1 | 0.1 | PDF |
| 70170-D | \$6.25 | Macromatic relay socket, 11-pin, 35mm DIN rail or panel mount. For use with ProSense octal relays. | 1 | 0.1 | PDF |
| 750-2C-SKT | \$4.75 | AutomationDirect relay socket, 8-pin, 35mm DIN rail or panel mount. For use with 750-2C and H750-2C series octal relays. | 1 | 0.1 | PDF |


| Octal Sockets Specifications | | | | | | | | |
|------------------------------|----------------|---------|---------|------------|----------------------|--------------|-------------------------------|--------------------------------|
| Part Number | Number of Pins | Voltage | Current | Screw Size | Wire Size (capacity) | Screw Torque | Screw Chassis Mounting Torque | Agency Approval * |
| 70169-D | 8 | 600V | 10A | 6-32 | 1 or 2, 12-20 AWG | 12 in-lb | 7 in-lb | UL Recognized E169693, CSA, CE |
| 70170-D | 11 | 300V | 10A | 6-32 | 1 or 2, 12-20 AWG | 12 in-lb | 12 in-lb | |
| 750-2C-SKT | 8 | 600V | 5A | M3.5 | 1-12 AWG / 1-14 AWG | 9 in-lb | 7 in-lb | UL Recognized E225080, CSA, CE |

* To obtain the most current agency approval information, see the Agency Compliance & Certifications Checklist section on the specific part number's web page.


Socket Pinouts

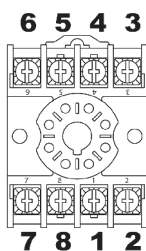

70169-D

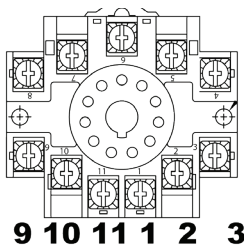

70170-D

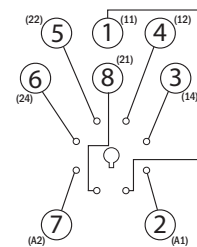

750-2C-SKT