

CR8 Series Inductive Proximity Sensors



8 x 8 mm rectangular metal – DC

- Compact 8 x 8 x 40 mm metal housing
- Axial cable or M8 quick-disconnect models; purchase cable separately
- Complete overload protection
- IP67 rated
- Screws included
- Lifetime warranty



CR8 Series 8x8 Rectangular DC Inductive Proximity Selection Chart

Part Number	Price	Sensing Range	Mounting	Output State	Logic	Connection	Wiring	Dimensions
Standard Distance								
CR8-AN-1A	\$32.50	0-1.5 mm [0-0.06 in]	Flush	N.O.	NPN	2m [6.5 ft] axial cable	Diagram 1	Figure 1
CR8-AP-1A	\$32.50				PNP	2m [6.5 ft] axial cable	Diagram 2	Figure 1
CR8-AN-1F	\$32.50				NPN	M8 [8mm] connector	Diagram 1	Figure 2
CR8-AP-1F	\$32.50				PNP	M8 [8mm] connector	Diagram 2	Figure 2
Extended Distance								
CR8-AN-2A	\$45.00	0-2 mm [0-0.08 in]	Flush	N.O.	NPN	2m [6.5 ft] axial cable	Diagram 1	Figure 1
CR8-AP-2A	\$45.00				PNP	2m [6.5 ft] axial cable	Diagram 2	Figure 1
CR8-AN-2F	\$45.00				NPN	M8 [8mm] connector	Diagram 1	Figure 2
CR8-AP-2F	\$45.00				PNP	M8 [8mm] connector	Diagram 2	Figure 2
Triple Distance								
CR8-AN-3A	\$102.00	3mm [0.118 in]	Semi-flush	N.O.	NPN	2m [6.5 ft] axial cable	Diagram 1	Figure 1
CR8-AP-3A	\$102.00				PNP	2m [6.5 ft] axial cable	Diagram 2	Figure 1
CR8-AN-3F	\$102.00				NPN	M8 [8mm] connector	Diagram 1	Figure 2
CR8-AP-3F	\$102.00				PNP	M8 [8mm] connector	Diagram 2	Figure 2

Wiring Diagrams

Diagram 1

NPN output


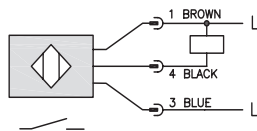



Diagram 2

PNP output

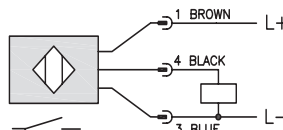

Connector

 M8 connector



CR8 Series Inductive Proximity Sensors

To obtain the most current agency approval information, see the Agency Approval Checklist section on the specific part number's web page.

Dimensions

mm [inches]

Figure 1

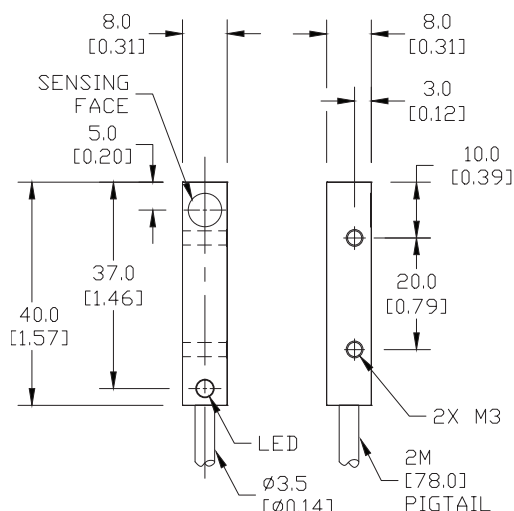


Figure 2

