

NEMA 3R Wiring Trough



Applications

These enclosures are designed to protect wiring against rain, sleet and snow in outdoor installations, or indoors against dripping water.

Construction

- Trough and cover fabricated from 16-gauge carbon steel
- Drip shield top and smooth seamless sides, front and back, prevent rain, snow and sleet from entering the enclosure
- Embossed mounting holes are conveniently located on the back
- A slip-on removable cover is securely fastened with screws located along the bottom edge
- Knockouts are provided on bottom of enclosure

Finish

- ANSI-61 gray polyester powder inside and out over phosphatized surfaces

Listings

- UL 870
- UL File E32576
- CSA File LL66078
- Meets NEMA/EEMAC 1 and 3R requirements




RSCG Series NEMA 3R Wiring Trough				
Part Number	Price	Body/Door Steel Gauge	Enclosure Size HxDxL	Knockout Pattern
<u>RSCG040412</u>	\$70.00	16/16	4.00 x 4.00 x 12.00 [102 x 102 x 305]	B-A-C-D-A-B repeated
<u>RSCG040424</u>	\$93.00	16/16	4.00 x 4.00 x 24.00 [102 x 102 x 610]	B-A-C-D-A-B repeated
<u>RSCG040436</u>	\$130.00	16/16	4.00 x 4.00 x 36.00 [102 x 102 x 914]	B-A-C-D-A-B repeated
<u>RSCG040448</u>	\$153.00	16/16	4.00 x 4.00 x 48.00 [102 x 102 x 1219]	B-A-C-D-A-B repeated
<u>RSCG060612</u>	\$92.00	16/16	6.00 x 6.00 x 12.00 [152 x 152 x 305]	B-A-C-D-A-B repeated
<u>RSCG060624</u>	\$127.00	16/16	6.00 x 6.00 x 24.00 [152 x 152 x 610]	B-A-C-D-A-B repeated
<u>RSCG060636</u>	\$168.00	16/16	6.00 x 6.00 x 36.00 [152 x 152 x 914]	B-A-C-D-A-B repeated
<u>RSCG060648</u>	\$210.00	16/16	6.00 x 6.00 x 48.00 [152 x 152 x 1219]	B-A-C-D-A-B repeated
Note: Dimensions in inches (millimeters). Letters in table correspond to letters on dimensional drawings.				

NEMA 3R Wiring Trough



Dimensions

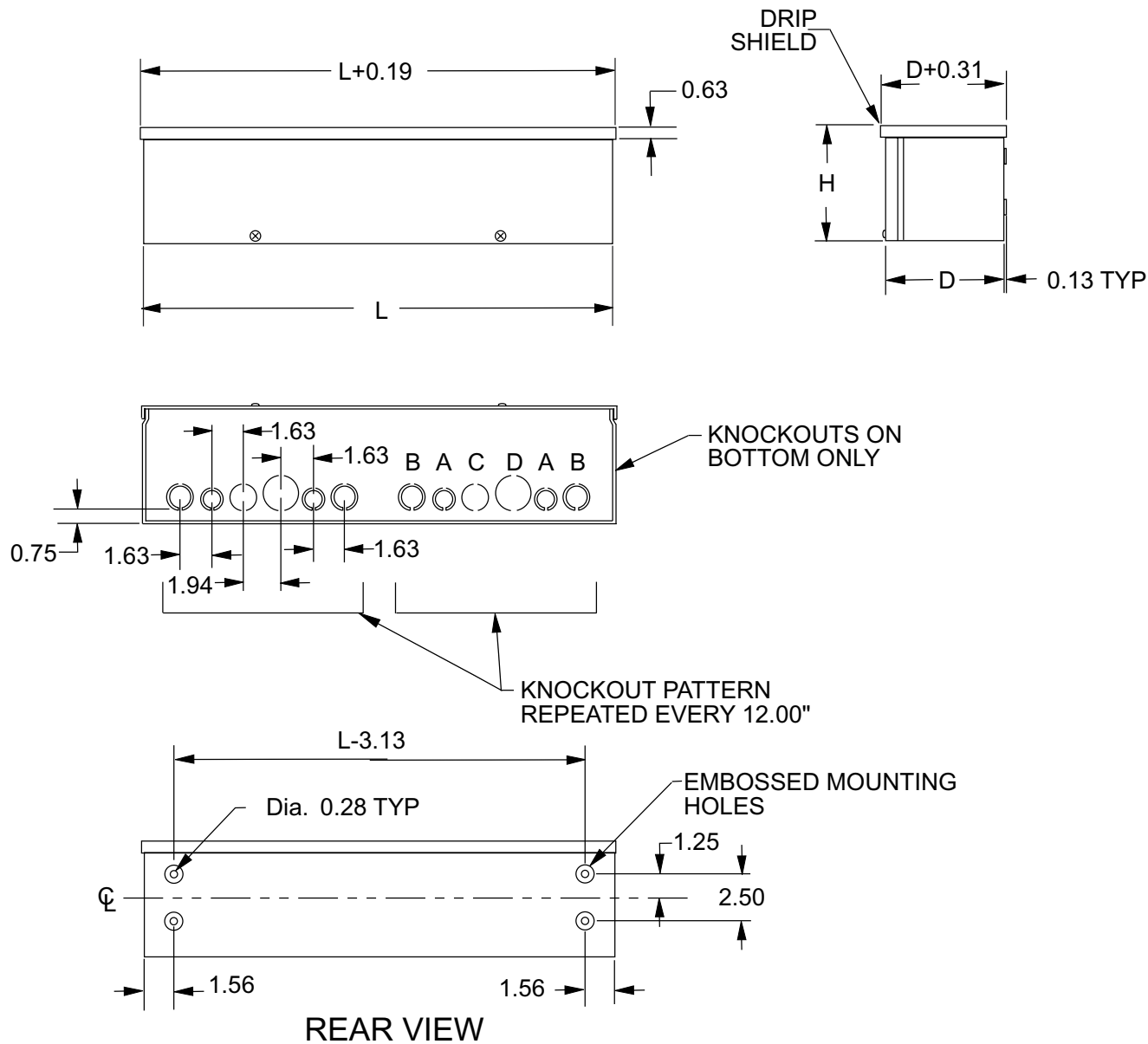

KNOCKOUT SIZES

B = 3/4" x 1" CONCENTRIC KO
 A = 1/2" x 3/4" CONCENTRIC KO
 C = 1" SOLID KO
 D = 1-1/4" SOLID KO

G19RSCG