

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount with Knockouts



Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

Construction

- Bodies and doors fabricated from 14- or 16-gauge carbon steel (see table)
- Drip shield top and smooth seamless sides and front
- Slip-on reversible cover securely fastened with screws located along bottom edge
- No gasket required
- Hasp for padlocking or meter seal provided, except as noted

Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted pre-galvanized steel

Listings

- UL 50, Types 1 and 3 [UL file E23553]
- NEMA/EEMAC 1 and 3R



Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount with Knockouts

ANSI 61 Gray Light-Textured	Price	Body/Door Steel Gauge	Enclosure Size HxWxD	Knockout Patterns
RSC040404*	\$24.00	16/16	4.25 x 4.63 x 4.63 [108 x 118 x 118]	A
RSC040604*	\$28.50	16/16	6.25 x 4.63 x 4.63 [159 x 118 x 118]	A
RSC060604	\$30.50	16/16	6.25 x 6.63 x 4.63 [159 x 168 x 118]	A-B-A
RSC060606	\$32.00	16/16	6.25 x 6.63 x 6.63 [159 x 168 x 168]	A-B-A
RSC060804	\$35.00	16/16	8.25 x 6.63 x 4.63 [210 x 168 x 118]	A-B-A
RSC060806	\$40.50	16/16	8.25 x 6.63 x 6.63 [210 x 168 x 168]	A-B-A
RSC080804	\$40.00	16/16	8.25 x 8.63 x 4.63 [210 x 219 x 118]	A-B-A
RSC080806	\$47.00	16/16	8.25 x 8.63 x 6.63 [210 x 219 x 168]	A-B-A
RSC081004	\$45.50	16/16	10.25 x 8.63 x 4.63 [260 x 219 x 118]	A-B-A
RSC081006	\$53.00	16/16	10.25 x 8.63 x 6.63 [260 x 219 x 168]	A-B-A
RSC081206	\$59.00	16/16	12.25 x 8.63 x 6.63 [311 x 219 x 168]	A-B-A
RSC101004	\$51.00	16/16	10.25 x 10.63 x 4.63 [260 x 270 x 118]	B-A-F-F-A
RSC101006	\$60.00	16/16	10.25 x 10.63 x 6.63 [260 x 270 x 168]	B-A-F-F-A
RSC101204	\$58.00	16/16	12.19 x 10.63 x 4.63 [310 x 270 x 118]	B-A-F-F-A
RSC101206	\$67.00	16/16	12.19 x 10.63 x 6.63 [310 x 270 x 168]	B-A-F-F-A
RSC121204	\$65.00	16/16	12.19 x 12.63 x 4.63 [310 x 321 x 118]	B-A-F-F-A-B
RSC121206	\$75.00	16/16	12.19 x 12.63 x 6.63 [310 x 321 x 168]	B-A-F-F-A-B
RSC121504	\$74.00	16/16	15.19 x 12.63 x 4.63 [386 x 321 x 118]	B-A-F-F-A-B
RSC121506	\$86.00	16/16	15.19 x 12.63 x 6.63 [386 x 321 x 168]	B-A-F-F-A-B
RSC121806	\$107.00	16/16	18.19 x 12.63 x 6.63 [462 x 321 x 168]	B-A-F-F-A-B
RSC151806	\$126.00	16/16	18.19 x 15.63 x 6.63 [462 x 397 x 168]	A-B-A-F-F-A-B-A
RSC181804	\$132.00	16/16	18.19 x 18.63 x 4.63 [462 x 473 x 118]	A-B-A-F-F-A-B-A
RSC181806	\$151.00	16/16	18.19 x 18.63 x 6.63 [462 x 473 x 168]	A-B-A-F-F-A-B-A
RSC242406	\$227.00	14/14	24.19 x 24.62 x 6.63 [614 x 625 x 168]	A-B-A-F-F-A-B-A

Notes: Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.

*No hasp or meter seal.


Notes: To remove cover, move down, then out. 4x 4 x 4 in [102 x 102 x 102 mm] only has 2 mounting holes centered horizontally. 4x 6 x 4 in [102 x 152 x 102 mm] only has 2 mounting holes centered vertically.

A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount



Dimensions

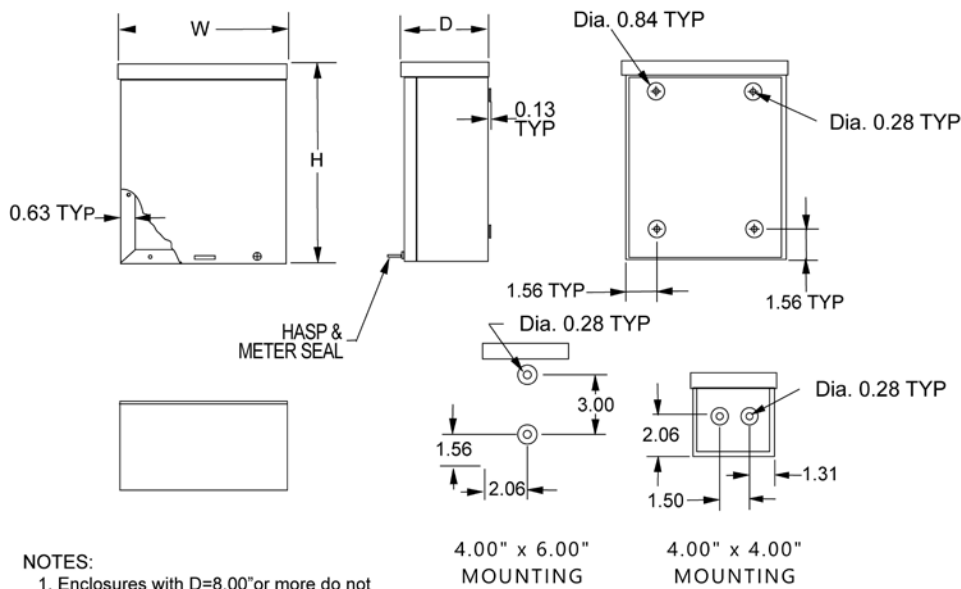

Grounding Kit		
Part Number	Description	Price
WGNDKT	Grounding Kit	\$3.25
Note: Field grounding kit includes necessary parts to properly ground enclosure.		

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.