

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount without Knockouts



Shipping Schedule

Same day 1 - 5 days 1 - 7 days 1-10 days 1 - 15 days 1 - 20 days

Color indicates shipping lead time in business days.

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount without Knockouts

| ANSI 61 Gray Light-Textured | Price | Body/Door Steel Gauge | Enclosure Size HxWxD |
|------------------------------|----------|-----------------------|---|
| RSC040404NK* | \$24.00 | 16/16 | 4.25 x 4.63 x 4.63 [108 x 118 x 118] |
| RSC040604NK* | \$28.50 | 16/16 | 6.25 x 4.63 x 4.63 [159 x 118 x 118] |
| RSC060604NK | \$30.50 | 16/16 | 6.25 x 6.63 x 4.63 [159 x 168 x 118] |
| RSC060606NK | \$32.00 | 16/16 | 6.25 x 6.63 x 6.63 [159 x 168 x 168] |
| RSC060804NK | \$35.00 | 16/16 | 8.25 x 6.63 x 4.63 [210 x 168 x 118] |
| RSC060806NK | \$40.50 | 16/16 | 8.25 x 6.63 x 6.63 [210 x 168 x 168] |
| RSC080804NK | \$40.00 | 16/16 | 8.25 x 8.63 x 4.63 [210 x 219 x 118] |
| RSC080806NK | \$47.00 | 16/16 | 8.25 x 8.63 x 6.63 [210 x 219 x 168] |
| RSC081004NK | \$45.50 | 16/16 | 10.25 x 8.63 x 4.63 [260 x 219 x 118] |
| RSC081006NK | \$53.00 | 16/16 | 10.25 x 8.63 x 6.63 [260 x 219 x 168] |
| RSC081206NK | \$59.00 | 16/16 | 12.25 x 8.63 x 6.63 [311 x 219 x 168] |
| RSC101004NK | \$51.00 | 16/16 | 10.25 x 10.63 x 4.63 [260 x 270 x 118] |
| RSC101006NK | \$60.00 | 16/16 | 10.25 x 10.63 x 6.63 [260 x 270 x 168] |
| RSC101204NK | \$58.00 | 16/16 | 12.25 x 10.63 x 4.63 [311 x 270 x 118] |
| RSC101206NK | \$67.00 | 16/16 | 12.25 x 10.63 x 6.63 [311 x 270 x 168] |
| RSC121204NK | \$65.00 | 16/16 | 12.25 x 12.63 x 4.63 [311 x 321 x 118] |
| RSC121206NK | \$75.00 | 16/16 | 12.25 x 12.63 x 6.63 [311 x 321 x 168] |
| RSC121208 | \$91.00 | 16/16 | 12.06 x 12.31 x 8.38 [306 x 313 x 213] |
| RSC121210 | \$95.00 | 16/16 | 12.06 x 12.31 x 10.38 [306 x 313 x 264] |
| RSC121504NK | \$74.00 | 16/16 | 15.25 x 12.63 x 4.63 [387 x 321 x 118] |
| RSC121506NK | \$86.00 | 16/16 | 15.25 x 12.63 x 6.63 [387 x 321 x 168] |
| RSC121806NK | \$107.00 | 16/16 | 18.25 x 12.63 x 6.63 [464 x 321 x 168] |
| RSC121808 | \$112.00 | 16/16 | 18.06 x 12.31 x 8.38 [459 x 313 x 213] |
| RSC151806NK | \$126.00 | 16/16 | 18.25 x 15.63 x 6.63 [464 x 397 x 168] |
| RSC151808 | \$136.00 | 16/16 | 18.06 x 15.31 x 8.38 [459 x 389 x 213] |
| RSC161610 | \$126.00 | 16/16 | 16.06 x 16.31 x 10.38 [408 x 414 x 264] |
| RSC181804NK | \$132.00 | 16/16 | 18.25 x 18.63 x 4.63 [464 x 473 x 118] |
| RSC181806NK | \$151.00 | 16/16 | 18.25 x 18.63 x 6.63 [464 x 473 x 168] |
| RSC181808 | \$169.00 | 16/16 | 18.06 x 18.31 x 8.38 [459 x 465 x 213] |
| RSC182406NK | \$191.00 | 16/16 | 24.25 x 18.63 x 6.63 [616 x 473 x 168] |
| RSC242406NK | \$227.00 | 14/14 | 24.25 x 24.62 x 6.63 [616 x 625 x 168] |
| RSC242408 | \$256.00 | 14/14 | 24.07 x 24.34 x 8.38 [611 x 618 x 213] |
| RSC242416 | \$360.00 | 14/14 | 24.07 x 24.34 x 16.38 [611 x 618 x 416] |
| RSC303012 | \$551.00 | 12/12 | 30.09 x 30.37 x 12.38 [764 x 771 x 314] |
| RSC303016 | \$568.00 | 12/12 | 30.09 x 30.37 x 16.38 [764 x 771 x 416] |
| RSC363612 | \$724.00 | 12/12 | 36.09 x 36.37 x 12.38 [917 x 924 x 314] |
| RSC363616 | \$733.00 | 12/12 | 36.09 x 36.37 x 16.38 [917 x 924 x 416] |

Notes: Dimensions in inches [millimeters]; letters in table correspond to letters on dimensional drawings.

*No hasp or meter seal



Applications

Designed for use as wiring boxes and junction boxes, these enclosures provide protection against rain, sleet and snow in outdoor applications, or against dripping water indoors.

Construction

- Bodies and doors fabricated from 12-, 14-, or 16-gauge carbon steel (see table)
- Drip shield top and smooth seamless sides and front
- Slip-on reversible cover securely fastened with screws located along bottom edge
- No gasket required
- Hasp for padlocking or meter seal is provided except as noted

Finish

- ANSI 61 gray polyester powder light texture inside and out over phosphatized surfaces
- Unpainted, pre-galvanized steel

Listings

- UL 50, Types 1 and 3R [UL file E23553]
- NEMA/EEMAC 1 and 3R




Note: To remove cover, move down, then out. 4x 4 x 4 in [102 x 102 x 102 mm] only has 2 mounting holes centered horizontally. 4x 6 x 4 in [102 x 152 x 102 mm] only has 2 mounting holes centered vertically.

RSC Series NEMA 1 and 3R Screw Cover Wall-Mount



Dimensions

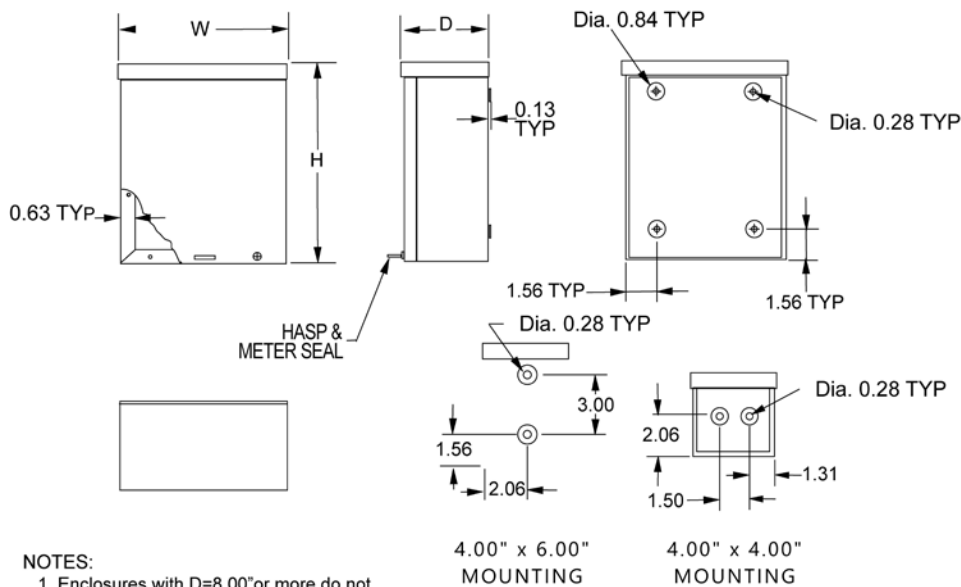

NOTES:
1. Enclosures with D=8.00" or more do not have an internal flange.

| Grounding Kit | | |
|--|---------------|--------|
| Part Number | Description | Price |
| WGNDKT | Grounding Kit | \$3.25 |
| Note: Field grounding kit includes necessary parts to properly ground enclosure. | | |

Note: A WGNDKT must be ordered with each RSC enclosure to meet the CSA standard.