

# Enclosure Accessories

## Deep-Hinged Doors



**SCE-HA1010LG**

Designed to house electrical controls, instruments, and components used in an indoor or outdoor environment to provide a degree of protection for the equipment inside the enclosure against ingress of solid foreign objects (falling dirt); and provide a degree of protection with respect to the harmful effects on the equipment due to the ingress of water (rain, sleet, snow). ELJ hinges. Black, mini 1/4-turn latches Gasket and hardware included.


### Listings

- Carbon Steel:
  - NEMA Type 3R, 4, 12, and 13
  - UL Listed Type 3R, 4 & 12 [File E69392]
- Stainless Steel:
  - NEMA Type 3R, 4, 4X, 12, and 13
  - UL Listed Type 3R, 4, 4X, 12, and 13 [File E69392]

Deep-Hinged Doors							
RAL7035	ANSI 61	White	Price	304 Stainless Steel	Price	Size HxWxD	Drawing Link
<a href="#"><u>SCE-HA1010LG</u></a>	<a href="#"><u>SCE-HA1010</u></a>	<a href="#"><u>SCE-HA1010-05</u></a>	\$271.00	<a href="#"><u>SCE-HA1010SS</u></a>	\$619.00	10.00 x 10.00 x 2.63 [254 x 254 x 67]	<a href="#"><u>PDF</u></a>
—	<a href="#"><u>SCE-HA1014</u></a>	—	\$286.00	<a href="#"><u>SCE-HA1014SS</u></a>	\$618.00	10.00 x 14.00 x 2.63 [254 x 356 x 67]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-HA1212LG</u></a>	<a href="#"><u>SCE-HA1212</u></a>	<a href="#"><u>SCE-HA1212-05</u></a>	\$294.00	<a href="#"><u>SCE-HA1212SS</u></a>	\$647.00	12.00 x 12.00 x 2.63 [305 x 305 x 67]	<a href="#"><u>PDF</u></a>
—	<a href="#"><u>SCE-HA1216</u></a>	—	\$309.00	<a href="#"><u>SCE-HA1216SS</u></a>	\$668.00	12.00 x 16.00 x 2.63 [305 x 406 x 67]	<a href="#"><u>PDF</u></a>
	<a href="#"><u>SCE-HA1418</u></a>		\$348.00	<a href="#"><u>SCE-HA1418SS</u></a>	\$887.00	14.00 x 18.00 x 2.63 [356 x 457 x 67]	<a href="#"><u>PDF</u></a>
	<a href="#"><u>SCE-HA1620</u></a>		\$380.00	<a href="#"><u>SCE-HA1620SS</u></a>	\$822.00	16.00 x 20.00 x 2.63 [406 x 508 x 67]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-HA1814LG</u></a>	<a href="#"><u>SCE-HA1814</u></a>	—	\$348.00	<a href="#"><u>SCE-HA1814SS</u></a>	\$887.00	18.00 x 14.00 x 2.63 [457 x 356 x 67]	<a href="#"><u>PDF</u></a>
Note: Dimensions in inches [millimeters].							

# Enclosure Accessories

## Deep-Hinged Doors with Windows

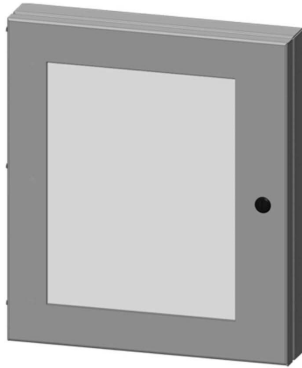

[SCE-HWK1212](#)

Designed to mount on the exterior of an enclosure to provide protection for controls with easy access. ELJ hinges. Black, mini 1/4-turn latches UV stable Polycarbonate viewing window. Gasket and hardware included. Made of heavy gauge carbon steel and powder coated.

"SS" parts made of heavy gauge stainless steel Type 304 with #4 brushed finish. Recommend use as Type 3R rating in full outdoor exposure and extreme weather environments – the addition of ventilation is necessary to handle the large negative pressure differential caused in a tightly sealed enclosure in extreme weather conditions. Temperatures that may exceed 140°F, such as outdoor in direct sunlight should be evaluated, shading or sun shield may be necessary.

### Listings

- NEMA Type 3R, 12, & 13
- UL Recognized Type 3R & 12

Deep-Hinged Doors with Windows								
ANSI 61	RAL 7035	Price	304 Stainless Steel	Price	Overall Size HxWxD	Window Size HxW	Maximum Cut-Out Size HxW	Drawing Link
<u><a href="#">SCE-HWK1014</a></u>	—	\$312.00	<u><a href="#">SCE-HWK1014SS</a></u>	\$674.00	10.00 x 14.00 x 2.63 [254 x 356 x 67]	6.00 x 9.38 [152 x 238]	7.50 x 11.50 [191 x 292]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK1212</a></u>	<u><a href="#">SCE-HWK1212LG</a></u>	\$339.00	<u><a href="#">SCE-HWK1212SS</a></u>	\$700.00	12.00 x 12.00 x 2.63 [305 x 305 x 67]	8.00 x 7.38 [203 x 187]	9.50 x 9.50 [241 x 241]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK1216</a></u>	—	\$380.00	<u><a href="#">SCE-HWK1216SS</a></u>	\$822.00	12.00 x 16.00 x 2.63 [305 x 406 x 67]	8.00 x 11.38 [203 x 289]	9.50 x 13.50 [241 x 343]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK1312</a></u>	—	\$355.00	—	—	13.00 x 12.00 x 2.63 [330 x 305 x 67]	8.00 x 7.38 [203 x 187]	10.50 x 9.50 [267 x 241]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK1418</a></u>	—	\$393.00	<u><a href="#">SCE-HWK1418SS</a></u>	\$850.00	14.00 x 18.00 x 2.63 [356 x 457 x 67]	10.00 x 13.38 [254 x 340]	11.50 x 15.50 [292 x 394]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK1620</a></u>	—	\$437.00	<u><a href="#">SCE-HWK1620SS</a></u>	\$943.00	16.00 x 20.00 x 2.63 [406 x 508 x 67]	12.00 x 15.38 [305 x 391]	13.50 x 17.50 [343 x 445]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK1814</a></u>	<u><a href="#">SCE-HWK1814LG</a></u>	\$393.00	<u><a href="#">SCE-HWK1814SS</a></u>	\$950.00	18.00 x 14.00 x 2.63 [457 x 356 x 67]	14.00 x 9.38 [356 x 238]	15.50 x 11.50 [394 x 292]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK2218</a></u>	<u><a href="#">SCE-HWK2218LG</a></u>	\$475.00	<u><a href="#">SCE-HWK2218SS</a></u>	\$1,145.00	22.00 x 18.00 x 2.63 [559 x 457 x 67]	18.00 x 13.38 [457 x 340]	19.50 x 15.50 [495 x 394]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK2228</a></u>	<u><a href="#">SCE-HWK2228LG</a></u>	\$543.00	<u><a href="#">SCE-HWK2228SS</a></u>	\$1,416.00	22.00 x 28.00 x 2.63 [559 x 711 x 67]	(2) 18.00 x 10.56 [457 x 268]	19.50 x 25.50 [495 x 648]	<u><a href="#">PDF</a></u>
<u><a href="#">SCE-HWK2822</a></u>	<u><a href="#">SCE-HWK2822LG</a></u>	\$543.00	<u><a href="#">SCE-HWK2822SS</a></u>	\$1,416.00	28.00 x 22.00 x 2.63 [711 x 559 x 67]	(2) 10.88 x 17.38 [276 x 441]	25.50 x 19.50 [648 x 495]	<u><a href="#">PDF</a></u>

Note: Dimensions in inches [millimeters].

# Enclosure Accessories

## Hinges and Hinge Pins



Standard replacement hinges for standard Saginaw enclosures. Includes hinge, pin, and clip.



SCE-3916



SCE-ELJHINGE



SCE-101670



SCE-101221

Replacement Hinges					
Carbon Steel	Price	304 Stainless Steel	Price	Description	Qty
<u>SCE-3916</u>	\$13.75	<u>SCE-3916SS</u>	\$29.00	large concealed hinge	1
<u>SCE-3918</u>	\$22.00	<u>SCE-3918SS</u>	\$53.00	small concealed hinge	1
<u>SCE-ELJHINGE</u>	\$7.50	—	—	ELJ hinge	1
<u>SCE-101670</u>	\$14.00	—	—	retaining clip for concealed hinge	1
<u>SCE-101221</u>	\$35.50	—	—	large hinge pin	20
<u>SCE-101226</u>	\$67.00	—	—	small hinge pin	20

# Enclosure Accessories

## Enclosure Windows



SCE-PWK53NF

Designed for use on most SCE Type 4, 4X and 12 enclosures. Includes frame, window, oil-resistant gasket, and mounting hardware. Installed by making a cutout in the enclosure and fastening the window and frame in place.

The window is 0.25" UV stable polycarbonate material. Made of heavy gauge steel and powder coated ANSI 61 gray. "SS" kits are made of Type 304 stainless with #4 brushed finish. Recommend use as Type 3R rating in full outdoor exposure and extreme weather environments.

### Listings

- NEMA Type 1, 3R, 4, 4X & 12
- UL Recognized Type 1, 3R & 12

UV-Resistant Window Kits					
Carbon Steel	Price	304 Stainless Steel	Price	Window Size HxW	Drawing Link
<a href="#"><u>SCE-PWK53NF</u></a>	\$132.00	<a href="#"><u>SCE-PWK53NFSS</u></a>	\$198.00	5.25 x 3.25 [133 x 83]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-PWK63NF</u></a>	\$145.00	—	—	6.55 x 2.85 [166 x 72]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-PWK95NF</u></a>	\$158.00	<a href="#"><u>SCE-PWK95NFSS</u></a>	\$239.00	9.25 x 5.75 [235 x 146]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-PWK138NF</u></a>	\$201.00	<a href="#"><u>SCE-PWK138NFSS</u></a>	\$304.00	13.25 x 8.25 [337 x 210]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-PWK1711NF</u></a>	\$277.00	<a href="#"><u>SCE-PWK1711NFSS</u></a>	\$399.00	17.25 x 11.25 [438 x 286]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-PWK2315NF</u></a>	\$341.00	<a href="#"><u>SCE-PWK2315NFSS</u></a>	\$516.00	23.25 x 15.25 [591 x 387]	<a href="#"><u>PDF</u></a>
<a href="#"><u>SCE-PWK2919NF</u></a>	\$508.00	<a href="#"><u>SCE-PWK2919NFSS</u></a>	\$765.00	29.25 x 19.25 [743 x 489]	<a href="#"><u>PDF</u></a>

Note: Dimensions in inches [millimeters].