


# Enclosure Accessories

## Floor Stands



Your Enclosure Source®

- Can be installed on most wall-mounted enclosures with a width of 20in or more.
- Can also be installed on SCE freestanding enclosures
- Kits include two stands
- Carbon steel

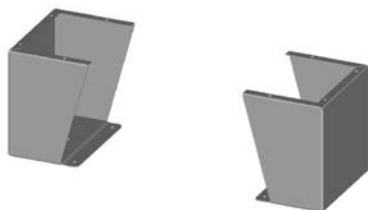

SCE-FK0418

### Gray Floor Stands

| ANSI 61                    | RAL 7035                     | Price    | For Use With | Stand Height | Drawing Link        |
|----------------------------|------------------------------|----------|--------------|--------------|---------------------|
| <a href="#">SCE-FK0608</a> | <a href="#">SCE-FK0608LG</a> | \$148.00 | 8in deep     | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1208</a> | <a href="#">SCE-FK1208LG</a> | \$185.00 | 8in deep     | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1808</a> | <a href="#">SCE-FK1808LG</a> | \$224.00 | 8in deep     | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK2408</a> | —                            | \$235.00 | 8in deep     | 24.00 [610]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0610</a> | <a href="#">SCE-FK0610LG</a> | \$155.00 | 10in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1210</a> | <a href="#">SCE-FK1210LG</a> | \$195.00 | 10in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1810</a> | <a href="#">SCE-FK1810LG</a> | \$238.00 | 10in deep    | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK2410</a> | —                            | \$257.00 | 10in deep    | 24.00 [610]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0612</a> | <a href="#">SCE-FK0612LG</a> | \$175.00 | 12in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1212</a> | <a href="#">SCE-FK1212LG</a> | \$205.00 | 12in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1512</a> | <a href="#">SCE-FK1512LG</a> | \$238.00 | 12in deep    | 15.00 [381]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1812</a> | <a href="#">SCE-FK1812LG</a> | \$247.00 | 12in deep    | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK2412</a> | <a href="#">SCE-FK2412LG</a> | \$262.00 | 12in deep    | 24.00 [610]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0614</a> | —                            | \$197.00 | 14in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1214</a> | —                            | \$236.00 | 14in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0616</a> | —                            | \$201.00 | 16in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1216</a> | <a href="#">SCE-FK1216LG</a> | \$238.00 | 16in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1516</a> | <a href="#">SCE-FK1516LG</a> | \$247.00 | 16in deep    | 15.00 [381]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1816</a> | <a href="#">SCE-FK1816LG</a> | \$274.00 | 16in deep    | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK2416</a> | —                            | \$313.00 | 16in deep    | 24.00 [610]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0418</a> | <a href="#">SCE-FK0418LG</a> | \$196.00 | 18in deep    | 4.00 [102]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK0618</a> | <a href="#">SCE-FK0618LG</a> | \$205.00 | 18in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1218</a> | <a href="#">SCE-FK1218LG</a> | \$247.00 | 18in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1518</a> | <a href="#">SCE-FK1518LG</a> | \$269.00 | 18in deep    | 15.00 [381]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1818</a> | —                            | \$387.00 | 18in deep    | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0620</a> | —                            | \$221.00 | 20in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1220</a> | <a href="#">SCE-FK1220LG</a> | \$261.00 | 20in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0624</a> | <a href="#">SCE-FK0624LG</a> | \$238.00 | 24in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1224</a> | <a href="#">SCE-FK1224LG</a> | \$267.00 | 24in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1524</a> | <a href="#">SCE-FK1524LG</a> | \$294.00 | 24in deep    | 15.00 [381]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1824</a> | <a href="#">SCE-FK1824LG</a> | \$346.00 | 24in deep    | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0636</a> | —                            | \$296.00 | 36in deep    | 6.00 [152]   | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

### White Floor Stands

| Part Number                   | Price    | For Use With | Stand Height | Drawing Link        |
|-------------------------------|----------|--------------|--------------|---------------------|
| <a href="#">SCE-FK1214-05</a> | \$236.00 | 14in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1216-05</a> | \$238.00 | 16in deep    | 12.00 [305]  | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].


# Enclosure Accessories

## Floor Stands



Your Enclosure Source®

- Can be installed on most wall-mounted enclosures with a width of 20in or more
- Can also be installed on SCE free-standing enclosures
- Kits include two stands
- Made of stainless steel Type 304 with #4 brushed finish or stainless steel Type 316/316L with #4 brushed finish

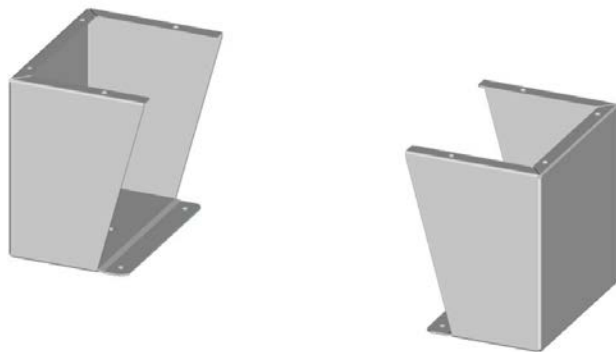

[SCE-FK1208SS](#)

### 304 Stainless Steel Floor Stand

| 304 Stainless Steel          | Price    | 304 Stainless Steel           | Price    | For Use With | Stand Height | Drawing Link        |
|------------------------------|----------|-------------------------------|----------|--------------|--------------|---------------------|
| <a href="#">SCE-FK1208SS</a> | \$505.00 | —                             | —        | 8in deep     | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1210SS</a> | \$544.00 | —                             | —        | 10in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK2410SS</a> | \$772.00 | —                             | —        | 10in deep    | 24.00 [610]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1212SS</a> | \$581.00 | <a href="#">SCE-FK1212SS6</a> | \$697.00 | 12in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1512SS</a> | \$713.00 | <a href="#">SCE-FK1512SS6</a> | \$855.00 | 12in deep    | 15.00 [381]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1812SS</a> | \$745.00 | —                             | —        | 12in deep    | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK2412SS</a> | \$808.00 | <a href="#">SCE-FK2412SS6</a> | \$970.00 | 12in deep    | 24.00 [610]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0616SS</a> | \$555.00 | —                             | —        | 16in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1216SS</a> | \$660.00 | <a href="#">SCE-FK1216SS6</a> | \$792.00 | 16in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK2416SS</a> | \$941.00 | —                             | —        | 16in deep    | 24.00 [610]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0618SS</a> | \$588.00 | —                             | —        | 18in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1218SS</a> | \$696.00 | <a href="#">SCE-FK1218SS6</a> | \$835.00 | 18in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1518SS</a> | \$777.00 | <a href="#">SCE-FK1518SS6</a> | \$932.00 | 18in deep    | 15.00 [381]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1818SS</a> | \$798.00 | <a href="#">SCE-FK1818SS6</a> | \$957.00 | 18in deep    | 18.00 [457]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1220SS</a> | \$685.00 | —                             | —        | 20in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK0624SS</a> | \$683.00 | —                             | —        | 24in deep    | 6.00 [152]   | <a href="#">PDF</a> |
| <a href="#">SCE-FK1224SS</a> | \$734.00 | <a href="#">SCE-FK1224SS6</a> | \$881.00 | 24in deep    | 12.00 [305]  | <a href="#">PDF</a> |
| <a href="#">SCE-FK1524SS</a> | \$822.00 | <a href="#">SCE-FK1524SS6</a> | \$986.00 | 24in deep    | 15.00 [381]  | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

# Enclosure Accessories

## Floor Stand Skirts



Designed for use with standard floor stands to restrict access or conceal the area under the enclosure. Vented skirts available to conceal transformers or other devices in this area while allowing air circulation. Heavy gauge construction. Each skirt panel will fit a range of enclosure widths. Installed by drilling holes in floor stand kit (not included). Skirt Kit includes two panels and mounting hardware.

### Material

- Carbon Steel, Powder Coated ANSI 61 Gray
- Stainless Steel Type 304 Stainless Steel, #4 Brushed Finish on all exterior surfaces

### Non-Vented



### Vented



SCE-SK126068SS

SCE-SKL127280SS

| Carbon Steel Skirts          |          |                               |          |                            |                                          |                     |
|------------------------------|----------|-------------------------------|----------|----------------------------|------------------------------------------|---------------------|
| Non-Vented                   | Price    | Vented                        | Price    | Size HxW                   | For Use With                             | Drawing Link        |
| <a href="#">SCE-SK123644</a> | \$236.00 | <a href="#">SCE-SKL123644</a> | \$303.00 | 11.94 x 35.75 [303 x 908]  | 36-44in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK124856</a> | \$282.00 | <a href="#">SCE-SKL124856</a> | \$349.00 | 11.94 x 47.75 [303 x 1213] | 48-56in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK126068</a> | \$328.00 | <a href="#">SCE-SKL126068</a> | \$395.00 | 11.94 x 59.75 [303 x 1518] | 60-68in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK127280</a> | \$374.00 | <a href="#">SCE-SKL127280</a> | \$441.00 | 11.94 x 71.75 [303 x 1822] | 72-80in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK153644</a> | \$271.00 | <a href="#">SCE-SKL153644</a> | \$337.00 | 14.94 x 35.75 [379 x 908]  | 36-44in floor-mount on 15in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK154856</a> | \$328.00 | <a href="#">SCE-SKL154856</a> | \$394.00 | 14.94 x 47.75 [379 x 1213] | 48-56in floor-mount on 15in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK156068</a> | \$385.00 | <a href="#">SCE-SKL156068</a> | \$452.00 | 14.94 x 59.75 [379 x 1518] | 60-68in floor-mount on 15in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK157280</a> | \$443.00 | <a href="#">SCE-SKL157280</a> | \$509.00 | 14.94 x 71.75 [379 x 1822] | 72-80in floor-mount on 15in floor stands | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].

| 304 Stainless Steel Skirts     |            |                                 |            |                            |                                          |                     |
|--------------------------------|------------|---------------------------------|------------|----------------------------|------------------------------------------|---------------------|
| Non-Vented                     | Price      | Vented                          | Price      | Size HxW                   | For Use With                             | Drawing Link        |
| <a href="#">SCE-SK123644SS</a> | \$442.00   | <a href="#">SCE-SKL123644SS</a> | \$508.00   | 11.94 x 35.75 [303 x 908]  | 36-44in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK124856SS</a> | \$556.00   | <a href="#">SCE-SKL124856SS</a> | \$623.00   | 11.94 x 47.75 [303 x 1213] | 48-56in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK126068SS</a> | \$671.00   | <a href="#">SCE-SKL126068SS</a> | \$738.00   | 11.94 x 59.75 [303 x 1518] | 60-68in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK127280SS</a> | \$786.00   | <a href="#">SCE-SKL127280SS</a> | \$852.00   | 11.94 x 71.75 [303 x 1822] | 72-80in floor-mount on 12in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK153644SS</a> | \$527.00   | <a href="#">SCE-SKL153644SS</a> | \$593.00   | 14.94 x 35.75 [379 x 908]  | 36-44in floor-mount on 15in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK154856SS</a> | \$671.00   | <a href="#">SCE-SKL154856SS</a> | \$737.00   | 14.94 x 47.75 [379 x 1213] | 48-56in floor-mount on 15in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK156068SS</a> | \$814.00   | <a href="#">SCE-SKL156068SS</a> | \$880.00   | 14.94 x 59.75 [379 x 1518] | 60-68in floor-mount on 15in floor stands | <a href="#">PDF</a> |
| <a href="#">SCE-SK157280SS</a> | \$1,024.00 | <a href="#">SCE-SKL157280SS</a> | \$1,024.00 | 14.94 x 71.75 [379 x 1822] | 72-80in floor-mount on 15in floor stands | <a href="#">PDF</a> |

Note: Dimensions in inches [millimeters].