


Enclosure Accessories

Floor Stands



Your Enclosure Source®

- Can be installed on most wall-mounted enclosures with a width of 20in or more.
- Can also be installed on SCE freestanding enclosures
- Kits include two stands
- Carbon steel

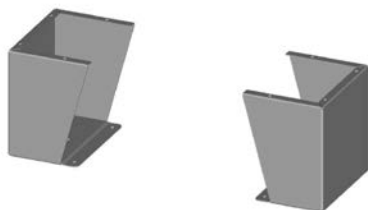

SCE-FK0418

Gray Floor Stands

ANSI 61	RAL 7035	Price	For Use With	Stand Height	Drawing Link
SCE-FK0608	SCE-FK0608LG	\$162.00	8in deep	6.00 [152]	PDF
SCE-FK1208	SCE-FK1208LG	\$201.00	8in deep	12.00 [305]	PDF
SCE-FK1808	SCE-FK1808LG	\$245.00	8in deep	18.00 [457]	PDF
SCE-FK2408	—	\$256.00	8in deep	24.00 [610]	PDF
SCE-FK0610	SCE-FK0610LG	\$169.00	10in deep	6.00 [152]	PDF
SCE-FK1210	SCE-FK1210LG	\$212.00	10in deep	12.00 [305]	PDF
SCE-FK1810	SCE-FK1810LG	\$259.00	10in deep	18.00 [457]	PDF
SCE-FK2410	—	\$280.00	10in deep	24.00 [610]	PDF
SCE-FK0612	SCE-FK0612LG	\$191.00	12in deep	6.00 [152]	PDF
SCE-FK1212	SCE-FK1212LG	\$223.00	12in deep	12.00 [305]	PDF
SCE-FK1512	SCE-FK1512LG	\$259.00	12in deep	15.00 [381]	PDF
SCE-FK1812	SCE-FK1812LG	\$270.00	12in deep	18.00 [457]	PDF
SCE-FK2412	SCE-FK2412LG	\$285.00	12in deep	24.00 [610]	PDF
SCE-FK0614	—	\$215.00	14in deep	6.00 [152]	PDF
SCE-FK1214	—	\$257.00	14in deep	12.00 [305]	PDF
SCE-FK0616	—	\$219.00	16in deep	6.00 [152]	PDF
SCE-FK1216	SCE-FK1216LG	\$259.00	16in deep	12.00 [305]	PDF
SCE-FK1516	SCE-FK1516LG	\$270.00	16in deep	15.00 [381]	PDF
SCE-FK1816	SCE-FK1816LG	\$299.00	16in deep	18.00 [457]	PDF
SCE-FK2416	—	\$341.00	16in deep	24.00 [610]	PDF
SCE-FK0418	SCE-FK0418LG	\$214.00	18in deep	4.00 [102]	PDF
SCE-FK0618	SCE-FK0618LG	\$223.00	18in deep	6.00 [152]	PDF
SCE-FK1218	SCE-FK1218LG	\$270.00	18in deep	12.00 [305]	PDF
SCE-FK1518	SCE-FK1518LG	\$294.00	18in deep	15.00 [381]	PDF
SCE-FK1818	—	\$422.00	18in deep	18.00 [457]	PDF
SCE-FK0620	—	\$241.00	20in deep	6.00 [152]	PDF
SCE-FK1220	SCE-FK1220LG	\$284.00	20in deep	12.00 [305]	PDF
SCE-FK0624	SCE-FK0624LG	\$259.00	24in deep	6.00 [152]	PDF
SCE-FK1224	SCE-FK1224LG	\$291.00	24in deep	12.00 [305]	PDF
SCE-FK1524	SCE-FK1524LG	\$320.00	24in deep	15.00 [381]	PDF
SCE-FK1824	SCE-FK1824LG	\$378.00	24in deep	18.00 [457]	PDF
SCE-FK0636	—	\$323.00	36in deep	6.00 [152]	PDF

Note: Dimensions in inches [millimeters].

White Floor Stands

Part Number	Price	For Use With	Stand Height	Drawing Link
SCE-FK1214-05	\$257.00	14in deep	12.00 [305]	PDF
SCE-FK1216-05	\$259.00	16in deep	12.00 [305]	PDF

Note: Dimensions in inches [millimeters].


Enclosure Accessories

Floor Stands



Your Enclosure Source®

- Can be installed on most wall-mounted enclosures with a width of 20in or more
- Can also be installed on SCE free-standing enclosures
- Kits include two stands
- Made of stainless steel Type 304 with #4 brushed finish or stainless steel Type 316/316L with #4 brushed finish

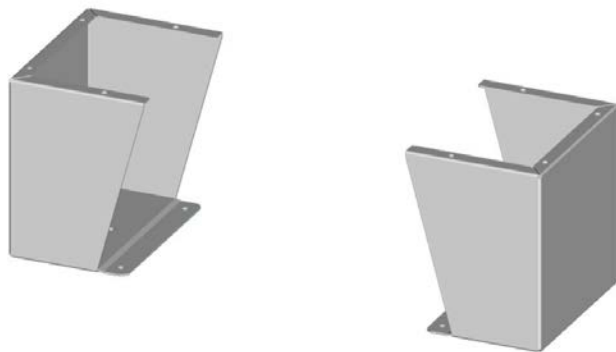

[SCE-FK1208SS](#)

304 Stainless Steel Floor Stand						
304 Stainless Steel	Price	304 Stainless Steel	Price	For Use With	Stand Height	Drawing Link
<u>SCE-FK1208SS</u>	\$479.00	—	—	8in deep	12.00 [305]	<u>PDF</u>
<u>SCE-FK1210SS</u>	\$517.00	—	—	10in deep	12.00 [305]	<u>PDF</u>
<u>SCE-FK2410SS</u>	\$733.00	—	—	10in deep	24.00 [610]	<u>PDF</u>
<u>SCE-FK1212SS</u>	\$551.00	<u>SCE-FK1212SS6</u>	\$634.00	12in deep	12.00 [305]	<u>PDF</u>
<u>SCE-FK1512SS</u>	\$677.00	<u>SCE-FK1512SS6</u>	\$778.00	12in deep	15.00 [381]	<u>PDF</u>
<u>SCE-FK1812SS</u>	\$707.00	—	—	12in deep	18.00 [457]	<u>PDF</u>
<u>SCE-FK2412SS</u>	\$767.00	<u>SCE-FK2412SS6</u>	\$883.00	12in deep	24.00 [610]	<u>PDF</u>
<u>SCE-FK0616SS</u>	\$527.00	—	—	16in deep	6.00 [152]	<u>PDF</u>
<u>SCE-FK1216SS</u>	\$626.00	<u>SCE-FK1216SS6</u>	\$720.00	16in deep	12.00 [305]	<u>PDF</u>
<u>SCE-FK2416SS</u>	\$893.00	—	—	16in deep	24.00 [610]	<u>PDF</u>
<u>SCE-FK0618SS</u>	\$558.00	—	—	18in deep	6.00 [152]	<u>PDF</u>
<u>SCE-FK1218SS</u>	\$661.00	<u>SCE-FK1218SS6</u>	\$760.00	18in deep	12.00 [305]	<u>PDF</u>
<u>SCE-FK1518SS</u>	\$738.00	<u>SCE-FK1518SS6</u>	\$848.00	18in deep	15.00 [381]	<u>PDF</u>
<u>SCE-FK1818SS</u>	\$757.00	<u>SCE-FK1818SS6</u>	\$871.00	18in deep	18.00 [457]	<u>PDF</u>
<u>SCE-FK1220SS</u>	\$650.00	—	—	20in deep	12.00 [305]	<u>PDF</u>
<u>SCE-FK0624SS</u>	\$649.00	—	—	24in deep	6.00 [152]	<u>PDF</u>
<u>SCE-FK1224SS</u>	\$697.00	<u>SCE-FK1224SS6</u>	\$801.00	24in deep	12.00 [305]	<u>PDF</u>
<u>SCE-FK1524SS</u>	\$780.00	<u>SCE-FK1524SS6</u>	\$897.00	24in deep	15.00 [381]	<u>PDF</u>
Note: Dimensions in inches [millimeters].						

Enclosure Accessories

Floor Stand Skirts




Designed for use with standard floor stands to restrict access or conceal the area under the enclosure. Vented skirts available to conceal transformers or other devices in this area while allowing air circulation. Heavy gauge construction. Each skirt panel will fit a range of enclosure widths. Installed by drilling holes in floor stand kit (not included). Skirt Kit includes two panels and mounting hardware.

Material

- Carbon Steel, Powder Coated ANSI 61 Gray
- Stainless Steel Type 304 Stainless Steel, #4 Brushed Finish on all exterior surfaces

Non-Vented

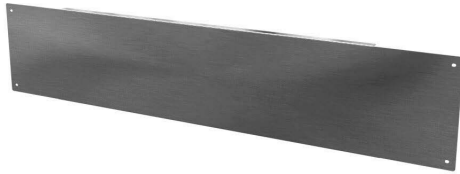

Vented



SCE-SK126068SS

SCE-SKL127280SS

Carbon Steel Skirts						
Non-Vented	Price	Vented	Price	Size HxW	For Use With	Drawing Link
SCE-SK123644	\$258.00	SCE-SKL123644	\$330.00	11.94 x 35.75 [303 x 908]	36-44in floor-mount on 12in floor stands	PDF
SCE-SK124856	\$308.00	SCE-SKL124856	\$380.00	11.94 x 47.75 [303 x 1213]	48-56in floor-mount on 12in floor stands	PDF
SCE-SK126068	\$358.00	SCE-SKL126068	\$430.00	11.94 x 59.75 [303 x 1518]	60-68in floor-mount on 12in floor stands	PDF
SCE-SK127280	\$408.00	SCE-SKL127280	\$480.00	11.94 x 71.75 [303 x 1822]	72-80in floor-mount on 12in floor stands	PDF
SCE-SK153644	\$295.00	SCE-SKL153644	\$367.00	14.94 x 35.75 [379 x 908]	36-44in floor-mount on 15in floor stands	PDF
SCE-SK154856	\$358.00	SCE-SKL154856	\$430.00	14.94 x 47.75 [379 x 1213]	48-56in floor-mount on 15in floor stands	PDF
SCE-SK156068	\$420.00	SCE-SKL156068	\$492.00	14.94 x 59.75 [379 x 1518]	60-68in floor-mount on 15in floor stands	PDF
SCE-SK157280	\$483.00	SCE-SKL157280	\$555.00	14.94 x 71.75 [379 x 1822]	72-80in floor-mount on 15in floor stands	PDF

Note: Dimensions in inches [millimeters].

304 Stainless Steel Skirts						
Non-Vented	Price	Vented	Price	Size HxW	For Use With	Drawing Link
SCE-SK123644SS	\$419.00	SCE-SKL123644SS	\$482.00	11.94 x 35.75 [303 x 908]	36-44in floor-mount on 12in floor stands	PDF
SCE-SK124856SS	\$528.00	SCE-SKL124856SS	\$591.00	11.94 x 47.75 [303 x 1213]	48-56in floor-mount on 12in floor stands	PDF
SCE-SK126068SS	\$637.00	SCE-SKL126068SS	\$700.00	11.94 x 59.75 [303 x 1518]	60-68in floor-mount on 12in floor stands	PDF
SCE-SK127280SS	\$746.00	SCE-SKL127280SS	\$809.00	11.94 x 71.75 [303 x 1822]	72-80in floor-mount on 12in floor stands	PDF
SCE-SK153644SS	\$500.00	SCE-SKL153644SS	\$563.00	14.94 x 35.75 [379 x 908]	36-44in floor-mount on 15in floor stands	PDF
SCE-SK154856SS	\$637.00	SCE-SKL154856SS	\$700.00	14.94 x 47.75 [379 x 1213]	48-56in floor-mount on 15in floor stands	PDF
SCE-SK156068SS	\$773.00	SCE-SKL156068SS	\$836.00	14.94 x 59.75 [379 x 1518]	60-68in floor-mount on 15in floor stands	PDF
SCE-SK157280SS	\$972.00	SCE-SKL157280SS	\$972.00	14.94 x 71.75 [379 x 1822]	72-80in floor-mount on 15in floor stands	PDF

Note: Dimensions in inches [millimeters].