

# NEMA 3R, 12, and 13 Multi-Door Freestanding



Your Enclosure Source®

## Applications

Designed to house electrical equipment and provide degree of protection from dirt, dust, oil and water.

## Construction


- 1/8 in [3mm] carbon steel
- Seams continuously welded and ground smooth
- Heavy-duty lifting eyes
- Reinforced top.
- Steel stiffeners welded to back inside of enclosure.
- two-door openings have no center post.
- Black zinc diecast padlocking handle.
- 3-point latching mechanism
- Concealed hinges
- Mechanical interlock
- Far right-hand door is main door.
- Panel supports
- Removable subpanels are mounted on collar studs.
- Poured-in-place oil- and water-resistant gasket
- Ground stud on door and body
- Removable print pocket
- Flange trough collar around all sides of door opening
- Hole plugs are provided to seal holes in bottom of enclosure.
- Provisions for light kit

## Finish

- ANSI 61 gray powder coated inside and out
- Optional subpanels are powder coated white.

## Listings

- NEMA Type 3R, 12, and 13
- cULus Listed Type 3R and 12 [File E69392]
- IEC 60529 IP55

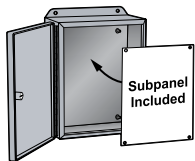

## Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

## NEMA 3R, 12, and 13 Multi-Door Freestanding

| Part Number                 | Price      | Size<br>HxWxD                              | Doors | Drawing<br>Link     | Included<br>Subpanel 1     | Price    | Included<br>Subpanel 2    | Price    |
|-----------------------------|------------|--------------------------------------------|-------|---------------------|----------------------------|----------|---------------------------|----------|
| <a href="#">SCE-86M3E</a>   | \$7,052.00 | 86.00 x 112.00 x 15.07 [2184 x 2845 x 383] | 3     | <a href="#">PDF</a> | <a href="#">SCE-82P76</a>  | \$696.00 | <a href="#">SCE-82P37</a> | \$387.00 |
| <a href="#">SCE-86M3E20</a> | \$7,766.00 | 86.00 x 112.00 x 21.07 [2184 x 2845 x 535] | 3     | <a href="#">PDF</a> | <a href="#">SCE-82P76</a>  | \$696.00 | <a href="#">SCE-82P37</a> | \$387.00 |
| <a href="#">SCE-86M4E</a>   | Retired    | 86.00 x 149.19 x 15.07 [2184 x 3789 x 383] | 4     | <a href="#">PDF</a> | <a href="#">SCE-82P76*</a> | \$696.00 | —                         | —        |
| <a href="#">SCE-86M4E20</a> | Retired    | 86.00 x 149.19 x 21.07 [2184 x 3789 x 535] | 4     | <a href="#">PDF</a> | <a href="#">SCE-82P76*</a> | \$696.00 | —                         | —        |
| <a href="#">SCE-86M5E</a>   | Retired    | 86.00 x 187.00 x 15.07 [2184 x 4750 x 383] | 5     | <a href="#">PDF</a> | <a href="#">SCE-82P76</a>  | \$696.00 | <a href="#">SCE-82P37</a> | \$387.00 |
| <a href="#">SCE-86M5E20</a> | Retired    | 86.00 x 187.00 x 21.07 [2184 x 4750 x 535] | 5     | <a href="#">PDF</a> | <a href="#">SCE-82P76</a>  | \$696.00 | <a href="#">SCE-82P37</a> | \$387.00 |

Note: Dimensions in inches [millimeters].

\* Two of this subpanel part included.