


# Heavy Duty Stainless Steel Freestanding Enclosure with External Disconnect



Your Enclosure Source®

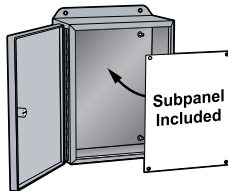

## Applications

Designed to house the main power supply in external enclosure on the right side of main enclosure, keeping the live side of the power supply separate from the primary electrical equipment. Provides protection from dirt, dust, oil and water and can house most standard type disconnects.

## Construction

- 12-gauge [3mm] 304 or 316 stainless steel
- Seams continuously welded and ground smooth
- Flange trough collar around all sides of door opening
- Body stiffeners are provided in large enclosures for extra rigidity.
- Heavy duty lifting eyes anchor into the reinforced top.
- Removable center posts permit easy subpanel installation.
- Concealed hinges
- Black zinc diecast coinproof/padlocking handle on main door with black zinc diecast padlocking handle on slave doors
- 3-point latching mechanism
- Large, removable print pockets
- Poured-in-place oil- and water-resistant gasket
- Removable subpanels mount on collar studs
- Defeater on master door requires a screwdriver to open.
- Mechanical interlock activated by the External Disconnect prevents main door of the enclosure from closing unless the EXD enclosure is first closed.
- Mechanical interlock activated by master door prevents slave doors from being opened first.
  - The doors can be closed in any order.
- Ground stud on door and body
- Provisions for light kit

Note: Disconnect switch (or circuit breaker) and operating mechanism are not furnished with this enclosure.

## Finish

- #4 brushed finish on all exterior surfaces
- Optional subpanels are powder coated white.

## Listings

- NEMA Type 3R, 12, and 13
- cULus Listed Type 3R and 12 [File E69392]
- IEC 60529 IP55



# Heavy Duty Stainless Steel Freestanding Enclosure with External Disconnect



Your Enclosure Source®



Shipping Schedule	
Same day	1 - 15 days

Color indicates shipping lead time in business days.

Single-Door						
304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Included Subpanel
<a href="#"><u>SCE-72XD2818SS</u></a>	\$6,930.00	<a href="#"><u>SCE-72XD2818SS6</u></a>	\$8,154.00	72.00 x 27.50 x 19.07 [1829 x 699 x 484]	<a href="#"><u>PDF</u></a>	<a href="#"><u>SCE-64P25</u></a>
<a href="#"><u>SCE-72XD3418SS</u></a>	\$7,429.00	<a href="#"><u>SCE-72XD3418SS6</u></a>	\$8,744.00	72.00 x 34.50 x 19.07 [1829 x 876 x 484]	<a href="#"><u>PDF</u></a>	<a href="#"><u>SCE-64P31</u></a>
<a href="#"><u>SCE-72XD4018SS</u></a>	\$7,929.00	<a href="#"><u>SCE-72XD4018SS6</u></a>	\$9,335.00	72.00 x 39.50 x 19.07 [1829 x 1003 x 484]	<a href="#"><u>PDF</u></a>	<a href="#"><u>SCE-64P37</u></a>
<a href="#"><u>SCE-84XD4018SS</u></a>	\$8,555.00	<a href="#"><u>SCE-84XD4018SS6</u></a>	\$10,075.00	84.00 x 39.50 x 19.07 [2134 x 1003 x 484]	<a href="#"><u>PDF</u></a>	<a href="#"><u>SCE-76P37</u></a>
<a href="#"><u>SCE-90XD4018SS</u></a>	\$9,173.00	<a href="#"><u>SCE-90XD4018SS6</u></a>	\$10,774.00	90.00 x 39.50 x 19.07 [2286 x 1003 x 484]	<a href="#"><u>PDF</u></a>	<a href="#"><u>SCE-82P37</u></a>

Note: Dimensions in inches [millimeters].

# Heavy Duty Stainless Steel Freestanding Enclosure with External Disconnect



## Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

## Two-Door

304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Included Subpanel
<a href="#">SCE-72XD5418SS</a>	\$10,414.00	<a href="#">SCE-72XD5418SS6</a>	\$12,272.00	72.00 x 53.75 x 19.07 [1829 x 1365 x 484]	<a href="#">PDF</a>	<a href="#">SCE-64P52</a>
<a href="#">SCE-72XD6618SS</a>	\$11,441.00	<a href="#">SCE-72XD6618SS6</a>	\$13,487.00	72.00 x 65.75 x 19.07 [1829 x 1670 x 484]	<a href="#">PDF</a>	<a href="#">SCE-64P64</a>
<a href="#">SCE-72XD7818SS</a>	\$12,564.00	—	—	72.00 x 77.75 x 19.07 [1829 x 1975 x 484]	<a href="#">PDF</a>	<a href="#">SCE-64P76</a>
<a href="#">SCE-84XD7818SS</a>	\$13,840.00	<a href="#">SCE-84XD7818SS6</a>	\$16,279.00	84.00 x 77.75 x 19.07 [2134 x 1975 x 484]	<a href="#">PDF</a>	<a href="#">SCE-76P76</a>
<a href="#">SCE-90XD7818SS</a>	\$14,777.00	<a href="#">SCE-90XD7818SS6</a>	\$17,356.00	90.00 x 77.75 x 19.07 [2286 x 1975 x 484]	<a href="#">PDF</a>	<a href="#">SCE-82P76</a>

Note: Dimensions in inches [millimeters].

## Three-Door

304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Included Subpanel
<a href="#">SCE-72XD3EQ18SS</a>	\$14,872.00	<a href="#">SCE-72XD3EQ18SS6</a>	\$17,469.00	72.00 x 99.50 x 19.07 [1829 x 2527 x 484]	<a href="#">PDF</a>	<a href="#">SCE-64P64</a>
<a href="#">SCE-72XD3EW18SS</a>	\$16,411.00	<a href="#">SCE-72XD3EW18SS6</a>	\$19,286.00	72.00 x 117.50 x 19.07 [1829 x 2985 x 484]	<a href="#">PDF</a>	<a href="#">SCE-64P76</a>
<a href="#">SCE-84XD3EW18SS</a>	\$17,997.00	<a href="#">SCE-84XD3EW18SS6</a>	\$21,159.00	84.00 x 117.50 x 19.07 [2134 x 2985 x 484]	<a href="#">PDF</a>	<a href="#">SCE-76P76</a>

Note: Dimensions in inches [millimeters].