

NEMA 4, 4X, 12, and 13 22mm Stainless Steel Wall-Mount Pushbutton



Applications

Designed to offer protection for oil-tight pushbuttons, switches, and pilot lights in wet and hosed down areas and in corrosive atmospheres.

Construction

- 16-gauge stainless steel Type 304 or 316/316L
- Continuously-welded seams
- Captivated cover screws thread into sealed wells.
- 4-way pushbutton holes accept all brands of oil-tight pushbuttons, switches and pilot lights.
- Hole diameter is 0.87in [22.5 mm]
- Fully-removable cover
- Poured-in-place oil- and water-resistant gasket
- Welded mounting provision top and bottom of back

Finish

- #4 brushed finish on all exterior surfaces

Listings

- NEMA Type 4, 4X, 12, and 13
- cULus Listed Type 4, 4X, and 12 [File E69392]
- IEC 60529 IP66



Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 4, 4X, 12, and 13 22mm Stainless Steel Wall-Mount Pushbutton

304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Holes	Drawing Link
<u>SCE-1PBSSI</u>	\$123.00	<u>SCE-1PBSS6I</u>	\$148.00	3.81 x 3.56 x 2.91 [97 x 90 x 74]	1	<u>PDF</u>
<u>SCE-1PBXSSI</u>	\$164.00	<u>SCE-1PBXSS6I</u>	\$197.00	4.31 x 4.31 x 4.91 [109 x 109 x 125]	1	<u>PDF</u>
<u>SCE-2PBSSI</u>	\$154.00	<u>SCE-2PBSS6I</u>	\$185.00	6.06 x 3.56 x 2.91 [154 x 90 x 74]	2	<u>PDF</u>
<u>SCE-3PBSSI</u>	\$168.00	<u>SCE-3PBSS6I</u>	\$201.00	8.31 x 3.56 x 2.91 [211 x 90 x 74]	3	<u>PDF</u>
<u>SCE-4PBSSI</u>	\$190.00	<u>SCE-4PBSS6I</u>	\$228.00	10.56 x 3.56 x 2.91 [268 x 90 x 74]	4	<u>PDF</u>
<u>SCE-4PBXSSI</u>	\$226.00	<u>SCE-4PBXSS6I</u>	\$271.00	10.31 x 4.31 x 4.91 [262 x 109 x 125]	4	<u>PDF</u>
<u>SCE-4SPBSSI</u>	\$209.00	<u>SCE-4SPBSS6I</u>	\$251.00	7.56 x 6.56 x 3.16 [192 x 167 x 80]	4	<u>PDF</u>
<u>SCE-6PBSSI</u>	\$250.00	<u>SCE-6PBSS6I</u>	\$300.00	9.81 x 6.56 x 3.16 [249 x 167 x 80]	6	<u>PDF</u>
<u>SCE-9PBSSI</u>	\$282.00	<u>SCE-9PBSS6I</u>	\$339.00	9.81 x 8.81 x 3.16 [249 x 224 x 80]	9	<u>PDF</u>
<u>SCE-12PBSSI</u>	\$322.00	<u>SCE-12PBSS6I</u>	\$386.00	12.06 x 8.81 x 3.16 [306 x 224 x 80]	12	<u>PDF</u>

 

Note: Dimensions in inches [millimeters].

NEMA 4, 4X, 12, and 13 22mm Stainless Steel Wall-Mount Pushbutton




Your Enclosure Source®


Dimensions

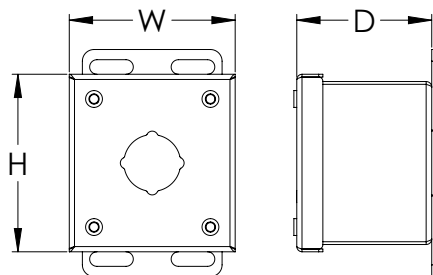


1

 


2

 


3

 


4

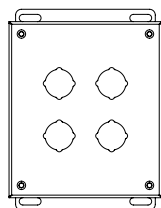


4S

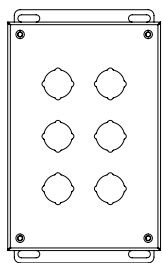

6

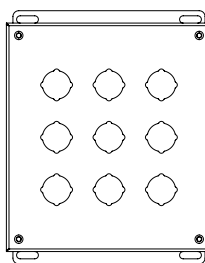

9

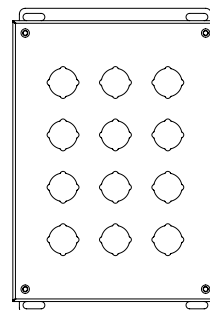

12