

# NEMA 1 Single-Door Wall-Mount with Knockouts



Your Enclosure Source®




## Applications

Designed to house electrical controls, instruments, and components in areas that do not require oil, water and dust tight protection.

## Construction

- 14-gauge, 16-gauge, or 18-gauge carbon steel, depending on size
- Spot weld construction
- Knockouts are provided in the top, bottom, right and left side.
- Standoffs are provided for mounting optional subpanels.
- Butt hinge
- Doors open 180°
- Keylocking 1/4-turn latches
- Latches are opened or closed with a screwdriver.
- Mounting holes in back of enclosure
- Sub-panel with 2 in x 2 in [51 mm x 51 mm] mounting grid pattern included

Note: Tamper-resistant inserts available. Optional mounting straps available.

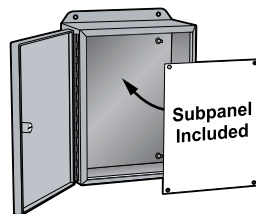

## Finish

- Precaution Blue or Taupe Tan powder coat finish inside and out
- Subpanels are powder coated white.

## Listings

- NEMA Type 1
- cULus Listed Type 1
- IEC 60529 IP30



### Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

### NEMA 1 Single-Door Wall-Mount with Knockouts

Blue	Tan	Price	Size HxWxD	Steel Thickness	Drawing Link
<a href="#">SCE-18N1606NK-B</a>	<a href="#">SCE-18N1606NK-T</a>	\$195.00	18.38 x 16.38 x 6.13 [467 x 416 x 156]	18-gauge	<a href="#">PDF</a>
<a href="#">SCE-24N2006NK-B</a>	<a href="#">SCE-24N2006NK-T</a>	\$230.00	24.38 x 20.38 x 6.13 [619 x 518 x 156]	16-gauge	<a href="#">PDF</a>
<a href="#">SCE-36N2406NK-B</a>	<a href="#">SCE-36N2406NK-T</a>	\$354.00	36.38 x 24.38 x 6.13 [924 x 619 x 156]	14-gauge	<a href="#">PDF</a>

Note: Dimensions in inches [millimeters].

# NEMA 1 Single-Door Wall-Mount with Knockouts



Your Enclosure Source®

## Dimensions

