

NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



Applications

Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. Provides protection from dust, dirt, oil and water.

Construction

- 16-gauge carbon steel
- Seams continuously welded and ground smooth— no holes or knockouts
- Bolt-on continuous hinge with stainless steel pin
- Stainless steel external screw clamps are quick and easy to operate.
- Poured-in-place oil- and water-resistant gasket
- Standoffs are provided for mounting optional subpanels.
- Welded mounting provision top and bottom of back
- Ground studs on door and body

Finish


- ANSI 61 gray powder coated inside and out
- Optional subpanels are powder coated white.

Listings

- NEMA Type 3R, 4, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



Dimensions

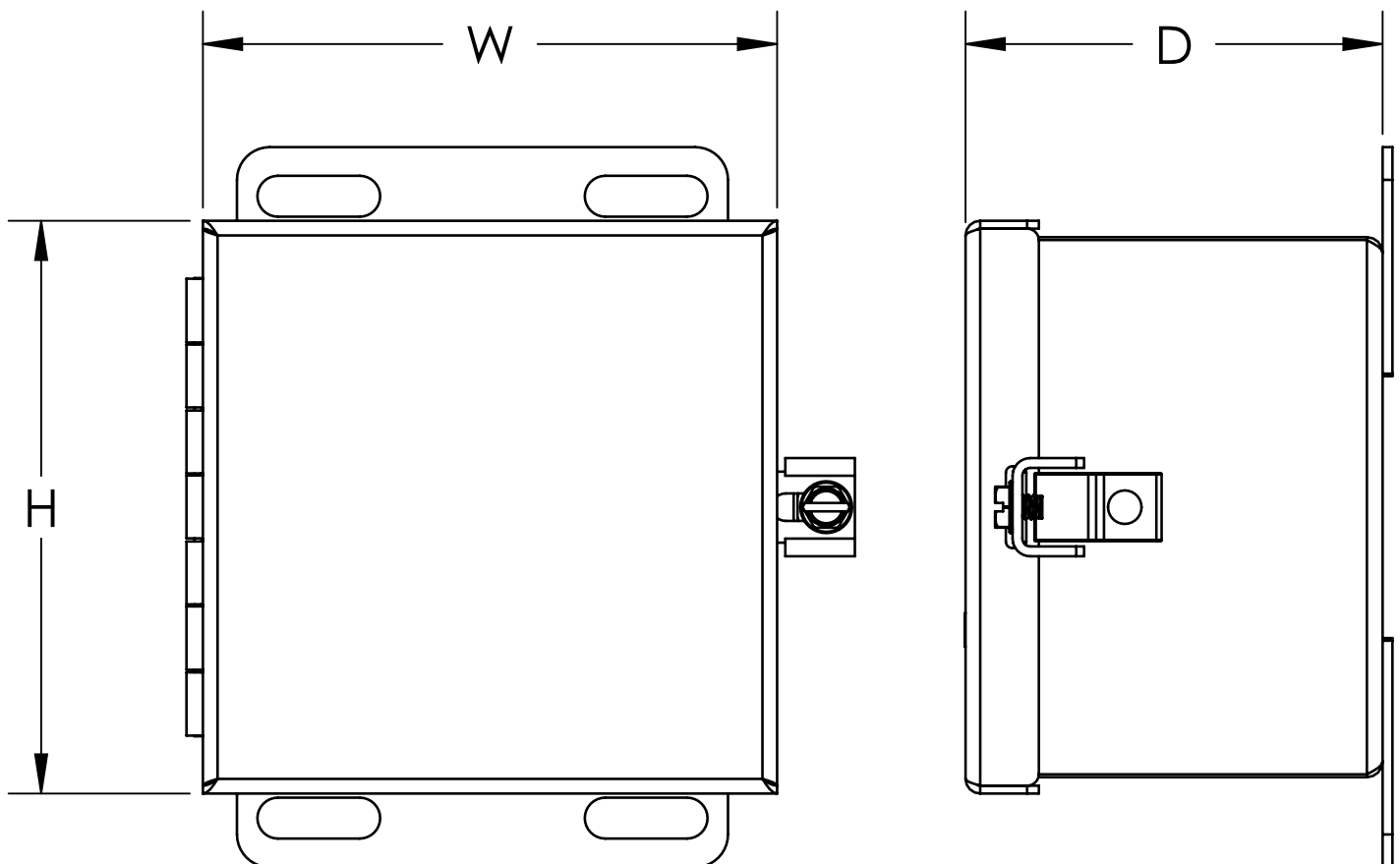

NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount



Shipping Schedule

Same day	1 - 15 days
----------	-------------

Color indicates shipping lead time in business days.

NEMA 3R, 4, 12, and 13 Single-Door Wall-Mount

Part Number	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-404CHNF	\$48.50	4.38 x 4.39 x 3.20 [111 x 112 x 81]	PDF	—	—
SCE-4044CHNF	\$50.00	4.38 x 4.39 x 4.20 [111 x 112 x 107]	PDF	—	—
SCE-604CHNF	\$54.00	6.38 x 4.39 x 3.20 [162 x 112 x 81]	PDF	SCE-6P4	\$4.25
SCE-6044CHNF	\$59.00	6.38 x 4.39 x 4.20 [162 x 112 x 107]	PDF	SCE-6P4	\$4.25
SCE-606CHNF	\$64.00	6.38 x 6.39 x 4.20 [162 x 162 x 107]	PDF	SCE-6P6	\$5.00
SCE-806CHNF	\$69.00	8.38 x 6.39 x 3.70 [213 x 162 x 94]	PDF	SCE-8P6	\$5.75
SCE-8066CHNF	\$81.00	8.38 x 6.39 x 6.20 [213 x 162 x 157]	PDF	SCE-8P6	\$5.75
SCE-808CHNF	\$77.00	8.38 x 8.39 x 4.20 [213 x 213 x 107]	PDF	SCE-8P8	\$6.75
SCE-8086CHNF	\$88.00	8.38 x 8.39 x 6.20 [213 x 213 x 157]	PDF	SCE-8P8	\$6.75
SCE-1008CHSNF*	\$94.00	8.39 x 10.38 x 4.20 [213 x 264 x 107]	PDF	SCE-10P8	\$8.00
SCE-1008CHNF	\$89.00	10.38 x 8.39 x 4.20 [264 x 213 x 107]	PDF	SCE-10P8	\$8.00
SCE-10086CHNF	\$102.00	10.38 x 8.39 x 6.20 [264 x 213 x 157]	PDF	SCE-10P8	\$8.00
SCE-10106CHNF	\$104.00	10.38 x 10.39 x 6.20 [264 x 264 x 157]	PDF	SCE-10P10	\$9.25
SCE-1210CHSNF*	\$115.00	10.39 x 12.38 x 5.20 [264 x 314 x 132]	PDF	SCE-12P10	\$10.75
SCE-12064CHNF	\$82.00	12.38 x 6.39 x 4.20 [314 x 162 x 107]	PDF	SCE-12P6	\$7.50
SCE-1210CHNF	\$112.00	12.38 x 10.39 x 5.20 [314 x 264 x 132]	PDF	SCE-12P10	\$10.75
SCE-12106CHNF	\$118.00	12.38 x 10.39 x 6.20 [314 x 264 x 157]	PDF	SCE-12P10	\$10.75
SCE-12108CHNF	\$127.00	12.38 x 10.39 x 8.20 [314 x 264 x 208]	PDF	SCE-12P10	\$10.75
SCE-1212CHNF	\$130.00	12.38 x 12.39 x 6.20 [314 x 315 x 157]	PDF	SCE-12P12	\$12.50
SCE-1412CHSNF*	\$152.00	12.39 x 14.38 x 6.20 [315 x 365 x 157]	PDF	SCE-14P12	\$14.00
SCE-14086CHNF	\$112.00	14.38 x 8.39 x 6.20 [365 x 213 x 157]	PDF	SCE-14P8	\$10.25
SCE-1412CHNF	\$145.00	14.38 x 12.39 x 6.20 [365 x 315 x 157]	PDF	SCE-14P12	\$14.00
SCE-14128CHNF	\$153.00	14.38 x 12.39 x 8.20 [365 x 315 x 208]	PDF	SCE-14P12	\$14.00
SCE-1614CHSNF*	\$178.00	14.39 x 16.38 x 6.20 [366 x 416 x 157]	PDF	SCE-16P14	\$27.50
SCE-16106CHNF	\$132.00	16.38 x 10.39 x 6.20 [416 x 264 x 157]	PDF	SCE-16P10	\$13.75
SCE-1614CHNF	\$169.00	16.38 x 14.39 x 6.20 [416 x 366 x 157]	PDF	SCE-16P14	\$27.50
SCE-16148CHNF	\$185.00	16.38 x 14.39 x 8.20 [416 x 366 x 208]	PDF	SCE-16P14	\$27.50
SCE-161410CHNF	\$194.00	16.38 x 14.39 x 10.20 [416 x 366 x 259]	PDF	SCE-16P14	\$27.50

Note: *Part numbers containing an S are hinged on the short side.
Dimensions in inches [millimeters].