

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®



## Applications

Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. For use in wet and hosed down areas and in corrosive atmospheres.

## Construction

- 16-gauge stainless steel Type 304 or 316/316L
- Seams continuously welded and ground smooth
- Stainless steel continuous hinge
- Stainless steel external screw clamps are quick and easy to operate.
- Poured-in-place oil- and water-resistant gasket
- Ground stud on door and body
- Standoffs are provided for mounting optional subpanels.
- Welded mounting provision top and bottom of back

## Finish

- #4 brushed finish on all exterior surfaces
- Optional subpanels are powder coated white.

## Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



## Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

## NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

| 304 Stainless Steel             | Price    | 316L Stainless Steel             | Price    | Size<br>HxWxD                          | Drawing<br>Link     | Optional<br>Subpanel      | Price   |
|---------------------------------|----------|----------------------------------|----------|----------------------------------------|---------------------|---------------------------|---------|
| <a href="#">SCE-6044CHNFSS</a>  | \$196.00 | <a href="#">SCE-6044CHNFSS6</a>  | \$243.00 | 6.38 x 4.39 x 3.20 [162 x 112 x 81]    | <a href="#">PDF</a> | <a href="#">SCE-6P4</a>   | \$4.25  |
| <a href="#">SCE-606CHNFSS</a>   | \$245.00 | <a href="#">SCE-606CHNFSS6</a>   | \$277.00 | 6.38 x 6.39 x 4.20 [162 x 162 x 107]   | <a href="#">PDF</a> | <a href="#">SCE-6P6</a>   | \$5.00  |
| <a href="#">SCE-8064CHNFSS</a>  | \$255.00 | <a href="#">SCE-8064CHNFSS6</a>  | \$303.00 | 8.38 x 6.39 x 3.70 [213 x 162 x 94]    | <a href="#">PDF</a> | <a href="#">SCE-8P6</a>   | \$5.75  |
| <a href="#">SCE-1008CHNFSS</a>  | \$369.00 | <a href="#">SCE-1008CHNFSS6</a>  | \$448.00 | 10.38 x 8.39 x 4.20 [264 x 213 x 107]  | <a href="#">PDF</a> | <a href="#">SCE-10P8</a>  | \$8.00  |
| <a href="#">SCE-10086CHNFSS</a> | \$403.00 | <a href="#">SCE-10086CHNFSS6</a> | \$490.00 | 10.38 x 8.39 x 6.20 [264 x 213 x 157]  | <a href="#">PDF</a> | <a href="#">SCE-10P8</a>  | \$8.00  |
| <a href="#">SCE-12106CHNFSS</a> | \$456.00 | <a href="#">SCE-12106CHNFSS6</a> | \$526.00 | 12.38 x 10.39 x 6.20 [314 x 264 x 157] | <a href="#">PDF</a> | <a href="#">SCE-12P10</a> | \$10.75 |
| <a href="#">SCE-12108CHNFSS</a> | \$486.00 | <a href="#">SCE-12108CHNFSS6</a> | \$605.00 | 12.38 x 10.39 x 8.20 [314 x 264 x 208] | <a href="#">PDF</a> | <a href="#">SCE-12P10</a> | \$10.75 |
| <a href="#">SCE-1212CHNFSS</a>  | \$488.00 | <a href="#">SCE-1212CHNFSS6</a>  | \$580.00 | 12.38 x 12.39 x 6.20 [314 x 315 x 157] | <a href="#">PDF</a> | <a href="#">SCE-12P12</a> | \$12.50 |
| <a href="#">SCE-1412CHNFSS</a>  | \$515.00 | <a href="#">SCE-1412CHNFSS6</a>  | \$635.00 | 14.38 x 12.39 x 6.20 [365 x 315 x 157] | <a href="#">PDF</a> | <a href="#">SCE-14P12</a> | \$14.00 |
| <a href="#">SCE-1614CHNFSS</a>  | \$608.00 | <a href="#">SCE-1614CHNFSS6</a>  | \$756.00 | 16.38 x 14.39 x 6.20 [416 x 366 x 157] | <a href="#">PDF</a> | <a href="#">SCE-16P14</a> | \$27.50 |
| <a href="#">SCE-16148CHNFSS</a> | \$674.00 | <a href="#">SCE-16148CHNFSS6</a> | \$782.00 | 16.38 x 14.39 x 8.20 [416 x 366 x 208] | <a href="#">PDF</a> | <a href="#">SCE-16P14</a> | \$27.50 |


Note: Dimensions in inches [millimeters].

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



*Your Enclosure Source®*

## Dimensions

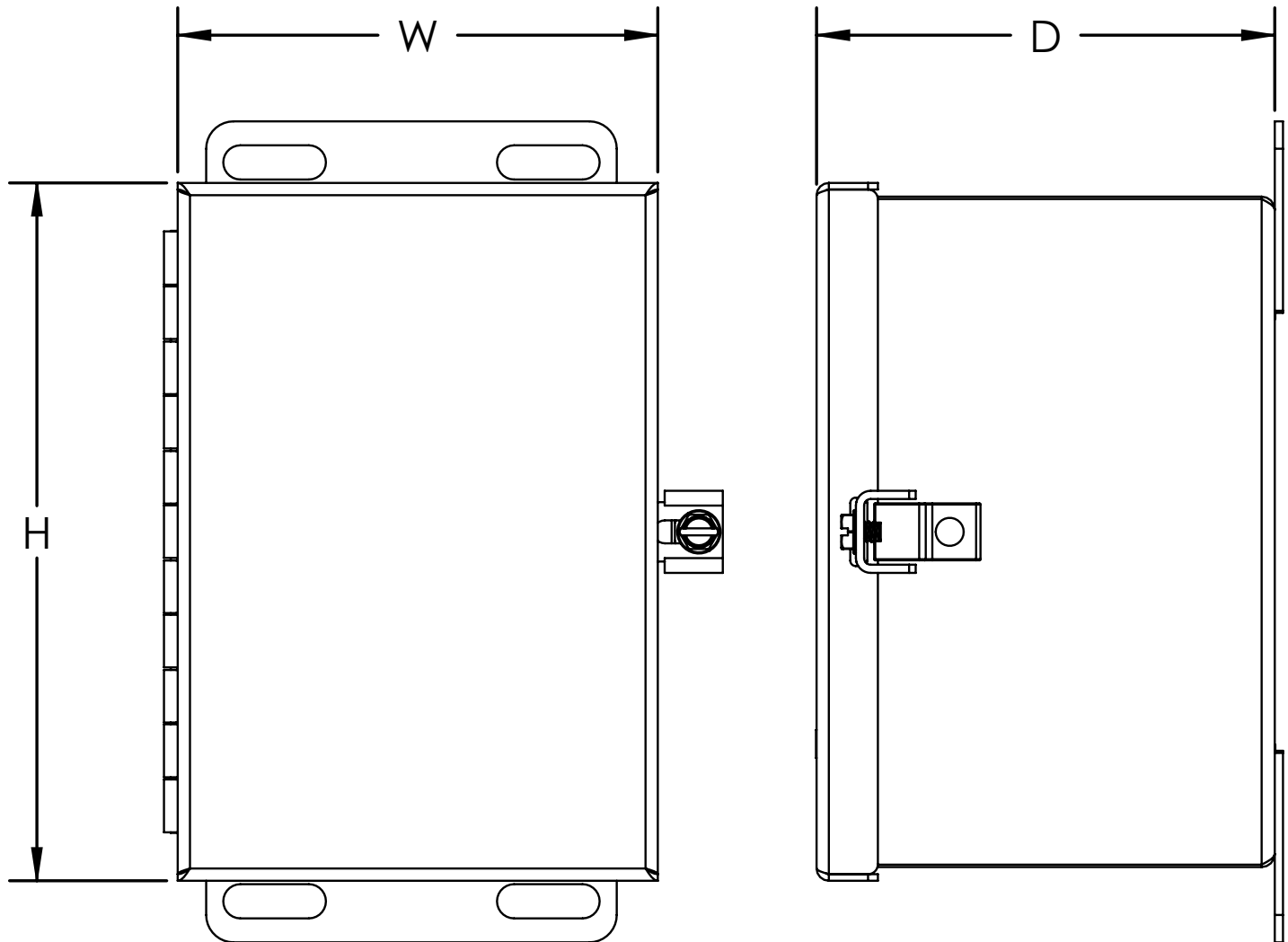

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



*Your Enclosure Source®*



## Applications

Designed to house electrical and electronic controls, instruments and components in areas which are in very wet conditions. Provides a degree of protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended.

### Construction

- 14-gauge Type 304 or 316L stainless steel
- Seams continuously welded and ground smooth
- Flange trough collar around all sides of door opening
- Poured-in-place oil- and water-resistant gasket
- Collar studs are provided for mounting optional subpanels.
- Stainless steel continuous hinges
- Interior print pocket
- Ground studs on door and body
- Stainless steel door clamps
- Hasp and staple for padlocking
- Welded mounting provision top and bottom of back

## Finish

- #4 brushed finish on all exterior surfaces
- Optional subpanels are powder coated white.

## Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4, 4X, and 12 [File E69392]
- IEC 60529 IP66



# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®

## Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

| NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount Right-Flange Disconnect |            |                                  |            |                                          |                     |                           |          |
|-------------------------------------------------------------------------------------------|------------|----------------------------------|------------|------------------------------------------|---------------------|---------------------------|----------|
| 304 Stainless Steel                                                                       | Price      | 316L Stainless Steel             | Price      | Size<br>HxWxD                            | Drawing<br>Link     | Optional<br>Subpanel      | Price    |
| <a href="#">SCE-16H1206SSLP</a>                                                           | \$701.00   | <a href="#">SCE-16H1206SS6LP</a> | \$865.00   | 16.00 x 12.00 x 7.07 [406 x 305 x 180]   | <a href="#">PDF</a> | <a href="#">SCE-16P12</a> | \$20.50  |
| <a href="#">SCE-16H1208SSLP</a>                                                           | \$751.00   | <a href="#">SCE-16H1208SS6LP</a> | \$927.00   | 16.00 x 12.00 x 9.07 [406 x 305 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-16P12</a> | \$20.50  |
| <a href="#">SCE-16H1606SSLP</a>                                                           | \$779.00   | <a href="#">SCE-16H1606SS6LP</a> | \$935.00   | 16.00 x 16.00 x 7.07 [406 x 406 x 180]   | <a href="#">PDF</a> | <a href="#">SCE-16P16</a> | \$34.00  |
| <a href="#">SCE-16H2006SSLP</a>                                                           | \$856.00   | <a href="#">SCE-16H2006SS6LP</a> | \$1,027.00 | 16.00 x 20.00 x 7.07 [406 x 508 x 180]   | <a href="#">PDF</a> | <a href="#">SCE-20P16</a> | \$42.00  |
| <a href="#">SCE-20H1606SSLP</a>                                                           | \$856.00   | <a href="#">SCE-20H1606SS6LP</a> | \$1,056.00 | 20.00 x 16.00 x 7.07 [508 x 406 x 180]   | <a href="#">PDF</a> | <a href="#">SCE-20P16</a> | \$42.00  |
| <a href="#">SCE-20H1608SSLP</a>                                                           | \$917.00   | <a href="#">SCE-20H1608SS6LP</a> | \$1,131.00 | 20.00 x 16.00 x 9.07 [508 x 406 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-20P16</a> | \$42.00  |
| <a href="#">SCE-20H1610SSLP</a>                                                           | \$979.00   | <a href="#">SCE-20H1610SS6LP</a> | \$1,208.00 | 20.00 x 16.00 x 11.07 [508 x 406 x 281]  | <a href="#">PDF</a> | <a href="#">SCE-20P16</a> | \$42.00  |
| <a href="#">SCE-20H2006SSLP</a>                                                           | \$944.00   | <a href="#">SCE-20H2006SS6LP</a> | \$1,165.00 | 20.00 x 20.00 x 7.07 [508 x 508 x 180]   | <a href="#">PDF</a> | <a href="#">SCE-20P20</a> | \$49.00  |
| <a href="#">SCE-20H2408SSLP</a>                                                           | \$1,108.00 | <a href="#">SCE-20H2408SS6LP</a> | \$1,367.00 | 20.00 x 24.00 x 9.07 [508 x 610 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-24P20</a> | \$63.00  |
| <a href="#">SCE-24H1608SSLP</a>                                                           | \$997.00   | <a href="#">SCE-24H1608SS6LP</a> | \$1,230.00 | 24.00 x 16.00 x 9.07 [610 x 406 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-24P16</a> | \$45.50  |
| <a href="#">SCE-24H2006SSLP</a>                                                           | \$1,034.00 | <a href="#">SCE-24H2006SS6LP</a> | \$1,275.00 | 24.00 x 20.00 x 7.07 [610 x 508 x 180]   | <a href="#">PDF</a> | <a href="#">SCE-24P20</a> | \$63.00  |
| <a href="#">SCE-24H2008SSLP</a>                                                           | \$1,108.00 | <a href="#">SCE-24H2008SS6LP</a> | \$1,367.00 | 24.00 x 20.00 x 9.07 [610 x 508 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-24P20</a> | \$63.00  |
| <a href="#">SCE-24H2010SSLP</a>                                                           | \$1,184.00 | <a href="#">SCE-24H2010SS6LP</a> | \$1,460.00 | 24.00 x 20.00 x 11.07 [610 x 508 x 281]  | <a href="#">PDF</a> | <a href="#">SCE-24P20</a> | \$63.00  |
| <a href="#">SCE-24H2406SSLP</a>                                                           | \$1,063.00 | —                                | —          | 24.00 x 24.00 x 7.07 [610 x 610 x 180]   | <a href="#">PDF</a> | <a href="#">SCE-24P24</a> | \$74.00  |
| <a href="#">SCE-24H2408SSLP</a>                                                           | \$1,219.00 | <a href="#">SCE-24H2408SS6LP</a> | \$1,504.00 | 24.00 x 24.00 x 9.07 [610 x 610 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-24P24</a> | \$74.00  |
| <a href="#">SCE-24H2412SSLP</a>                                                           | \$1,385.00 | <a href="#">SCE-24H2412SS6LP</a> | \$1,708.00 | 24.00 x 24.00 x 13.07 [610 x 610 x 332]  | <a href="#">PDF</a> | <a href="#">SCE-24P24</a> | \$74.00  |
| <a href="#">SCE-24H3008SSLP</a>                                                           | \$1,385.00 | <a href="#">SCE-24H3008SS6LP</a> | \$1,708.00 | 24.00 x 30.00 x 9.07 [610 x 762 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-30P24</a> | \$88.00  |
| <a href="#">SCE-30H2008SSLP</a>                                                           | \$1,254.00 | <a href="#">SCE-30H2008SS6LP</a> | \$1,547.00 | 30.00 x 20.00 x 9.07 [762 x 508 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-30P20</a> | \$77.00  |
| <a href="#">SCE-30H2408SSLP</a>                                                           | \$1,385.00 | <a href="#">SCE-30H2408SS6LP</a> | \$1,708.00 | 30.00 x 24.00 x 9.07 [762 x 610 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-30P24</a> | \$88.00  |
| <a href="#">SCE-30H2412SSLP</a>                                                           | \$1,570.00 | <a href="#">SCE-30H2412SS6LP</a> | \$1,936.00 | 30.00 x 24.00 x 13.07 [762 x 610 x 332]  | <a href="#">PDF</a> | <a href="#">SCE-30P24</a> | \$88.00  |
| <a href="#">SCE-30H2416SSLP</a>                                                           | \$1,758.00 | <a href="#">SCE-30H2416SS6LP</a> | \$2,168.00 | 30.00 x 24.00 x 17.07 [762 x 610 x 434]  | <a href="#">PDF</a> | <a href="#">SCE-30P24</a> | \$88.00  |
| <a href="#">SCE-30H3008SSLP</a>                                                           | \$1,582.00 | <a href="#">SCE-30H3008SS6LP</a> | \$1,951.00 | 30.00 x 30.00 x 9.07 [762 x 762 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-30P30</a> | \$116.00 |
| <a href="#">SCE-36H2408SSLP</a>                                                           | \$1,550.00 | <a href="#">SCE-36H2408SS6LP</a> | \$1,912.00 | 36.00 x 24.00 x 9.07 [914 x 610 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-36P24</a> | \$105.00 |
| <a href="#">SCE-36H2410SSLP</a>                                                           | \$1,655.00 | <a href="#">SCE-36H2410SS6LP</a> | \$2,041.00 | 36.00 x 24.00 x 11.07 [914 x 610 x 281]  | <a href="#">PDF</a> | <a href="#">SCE-36P24</a> | \$105.00 |
| <a href="#">SCE-36H3008SSLP</a>                                                           | \$1,778.00 | <a href="#">SCE-36H3008SS6LP</a> | \$2,193.00 | 36.00 x 30.00 x 9.07 [914 x 762 x 230]   | <a href="#">PDF</a> | <a href="#">SCE-36P30</a> | \$141.00 |
| <a href="#">SCE-36H3010SSLP</a>                                                           | \$1,892.00 | <a href="#">SCE-36H3010SS6LP</a> | \$2,333.00 | 36.00 x 30.00 x 11.07 [914 x 762 x 281]  | <a href="#">PDF</a> | <a href="#">SCE-36P30</a> | \$141.00 |
| <a href="#">SCE-36H3012SSLP</a>                                                           | \$2,005.00 | <a href="#">SCE-36H3012SS6LP</a> | \$2,473.00 | 36.00 x 30.00 x 13.07 [914 x 762 x 332]  | <a href="#">PDF</a> | <a href="#">SCE-36P30</a> | \$141.00 |
| <a href="#">SCE-36H3016SSLP</a>                                                           | \$2,232.00 | <a href="#">SCE-36H3016SS6LP</a> | \$2,752.00 | 36.00 x 30.00 x 17.07 [914 x 762 x 434]  | <a href="#">PDF</a> | <a href="#">SCE-36P30</a> | \$141.00 |
| <a href="#">SCE-36H3612SSLP</a>                                                           | \$2,253.00 | <a href="#">SCE-36H3612SS6LP</a> | \$2,779.00 | 36.00 x 36.00 x 13.07 [914 x 914 x 332]  | <a href="#">PDF</a> | <a href="#">SCE-36P36</a> | \$165.00 |
| <a href="#">SCE-42H3010SSLP</a>                                                           | \$2,098.00 | <a href="#">SCE-42H3010SS6LP</a> | \$2,588.00 | 42.00 x 30.00 x 11.07 [1067 x 762 x 281] | <a href="#">PDF</a> | <a href="#">SCE-42P30</a> | \$162.00 |
| <a href="#">SCE-42H3608SSLP</a>                                                           | \$2,232.00 | <a href="#">SCE-42H3608SS6LP</a> | \$2,752.00 | 42.00 x 36.00 x 9.07 [1067 x 914 x 230]  | <a href="#">PDF</a> | <a href="#">SCE-42P36</a> | \$190.00 |
| <a href="#">SCE-48H3608SSLP</a>                                                           | \$2,459.00 | <a href="#">SCE-48H3608SS6LP</a> | \$3,033.00 | 48.00 x 36.00 x 9.07 [1219 x 914 x 230]  | <a href="#">PDF</a> | <a href="#">SCE-48P36</a> | \$214.00 |
| <a href="#">SCE-48H3610SSLP</a>                                                           | \$2,730.00 | —                                | —          | 48.00 x 36.00 x 11.07 [1219 x 914 x 281] | <a href="#">PDF</a> | <a href="#">SCE-48P36</a> | \$214.00 |
| <a href="#">SCE-48H3612SSLP</a>                                                           | \$2,748.00 | <a href="#">SCE-48H3612SS6LP</a> | \$3,389.00 | 48.00 x 36.00 x 13.07 [1219 x 914 x 332] | <a href="#">PDF</a> | <a href="#">SCE-48P36</a> | \$214.00 |
| <a href="#">SCE-48H3616SSLP</a>                                                           | \$3,038.00 | <a href="#">SCE-48H3616SS6LP</a> | \$3,747.00 | 48.00 x 36.00 x 17.07 [1219 x 914 x 434] | <a href="#">PDF</a> | <a href="#">SCE-48P36</a> | \$214.00 |
| <a href="#">SCE-60H3612SSLP</a>                                                           | \$3,244.00 | <a href="#">SCE-60H3612SS6LP</a> | \$4,001.00 | 60.00 x 36.00 x 13.07 [1524 x 914 x 332] | <a href="#">PDF</a> | <a href="#">SCE-60P36</a> | \$264.00 |

Note: Dimensions in inches [millimeters].

# NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



## Dimensions

