

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®



Applications

Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. For use in wet and hosed down areas and in corrosive atmospheres.

Construction

- 16-gauge stainless steel Type 304 or 316/316L
- Seams continuously welded and ground smooth
- Stainless steel continuous hinge
- Stainless steel external screw clamps are quick and easy to operate.
- Poured-in-place oil- and water-resistant gasket
- Ground stud on door and body
- Standoffs are provided for mounting optional subpanels.
- Welded mounting provision top and bottom of back

Finish

- #4 brushed finish on all exterior surfaces
- Optional subpanels are powder coated white.

Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



Shipping Schedule

Same day 1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-6044CHNFSS	\$196.00	SCE-6044CHNFSS6	\$243.00	6.38 x 4.39 x 3.20 [162 x 112 x 81]	PDF	SCE-6P4	\$4.25
SCE-606CHNFSS	\$245.00	SCE-606CHNFSS6	\$277.00	6.38 x 6.39 x 4.20 [162 x 162 x 107]	PDF	SCE-6P6	\$5.00
SCE-8064CHNFSS	\$255.00	SCE-8064CHNFSS6	\$303.00	8.38 x 6.39 x 3.70 [213 x 162 x 94]	PDF	SCE-8P6	\$5.75
SCE-1008CHNFSS	\$369.00	SCE-1008CHNFSS6	\$448.00	10.38 x 8.39 x 4.20 [264 x 213 x 107]	PDF	SCE-10P8	\$8.00
SCE-10086CHNFSS	\$403.00	SCE-10086CHNFSS6	\$490.00	10.38 x 8.39 x 6.20 [264 x 213 x 157]	PDF	SCE-10P8	\$8.00
SCE-12106CHNFSS	\$456.00	SCE-12106CHNFSS6	\$526.00	12.38 x 10.39 x 6.20 [314 x 264 x 157]	PDF	SCE-12P10	\$10.75
SCE-12108CHNFSS	\$486.00	SCE-12108CHNFSS6	\$605.00	12.38 x 10.39 x 8.20 [314 x 264 x 208]	PDF	SCE-12P10	\$10.75
SCE-1212CHNFSS	\$488.00	SCE-1212CHNFSS6	\$580.00	12.38 x 12.39 x 6.20 [314 x 315 x 157]	PDF	SCE-12P12	\$12.50
SCE-1412CHNFSS	\$515.00	SCE-1412CHNFSS6	\$635.00	14.38 x 12.39 x 6.20 [365 x 315 x 157]	PDF	SCE-14P12	\$14.00
SCE-1614CHNFSS	\$608.00	SCE-1614CHNFSS6	\$756.00	16.38 x 14.39 x 6.20 [416 x 366 x 157]	PDF	SCE-16P14	\$27.50
SCE-16148CHNFSS	\$674.00	SCE-16148CHNFSS6	\$782.00	16.38 x 14.39 x 8.20 [416 x 366 x 208]	PDF	SCE-16P14	\$27.50


Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®

Dimensions

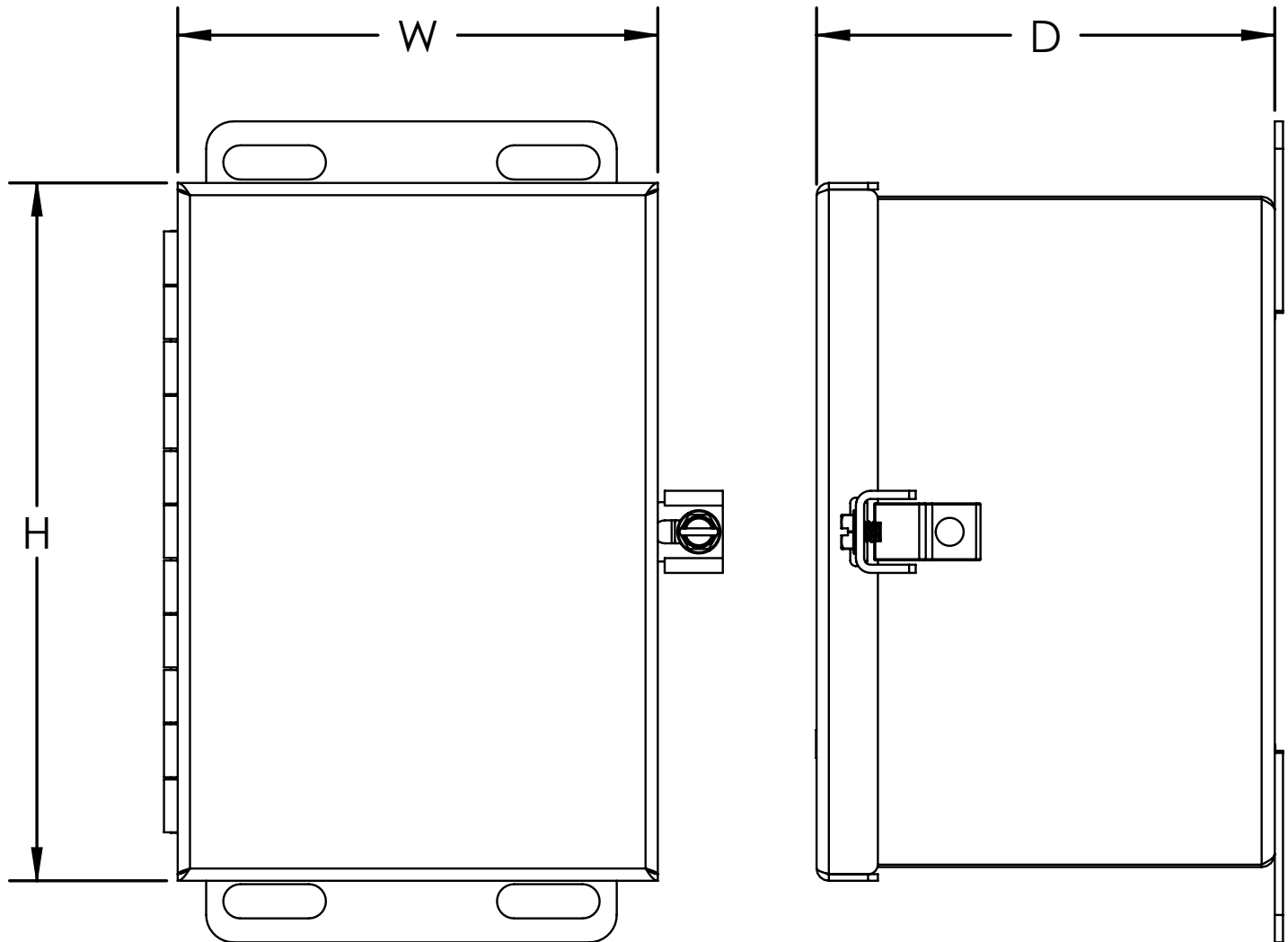

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®



Applications

Designed to house electrical and electronic controls, instruments and components in areas which are in very wet conditions. Provides a degree of protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended.

Construction

- 14-gauge Type 304 or 316L stainless steel
- Seams continuously welded and ground smooth
- Flange trough collar around all sides of door opening
- Poured-in-place oil- and water-resistant gasket
- Collar studs are provided for mounting optional subpanels.
- Stainless steel continuous hinges
- Interior print pocket
- Ground studs on door and body
- Stainless steel door clamps
- Hasp and staple for padlocking
- Welded mounting provision top and bottom of back

Finish

- #4 brushed finish on all exterior surfaces
- Optional subpanels are powder coated white.

Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4, 4X, and 12 [File E69392]
- IEC 60529 IP66



NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®

Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount Right-Flange Disconnect							
304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-16H1206SSLP	\$701.00	SCE-16H1206SS6LP	\$865.00	16.00 x 12.00 x 7.07 [406 x 305 x 180]	PDF	SCE-16P12	\$20.50
SCE-16H1208SSLP	\$751.00	SCE-16H1208SS6LP	\$927.00	16.00 x 12.00 x 9.07 [406 x 305 x 230]	PDF	SCE-16P12	\$20.50
SCE-16H1606SSLP	\$779.00	SCE-16H1606SS6LP	\$935.00	16.00 x 16.00 x 7.07 [406 x 406 x 180]	PDF	SCE-16P16	\$34.00
SCE-16H2006SSLP	\$856.00	SCE-16H2006SS6LP	\$1,027.00	16.00 x 20.00 x 7.07 [406 x 508 x 180]	PDF	SCE-20P16	\$42.00
SCE-20H1606SSLP	\$856.00	SCE-20H1606SS6LP	\$1,056.00	20.00 x 16.00 x 7.07 [508 x 406 x 180]	PDF	SCE-20P16	\$42.00
SCE-20H1608SSLP	\$917.00	SCE-20H1608SS6LP	\$1,131.00	20.00 x 16.00 x 9.07 [508 x 406 x 230]	PDF	SCE-20P16	\$42.00
SCE-20H1610SSLP	\$979.00	SCE-20H1610SS6LP	\$1,208.00	20.00 x 16.00 x 11.07 [508 x 406 x 281]	PDF	SCE-20P16	\$42.00
SCE-20H2006SSLP	\$944.00	SCE-20H2006SS6LP	\$1,165.00	20.00 x 20.00 x 7.07 [508 x 508 x 180]	PDF	SCE-20P20	\$49.00
SCE-20H2408SSLP	\$1,108.00	SCE-20H2408SS6LP	\$1,367.00	20.00 x 24.00 x 9.07 [508 x 610 x 230]	PDF	SCE-24P20	\$63.00
SCE-24H1608SSLP	\$997.00	SCE-24H1608SS6LP	\$1,230.00	24.00 x 16.00 x 9.07 [610 x 406 x 230]	PDF	SCE-24P16	\$45.50
SCE-24H2006SSLP	\$1,034.00	SCE-24H2006SS6LP	\$1,275.00	24.00 x 20.00 x 7.07 [610 x 508 x 180]	PDF	SCE-24P20	\$63.00
SCE-24H2008SSLP	\$1,108.00	SCE-24H2008SS6LP	\$1,367.00	24.00 x 20.00 x 9.07 [610 x 508 x 230]	PDF	SCE-24P20	\$63.00
SCE-24H2010SSLP	\$1,184.00	SCE-24H2010SS6LP	\$1,460.00	24.00 x 20.00 x 11.07 [610 x 508 x 281]	PDF	SCE-24P20	\$63.00
SCE-24H2406SSLP	\$1,063.00	—	—	24.00 x 24.00 x 7.07 [610 x 610 x 180]	PDF	SCE-24P24	\$74.00
SCE-24H2408SSLP	\$1,219.00	SCE-24H2408SS6LP	\$1,504.00	24.00 x 24.00 x 9.07 [610 x 610 x 230]	PDF	SCE-24P24	\$74.00
SCE-24H2412SSLP	\$1,385.00	SCE-24H2412SS6LP	\$1,708.00	24.00 x 24.00 x 13.07 [610 x 610 x 332]	PDF	SCE-24P24	\$74.00
SCE-24H3008SSLP	\$1,385.00	SCE-24H3008SS6LP	\$1,708.00	24.00 x 30.00 x 9.07 [610 x 762 x 230]	PDF	SCE-30P24	\$88.00
SCE-30H2008SSLP	\$1,254.00	SCE-30H2008SS6LP	\$1,547.00	30.00 x 20.00 x 9.07 [762 x 508 x 230]	PDF	SCE-30P20	\$77.00
SCE-30H2408SSLP	\$1,385.00	SCE-30H2408SS6LP	\$1,708.00	30.00 x 24.00 x 9.07 [762 x 610 x 230]	PDF	SCE-30P24	\$88.00
SCE-30H2412SSLP	\$1,570.00	SCE-30H2412SS6LP	\$1,936.00	30.00 x 24.00 x 13.07 [762 x 610 x 332]	PDF	SCE-30P24	\$88.00
SCE-30H2416SSLP	\$1,758.00	SCE-30H2416SS6LP	\$2,168.00	30.00 x 24.00 x 17.07 [762 x 610 x 434]	PDF	SCE-30P24	\$88.00
SCE-30H3008SSLP	\$1,582.00	SCE-30H3008SS6LP	\$1,951.00	30.00 x 30.00 x 9.07 [762 x 762 x 230]	PDF	SCE-30P30	\$116.00
SCE-36H2408SSLP	\$1,550.00	SCE-36H2408SS6LP	\$1,912.00	36.00 x 24.00 x 9.07 [914 x 610 x 230]	PDF	SCE-36P24	\$105.00
SCE-36H2410SSLP	\$1,655.00	SCE-36H2410SS6LP	\$2,041.00	36.00 x 24.00 x 11.07 [914 x 610 x 281]	PDF	SCE-36P24	\$105.00
SCE-36H3008SSLP	\$1,778.00	SCE-36H3008SS6LP	\$2,193.00	36.00 x 30.00 x 9.07 [914 x 762 x 230]	PDF	SCE-36P30	\$141.00
SCE-36H3010SSLP	\$1,892.00	SCE-36H3010SS6LP	\$2,333.00	36.00 x 30.00 x 11.07 [914 x 762 x 281]	PDF	SCE-36P30	\$141.00
SCE-36H3012SSLP	\$2,005.00	SCE-36H3012SS6LP	\$2,473.00	36.00 x 30.00 x 13.07 [914 x 762 x 332]	PDF	SCE-36P30	\$141.00
SCE-36H3016SSLP	\$2,232.00	SCE-36H3016SS6LP	\$2,752.00	36.00 x 30.00 x 17.07 [914 x 762 x 434]	PDF	SCE-36P30	\$141.00
SCE-36H3612SSLP	\$2,253.00	SCE-36H3612SS6LP	\$2,779.00	36.00 x 36.00 x 13.07 [914 x 914 x 332]	PDF	SCE-36P36	\$165.00
SCE-42H3010SSLP	\$2,098.00	SCE-42H3010SS6LP	\$2,588.00	42.00 x 30.00 x 11.07 [1067 x 762 x 281]	PDF	SCE-42P30	\$162.00
SCE-42H3608SSLP	\$2,232.00	SCE-42H3608SS6LP	\$2,752.00	42.00 x 36.00 x 9.07 [1067 x 914 x 230]	PDF	SCE-42P36	\$190.00
SCE-48H3608SSLP	\$2,459.00	SCE-48H3608SS6LP	\$3,033.00	48.00 x 36.00 x 9.07 [1219 x 914 x 230]	PDF	SCE-48P36	\$214.00
SCE-48H3610SSLP	\$2,730.00	—	—	48.00 x 36.00 x 11.07 [1219 x 914 x 281]	PDF	SCE-48P36	\$214.00
SCE-48H3612SSLP	\$2,748.00	SCE-48H3612SS6LP	\$3,389.00	48.00 x 36.00 x 13.07 [1219 x 914 x 332]	PDF	SCE-48P36	\$214.00
SCE-48H3616SSLP	\$3,038.00	SCE-48H3616SS6LP	\$3,747.00	48.00 x 36.00 x 17.07 [1219 x 914 x 434]	PDF	SCE-48P36	\$214.00
SCE-60H3612SSLP	\$3,244.00	SCE-60H3612SS6LP	\$4,001.00	60.00 x 36.00 x 13.07 [1524 x 914 x 332]	PDF	SCE-60P36	\$264.00

Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Dimensions

