

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®



Applications

Designed for use as electrical junction boxes, terminal wiring boxes, instrument housings, and electrical control enclosures. For use in wet and hosed down areas and in corrosive atmospheres.

Construction

- 16-gauge stainless steel Type 304 or 316/316L
- Seams continuously welded and ground smooth
- Stainless steel continuous hinge
- Stainless steel external screw clamps are quick and easy to operate.
- Poured-in-place oil- and water-resistant gasket
- Ground stud on door and body
- Standoffs are provided for mounting optional subpanels.
- Welded mounting provision top and bottom of back

Finish

- #4 brushed finish on all exterior surfaces
- Optional subpanels are powder coated white.

Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4 and 12 [File E69392]
- IEC 60529 IP66



Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount

304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
<u>SCE-6044CHNFSS</u>	\$162.00	<u>SCE-6044CHNFSS6</u>	\$194.00	6.38 x 4.39 x 3.20 [162 x 112 x 81]	<u>PDF</u>	<u>SCE-6P4</u>	\$4.75
<u>SCE-606CHNFSS</u>	\$202.00	<u>SCE-606CHNFSS6</u>	\$221.00	6.38 x 6.39 x 4.20 [162 x 162 x 107]	<u>PDF</u>	<u>SCE-6P6</u>	\$5.50
<u>SCE-8064CHNFSS</u>	\$211.00	<u>SCE-8064CHNFSS6</u>	\$242.00	8.38 x 6.39 x 3.70 [213 x 162 x 94]	<u>PDF</u>	<u>SCE-8P6</u>	\$6.50
<u>SCE-1008CHNFSS</u>	\$305.00	<u>SCE-1008CHNFSS6</u>	\$357.00	10.38 x 8.39 x 4.20 [264 x 213 x 107]	<u>PDF</u>	<u>SCE-10P8</u>	\$8.75
<u>SCE-10086CHNFSS</u>	\$333.00	<u>SCE-10086CHNFSS6</u>	\$390.00	10.38 x 8.39 x 6.20 [264 x 213 x 157]	<u>PDF</u>	<u>SCE-10P8</u>	\$8.75
<u>SCE-12106CHNFSS</u>	\$377.00	<u>SCE-12106CHNFSS6</u>	\$419.00	12.38 x 10.39 x 6.20 [314 x 264 x 157]	<u>PDF</u>	<u>SCE-12P10</u>	\$12.00
<u>SCE-12108CHNFSS</u>	\$401.00	<u>SCE-12108CHNFSS6</u>	\$482.00	12.38 x 10.39 x 8.20 [314 x 264 x 208]	<u>PDF</u>	<u>SCE-12P10</u>	\$12.00
<u>SCE-1212CHNFSS</u>	\$404.00	<u>SCE-1212CHNFSS6</u>	\$462.00	12.38 x 12.39 x 6.20 [314 x 315 x 157]	<u>PDF</u>	<u>SCE-12P12</u>	\$14.25
<u>SCE-1412CHNFSS</u>	\$426.00	<u>SCE-1412CHNFSS6</u>	\$506.00	14.38 x 12.39 x 6.20 [365 x 315 x 157]	<u>PDF</u>	<u>SCE-14P12</u>	\$15.75
<u>SCE-1614CHNFSS</u>	\$502.00	<u>SCE-1614CHNFSS6</u>	\$603.00	16.38 x 14.39 x 6.20 [416 x 366 x 157]	<u>PDF</u>	<u>SCE-16P14</u>	\$31.00
<u>SCE-16148CHNFSS</u>	\$557.00	<u>SCE-16148CHNFSS6</u>	\$623.00	16.38 x 14.39 x 8.20 [416 x 366 x 208]	<u>PDF</u>	<u>SCE-16P14</u>	\$31.00


Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®

Dimensions

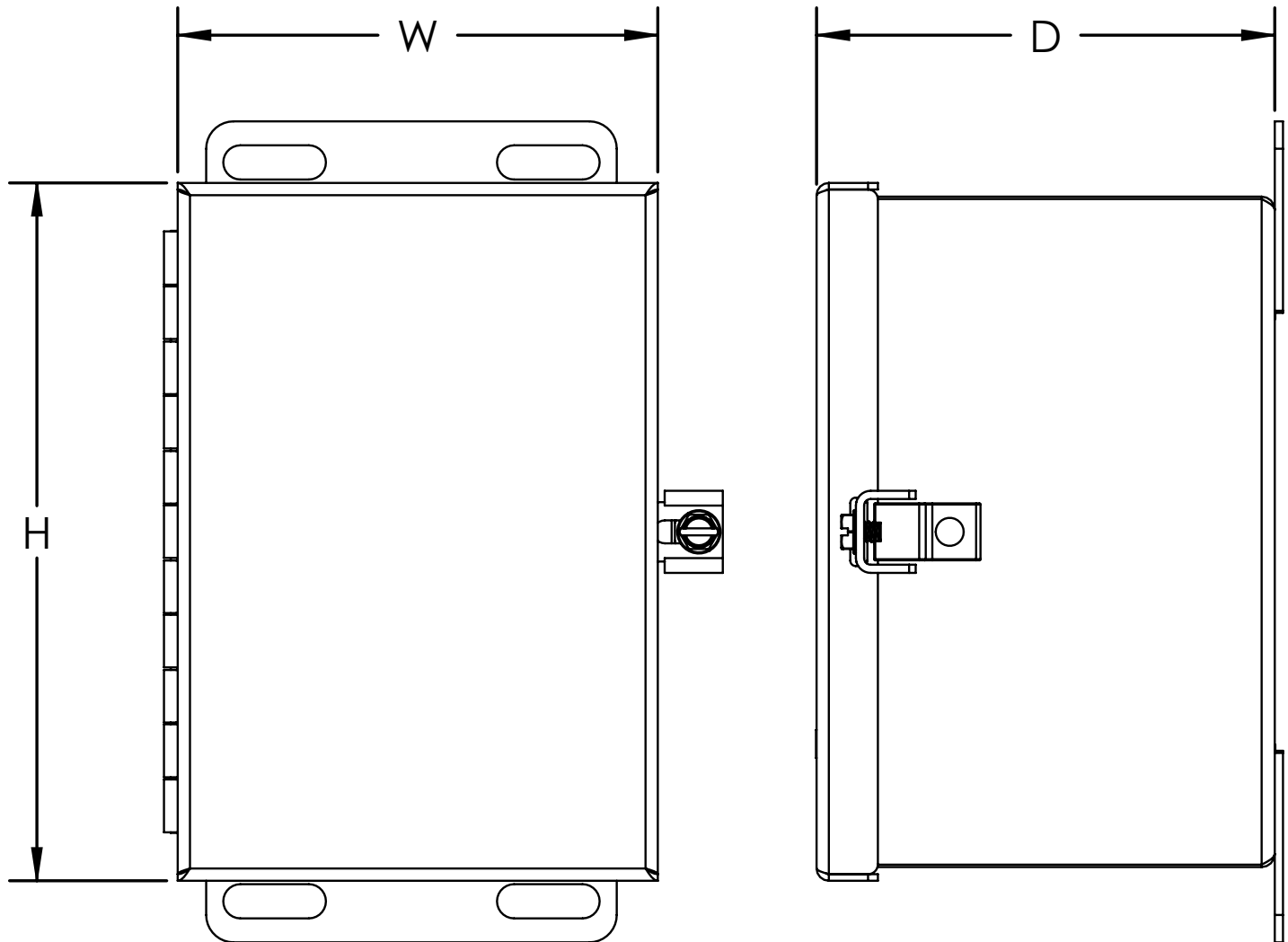

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®



Applications

Designed to house electrical and electronic controls, instruments and components in areas which are in very wet conditions. Provides a degree of protection from dust, dirt, oil, and water. For outdoor application a drip shield is recommended.

Construction

- 14-gauge Type 304 or 316L stainless steel
- Seams continuously welded and ground smooth
- Flange trough collar around all sides of door opening
- Poured-in-place oil- and water-resistant gasket
- Collar studs are provided for mounting optional subpanels.
- Stainless steel continuous hinges
- Interior print pocket
- Ground studs on door and body
- Stainless steel door clamps
- Hasp and staple for padlocking
- Welded mounting provision top and bottom of back

Finish

- #4 brushed finish on all exterior surfaces
- Optional subpanels are powder coated white.

Listings

- NEMA Type 3R, 4, 4X, 12, and 13
- cULus Listed Type 3R, 4, 4X, and 12 [File E69392]
- IEC 60529 IP66



NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®

Shipping Schedule

Same day

1 - 15 days

Color indicates shipping lead time in business days.

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount Right-Flange Disconnect							
304 Stainless Steel	Price	316L Stainless Steel	Price	Size HxWxD	Drawing Link	Optional Subpanel	Price
SCE-16H1206SSLP	\$580.00	SCE-16H1206SS6LP	\$689.00	16.00 x 12.00 x 7.07 [406 x 305 x 180]	PDF	SCE-16P12	\$23.00
SCE-16H1208SSLP	\$621.00	SCE-16H1208SS6LP	\$738.00	16.00 x 12.00 x 9.07 [406 x 305 x 230]	PDF	SCE-16P12	\$23.00
SCE-16H1606SSLP	\$644.00	SCE-16H1606SS6LP	\$744.00	16.00 x 16.00 x 7.07 [406 x 406 x 180]	PDF	SCE-16P16	\$38.00
SCE-16H2006SSLP	\$708.00	SCE-16H2006SS6LP	\$818.00	16.00 x 20.00 x 7.07 [406 x 508 x 180]	PDF	SCE-20P16	\$47.00
SCE-20H1606SSLP	\$708.00	SCE-20H1606SS6LP	\$841.00	20.00 x 16.00 x 7.07 [508 x 406 x 180]	PDF	SCE-20P16	\$47.00
SCE-20H1608SSLP	\$758.00	SCE-20H1608SS6LP	\$901.00	20.00 x 16.00 x 9.07 [508 x 406 x 230]	PDF	SCE-20P16	\$47.00
SCE-20H1610SSLP	\$809.00	SCE-20H1610SS6LP	\$962.00	20.00 x 16.00 x 11.07 [508 x 406 x 281]	PDF	SCE-20P16	\$47.00
SCE-20H2006SSLP	\$780.00	SCE-20H2006SS6LP	\$928.00	20.00 x 20.00 x 7.07 [508 x 508 x 180]	PDF	SCE-20P20	\$55.00
SCE-20H2408SSLP	\$916.00	SCE-20H2408SS6LP	\$1,089.00	20.00 x 24.00 x 9.07 [508 x 610 x 230]	PDF	SCE-24P20	\$71.00
SCE-24H1608SSLP	\$824.00	SCE-24H1608SS6LP	\$980.00	24.00 x 16.00 x 9.07 [610 x 406 x 230]	PDF	SCE-24P16	\$51.00
SCE-24H2006SSLP	\$854.00	SCE-24H2006SS6LP	\$1,016.00	24.00 x 20.00 x 7.07 [610 x 508 x 180]	PDF	SCE-24P20	\$71.00
SCE-24H2008SSLP	\$916.00	SCE-24H2008SS6LP	\$1,089.00	24.00 x 20.00 x 9.07 [610 x 508 x 230]	PDF	SCE-24P20	\$71.00
SCE-24H2010SSLP	\$979.00	SCE-24H2010SS6LP	\$1,163.00	24.00 x 20.00 x 11.07 [610 x 508 x 281]	PDF	SCE-24P20	\$71.00
SCE-24H2406SSLP	\$878.00	—	—	24.00 x 24.00 x 7.07 [610 x 610 x 180]	PDF	SCE-24P24	\$83.00
SCE-24H2408SSLP	\$1,007.00	SCE-24H2408SS6LP	\$1,198.00	24.00 x 24.00 x 9.07 [610 x 610 x 230]	PDF	SCE-24P24	\$83.00
SCE-24H2412SSLP	\$1,144.00	SCE-24H2412SS6LP	\$1,360.00	24.00 x 24.00 x 13.07 [610 x 610 x 332]	PDF	SCE-24P24	\$83.00
SCE-24H3008SSLP	\$1,295.00	SCE-24H3008SS6LP	\$1,532.00	24.00 x 30.00 x 9.07 [610 x 762 x 230]	PDF	SCE-30P24	\$98.00
SCE-30H2008SSLP	\$1,036.00	SCE-30H2008SS6LP	\$1,232.00	30.00 x 20.00 x 9.07 [762 x 508 x 230]	PDF	SCE-30P20	\$87.00
SCE-30H2408SSLP	\$1,295.00	SCE-30H2408SS6LP	\$1,532.00	30.00 x 24.00 x 9.07 [762 x 610 x 230]	PDF	SCE-30P24	\$98.00
SCE-30H2412SSLP	\$1,431.00	SCE-30H2412SS6LP	\$1,700.00	30.00 x 24.00 x 13.07 [762 x 610 x 332]	PDF	SCE-30P24	\$98.00
SCE-30H2416SSLP	\$1,569.00	SCE-30H2416SS6LP	\$1,870.00	30.00 x 24.00 x 17.07 [762 x 610 x 434]	PDF	SCE-30P24	\$98.00
SCE-30H3008SSLP	\$1,440.00	SCE-30H3008SS6LP	\$1,711.00	30.00 x 30.00 x 9.07 [762 x 762 x 230]	PDF	SCE-30P30	\$130.00
SCE-36H2408SSLP	\$1,416.00	SCE-36H2408SS6LP	\$1,682.00	36.00 x 24.00 x 9.07 [914 x 610 x 230]	PDF	SCE-36P24	\$118.00
SCE-36H2410SSLP	\$1,493.00	SCE-36H2410SS6LP	\$1,777.00	36.00 x 24.00 x 11.07 [914 x 610 x 281]	PDF	SCE-36P24	\$118.00
SCE-36H3008SSLP	\$1,584.00	SCE-36H3008SS6LP	\$1,888.00	36.00 x 30.00 x 9.07 [914 x 762 x 230]	PDF	SCE-36P30	\$157.00
SCE-36H3010SSLP	\$1,667.00	SCE-36H3010SS6LP	\$1,992.00	36.00 x 30.00 x 11.07 [914 x 762 x 281]	PDF	SCE-36P30	\$157.00
SCE-36H3012SSLP	\$1,751.00	SCE-36H3012SS6LP	\$2,095.00	36.00 x 30.00 x 13.07 [914 x 762 x 332]	PDF	SCE-36P30	\$157.00
SCE-36H3016SSLP	\$1,917.00	SCE-36H3016SS6LP	\$2,300.00	36.00 x 30.00 x 17.07 [914 x 762 x 434]	PDF	SCE-36P30	\$157.00
SCE-36H3612SSLP	\$1,933.00	SCE-36H3612SS6LP	\$2,319.00	36.00 x 36.00 x 13.07 [914 x 914 x 332]	PDF	SCE-36P36	\$185.00
SCE-42H3010SSLP	\$1,819.00	SCE-42H3010SS6LP	\$2,179.00	42.00 x 30.00 x 11.07 [1067 x 762 x 281]	PDF	SCE-42P30	\$181.00
SCE-42H3608SSLP	\$1,917.00	SCE-42H3608SS6LP	\$2,300.00	42.00 x 36.00 x 9.07 [1067 x 914 x 230]	PDF	SCE-42P36	\$213.00
SCE-48H3608SSLP	\$2,084.00	SCE-48H3608SS6LP	\$2,506.00	48.00 x 36.00 x 9.07 [1219 x 914 x 230]	PDF	SCE-48P36	\$240.00
SCE-48H3610SSLP	\$2,283.00	—	—	48.00 x 36.00 x 11.07 [1219 x 914 x 281]	PDF	SCE-48P36	\$240.00
SCE-48H3612SSLP	\$2,296.00	SCE-48H3612SS6LP	\$2,767.00	48.00 x 36.00 x 13.07 [1219 x 914 x 332]	PDF	SCE-48P36	\$240.00
SCE-48H3616SSLP	\$2,510.00	SCE-48H3616SS6LP	\$3,030.00	48.00 x 36.00 x 17.07 [1219 x 914 x 434]	PDF	SCE-48P36	\$240.00
SCE-60H3612SSLP	\$2,681.00	SCE-60H3612SS6LP	\$3,217.00	60.00 x 36.00 x 13.07 [1524 x 914 x 332]	PDF	SCE-60P36	\$295.00

Note: Dimensions in inches [millimeters].

NEMA 3R, 4, 4X, 12, and 13 Stainless Steel Single-Door Wall-Mount



Your Enclosure Source®

Dimensions

