

# StrideLinx Remote Access Solution

## Cellular Antennas for [SE-SL3011-4GG](#) Routers



**[SE-ANT110](#) \$13.50**

STRIDE whip/tilt LTE antenna, connector mount.



**[SE-ANT130](#) \$32.00**

STRIDE whip/straight LTE antenna, magnetic base mount, 9.8ft/3m cable length.



**[SE-ANT150](#) \$41.00**

STRIDE dome LTE antenna, IP67, panel mount, 9.8ft/3m cable length.

| 4G LTE Antenna Specifications |                                  |                           |                           |
|-------------------------------|----------------------------------|---------------------------|---------------------------|
|                               | <b><i>SE-ANT110</i></b>          | <b><i>SE-ANT130*</i></b>  | <b><i>SE-ANT150</i></b>   |
| <b>Price</b>                  | \$13.50                          | \$32.00                   | \$41.00                   |
| <b>Fits</b>                   | <a href="#">SE-SL3011-4GG</a>    |                           |                           |
| <b>Antenna Connector</b>      | SMA (M)                          |                           |                           |
| <b>Application</b>            | LTE, CDMA, GSM, HSPA, UMTS, GPRS |                           |                           |
| <b>Impedance</b>              | 50Ω                              |                           |                           |
| <b>Antenna Type</b>           | whip, tilt                       | whip, straight            | dome                      |
| <b>Cable Length</b>           | N/A                              | 3m [9.8 ft]               | 3m [9.8 ft]               |
| <b>Frequency Range</b>        | 700–960MHz / 1.71–3.8 GHz        | 700–960MHz / 1.71–3.5 GHz | 700–960MHz / 1.71–2.7 GHz |
| <b>Gain</b>                   | -3.0 dBi / 0.9 dBi               | -2.5dBi / 0.1dBi          | 1.2 dBi / 3.2 dBi         |
| <b>Height</b>                 | 2.84 in                          | 13 in                     | 1.89 in                   |
| <b>IP Rating</b>              | –                                | –                         | IP67                      |
| <b>Maximum Power</b>          | 10W                              | 50W                       | 5W                        |
| <b>Mounting Screw Torque</b>  | NA                               | NA                        | 2.94 N·m                  |


\* Gains listed are based on the antenna being mounted on a suitable ground plane.




## Cellular Antennas for SE-SL3011-4G and SE-SL3011-4GG Routers

## mm [inches]


## SE-ANT110:

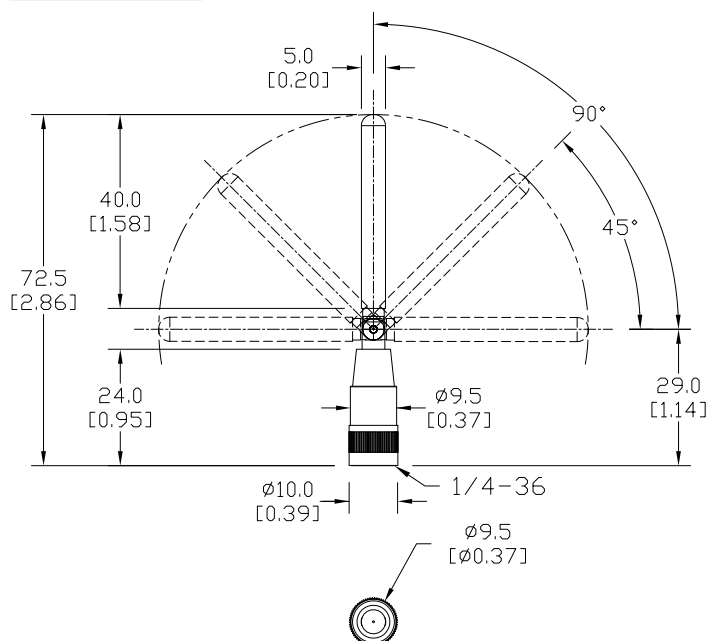

## SE-ANT130:

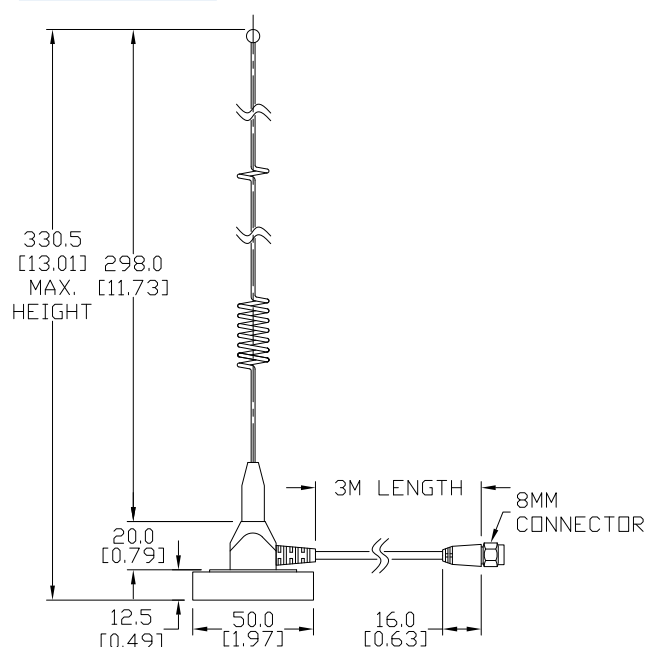

## SE-ANT150:

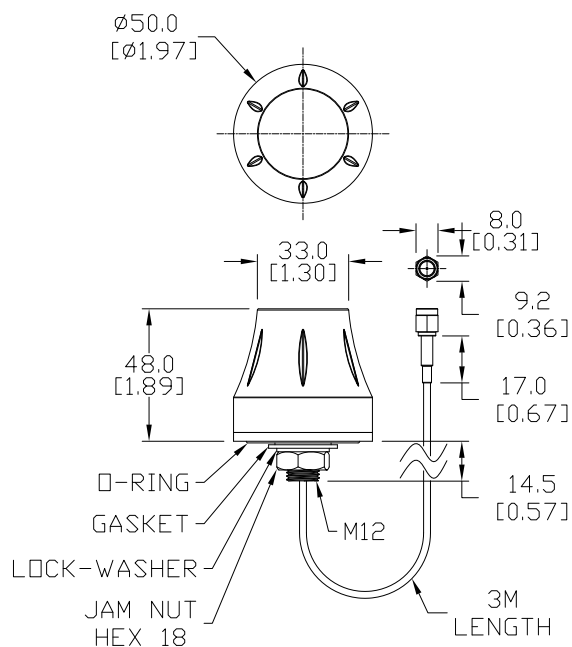

[www.automationdirect.com](http://www.automationdirect.com)