

StrideLinx Remote Access Solution

2.4GHz WiFi Antennas for [SE-SL3011-WF](#) Routers (1 antenna required)



[SE-ANT210](#) \$10.50

STRIDE whip/straight 2.4 GHz WiFi antenna, IP65, connector mount.



[SE-ANT250](#) \$37.00

STRIDE dome 2.4 GHz WiFi antenna, IP67, panel mount, 9.8ft/3m cable length.

802.11 b/g/n 2.4 GHz WiFi Antenna Specifications

	<i>SE-ANT210</i>	<i>SE-ANT250</i>
Price	\$10.50	\$37.00
Fits	SE-SL3011-WF	
Antenna Connector	RP-SMA (M)	
Application	802.11 b/g/n	
Impedance	50Ω	
Antenna Type	whip, straight	dome
Cable Length	N/A	3m [9.8 ft]
Frequency Range	2.4–2.5 GHz	2.4–2.5 GHz
Gain	1.8 dBi	1.5 dBi
Height	1.2 in	1.89 in
IP Rating	IP65	IP67
Maximum Power	1W	5W
Mounting Screw Torque	NA	2.94 N·m


StrideLinx Remote Access Solution

2.4GHz WiFi Antennas for SE-SL3011-WF Routers


Dimensions

mm [inches]

SE-ANT210:

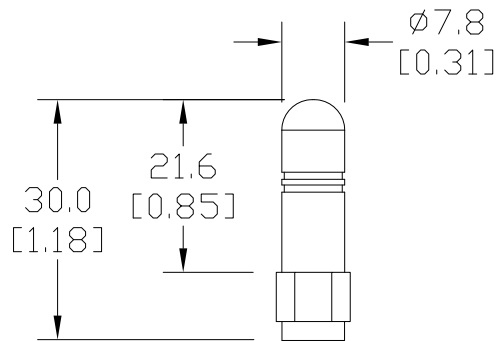

SE-ANT250:

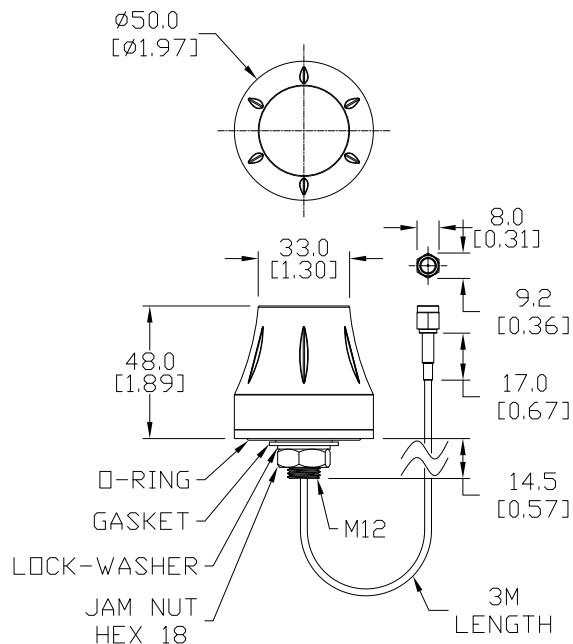

See our website: www.AutomationDirect.com for complete engineering drawings.