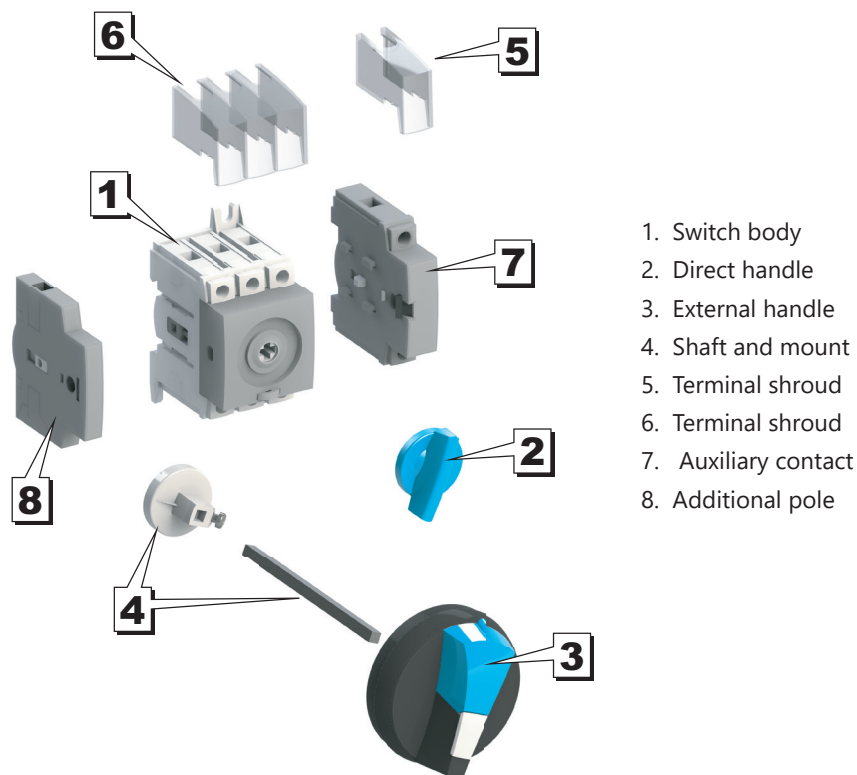


# Non-Fusible Disconnect Switches

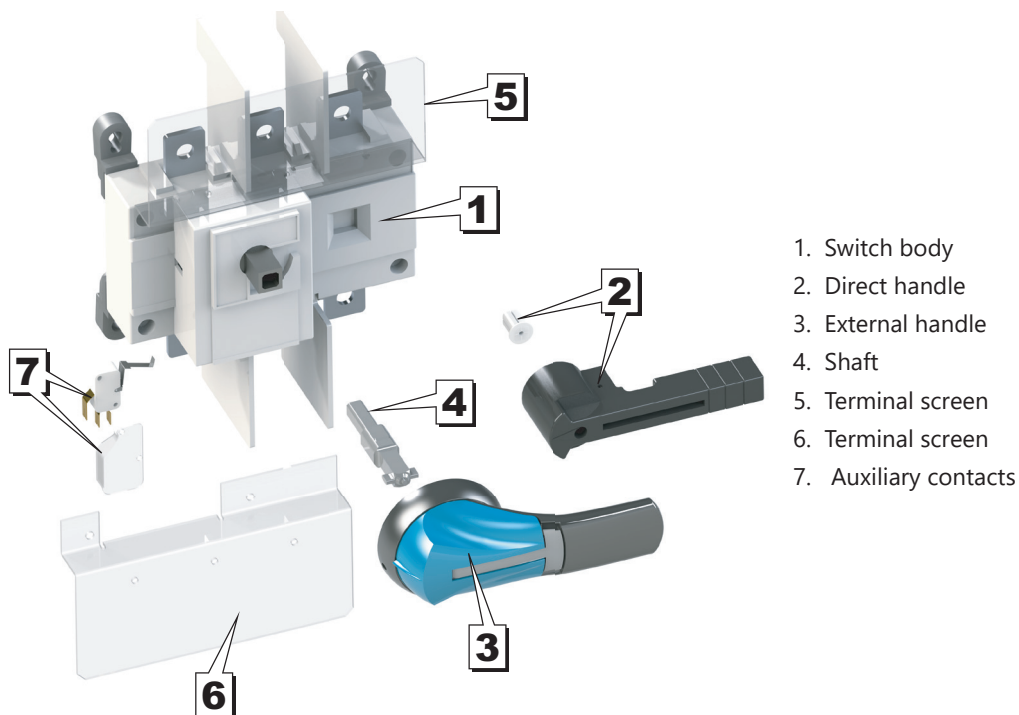
## Assembly of Accessories



### Non-fusible 16 - 100A Disconnect Switches Accessories



### Non-fusible 100 - 600A Disconnect Switches Accessories




# SIRCO M UL 98

## Compact Non-Fusible Disconnect Switches




To assemble a switch, please select:
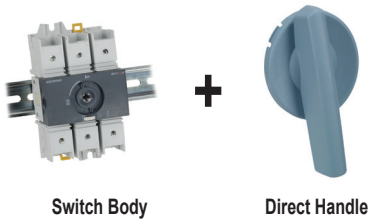
### Direct Operation



### External Operation

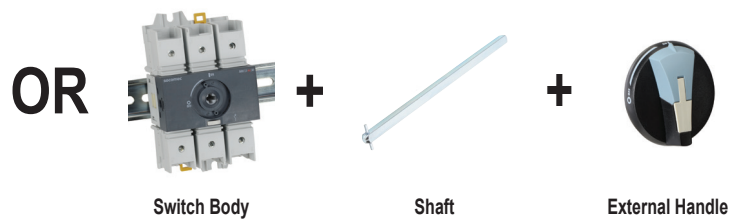

| UL 98 Compact Non-Fusible Disconnect Switches |                                                            |            |                |          |
|-----------------------------------------------|------------------------------------------------------------|------------|----------------|----------|
| Part Number*                                  | Description                                                | Amp Rating | Voltage Rating | Price    |
| <a href="#">22013003</a>                      | Non-fusible rotary 3-pole disconnect switch, M3 frame size | 30         | 600VAC         | \$78.00  |
| <a href="#">22013006</a>                      |                                                            | 60         | 600VAC         | \$91.00  |
| <a href="#">22003010</a>                      |                                                            | 100        | 600VAC         | \$106.00 |

\* These part numbers are direct replacements for previous part numbers with a "-UL" suffix. They have identical technical specs, form, fit and function. There is no change in agency approvals, the UL mark, listing, or File numbers E173959 and E201138.

| Handles – Defeatable and Lockable |                                                       |                        |              |             |              |         |
|-----------------------------------|-------------------------------------------------------|------------------------|--------------|-------------|--------------|---------|
| Part Number                       | Description                                           | Switch Body Rating (A) | Handle Color | Handle Type | NEMA/UL Type | Price   |
| <a href="#">22995032</a>          | Mounts directly on switch, no shaft required*         | 30 - 100               | Blue         | M01         | —            | \$5.50  |
| <a href="#">147D1111</a>          | External front and right side handles, shaft required | 16 - 100               | Black/Blue   | S00         | 4, 4X        | \$27.50 |
| <a href="#">147E1111</a>          |                                                       |                        | Red/Yellow   |             |              | \$27.50 |
| <a href="#">14831111</a>          |                                                       | 16 - 100               | Black/Blue   | S0          | 1, 3R, 12    | \$29.00 |
| <a href="#">14841111</a>          |                                                       |                        | Red/Yellow   |             |              | \$29.00 |
| <a href="#">148D1111</a>          |                                                       |                        | Black/Blue   |             | 4, 4X        | \$48.50 |
| <a href="#">148E1111</a>          |                                                       |                        | Red/Yellow   |             |              | \$48.50 |
| <a href="#">140F2111</a>          |                                                       |                        | Black/Blue   | S01         | 1, 3R, 12    | \$35.00 |
| <a href="#">140G2111</a>          |                                                       |                        | Red/Yellow   |             |              | \$35.00 |
| <a href="#">140D2111</a>          |                                                       |                        | Black/Blue   |             | 4, 4X        | \$51.00 |
| <a href="#">140E2111</a>          |                                                       |                        | Red/Yellow   |             |              | \$51.00 |



\* Not defeatable

| Shafts for External Handles |                        |             |             |             |         |
|-----------------------------|------------------------|-------------|-------------|-------------|---------|
| Part Number                 | Switch Body Rating (A) | Handle Type | Length (in) | Length (mm) | Price   |
| <a href="#">14070515</a>    | 16 - 100               | S00, S0     | 5.9         | 150         | \$7.00  |
| <a href="#">14070520</a>    |                        |             | 7.9         | 200         | \$8.25  |
| <a href="#">14070532</a>    |                        |             | 12.6        | 320         | \$9.00  |
| <a href="#">14040520</a>    |                        | S01         | 7.9         | 200         | \$11.00 |
| <a href="#">14040532</a>    |                        |             | 12.6        | 320         | \$13.50 |
| <a href="#">14040540</a>    |                        |             | 15.7        | 400         | \$22.00 |



# SIRCO M UL 98

## Compact Non-Fusible Disconnect Switches



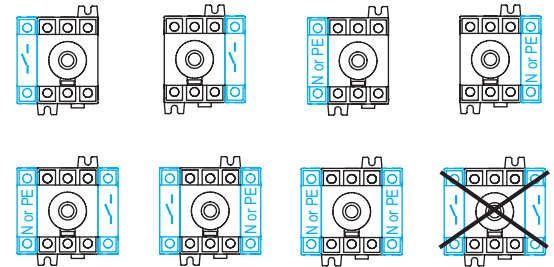
### Shaft Guide for External Handle

| Part Number              | Description                                                                                                                                                                                    | Handle Type     | Price  |
|--------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------|--------|
| <a href="#">14190000</a> | This accessory makes alignment connections between the shaft and handle easier. Allows up to 15mm misalignment tolerance. Required for a shaft length over 300mm. Included with longer shafts. | S00, S0         | \$3.25 |
| <a href="#">14290000</a> |                                                                                                                                                                                                | S01, S1, S2, S3 | \$6.75 |

[14190000](#)

### Additional Poles

| Part Number*             | Description                                   | Switch Body Rating (A) | No. of Poles | Use                                                                                           | Price   |
|--------------------------|-----------------------------------------------|------------------------|--------------|-----------------------------------------------------------------------------------------------|---------|
| <a href="#">22011003</a> | Fourth pole module switched 600VAC 100kA SCCR | 30                     | 1            | Adding one additional pole transforms a non-fusible disconnect switch from 3 poles to 4 poles | \$23.50 |
| <a href="#">22011006</a> | Fourth pole module switched 600VAC 65kA SCCR  | 60                     | 1            |                                                                                               | \$27.00 |
| <a href="#">22001010</a> | Fourth pole module switched 600VAC 100kA SCCR | 100                    | 1            |                                                                                               | \$33.50 |
| <a href="#">22005011</a> | Solid neutral pole module unswitched 600VAC   | 30 - 100               | 1            | Transforms the 3-pole switch into a 3-pole + solid neutral                                    | \$28.00 |
| <a href="#">22009011</a> | Grounding pole module unswitched 600VAC       | 30 - 100               | 1            | Adds 1 ground module pole to the switch-disconnector                                          | \$28.00 |

[22011003](#)

4th Pole Configurations

\* These part numbers are direct replacements for previous part numbers with a "-UL" suffix. They have identical technical specs, form, fit and function. There is no change in agency approvals, the UL mark, listing, or File numbers E173959 and E201138.

### Terminal Shrouds

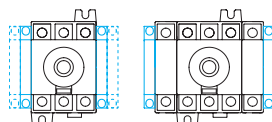
| Part Number              | Description                                                                                                          | Switch Body Rating (A) | No. of Poles | Price  |
|--------------------------|----------------------------------------------------------------------------------------------------------------------|------------------------|--------------|--------|
| <a href="#">22941011</a> | Terminal shroud line/load mount, 2 per pack, offers additional protection against direct contact with the terminals. | 30 - 100               | 1            | \$6.00 |
| <a href="#">22943016</a> |                                                                                                                      | 30 - 100               | 3            | \$8.00 |

[22941011](#)

### Auxiliary Contacts

| Part Number*             | Description                                                                                                                                                 | Switch Body Rating (A) | Contacts    | Price   |
|--------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------|-------------|---------|
| <a href="#">22990001</a> | Auxiliary contact block module, 10A @ 240VAC, can be mounted on left or right side of switch, maximum 4 auxiliary contacts can be used (requires 2 modules) | 16 - 100               | 1 NO / 1 NC | \$22.00 |
| <a href="#">22990011</a> |                                                                                                                                                             | 16 - 100               | 2 NO        | \$24.00 |

\* These part numbers are direct replacements for previous part numbers with a "-UL" suffix. They have identical technical specs, form, fit and function. There is no change in agency approvals, the UL mark, listing, or File numbers E173959 and E201138.

[22990001](#)

Auxiliary Contact Configurations

# SIRCO UL 98 Non-Fusible Disconnect Switches



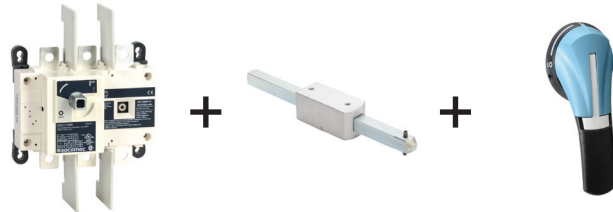
To assemble a switch, please select:

*Direct Operation*

*External Operation*



OR



Switch Body

Direct Handle

Switch Body

Shaft

External Handle

## UL 98 Non-Fusible Disconnect Switches

| Part Number              | Description                                        | Amp Rating | # of Poles | Price      |
|--------------------------|----------------------------------------------------|------------|------------|------------|
| <a href="#">27003011</a> | Non-fusible 600VAC rotary disconnect switch, 200kA | 100        | 3          | \$176.00   |
| <a href="#">27004011</a> |                                                    |            | 4          | \$206.00   |
| <a href="#">27003021</a> |                                                    | 200        | 3          | \$274.00   |
| <a href="#">27004021</a> |                                                    |            | 4          | \$302.00   |
| <a href="#">27003041</a> |                                                    | 400        | 3          | \$655.00   |
| <a href="#">27003060</a> |                                                    | 600        | 3          | \$1,134.00 |

## Handles – Defeatable and Lockable

| Part Number              | Description                                   | Switch Body Rating (A) | Handle Color                                        | Handle Type | NEMA/UL Type | Price      |
|--------------------------|-----------------------------------------------|------------------------|-----------------------------------------------------|-------------|--------------|------------|
| <a href="#">26995052</a> | Mounts directly on switch, no shaft required* | 100-400                | Black                                               | —           | —            | \$18.00    |
| <a href="#">37996012</a> |                                               | 600                    | Black                                               | —           | —            | \$36.50    |
| <a href="#">142F2111</a> | External front handles, shaft required        | 100-400                | Black/Blue                                          | S2          | 1, 3R, 12    | \$49.00    |
| <a href="#">142G2111</a> |                                               |                        | Red/Yellow                                          |             |              | \$49.00    |
| <a href="#">142D2111</a> |                                               |                        | Black/Blue                                          |             | \$68.00      |            |
| <a href="#">142E2111</a> |                                               |                        | Red/Yellow                                          |             | \$68.00      |            |
| <a href="#">143D3111</a> |                                               | 600                    | Black/Bue                                           | S3          | 4, 4X        | \$81.00    |
| <a href="#">143E3111</a> |                                               |                        | Red/Yellow                                          |             |              | \$81.00    |
| <a href="#">143F3111</a> |                                               |                        | Black/Blue                                          |             | 1, 3R, 12    | \$64.00    |
| <a href="#">143G3111</a> |                                               |                        | Red/Yellow                                          |             |              | \$64.00    |
| <a href="#">142D2911</a> |                                               |                        | External heavy duty front handles, shaft required** |             | 100-400      | Black/Blue |
| <a href="#">142E2911</a> | Red/Yellow                                    | \$85.00                |                                                     |             |              |            |
| <a href="#">143D3911</a> | 600                                           | Black/Blue             |                                                     | S3          | \$112.00     |            |
| <a href="#">143E3911</a> |                                               | Red/Yellow             |                                                     |             | \$112.00     |            |

\* Not defeatable.

\*\* Heavy duty handles have larger metal hasp to accommodate multiple locking devices.



## Shafts for External Handles

| Part Number              | Switch Body Rating (A) | Handle Type | Length (in) | Length (mm) | Price   |
|--------------------------|------------------------|-------------|-------------|-------------|---------|
| <a href="#">14001020</a> | 100-400                | S1, S2      | 7.9         | 200         | \$12.50 |
| <a href="#">14001032</a> |                        |             | 12.6        | 320         | \$13.50 |
| <a href="#">14001040</a> |                        |             | 15.7        | 400         | \$15.00 |
| <a href="#">14011520</a> | 600                    | S3          | 7.9         | 200         | \$16.00 |
| <a href="#">14011532</a> |                        |             | 12.6        | 320         | \$21.50 |
| <a href="#">14011540</a> |                        |             | 15.7        | 400         | \$24.00 |



# SIRCO UL 98 Non-Fusible Disconnect Switches



## Shaft Guide for External Handle

| Part Number                     | Description                                                                                                                                                                                   | Fits Handle Type | Price  |
|---------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------|--------|
| <a href="#"><u>14290000</u></a> | This accessory makes alignment connections between the shaft and handle easier. Allows up to 15mm misalignment tolerance. Required for a shaft length over 300mm. Included with longer shafts | S01, S1, S2, S3  | \$6.75 |

[14290000](#)

## Auxiliary Contacts

| Part Number                     | Description                                                          | Switch Body Rating (A) | Type                  | Contacts    | Price   |
|---------------------------------|----------------------------------------------------------------------|------------------------|-----------------------|-------------|---------|
| <a href="#"><u>27990021</u></a> | Auxiliary Contact Block: 1 Form C, 10A @ 125 VAC                     | 100-600                | C Type standard level | 1 NO / 1 NC | \$13.50 |
| <a href="#"><u>27990022</u></a> | Auxiliary Contact Block: 1 Form C, 10A @ 125 VAC, 2/pk               |                        |                       | 1 NO / 1 NC | \$18.00 |
| <a href="#"><u>27990121</u></a> | Auxiliary Contact Block: 1 Form C, 1A @ 125 VAC, low impedance       |                        | C Type low impedance  | 1 NO / 1 NC | \$15.50 |
| <a href="#"><u>27990122</u></a> | Auxiliary Contact Block: 1 Form C, 1A @ 125 VAC, low impedance, 2/pk |                        |                       | 1 NO / 1 NC | \$25.00 |

[27990021](#)

## Terminal Screens

| Part Number                      | Description                                                                                                 | Switch Body Rating (A) | No. of Poles | Position     | Price   |
|----------------------------------|-------------------------------------------------------------------------------------------------------------|------------------------|--------------|--------------|---------|
| <a href="#"><u>27983021</u></a>  | Terminal screens provide line or load protection against direct contact with terminals or connection parts. | 100-250                | 3            | Line         | \$21.50 |
| <a href="#"><u>27988021</u></a>  |                                                                                                             |                        |              | Load         | \$21.50 |
| <a href="#"><u>27984021</u></a>  |                                                                                                             |                        | 4            | Line or load | \$25.00 |
| <a href="#"><u>27983041</u></a>  |                                                                                                             | 400                    | 3            | Line         | \$32.00 |
| <a href="#"><u>27988041</u></a>  |                                                                                                             |                        |              | Load         | \$32.00 |
| <a href="#"><u>27983060*</u></a> |                                                                                                             | 600                    |              | Load         | \$71.00 |

[27983021](#)

\* Load side screen, the line side is included with the switch.

## Terminal Lugs

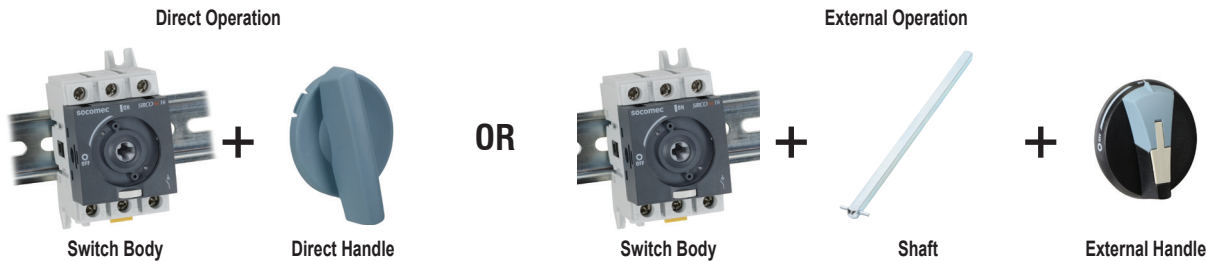
| Part Number                     | Description                                                                                                             | Switch Body Rating (A) | Wire Range       | Lugs per kit | No cables per lug | Price    |
|---------------------------------|-------------------------------------------------------------------------------------------------------------------------|------------------------|------------------|--------------|-------------------|----------|
| <a href="#"><u>39542020</u></a> | Terminal lug kits allow for the connection of bare copper cables on to the terminals (no spade lugs). Cable type Cu/Al. | 100-250                | #6 - 300MCM      | 2            | 1                 | \$18.00  |
| <a href="#"><u>39543020</u></a> |                                                                                                                         |                        |                  | 3            |                   | \$27.00  |
| <a href="#"><u>39544020</u></a> |                                                                                                                         |                        |                  | 4            |                   | \$35.00  |
| <a href="#"><u>39543040</u></a> |                                                                                                                         | 400                    | #4 - 600MCM      | 3            | 2                 | \$69.00  |
| <a href="#"><u>39543041</u></a> |                                                                                                                         |                        | 2x (#6 - 350MCM) |              |                   | \$94.00  |
| <a href="#"><u>39543060</u></a> |                                                                                                                         | 600                    | 2x (#2 - 600MCM) |              |                   | \$141.00 |

[39542020](#)

# SIRCO M UL 508 Non-Fusible Disconnect Switches



To assemble a switch, please select:



| UL 508 Non-Fusible Disconnect Switches |                                                               |                        |            |         |
|----------------------------------------|---------------------------------------------------------------|------------------------|------------|---------|
| Part Number*                           | Description                                                   | Switch Body Rating (A) | # of Poles | Price   |
| <a href="#">22003000</a>               | Non-fusible UL 508 disconnect rotary 600VAC disconnect switch | 16                     | 3          | \$29.50 |
| <a href="#">22003001</a>               |                                                               | 20                     | 3          | \$31.00 |
| <a href="#">22003002</a>               |                                                               | 25                     | 3          | \$34.00 |
| <a href="#">22003003</a>               |                                                               | 32                     | 3          | \$35.00 |
| <a href="#">22003004</a>               |                                                               | 40                     | 3          | \$36.00 |
| <a href="#">22003006</a>               |                                                               | 63                     | 3          | \$47.50 |
| <a href="#">22003008</a>               |                                                               | 80                     | 3          | \$53.00 |
| <a href="#">22003009</a>               |                                                               | 100                    | 3          | \$68.00 |

\* These part numbers are direct replacements for previous part numbers with a "-UL" suffix. They have identical technical specs, form, fit and function. There is no change in agency approvals, the UL mark, listing, or File number E173959.

| Handles – Defeatable and Lockable |                                                    |                        |              |             |               |           |         |
|-----------------------------------|----------------------------------------------------|------------------------|--------------|-------------|---------------|-----------|---------|
| Part Number                       | Description                                        | Switch Body Rating (A) | Handle Color | Handle Type | NEMA/ UL Type | Price     |         |
| <a href="#"><b>22995012</b></a>   | Direct operation handle, shaft not required*       | 16 - 100               | Blue         | M00         | –             | \$3.50    |         |
| <a href="#"><b>14731111</b></a>   | Front and right side handles I - O, shaft required |                        | Black/Blue   | S00         | 1, 3R, 12     | \$17.00   |         |
| <a href="#"><b>14741111</b></a>   |                                                    |                        | Red/Yellow   |             |               | \$17.00   |         |
| <a href="#"><b>147D1111</b></a>   |                                                    |                        | Black/Blue   |             |               | \$27.50   |         |
| <a href="#"><b>147E1111</b></a>   |                                                    |                        | Red/Yellow   | S0          | 4, 4X         | \$27.50   |         |
| <a href="#"><b>14831111</b></a>   |                                                    |                        | Black/Blue   |             |               | 1, 3R, 12 | \$29.00 |
| <a href="#"><b>14841111</b></a>   |                                                    |                        | Red/Yellow   |             |               |           | \$29.00 |
| <a href="#"><b>148D1111</b></a>   |                                                    |                        | Black/Blue   |             |               | 4, 4X     | \$48.50 |
| <a href="#"><b>148E1111</b></a>   |                                                    |                        | Red/Yellow   | \$48.50     |               |           |         |
| <a href="#"><b>140F2111</b></a>   |                                                    |                        | Black/Blue   | S01         | 1, 3R, 12     | \$35.00   |         |
| <a href="#"><b>140G2111</b></a>   |                                                    |                        | Red/Yellow   |             |               | \$35.00   |         |
| <a href="#"><b>140D2111</b></a>   |                                                    |                        | Black/Blue   |             | 4, 4X         | \$51.00   |         |
| <a href="#"><b>140E2111</b></a>   |                                                    |                        | Red/Yellow   |             |               | \$51.00   |         |

\* Not defeatable



| Shafts for External Handles |                                                                       |                        |             |        |     |         |
|-----------------------------|-----------------------------------------------------------------------|------------------------|-------------|--------|-----|---------|
| Part Number                 | Description                                                           | Switch Body Rating (A) | Handle Type | Length |     | Price   |
|                             |                                                                       |                        |             | in     | mm  |         |
| <a href="#">14070515</a>    | For 3/4-pole switches: shafts are for external front and side handle  | 16 - 100               | S00, S0     | 5.9    | 150 | \$7.00  |
| <a href="#">14070520</a>    |                                                                       |                        |             | 7.9    | 200 | \$8.25  |
| <a href="#">14070532</a>    |                                                                       |                        |             | 12.6   | 320 | \$9.00  |
| <a href="#">14040520</a>    | For 3/4-pole switches: shafts are for external front and side handle. |                        | S01         | 7.9    | 200 | \$11.00 |
| <a href="#">14040532</a>    |                                                                       |                        |             | 12.6   | 320 | \$13.50 |
| <a href="#">14040540</a>    |                                                                       |                        |             | 15.7   | 400 | \$22.00 |






# SIRCO M UL 508 Non-Fusible Disconnect Switches


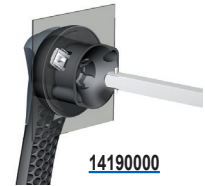
## Shaft Guide for External Handle


| Part Number              | Description                                                                                                                                                                                    | Fits Handle Type | Price  |
|--------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------|--------|
| <a href="#">14190000</a> | This accessory makes alignment connections between the shaft and handle easier. Allows up to 15mm misalignment tolerance. Required for a shaft length over 300mm. Included with longer shafts. | S0, S00          | \$3.25 |
| <a href="#">14290000</a> |                                                                                                                                                                                                | S01, S1, S2, S3  | \$6.75 |



## Additional Poles

| Part Number*             | Description              | Switch Body Rating (A) | No. of Poles | Use                                      | Price   |
|--------------------------|--------------------------|------------------------|--------------|------------------------------------------|---------|
| <a href="#">22001000</a> | Module switched 4th pole | 16                     | 1            | Transforms a 3-pole switch into a 4-pole | \$17.00 |
| <a href="#">22001001</a> |                          | 20                     |              |                                          | \$18.00 |
| <a href="#">22001002</a> |                          | 25                     |              |                                          | \$18.00 |
| <a href="#">22001003</a> |                          | 32                     |              |                                          | \$20.00 |
| <a href="#">22001004</a> |                          | 40                     |              |                                          | \$21.50 |

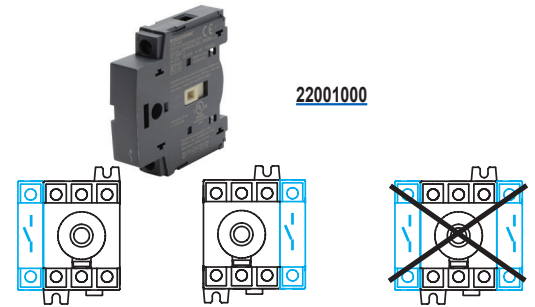\* These part numbers are direct replacements for previous part numbers with a "-UL" suffix. They have identical technical specs, form, fit and function. There is no change in agency approvals, the UL mark, listing, or File number E173959.



4th Pole Configurations

## Terminal Shrouds

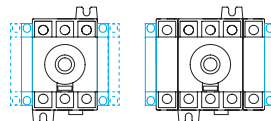
| Part Number              | Description                                                                                                          | Switch Body Rating (A) | No. of Poles | Price  |
|--------------------------|----------------------------------------------------------------------------------------------------------------------|------------------------|--------------|--------|
| <a href="#">22941005</a> | Terminal shroud line/load mount, 2 per pack, offers additional protection against direct contact with the terminals. | 16-40                  | 1            | \$3.50 |
| <a href="#">22943005</a> |                                                                                                                      |                        | 3            | \$5.50 |
| <a href="#">22941009</a> |                                                                                                                      | 63-100                 | 1            | \$4.25 |
| <a href="#">22943009</a> |                                                                                                                      |                        | 3            | \$7.00 |



## Auxiliary Contacts

| Part Number*             | Description                                                                                                                                                  | Switch Body Rating (A) | Contacts    | Price   |
|--------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------|-------------|---------|
| <a href="#">22990001</a> | Auxiliary contact block module, 10A @ 240VAC, can be mounted on left or right side of switch, maximum 4 auxiliary contacts can be used (requires 2 modules). | 16 - 100               | 1 NO / 1 NC | \$22.00 |
| <a href="#">22990011</a> |                                                                                                                                                              | 16 - 100               | 2 NO        | \$24.00 |

\* These part numbers are direct replacements for previous part numbers with a "-UL" suffix. They have identical technical specs, form, fit and function. There is no change in agency approvals, the UL mark, listing, or File number E173959.



Auxiliary Contact Configurations

[22990001](#)

## Conversion Kit

| Part Number              | Description                                                                             | Switch Body Rating (A) | Price   |
|--------------------------|-----------------------------------------------------------------------------------------|------------------------|---------|
| <a href="#">22096009</a> | Front mount transfer switch (2/4 pole) conversion kit. Open center transition (I-O-II). | 16 - 100               | \$32.50 |
| <a href="#">22696009</a> | Front mount multi-pole (6/8 pole) conversion kit.                                       | 16 - 100               | \$29.00 |

[22096009](#)

## Door Mounting Kit

| Part Number              | Description                                                                                                                                       | Switch Body Rating (A) | No. of Poles | Price  |
|--------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------|------------------------|--------------|--------|
| <a href="#">22993409</a> | This kit enables direct mounting of the switch on the panel door or on the right or left side of the panel. For use with S0 and S00 handles only. | 16-100                 | 3/4          | \$7.00 |

[22993409](#)

# SIRCO M UL 508 Enclosed Non-Fusible Disconnect Switches



Our enclosed UL 508 switches allow for the safe control and disconnection of any motor application.

## General characteristics

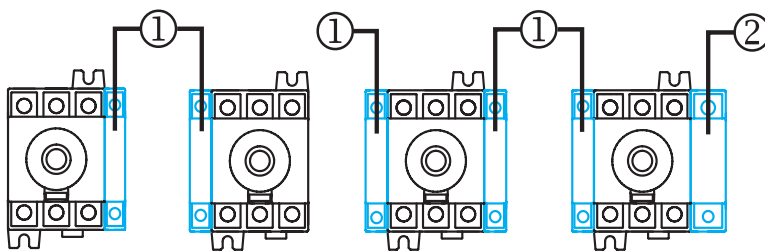
- Gray enclosure with red handle
- Equipped with a 3-pole SIRCO M
- 1 removable ground terminal
- Possibility of adding 1 power pole and 1 auxiliary contact
- Operating temperature -4° to +158°F (-20° to +70°C)
- Polycarbonate plastic
- Flammability rating UL94-5VA
- NEMA/UL Type 1, 3R, 4, 4X, 12

| UL 508 Enclosed Non-Fusible Disconnect Switches |                      |              |                |                |          | Accessories*                                     |                                                           |                                                 |
|-------------------------------------------------|----------------------|--------------|----------------|----------------|----------|--------------------------------------------------|-----------------------------------------------------------|-------------------------------------------------|
| Part Number                                     | Enclosure Rating (A) | No. of Poles | Enclosure Size | Weight lb (kg) | Price    | Switched 4th Pole Module                         | Auxiliary Contacts                                        | Terminal Shrouds (Line & Load)                  |
| <a href="#">22143503</a>                        | 30                   | 3            | 1              | 1.25 (0.56)    | \$108.00 | <b>1P</b><br><a href="#">22001003</a><br>\$20.00 | <b>1 NO / 1 NC</b><br><a href="#">22990001</a><br>\$22.00 | <b>1P</b><br><a href="#">22941005</a><br>\$3.50 |
| <a href="#">22243503</a>                        |                      |              | 2              | 1.60 (0.72)    | \$125.00 |                                                  |                                                           | <b>3P</b><br><a href="#">22943005</a><br>\$5.50 |
| <a href="#">22243506</a>                        | 60                   | 3            | 2              | 1.80 (0.82)    | \$149.00 | —                                                |                                                           | <b>1P</b><br><a href="#">22941009</a><br>\$4.25 |
|                                                 |                      |              |                |                |          |                                                  |                                                           | <b>3P</b><br><a href="#">22943009</a><br>\$7.00 |

Note: 2294100x fits 4th pole module only.

\* These part numbers are direct replacements for previous part numbers with a "-UL" suffix. They have identical technical specs, form, fit and function. There is no change in agency approvals, the UL mark, listing, or File number E173959.

## Configuration of the Auxiliary Contacts



1. M Type auxiliary contacts  
2. Additional 4th pole



See switch body drawings for dimensions

## Dimensions

Inches [mm]

Size 1

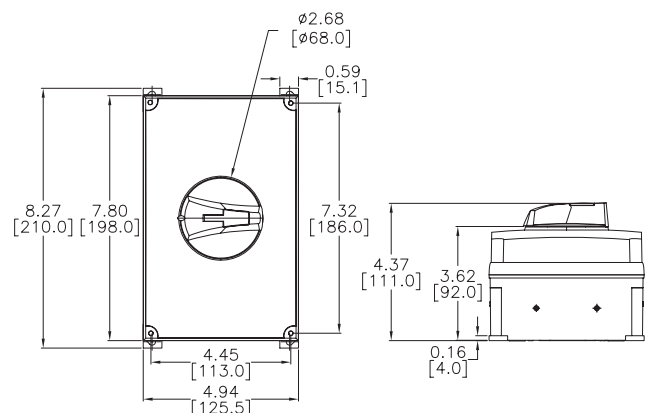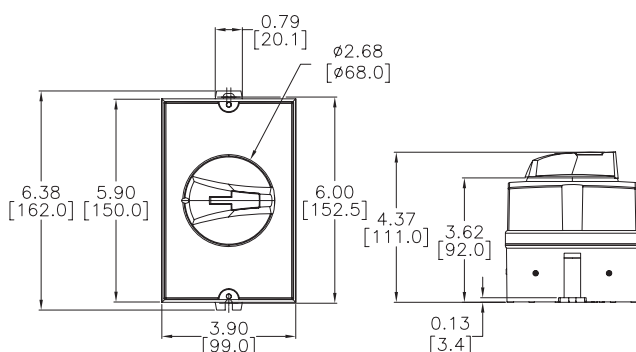Size 2



Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.



# SIRCO UL 98B DC Non-Fusible Disconnect Switches



To assemble a switch, please select:

*Direct Operation*

*External Operation*



OR



Switch Body

Direct Handle

Switch Body

Shaft

External Handle

## UL 98B Non-Fusible Disconnect Switches

| Part Number              | Description                                 | Switch Body Rating (A) | Voltage Rating | # of Poles | Price    |
|--------------------------|---------------------------------------------|------------------------|----------------|------------|----------|
| <a href="#">27DC3011</a> | Non-fusible UL 98B rotary disconnect switch | 100                    | 600VDC         | 3          | Retired  |
| <a href="#">27DC4011</a> |                                             |                        | 1000VDC        | 4          | \$371.00 |
| <a href="#">27DC3021</a> |                                             | 250                    | 600VDC         | 3          | Retired  |
| <a href="#">27DC4021</a> |                                             |                        | 1000VDC        | 4          | \$448.00 |

## Handles – Defeatable and Lockable

| Part Number              | Description                                         | Switch Body Rating (A) | Handle Color | Handle Type | NEMA/UL Type | Price   |
|--------------------------|-----------------------------------------------------|------------------------|--------------|-------------|--------------|---------|
| <a href="#">26995052</a> | Mounts directly on switch, no shaft required*       | 100-400                | Black        | –           | –            | \$18.00 |
| <a href="#">142F2111</a> | External front handles, shaft required              | 100-400                | Black/Blue   | S2          | 1, 3R, 12    | \$49.00 |
| <a href="#">142G2111</a> |                                                     |                        | Red/Yellow   |             |              | \$49.00 |
| <a href="#">142D2111</a> |                                                     |                        | Black/Blue   |             | 4, 4X        | \$68.00 |
| <a href="#">142E2111</a> |                                                     |                        | Red/Yellow   |             |              | \$68.00 |
| <a href="#">142D2911</a> | External heavy duty front handles, shaft required** | 100-400                | Black/Blue   | S2          | 4, 4X        | \$85.00 |
| <a href="#">142E2911</a> |                                                     |                        | Red/Yellow   |             |              | \$85.00 |

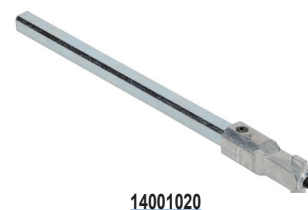
\* Not defeatable

\*\* Heavy duty handles have larger metal hasp to accommodate multiple locking devices.



## Shafts for External Handles

| Part Number              | Switch Body Rating (A) | Handle Type | Length (in) | Length (mm) | Price   |
|--------------------------|------------------------|-------------|-------------|-------------|---------|
| <a href="#">14001020</a> | 100-400                | S1, S2      | 7.9         | 200         | \$12.50 |
| <a href="#">14001032</a> |                        |             | 12.6        | 320         | \$13.50 |
| <a href="#">14001040</a> |                        |             | 15.7        | 400         | \$15.00 |



# SIRCO UL 98B DC Non-Fusible Disconnect Switches



## Shaft Guide for External Handle

| Part Number                     | Description                                                                                                                                                                                    | Fits Handle Type | Price  |
|---------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------|--------|
| <a href="#"><u>14290000</u></a> | This accessory makes alignment connections between the shaft and handle easier. Allows up to 15mm misalignment tolerance. Required for a shaft length over 300mm. Included with longer shafts. | S01, S1, S2, S3  | \$6.75 |

[14290000](#)

## Auxiliary Contacts

| Part Number                     | Description                                                         | Switch Body Rating (A) | Type                  | Contacts    | Price   |
|---------------------------------|---------------------------------------------------------------------|------------------------|-----------------------|-------------|---------|
| <a href="#"><u>27990021</u></a> | Auxiliary contact block: 1 Form C, 10A @ 125VAC                     | 100-600                | C Type standard level | 1 NO / 1 NC | \$13.50 |
| <a href="#"><u>27990022</u></a> | Auxiliary contact block: 1 Form C, 10A @ 125VAC, 2/pk               |                        |                       | 1 NO / 1 NC | \$18.00 |
| <a href="#"><u>27990121</u></a> | Auxiliary contact block: 1 Form C, 1A @ 125VAC, low impedance       |                        | C Type low impedance  | 1 NO / 1 NC | \$15.50 |
| <a href="#"><u>27990122</u></a> | Auxiliary contact block: 1 Form C, 1A @ 125VAC, low impedance, 2/PK |                        |                       | 1 NO / 1 NC | \$25.00 |

[27990021](#)

## Terminal Screens

| Part Number                     | Description                                                                                                 | Switch Body Rating (A) | No. of Poles | Position     | Price   |
|---------------------------------|-------------------------------------------------------------------------------------------------------------|------------------------|--------------|--------------|---------|
| <a href="#"><u>27983021</u></a> | Terminal screens provide line or load protection against direct contact with terminals or connection parts. | 100-250                | 3            | Line         | \$21.50 |
| <a href="#"><u>27988021</u></a> |                                                                                                             |                        |              | Load         | \$21.50 |
| <a href="#"><u>27984021</u></a> |                                                                                                             |                        | 4            | Line or load | \$25.00 |

[27983021](#)

## Terminal Lugs

| Part Number                     | Description                                                                                                             | Switch Body Rating (A) | Wire Range  | Lugs per kit | No cables per lug | Price   |
|---------------------------------|-------------------------------------------------------------------------------------------------------------------------|------------------------|-------------|--------------|-------------------|---------|
| <a href="#"><u>39542020</u></a> | Terminal lug kits allow for the connection of bare copper cables on to the terminals (no spade lugs). Cable type Cu/Al. | 100-250                | #6 - 300MCM | 2            | 1                 | \$18.00 |

[39542020](#)

# FUSERBLOC UL 489

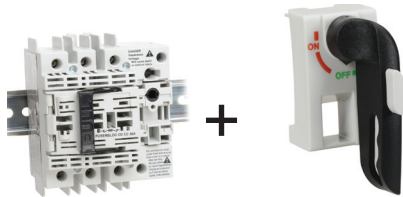
## Compact Fusible Disconnect Switches



To assemble a switch, please select:

Direct Operation

External Operation



OR



Switch Body

Direct Handle

Switch Body

Shaft

External Handle

### UL 498 Compact Fusible Disconnect Switches

| Part Number              | Description                                                                               | Frame Size | Fuse Type | Price    |
|--------------------------|-------------------------------------------------------------------------------------------|------------|-----------|----------|
| <a href="#">37103003</a> | Compact UL 489 fusible front operated switch, 30A, 600VAC, 3-pole                         | 1          | Class CC  | \$122.00 |
| <a href="#">37104003</a> | Compact UL 489 fusible front operated switch, 30A, 600VAC, 3-pole with switched neutral   |            |           | \$157.00 |
| <a href="#">37105003</a> | Compact UL 489 fusible front operated switch, 30A, 600VAC, 3-pole with unswitched neutral |            |           | \$150.00 |
| <a href="#">37103004</a> | Compact UL 489 fusible front operated switch, 30A, 600VAC, 3-pole                         | 2          | Class J   | \$122.00 |
| <a href="#">37104004</a> | Compact UL 489 fusible front operated switch, 30A, 600VAC, 3-pole with switched neutral   |            |           | \$157.00 |
| <a href="#">37105004</a> | Compact UL 489 fusible front operated switch, 30A, 600VAC, 3-pole with unswitched neutral |            |           | \$151.00 |

### Handles

| Part Number              | Description                                                                                    | Switch Body Rating (A) | Handle Color | Handle Type | NEMA/UL Type | Test         | Price   |
|--------------------------|------------------------------------------------------------------------------------------------|------------------------|--------------|-------------|--------------|--------------|---------|
| <a href="#">37294012</a> | Direct handle for class CC disconnect switches*                                                | 30                     | Black        | —           | —            | —            | \$22.00 |
| <a href="#">37294014</a> | Direct handle for class J disconnect switches*                                                 | 30                     | Black        | —           | —            | —            | \$22.00 |
| <a href="#">14930111</a> | Front operation handle for compact UL 489 fusible disconnect switches, defeatable and lockable | 30                     | Black/Blue   | S0          | 1, 3R, 12    | I - O        | \$29.00 |
| <a href="#">14940111</a> |                                                                                                | 30                     | Red/Yellow   | S0          |              | I - O        | \$29.00 |
| <a href="#">149D0111</a> |                                                                                                | 30                     | Black/Blue   | S0          | 4, 4X        | I - O        | \$35.50 |
| <a href="#">149E0111</a> |                                                                                                | 30                     | Red/Yellow   | S0          |              | I - O        | \$35.50 |
| <a href="#">141F2111</a> |                                                                                                | 30                     | Black/Blue   | S1          | 1, 3R, 12    | I - O        | \$34.00 |
| <a href="#">141G2111</a> |                                                                                                | 30                     | Red/Yellow   | S1          |              | I - O        | \$34.00 |
| <a href="#">141D2111</a> |                                                                                                | 30                     | Black/Blue   | S1          | 4, 4X        | I - O        | \$42.50 |
| <a href="#">141E2111</a> |                                                                                                | 30                     | Red/Yellow   | S1          |              | I - O        | \$42.50 |
| <a href="#">141D2115</a> |                                                                                                | 30                     | Black/Blue   | S1          |              | I - O - Test | \$46.00 |
| <a href="#">141E2115</a> |                                                                                                | 30                     | Red/Yellow   | S1          |              | I - O - Test | \$46.00 |
| <a href="#">141D2911</a> | External heavy duty front handles, shaft required**                                            | 30                     | Black/Blue   | S1          | 4, 4X        | I - O        | \$50.00 |
| <a href="#">141E2911</a> |                                                                                                | 30                     | Red/Yellow   | S1          |              | I - O        | \$50.00 |

\* Defeatable

\*\* Heavy duty handles have larger metal hasp to accommodate multiple locking devices.



Direct Handle  
[37294012](#)



S0 Handle  
[149D0111](#)



S1 Handle  
[141F2111](#)

### Shafts for External Handles

| Part Number              | Switch Body Rating (A) | Handle Type | Length |     | Price   |
|--------------------------|------------------------|-------------|--------|-----|---------|
|                          |                        |             | in     | mm  |         |
| <a href="#">14050620</a> | 30                     | S0          | 7.9    | 200 | \$11.00 |
| <a href="#">14050632</a> |                        |             | 12.6   | 320 | \$13.50 |
| <a href="#">14050640</a> |                        |             | 15.7   | 400 | \$13.50 |
| <a href="#">14010520</a> |                        | S1          | 7.9    | 200 | \$10.00 |
| <a href="#">14010532</a> |                        |             | 12.6   | 320 | \$11.50 |
| <a href="#">14010540</a> |                        |             | 15.7   | 400 | \$13.50 |



[14050620](#)



[14010520](#)

# FUSERBLOC UL 489

## Compact Fusible Disconnect Switches



### Shaft Guide for External Handle

| Part Number                     | Description                                                                                                                                                                                           | Fits Handle Type | Price  |
|---------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------|--------|
| <a href="#"><u>14290000</u></a> | This accessory makes alignment connections between the shaft and handle easier. Allows up to 15mm misalignment tolerance. Required for a shaft length longer than 300mm. Included with longer shafts. | S01, S1, S2, S3  | \$6.75 |
| <a href="#"><u>14190000</u></a> |                                                                                                                                                                                                       | S00, S0          | \$3.25 |

[14290000](#)

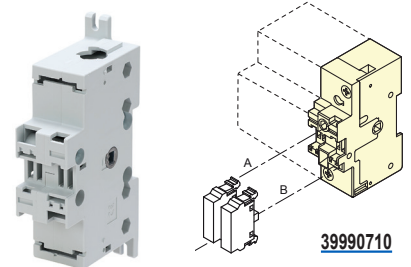
### Auxiliary Contacts

| Part Number                     | Description                                                                                                                                                                                                                                      | Switch Body Rating (A) | Contacts | Price  |
|---------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------|----------|--------|
| <a href="#"><u>39990701</u></a> | Front mount auxiliary contacts can be configured to be operated on standard and TEST position switches. Each slot can accommodate up to 2 interlocked auxiliary contacts. 3A @ 240VAC.<br><br>For 30 to 200A/J, maximum of 4 auxiliary contacts. | 30 - 600               | 1 NO     | \$9.25 |
| <a href="#"><u>39990702</u></a> |                                                                                                                                                                                                                                                  |                        | 1 NC     | \$9.25 |

[39990701](#)


### Contact Holder for Additional Auxiliary Contacts

| Part Number                     | Description                                                                                                                                                     | Switch Body Rating (A) | Fuse Types   | Price   |
|---------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------|--------------|---------|
| <a href="#"><u>39990710</u></a> | Additional auxiliary contact holder, side mount. For use with Class CC and J FUSERBLOC compact 30A fused switch bodies. Holds a maximum of 4 (2 wide x 2 high). | 30                     | Class CC / J | \$14.50 |

[39990710](#)

### NFPA 79 "Through the Door" Kit

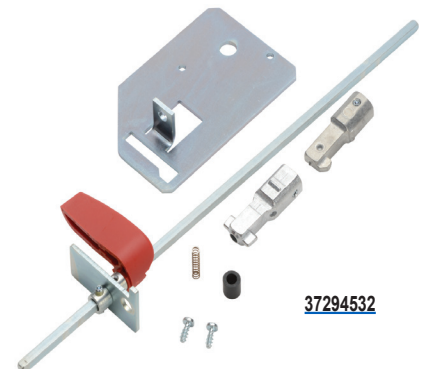
| Part Number                     | Description                                                                                                                                 | Switch Body Rating (A) | Frame Size | Price   |
|---------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------|------------------------|------------|---------|
| <a href="#"><u>37294532</u></a> | Allows retrofit of installations for 30A ratings. Meets both UL 508A and NFPA 79 requirements. Order an S1-type external handle separately. | 30                     | 1, 2       | \$47.00 |

[37294532](#)

# FUSERBLOC UL 98 Fusible Disconnect Switches

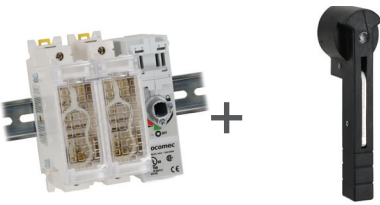To assemble a switch, please select:

Direct Operation




Switch Body

Direct Handle

OR

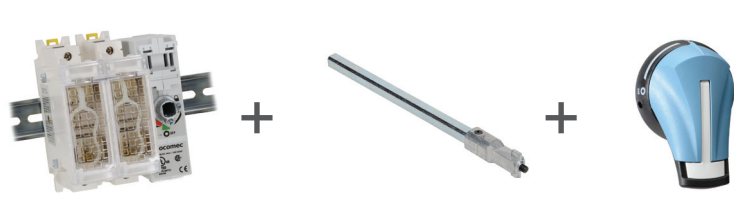External Operation



Switch Body

Shaft

External Handle

## UL 98 Fusible Disconnect Switches

| Part Number              | Description                                                         | Switch Body Rating (A) | Frame Size | Number of Poles | Price      |
|--------------------------|---------------------------------------------------------------------|------------------------|------------|-----------------|------------|
| <a href="#">38612004</a> | Front or side operated UL 98 Class J fusible switch, 600VAC, 250VDC | 30                     | 4          | 2               | \$115.00   |
| <a href="#">38613004</a> |                                                                     |                        |            | 3               | \$146.00   |
| <a href="#">38616004</a> |                                                                     |                        |            | 4               | \$174.00   |
| <a href="#">38612005</a> |                                                                     | 60                     | 4          | 2               | \$148.00   |
| <a href="#">38613005</a> |                                                                     |                        |            | 3               | \$183.00   |
| <a href="#">38616005</a> |                                                                     |                        |            | 4               | \$229.00   |
| <a href="#">38612010</a> |                                                                     | 100                    | 5          | 2               | \$199.00   |
| <a href="#">38613010</a> |                                                                     |                        |            | 3               | \$248.00   |
| <a href="#">38616010</a> |                                                                     |                        |            | 4               | \$316.00   |
| <a href="#">38612020</a> |                                                                     | 200                    | 6          | 2               | \$544.00   |
| <a href="#">38613020</a> |                                                                     |                        |            | 3               | \$669.00   |
| <a href="#">38616020</a> |                                                                     |                        |            | 4               | \$847.00   |
| <a href="#">38513038</a> |                                                                     | 400                    | 7          | 3               | \$920.00   |
| <a href="#">38503060</a> |                                                                     | 600                    | 8          | 3               | \$1,604.00 |

## Front Operation Handles

| Part Number              | Description                                                             | Switch Body Rating (A) | Fits Frame | Handle Color | Handle Type | NEMA/ UL Type | Test         | Price    |              |         |
|--------------------------|-------------------------------------------------------------------------|------------------------|------------|--------------|-------------|---------------|--------------|----------|--------------|---------|
| <a href="#">36297910</a> | Direct mount handle                                                     | 30-400                 | 4 - 7      | Black        | —           | —             | —            | \$28.00  |              |         |
| <a href="#">38596011</a> |                                                                         | 600                    | 8          | Black        | —           | —             | —            | \$50.00  |              |         |
| <a href="#">141F2111</a> | Front operation handle for UL 98 fusible disconnect switches            | 30-60                  | 4          | Black/Blue   | S1          | 1, 3R, 12     | I - O        | \$34.00  |              |         |
| <a href="#">141G2111</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$34.00  |              |         |
| <a href="#">141D2111</a> |                                                                         |                        |            | Black/Blue   | S1          | 4, 4X         | I - O        | \$42.50  |              |         |
| <a href="#">141E2111</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$42.50  |              |         |
| <a href="#">141D2115</a> |                                                                         |                        |            | Black/Blue   | S1          |               | I - O - Test | \$46.00  |              |         |
| <a href="#">141E2115</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$46.00  |              |         |
| <a href="#">142D2115</a> |                                                                         |                        |            | 100-200      | 5, 6        | Black/Blue    | S2           | 4, 4X    | I - O - Test | \$85.00 |
| <a href="#">142E2115</a> |                                                                         |                        |            |              |             | Red/Yellow    |              |          |              | \$85.00 |
| <a href="#">142F2111</a> |                                                                         | 100-400                | 5, 6, 7    | Black/Blue   | S2          | 1, 3R, 12     | I - O        | \$49.00  |              |         |
| <a href="#">142G2111</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$49.00  |              |         |
| <a href="#">142D2111</a> |                                                                         |                        |            | Black/Blue   |             | 4, 4X         | I - O        | \$68.00  |              |         |
| <a href="#">142E2111</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$68.00  |              |         |
| <a href="#">143F3111</a> |                                                                         | 600                    | 8          | Black/Blue   | S3          | 1, 3R, 12     | I - O        | \$64.00  |              |         |
| <a href="#">143G3111</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$64.00  |              |         |
| <a href="#">143D3111</a> |                                                                         |                        |            | Black/Blue   |             | 4, 4X         | I - O        | \$81.00  |              |         |
| <a href="#">143E3111</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$81.00  |              |         |
| <a href="#">141D2911</a> | Heavy duty front operation handle for UL 98 fusible disconnect switches | 30-60                  | 4          | Black/Blue   | S1          | 4, 4X         | I - O        | \$50.00  |              |         |
| <a href="#">141E2911</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$50.00  |              |         |
| <a href="#">142D2911</a> |                                                                         | 100-400                | 5, 6, 7    | Black/Blue   | S2          | 4, 4X         | I - O        | \$85.00  |              |         |
| <a href="#">142E2911</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$85.00  |              |         |
| <a href="#">143D3911</a> |                                                                         | 600                    | 8          | Black/Blue   | S3          | 4, 4X         | I - O        | \$112.00 |              |         |
| <a href="#">143E3911</a> |                                                                         |                        |            | Red/Yellow   |             |               |              | \$112.00 |              |         |



Direct Handle  
[36297910](#)



S1 Handle  
[142F2111](#)



S2 Handle  
[142G2111](#)



S3 Handle  
[143D3111](#)

# FUSERBLOC UL 98 Fusible Disconnect Switches

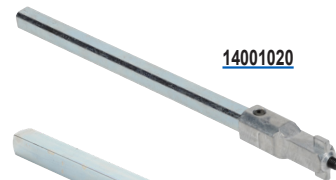
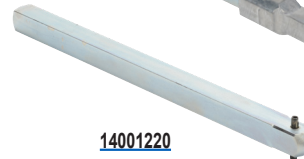


| Right Side Operation Handles (No door interlocking) |                                                                         |                        |            |              |             |              |       |          |
|-----------------------------------------------------|-------------------------------------------------------------------------|------------------------|------------|--------------|-------------|--------------|-------|----------|
| Part Number                                         | Description                                                             | Switch Body Rating (A) | Fits Frame | Handle Color | Handle Type | NEMA/UL Type | Test  | Price    |
| <a href="#">141H6111</a>                            | Side operation handle for UL 98 fusible disconnect switches             | 30-60                  | 4          | Black/Blue   | S1          | 4, 4X        | I - O | \$43.00  |
| <a href="#">141I6111</a>                            |                                                                         |                        |            | Red/Yellow   |             |              |       | \$43.00  |
| <a href="#">142H6111</a>                            |                                                                         | 100-400                | 5, 6, 7    | Black/Blue   | S2          |              |       | \$64.00  |
| <a href="#">142I6111</a>                            |                                                                         |                        |            | Red/Yellow   |             |              |       | \$64.00  |
| <a href="#">141H6911</a>                            | Heavy duty side operation handle for UL 98 fusible disconnect switches* | 30-60                  | 4          | Black/Blue   | S1          |              |       | \$86.00  |
| <a href="#">141I6911</a>                            |                                                                         |                        |            | Red/Yellow   |             |              |       | \$86.00  |
| <a href="#">142H6911</a>                            |                                                                         | 100-400                | 5, 6, 7    | Black/Blue   | S2          |              |       | \$107.00 |
| <a href="#">142I6911</a>                            |                                                                         |                        |            | Red/Yellow   |             |              |       | \$107.00 |

[141H6111](#)

\* Heavy duty handles have larger metal hasp to accommodate multiple locking devices.

| Shafts for External Handles |                        |             |        |     |         |
|-----------------------------|------------------------|-------------|--------|-----|---------|
| Part Number                 | Switch Body Rating (A) | Handle Type | Length |     | Price   |
|                             |                        |             | in     | mm  |         |
| <a href="#">14001020</a>    | 30-400                 | S1, S2      | 7.9    | 200 | \$12.50 |
| <a href="#">14001032</a>    |                        |             | 12.6   | 320 | \$13.50 |
| <a href="#">14001040</a>    |                        |             | 15.7   | 400 | \$15.00 |
| <a href="#">14001220</a>    | 600                    | S3          | 7.9    | 200 | \$16.00 |
| <a href="#">14001232</a>    |                        |             | 12.6   | 320 | \$19.00 |
| <a href="#">14001240</a>    |                        |             | 15.7   | 400 | \$22.00 |

[14001020](#)[14001220](#)

| Shaft Guide for External Handle |                                                                                                                                                                                                       |                  |        |
|---------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------|--------|
| Part Number                     | Description                                                                                                                                                                                           | Fits Handle Type | Price  |
| <a href="#">14290000</a>        | This accessory makes alignment connections between the shaft and handle easier. Allows up to 15mm misalignment tolerance. Required for a shaft length longer than 300mm. Included with longer shafts. | S1, S2, S3       | \$6.75 |

[14290000](#)

| Auxiliary Contacts       |                                                                                                                                                                                        |                        |           |         |
|--------------------------|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------------------------|-----------|---------|
| Part Number              | Description                                                                                                                                                                            | Body Switch Rating (A) | Contacts  | Price   |
| <a href="#">39990701</a> | Front mount auxiliary contacts can be configured to be operated on standard and TEST position switches. Each slot can accommodate up to 2 interlocked auxiliary contacts. 3A @ 240VAC. | 30 - 600               | 1 NO      | \$9.25  |
| <a href="#">39990702</a> |                                                                                                                                                                                        |                        | 1 NC      | \$9.25  |
|                          | For 30 to 200A/J, maximum of 4 auxiliary contacts                                                                                                                                      |                        |           |         |
| <a href="#">3999U041</a> | Side operated auxiliary contacts for frame sizes 3 to 8 UL 98 fusible disconnect switches, position OFF and ON signalled by 1 to 4 NO + NC auxiliary contacts. 10A @ 600 VAC/DC. 2/pk  | 30-200                 | 1 NO      | \$31.00 |
| <a href="#">3999U042</a> |                                                                                                                                                                                        | 30-200                 | 1NO / 1NC | \$60.00 |

[39990701](#)[3999U041](#)




# FUSERBLOC UL 98 Fusible Disconnect Switches


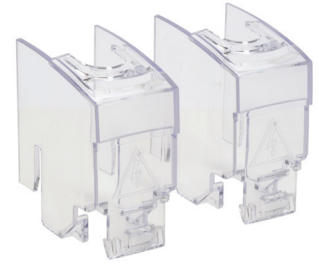
## Terminal Shrouds

| Part Number              | Description                                                                               | Switch Body Rating (A) | Pcs/pk | Price   |
|--------------------------|-------------------------------------------------------------------------------------------|------------------------|--------|---------|
| <a href="#">38982020</a> | Line or load protection against direct contact with terminals or connection parts, 1 pole | 200                    | 2      | \$18.50 |
| <a href="#">38983020</a> |                                                                                           | 200                    | 3      | \$27.00 |
| <a href="#">38984020</a> |                                                                                           | 200                    | 4      | \$34.50 |
| <a href="#">38983040</a> |                                                                                           | 400                    | 3      | \$34.00 |
| <a href="#">38983080</a> |                                                                                           | 600                    | 3      | \$60.00 |

[38982020](#)

## Terminal Lugs

| Part Number              | Switch Body Rating (A) | Wire Range        | Wires per lug | Lugs per Kit | Price    |
|--------------------------|------------------------|-------------------|---------------|--------------|----------|
| <a href="#">39542020</a> | 200                    | #6 - 300MCM       | 1             | 2            | \$18.00  |
| <a href="#">39543020</a> |                        |                   |               | 3            | \$27.00  |
| <a href="#">39544020</a> |                        |                   |               | 4            | \$35.00  |
| <a href="#">39543040</a> | 400                    | #2 - 600MCM       | 1             | 3            | \$69.00  |
| <a href="#">39543041</a> |                        | 2 x (#6 - 350MCM) | 2             | 3            | \$94.00  |
| <a href="#">39543060</a> | 600                    | 2 x (#2 - 600MCM) | 2             | 3            | \$141.00 |

[39542020](#)

Note: Accept either copper or aluminum wires

## NFPA 79 Accessories

### Flange Handles

| Part Number              | Description                                                                                         | Switch Body Rating (A) | Handle Color | Handle Type   | NEMA/UL Type        | Price    |
|--------------------------|-----------------------------------------------------------------------------------------------------|------------------------|--------------|---------------|---------------------|----------|
| <a href="#">37299002</a> | Flange handle, meets UL 508A and NFPA 79 requirements. The handle will operate the switch by cable. | 30-200                 | Gray         | Standard      | 1, 3, 3R, 4, 12     | \$131.00 |
| <a href="#">37299003</a> |                                                                                                     | 30-200                 | —            | Chrome plated | 1, 3, 3R, 4, 4X, 12 | \$352.00 |

Requires flange handle, cable operator and cable.

[37299002](#)[37299003](#)

### Cable Operator

| Part Number              | Description                                                                                              | Switch Body Rating (A) | Price    |
|--------------------------|----------------------------------------------------------------------------------------------------------|------------------------|----------|
| <a href="#">37299903</a> | Cable flange mechanism links to flange handle and side-operated switches. Must also order flange handle. | 30-200                 | \$135.00 |

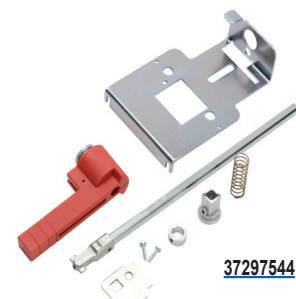
### Cables

| Part Number              | Cable Length (feet) | Cable Length (m) | Price    |
|--------------------------|---------------------|------------------|----------|
| <a href="#">37299992</a> | 3                   | 1                | \$158.00 |
| <a href="#">37299993</a> | 5                   | 1.5              | \$184.00 |

[37299992](#)[37299903](#)

## NFPA 79 "Through the Door" Kit

| Part Number              | Description                                                                                       | Min Enclosure Depth | Switch Body Rating (A) | Fits Frame Size | Price    |
|--------------------------|---------------------------------------------------------------------------------------------------|---------------------|------------------------|-----------------|----------|
| <a href="#">37297540</a> | Meets both UL 508A and NFPA 79 requirements. Order an S-type external handle separately (not S0). | 11.14 in (238mm)    | 30-200                 | 3, 4, 5, 6      | \$59.00  |
| <a href="#">37297544</a> |                                                                                                   | 11.81 in (300mm)    | 400                    | 7               | \$85.00  |
| <a href="#">37297552</a> |                                                                                                   | 14.96 in (380mm)    | 600                    | 8               | \$179.00 |

[37297544](#)

# Accessories Dimensions

## Handles

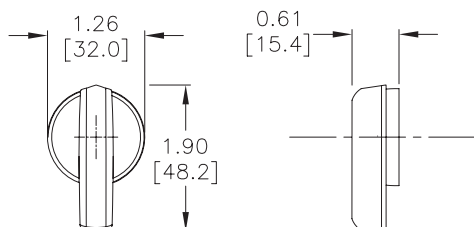
[inches/mm]



### Direct Handle for UL 98 Compact Non-Fusible Disconnect Switches

**22995032**

#### Handle Dimensions



### External Handles for UL 98 Compact Non-Fusible Disconnect Switches

#### S00 Type

| Handle Dimensions | Direction of Operation | Door Drilling |
|-------------------|------------------------|---------------|
|                   |                        |               |

#### S0 Type

| Handle Dimensions | Direction of Operation | Door Drilling |
|-------------------|------------------------|---------------|
|                   |                        |               |

#### S01 Type

| Handle Dimensions | Direction of Operation | Door Drilling |
|-------------------|------------------------|---------------|
|                   |                        |               |

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Accessories Dimensions

## Handles

[inches/mm]



| Direct Handles for UL 98 Non-Fusible Disconnect Switches |                   |
|----------------------------------------------------------|-------------------|
| 26995052                                                 | 37996012          |
| Handle Dimensions                                        | Handle Dimensions |
|                                                          |                   |

| External Handles for UL 98 Non-Fusible Disconnect Switches |                        |               |
|------------------------------------------------------------|------------------------|---------------|
| S2 Type                                                    |                        |               |
| Handle Dimensions                                          | Direction of Operation | Door Drilling |
|                                                            |                        |               |
| S3 Type                                                    |                        |               |
| Handle Dimensions                                          | Direction of Operation | Door Drilling |
|                                                            |                        |               |

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Accessories Dimensions

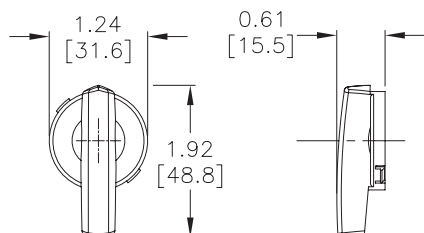
## Handles

[inches/mm]

### Direct Handle for UL 508 Non-Fusible Disconnect Switches

**22995012**

Handle Dimensions



### External Handles for UL 508 Non-Fusible Disconnect Switches

#### S00 Type

| Handle Dimensions | Direction of Operation | Door Drilling |
|-------------------|------------------------|---------------|
|                   |                        |               |

#### S0 Type

| Handle Dimensions | Direction of Operation | Door Drilling |
|-------------------|------------------------|---------------|
|                   |                        |               |

#### S01 Type

| Handle Dimensions | Direction of Operation | Door Drilling |
|-------------------|------------------------|---------------|
|                   |                        |               |

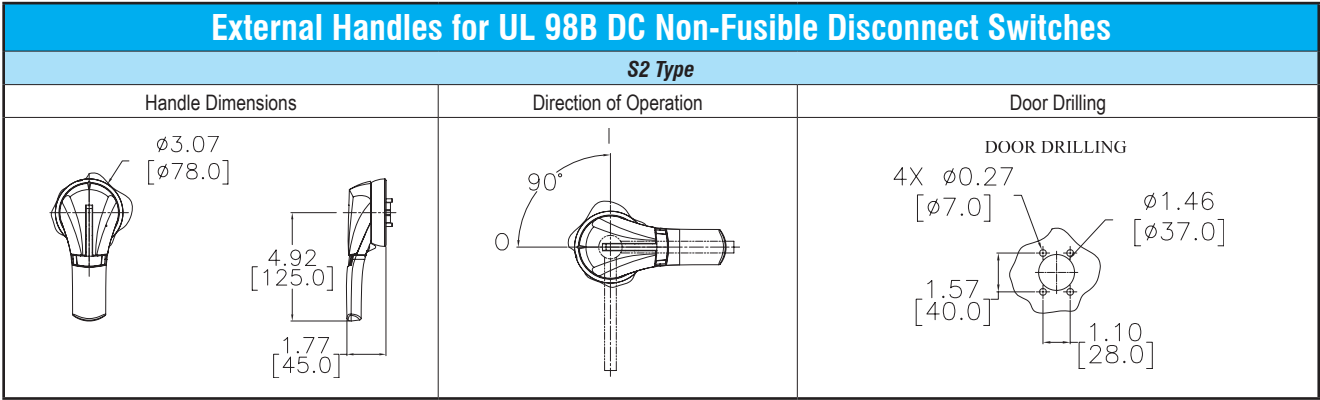
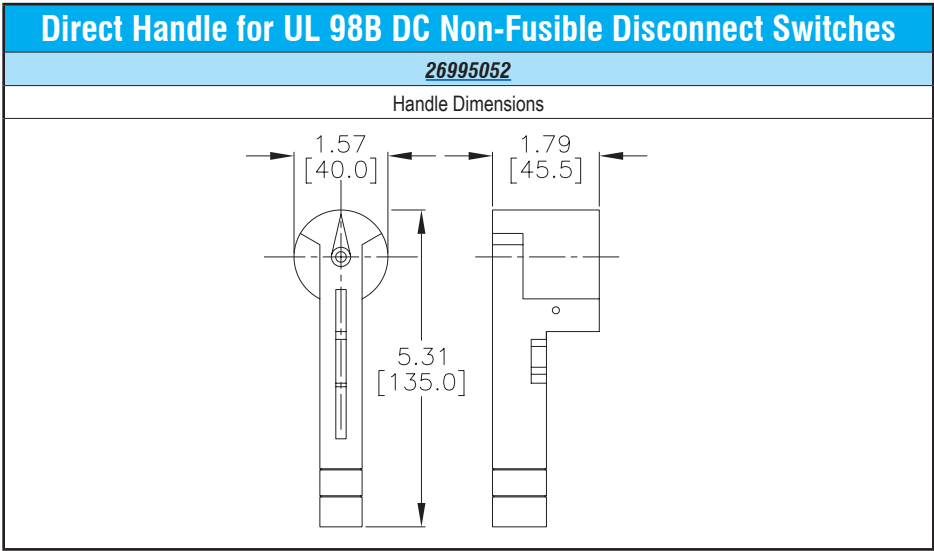
Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Accessories Dimensions



## Handles

[inches/mm]



Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Accessories Dimensions

## Handles

[inches/mm]



### Direct Handles for UL 489 Compact Fusible Disconnect Switches

| 26995052          | 37996012          |
|-------------------|-------------------|
| Handle Dimensions | Handle Dimensions |
|                   |                   |

### External Handles for UL 489 Compact Fusible Disconnect Switches

| S0 Type                                                              |                                                                                                                                 |                                                                                                                                                                   |
|----------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Handle Dimensions                                                    | Direction of Operation                                                                                                          | Door Drilling                                                                                                                                                     |
| <p>3.07<br/>[78.0]</p> <p>3.46<br/>[88.0]</p> <p>1.46<br/>[37.0]</p> | <p>90°</p>                                                                                                                      | <p>4X 0.27<br/>[7.0]</p> <p>1.22<br/>[31.0]</p> <p>0.12<br/>[3.0]</p> <p>0.53<br/>[13.5]</p> <p>1.10<br/>[28.0]</p> <p>1.57<br/>[40.0]</p> <p>0.89<br/>[22.5]</p> |
| S1 Type                                                              |                                                                                                                                 |                                                                                                                                                                   |
| Handle Dimensions                                                    | Direction of Operation                                                                                                          | Door Drilling                                                                                                                                                     |
| <p>3.07<br/>[78.0]</p> <p>2.76<br/>[70.0]</p> <p>1.73<br/>[44.0]</p> | <p>90°</p> <p>65°</p> <p>TEST</p> <p>TEST POSITION INCLUDED ON CERTAIN MODELS ONLY<br/>AS INDICATED IN THE SELECTION TABLES</p> | <p>0.27<br/>[7.0]</p> <p>1.46<br/>[37.0]</p> <p>1.57<br/>[40.0]</p> <p>1.10<br/>[28.0]</p> <p>1.46<br/>[37.0]</p>                                                 |

Note: Test position included on certain models only as indicated in the selection tables.

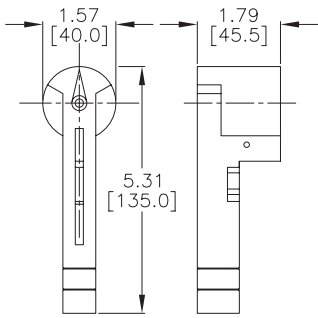
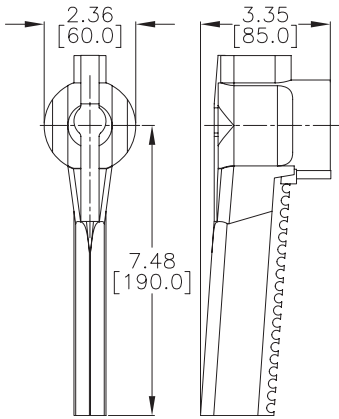
Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.



# Accessories Dimensions

## Handles

[inches/mm]

| Direct Handles for UL 98 Fusible Disconnect Switches                              |                                                                                    |
|-----------------------------------------------------------------------------------|------------------------------------------------------------------------------------|
| 36297910                                                                          | 38596011                                                                           |
| Handle Dimensions                                                                 | Handle Dimensions                                                                  |
|  |  |

## External Handles for UL 98 Fusible Disconnect Switches

| S1 Type                                                         |                                                                                                                             |                  |                                                                                      |
|-----------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------|------------------|--------------------------------------------------------------------------------------|
| Handle Dimensions                                               | Direction of Operation                                                                                                      |                  | Door Drilling                                                                        |
| <p>3.07<br/>[78.0]<br/>2.76<br/>[70.0]<br/>1.73<br/>[44.0]</p>  | <p>90°<br/>0<br/>65°<br/>TEST<br/>EST POSITION INCLUDED ON CERTAIN MODELS ONLY<br/>AS INDICATED IN THE SELECTION TABLES</p> | <p>90°<br/>0</p> | <p>0.27<br/>[7.0]<br/>1.46<br/>[37.0]<br/>1.57<br/>[40.0]<br/>1.10<br/>[28.0]</p>    |
| S2 Type                                                         |                                                                                                                             |                  |                                                                                      |
| Handle Dimensions                                               | Direction of Operation                                                                                                      |                  | Door Drilling                                                                        |
| <p>3.07<br/>[78.0]<br/>4.92<br/>[125.0]<br/>1.77<br/>[45.0]</p> | <p>90°<br/>0<br/>65°<br/>TEST<br/>EST POSITION INCLUDED ON CERTAIN MODELS ONLY<br/>AS INDICATED IN THE SELECTION TABLES</p> | <p>90°<br/>0</p> | <p>4X 0.27<br/>[7.0]<br/>1.46<br/>[37.0]<br/>1.57<br/>[40.0]<br/>1.10<br/>[28.0]</p> |
| S3 Type                                                         |                                                                                                                             |                  |                                                                                      |
| Handle Dimensions                                               | Direction of Operation                                                                                                      |                  | Door Drilling                                                                        |
| <p>3.07<br/>[78.0]<br/>8.27<br/>[210.0]<br/>2.36<br/>[60.0]</p> | <p>90°<br/>0<br/>65°<br/>TEST<br/>EST POSITION INCLUDED ON CERTAIN MODELS ONLY<br/>AS INDICATED IN THE SELECTION TABLES</p> | <p>90°<br/>0</p> | <p>4X 0.27<br/>[7.0]<br/>1.46<br/>[37.0]<br/>1.57<br/>[40.0]<br/>1.10<br/>[28.0]</p> |

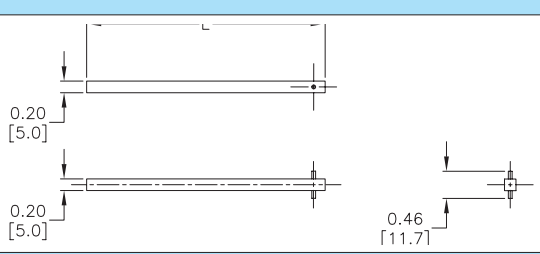
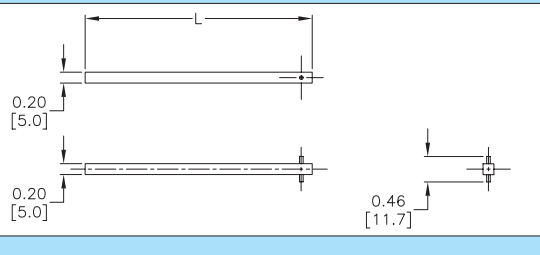
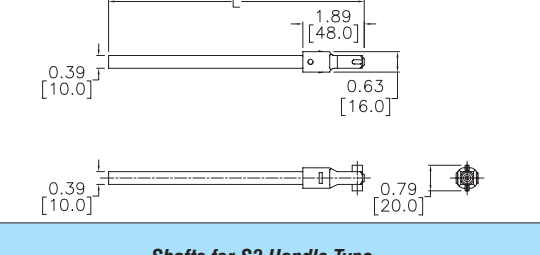
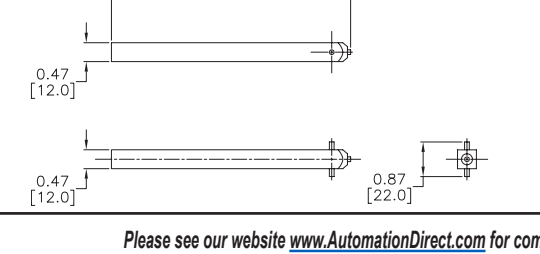
Note: Test position included on certain models only as indicated in the selection tables.

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Accessories Dimensions


## Shafts for Non-Fusible Disconnect Switches

[inches/mm]

| Shafts for Non-Fusible Disconnect Switches                                          |                          |                        |        |     |
|-------------------------------------------------------------------------------------|--------------------------|------------------------|--------|-----|
| Shafts for S00, S0 Handle Type                                                      | Part Number              | Switch Body Rating (A) | Length |     |
|                                                                                     |                          |                        | in     | mm  |
|    | <a href="#">14070515</a> | 16 - 100               | 5.9    | 150 |
|                                                                                     | <a href="#">14070520</a> |                        | 7.9    | 200 |
|                                                                                     | <a href="#">14070532</a> |                        | 12.6   | 320 |
| Shafts for S01 Handle Type                                                          | Part Number              | Switch Body Rating (A) | Length |     |
|                                                                                     |                          |                        | in     | mm  |
|    | <a href="#">14040520</a> | 16 - 100               | 7.9    | 200 |
|                                                                                     | <a href="#">14040532</a> |                        | 12.6   | 320 |
|                                                                                     | <a href="#">14040540</a> |                        | 15.7   | 400 |
| Shafts for S1, S2 Handle Type                                                       | Part Number              | Switch Body Rating (A) | Length |     |
|                                                                                     |                          |                        | in     | mm  |
|  | <a href="#">14001020</a> | 100 - 400              | 7.9    | 200 |
|                                                                                     | <a href="#">14001032</a> |                        | 12.6   | 320 |
|                                                                                     | <a href="#">14001040</a> |                        | 15.7   | 400 |
| Shafts for S3 Handle Type                                                           | Part Number              | Switch Body Rating (A) | Length |     |
|                                                                                     |                          |                        | in     | mm  |
|  | <a href="#">14011520</a> | 600                    | 7.9    | 200 |
|                                                                                     | <a href="#">14011532</a> |                        | 12.6   | 320 |
|                                                                                     | <a href="#">14011540</a> |                        | 15.7   | 400 |

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.





| Shaft Length Minimum Dimensions                                             |              |           |             |        |     |                          |
|-----------------------------------------------------------------------------|--------------|-----------|-------------|--------|-----|--------------------------|
| Use standard lengths:<br>7.9 in / 200mm – 12.6 in / 320mm – 15.7 in / 400mm |              |           |             |        |     |                          |
| Switch Body Rating (A)                                                      | Dimension X  |           | Handle Type | Length |     | Part Number              |
|                                                                             | in           | mm        |             | in     | mm  |                          |
| 100 - 400                                                                   | 5.31 - 10.43 | 135 - 265 | S2          | 7.9    | 200 | <a href="#">14001020</a> |
| 100 - 400                                                                   | 5.31 - 15.16 | 135 - 385 | S2          | 12.6   | 320 | <a href="#">14001032</a> |
| 100 - 400                                                                   | 5.31 - 18.31 | 135 - 465 | S2          | 15.7   | 400 | <a href="#">14001040</a> |
| 600                                                                         | 8.70 - 13.50 | 221 - 343 | S3          | 7.9    | 200 | <a href="#">14011520</a> |
| 600                                                                         | 8.70 - 18.23 | 221 - 463 | S3          | 12.6   | 320 | <a href="#">14011532</a> |
| 600                                                                         | 8.70 - 21.38 | 221 - 543 | S3          | 15.7   | 400 | <a href="#">14011540</a> |

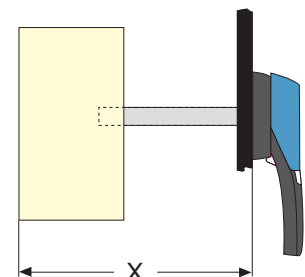

# Accessories Dimensions


## Shafts for Fusible Disconnect Switches

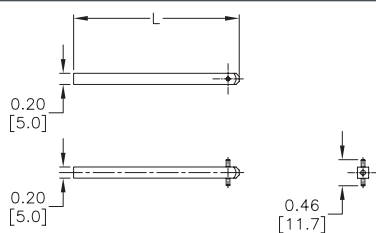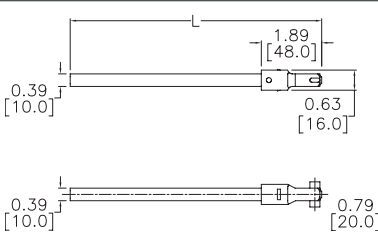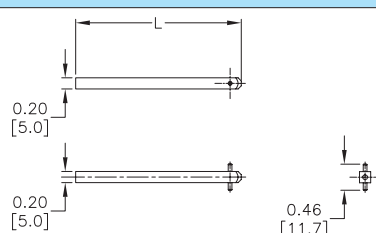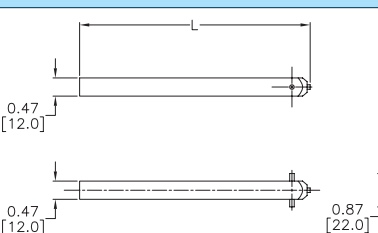[inches/mm]

| Shafts for Fusible Disconnect Switches                                            |                          |                    |        |     |                                                                                    |                          |                    |        |     |
|-----------------------------------------------------------------------------------|--------------------------|--------------------|--------|-----|------------------------------------------------------------------------------------|--------------------------|--------------------|--------|-----|
| Shafts for S0 Handle Type                                                         | Part Number              | Body Switch Rating | Length |     | Shafts for S2 Handle Type                                                          | Part Number              | Body Switch Rating | Length |     |
|                                                                                   |                          |                    | in     | mm  |                                                                                    |                          |                    | in     | mm  |
|  | <a href="#">14050620</a> | 30A                | 7.9    | 200 |  | <a href="#">14001020</a> | 30A to 400A        | 7.9    | 200 |
|                                                                                   | <a href="#">14050632</a> |                    | 12.6   | 320 |                                                                                    | <a href="#">14001032</a> | 30A to 200A        | 12.6   | 320 |
|                                                                                   | <a href="#">14050640</a> |                    | 15.7   | 400 |                                                                                    | <a href="#">14001040</a> | 30A to 400A        | 15.7   | 400 |
| Shafts for S1 Handle Type                                                         | Part Number              | Switch Body Rating | Length |     | Shafts for S3 Handle Type                                                          | Part Number              | Switch Body Rating | Length |     |
|  | <a href="#">14010520</a> | 30A                | 7.9    | 200 |  | <a href="#">14001220</a> | 600A               | 7.9    | 200 |
|                                                                                   | <a href="#">14010532</a> |                    | 12.6   | 320 |                                                                                    | <a href="#">14001232</a> |                    | 12.6   | 320 |
|                                                                                   | <a href="#">14010540</a> |                    | 15.7   | 400 |                                                                                    | <a href="#">14001240</a> |                    | 15.7   | 400 |

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

| Shaft Length Minimum Dimensions                                               |               |           |             |        |     |                          |
|-------------------------------------------------------------------------------|---------------|-----------|-------------|--------|-----|--------------------------|
| Use standard lengths:<br>- 7.9 in / 200mm - 12.6 in / 320mm - 15.7 in / 400mm |               |           |             |        |     |                          |
| Switch Body Rating (A)                                                        | Dimension X   |           | Handle Type | Length |     | Part Number              |
|                                                                               | in            | mm        |             | in     | mm  |                          |
| 30                                                                            | 4.02 - 9.65   | 102 - 245 | S0          | 7.9    | 200 | <a href="#">14050620</a> |
| 30                                                                            | 4.02 - 14.37  | 102 - 365 | S0          | 12.6   | 320 | <a href="#">14050632</a> |
| 30                                                                            | 4.02 - 17.52  | 102 - 445 | S0          | 15.7   | 400 | <a href="#">14050640</a> |
| 30                                                                            | 4.02 - 9.65   | 102 - 245 | S1          | 7.9    | 200 | <a href="#">14010520</a> |
| 30                                                                            | 4.02 - 14.37  | 102 - 365 | S1          | 12.6   | 320 | <a href="#">14010532</a> |
| 30                                                                            | 4.02 - 17.52  | 102 - 445 | S1          | 15.7   | 400 | <a href="#">14010540</a> |
| 30 - 100                                                                      | 5.3 - 9.06    | 135 - 230 | S2          | 7.9    | 200 | <a href="#">14001020</a> |
| 200                                                                           | 5.7 - 9.06    | 145 - 230 | S2          | 7.9    | 200 | <a href="#">14001020</a> |
| 400                                                                           | 7.87 - 10.24  | 200 - 260 | S2          | 7.9    | 200 | <a href="#">14001020</a> |
| 30 - 100                                                                      | 5.3 - 13.78   | 135 - 350 | S1, S2      | 12.6   | 320 | <a href="#">14001032</a> |
| 200                                                                           | 5.7 - 13.78   | 145 - 350 | S2          | 12.6   | 320 | <a href="#">14001032</a> |
| 400                                                                           | 7.87 - 14.96  | 200 - 380 | S2          | 12.6   | 320 | <a href="#">14001032</a> |
| 30 - 100                                                                      | 5.3 - 16.93   | 135 - 430 | S1, S2      | 15.7   | 400 | <a href="#">14001040</a> |
| 200                                                                           | 5.7 - 16.93   | 145 - 430 | S2          | 15.7   | 400 | <a href="#">14001040</a> |
| 400                                                                           | 7.87 - 18.1   | 200 - 460 | S2          | 15.7   | 400 | <a href="#">14001040</a> |
| 600 - 800                                                                     | 10.63 - 11.97 | 270 - 304 | S3          | 7.9    | 200 | <a href="#">14001220</a> |
| 600 - 800                                                                     | 10.63 - 16.69 | 270 - 424 | S3          | 12.6   | 320 | <a href="#">14001232</a> |
| 600 - 800                                                                     | 10.63 - 19.84 | 270 - 504 | S3          | 15.7   | 400 | <a href="#">14001240</a> |

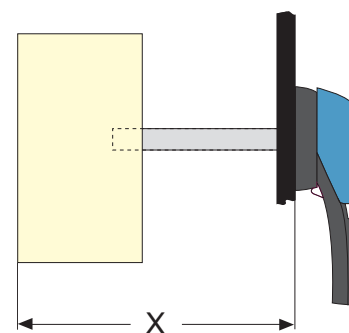


# Accessories Dimensions




## Lugs

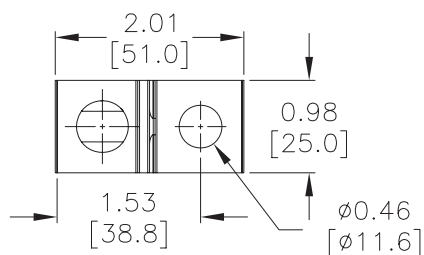
[inches/mm]




39542020, 39543020, 39544020

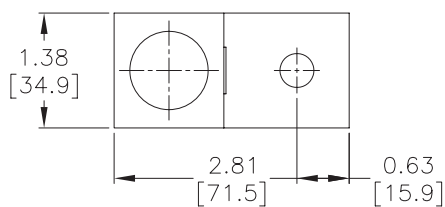

39543040

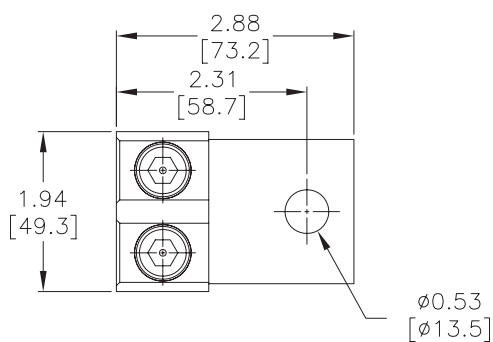

39543041

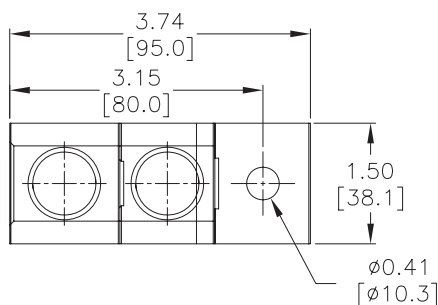















39543060

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Accessories Dimensions
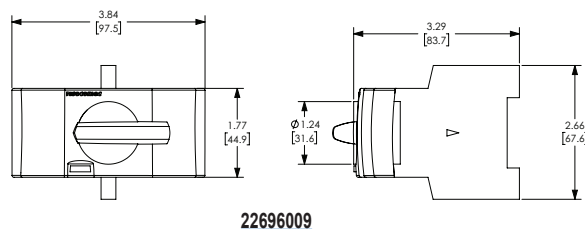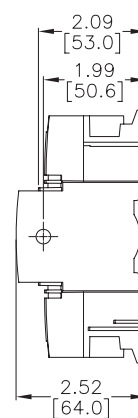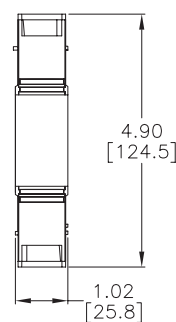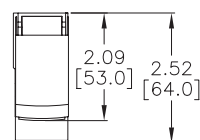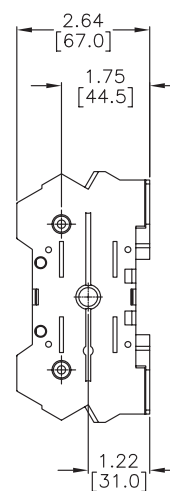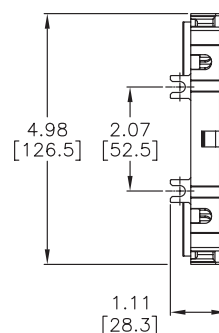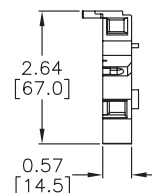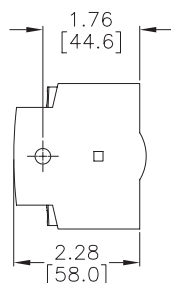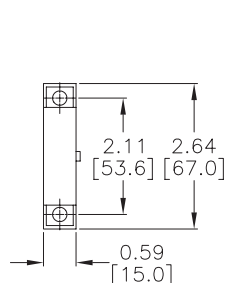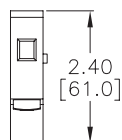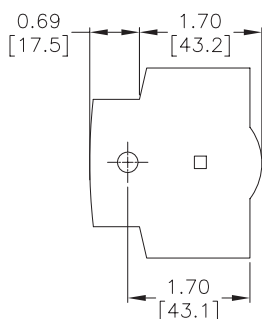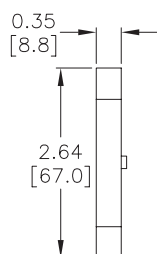 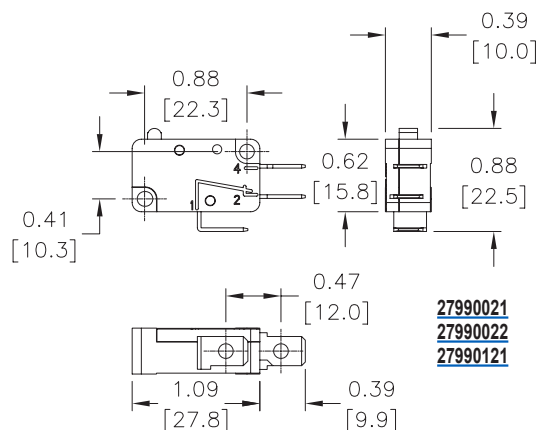
## Auxiliary Contacts and Additional Poles

[inches/mm]

Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Sircover UL 1008

## Manual Transfer

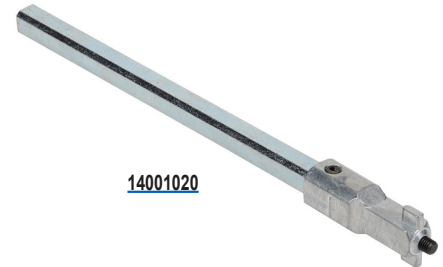
## Switching Equipment



### Shafts for External Handles

| Part Number              | Switch Body Rating (A) | Handle Type | Length (in / mm) | Price   |
|--------------------------|------------------------|-------------|------------------|---------|
| <a href="#">14001020</a> | 30-400                 | S1, S2      | 7.9 / 200        | \$12.50 |
| <a href="#">14001032</a> |                        |             | 12.6 / 320       | \$13.50 |
| <a href="#">14001040</a> |                        |             | 15.7 / 400       | \$15.00 |
| <a href="#">14011520</a> | 600                    | S3          | 7.9 / 200        | \$16.00 |
| <a href="#">14011532</a> |                        |             | 12.6 / 320       | \$21.50 |
| <a href="#">14011540</a> |                        |             | 15.7 / 400       | \$24.00 |

### Shaft for External Handle



[14001020](#)

### Bridging Bars

| Part Number              | Description                                                                                                                 | Switch Body Rating (A) | QTY             | Price    |
|--------------------------|-----------------------------------------------------------------------------------------------------------------------------|------------------------|-----------------|----------|
| <a href="#">41592021</a> | Allows creation of a common point, above or below the switch, between positions I and II for line or load side connections. | 100 - 200              | 2 bridging bars | \$92.00  |
| <a href="#">41593021</a> |                                                                                                                             |                        | 3 bridging bars | \$122.00 |
| <a href="#">41594021</a> |                                                                                                                             |                        | 4 bridging bars | \$154.00 |
| <a href="#">41592041</a> |                                                                                                                             | 260 - 400              | 2 bridging bars | \$96.00  |
| <a href="#">41593041</a> |                                                                                                                             |                        | 3 bridging bars | \$144.00 |
| <a href="#">41594041</a> |                                                                                                                             |                        | 4 bridging bars | \$209.00 |

### Bridging Bars



[41593021](#)

### Auxiliary Contacts

| Part Number              | Description                                                              | Switch Body Rating (A) | Contacts                             | Price   |
|--------------------------|--------------------------------------------------------------------------|------------------------|--------------------------------------|---------|
| <a href="#">41590021</a> | Auxiliary contact, side mount, 10A @ 125VAC/250VAC. Package of 2.        | 100 - 400              | NO/NC on position I and II           | \$15.50 |
| <a href="#">41590022</a> | Auxiliary contact, side mount, 1A @ 125VAC, low impedance. Package of 2. | 100 - 400              | Low level NO/NC on position I and II | \$24.00 |

### Auxiliary contacts



[41590021](#)

### Terminal Protection Screens

| Part Number                | Description                                                                                 | Switch Body Rating (A) | Number of poles | Price   |
|----------------------------|---------------------------------------------------------------------------------------------|------------------------|-----------------|---------|
| <a href="#">41583021</a> * | Use for top or bottom protection against direct contact with terminals or connecting parts. | 100 - 200              | 2/3 P           | \$21.50 |
| <a href="#">41584021</a> * |                                                                                             | 100 - 200              | 4 P             | \$32.50 |
| <a href="#">41583041</a>   |                                                                                             | 260 - 400              | 2/3 P           | \$30.00 |
| <a href="#">41584041</a>   |                                                                                             | 260 - 400              | 4 P             | \$34.50 |

### Terminal Protection Screens



[41583021](#)

\* Note: Screen covers line AND load terminals

### Terminal Lugs

| Part Number              | Description                                                                                  | Switch Body Rating (A) | Wires | Wires range | Lugs per kit | Wires per lug | Price    |
|--------------------------|----------------------------------------------------------------------------------------------|------------------------|-------|-------------|--------------|---------------|----------|
| <a href="#">39542020</a> | Kit of terminal lugs for connection of bare copper cables onto the terminals (without lugs). | 200                    | Cu/Al | #6 - 300MCM | 2            | 1             | \$18.00  |
| <a href="#">39542040</a> |                                                                                              | 260-400                |       | #4 - 600MCM | 2            |               | \$58.00  |
| <a href="#">39543020</a> |                                                                                              | 200                    |       | #6 - 300MCM | 3            |               | \$27.00  |
| <a href="#">39543040</a> |                                                                                              | 400                    |       | #2 - 600MCM | 3            |               | \$69.00  |
| <a href="#">39544020</a> |                                                                                              | 200                    |       | #6 - 300MCM | 4            |               | \$35.00  |
| <a href="#">39544040</a> |                                                                                              | 260-400                |       | #4 - 600MCM | 4            |               | \$112.00 |



[39542040](#)



# Sircover M UL 1008 Manual Transfer Switching Equipment

## Dimensions

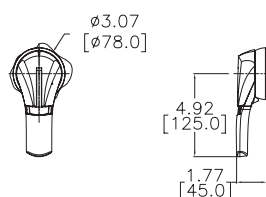
Inches [mm]




### External Handles for UL 1008 Manual Transfer Switches

#### S2 Handle


Handle Dimensions



Direction of Operation

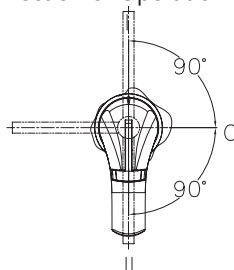


Door Drilling

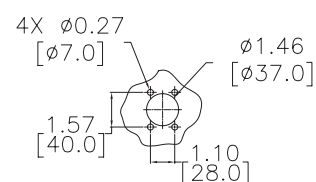


#### S3 Handle

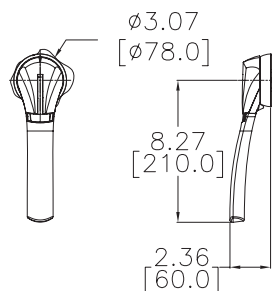
Handle Dimensions



Direction of Operation

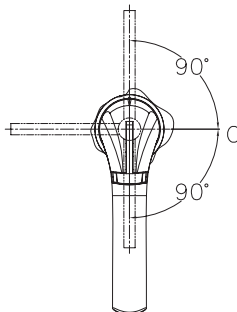


Door Drilling

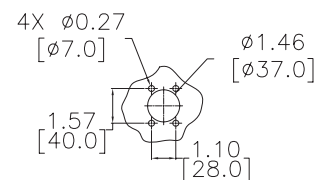

### Shaft Length Minimum Dimensions
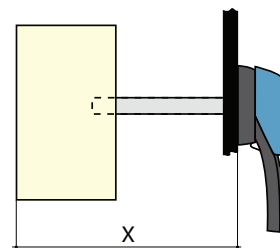
| Switch Body<br>Rating (A) | Dimension X |         | Handle Type | Length |     | Part<br>Number           |
|---------------------------|-------------|---------|-------------|--------|-----|--------------------------|
|                           | in          | mm      |             | in     | mm  |                          |
| 100 - 200                 | 10-14.3     | 254-362 | S2          | 7.9    | 200 | <a href="#">14001020</a> |
|                           | 10-19       | 254-482 |             | 12.6   | 320 | <a href="#">14001032</a> |
|                           | 10-22.1     | 254-562 |             | 15.7   | 400 | <a href="#">14001040</a> |
| 260-400                   | 20-23.4     | 508-594 | S3          | 7.9    | 200 | <a href="#">14011520</a> |
|                           | 20-28.1     | 508-714 |             | 12.6   | 320 | <a href="#">14011532</a> |
|                           | 20-31.3     | 508-794 |             | 15.7   | 400 | <a href="#">14011540</a> |




Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

# Sircover M UL 1008 Manual Transfer Switching Equipment


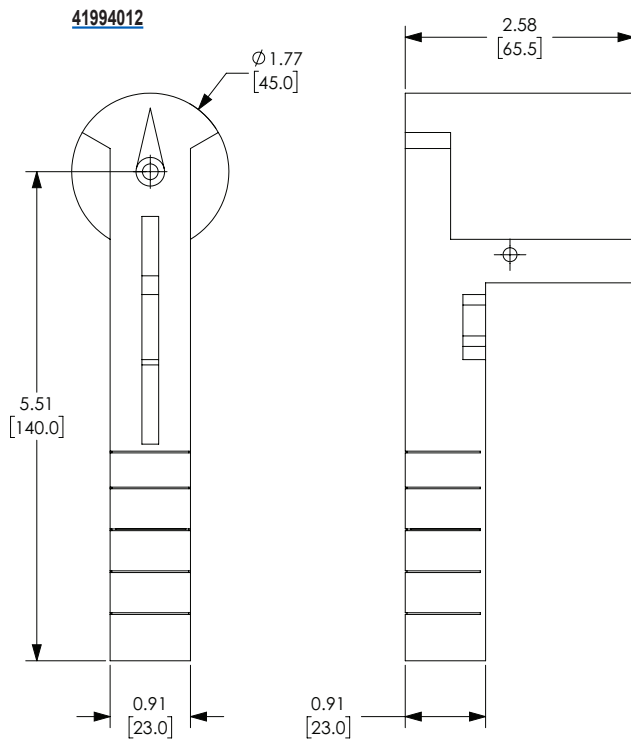
## Dimensions

Inches [mm]






## Direct Handle



## Bridging Bars

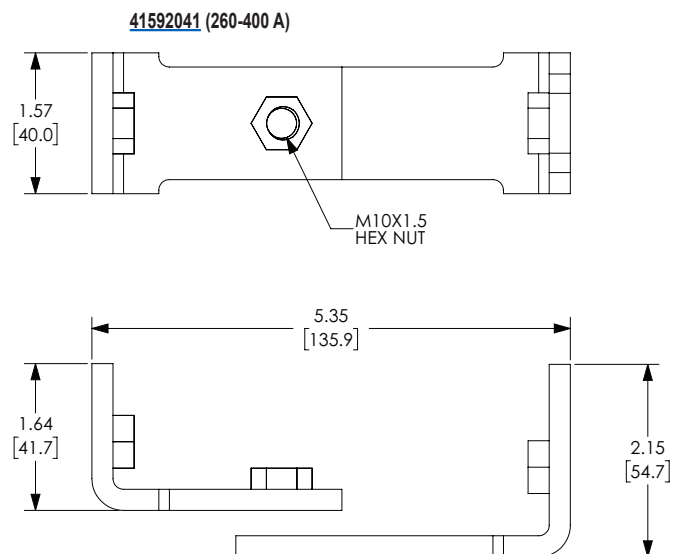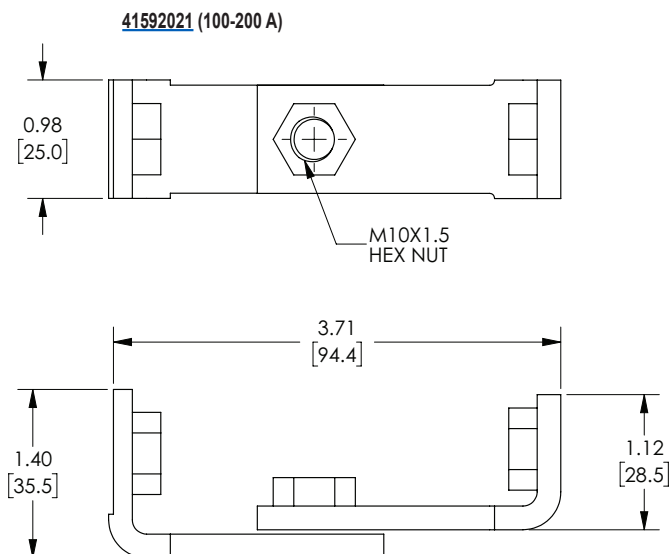Please see our website [www.AutomationDirect.com](http://www.AutomationDirect.com) for complete engineering drawings.

## Terminal Lugs

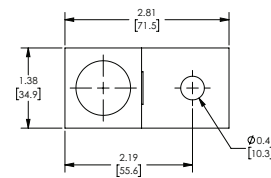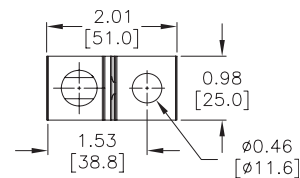 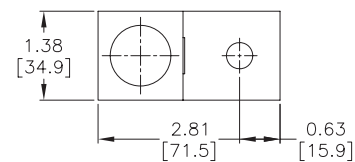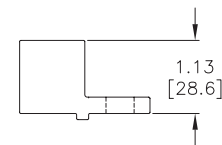**39542040**
**39542020**  
**39543020**  
**39544020**
**39544040**