



# Aluminum T-Slotted Rail

## 15 Series Fractional T-Slotted Aluminum Rail


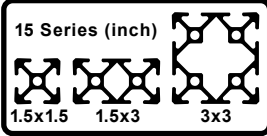






SureFrame™ T-slotted aluminum rails are extruded exclusively for AutomationDirect, with features, quality, and performance you expect. SureFrame T-slotted rails are compatible with other popular brands.

- Cut to length in 0.001 inch increments
- Minimum cut length: 6"
- Maximum cut length: 90"
- Cut accuracy: +/- 0.006"
- Corrosion and UV resistant



Properties	
<b>Material</b>	Aluminum 6063-T6
<b>Finish</b>	Clear or Black Anodize
<b>Hardness</b>	Webster Model B 11-12
<b>Straightness</b>	0.0125 inch/ft [1.042 mm/m]
<b>Twist</b>	0.25°/ft [0.25°/305mm]

 

15 Series (inch)								
		Core Hole Ø 0.27"				 Drop Lock <div>T-Slot Drop Lock feature improves connection strength and vibration resistance</div>		
Part Number	Part Image	Price per inch	Profile Size	Weight Class	Weight lbs/ft [kg/m]	Moment of Inertia Lx (in <sup>4</sup> [cm <sup>4</sup> ])	Moment of Inertia Ly (in <sup>4</sup> [cm <sup>4</sup> ])	Drawing Link
<a href="#">1515C</a>		\$0.56	1.5 x 1.5in	Standard	1.404 [2.089]	0.260 [10.816]	0.260 [10.816]	<a href="#">PDF</a>
<a href="#">1515B</a>		\$0.91						<a href="#">PDF</a>
<a href="#">1515CL</a>		\$0.45		Light	1.093 [1.627]	0.186 [7.738]	0.186 [7.738]	<a href="#">PDF</a>
<a href="#">1515BL</a>		\$0.76						<a href="#">PDF</a>
<a href="#">1515CUL</a>		\$0.42		Ultra-light	1.029 [1.531]	0.174 [7.238]	0.174 [7.238]	<a href="#">PDF</a>

Extruded T-slotted rails have a thru Core Hole feature that can be used to attach various components to the end of the profile using:

- Self-tapping / thread-forming screws (no tapping needed)
- A tap to thread the core hole for a threaded fastener



Please Note: Prices on aluminum are closely tied to the market price. This allows us to offer the best savings possible if conditions are favorable; however, it also means that our prices may increase if market conditions warrant.



# Aluminum T-Slotted Rail


## 15 Series Fractional T-Slotted Aluminum Rail

SureFrame™ T-slotted aluminum rails are extruded exclusively for AutomationDirect, with features, quality, and performance you expect. SureFrame T-slotted rails are compatible with other popular brands.

- Cut to length in 0.001 inch increments
- Minimum cut length: 6"
- Maximum cut length: 90"
- Cut accuracy: +/- 0.006"
- Corrosion and UV resistant




Properties	
<b>Material</b>	Aluminum 6063-T6
<b>Finish</b>	Clear or Black Anodize
<b>Hardness</b>	Webster Model B 11-12
<b>Straightness</b>	0.0125 inch/ft [1.042 mm/m]
<b>Twist</b>	0.25°/ft [0.25°/305mm]

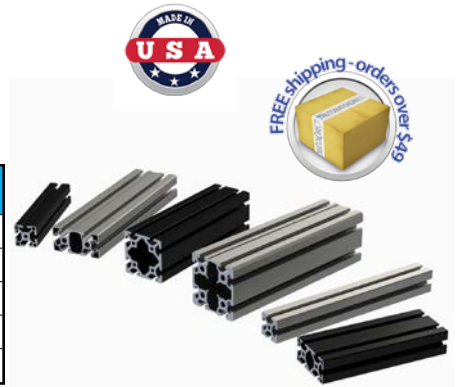

## 15 Series (inch) - Continued



Core Hole Ø 0.27"

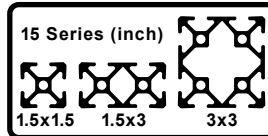

T-Slot Drop Lock feature improves connection strength and vibration resistance

Part Number	Part Image	Price per inch	Profile Size	Weight Class	Weight lbs/ft [kg/m]	Moment of Inertia Lx (in <sup>4</sup> [cm <sup>4</sup> ])	Moment of Inertia Ly (in <sup>4</sup> [cm <sup>4</sup> ])	Drawing Link
<a href="#">1530C</a>		\$1.01	1.5 x 3in	Standard	2.526 [3.759]	0.572 [23.795]	2.138 [88.982]	<a href="#">PDF</a>
<a href="#">1530B</a>		\$1.53						<a href="#">PDF</a>
<a href="#">1530CL</a>		\$0.86		Light	2.093 [3.115]	0.408 [16.973]	1.430 [59.529]	<a href="#">PDF</a>
<a href="#">1530BL</a>		\$1.32						<a href="#">PDF</a>
<a href="#">3030C</a>		\$1.62	3 x 3in	Standard	4.058 [6.039]	3.377 [140.566]	3.377 [140.566]	<a href="#">PDF</a>
<a href="#">3030B</a>		\$2.30						<a href="#">PDF</a>

Extruded T-slotted rails have a thru Core Hole feature that can be used to attach various components to the end of the profile using:

- Self-tapping / thread-forming screws (no tapping needed)
- A tap to thread the core hole for a threaded fastener



Please Note: Prices on aluminum are closely tied to the market price. This allows us to offer the best savings possible if conditions are favorable; however, it also means that our prices may increase if market conditions warrant.



# Aluminum T-Slotted Rail

## Deflection Calculations

Using the calculations below, find your approximate deflection\* for a specific extrusion.  
See table below for variations.

**As always when calculating, use diligence and work only in either imperial or metric units at one time.**

"E" = Modulus of Elasticity

"F" = Force

"I" = Moment of Inertia

 
"L" = Length

"W" = Weight

*\*for reference only*


### Supported Loads

CONCENTRATED LOAD AT CENTER (simply supported)




$$\text{MAX DEFLECTION} = \frac{FL^3}{48 EI}$$

 UNIFORMLY DISTRIBUTED LOAD (simply supported)




$$\text{MAX DEFLECTION} = \frac{5}{84} \frac{WL^4}{EI}$$

 CONCENTRATED LOAD AT CENTER (between fixed supports)



$$\text{MAX DEFLECTION} = \frac{FL^3}{192 EI}$$

 UNIFORMLY DISTRIBUTED LOAD (between fixed supports)




$$\text{MAX DEFLECTION} = \frac{WL^4}{384 EI}$$

### Aluminum 6063-T6 Properties

<b>Yield Strength</b>	29,007 psi [200 MPa]
<b>Tensile Strength</b>	33,359 psi [230 MPa]
<b>Modulus of Elasticity</b>	10,000,000 psi [68.9 GPa]


### Cantilever Loads

CONCENTRATED LOAD AT CENTER (simply supported)

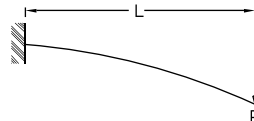

$$\text{MAX DEFLECTION} = \frac{FL^3}{3 EI}$$

UNIFORMLY DISTRIBUTED LOAD (simply supported)

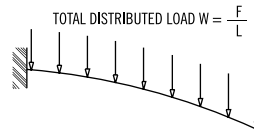
 


 

 

 



$$\text{MAX DEFLECTION} = \frac{WL^4}{8 EI}$$

# FATH® T-Slotted Rail Accessories

## T-Slot Nuts

- Designed to fit into the T-slot cavity of extruded aluminum rails.
- Hammer nuts provide safe electrostatic discharging (ESD) connection.
- No machining required.
- Material: zinc plated steel

T-Slot Nuts Selection					
Part Image	Nut Type	Installation	Holds Position Without Screw	ESD Connection	
	Double Economy T-Nut			No	
	Economy T-Nut				
	Hammer Nut		No	Yes	
	Slide-In Nut			No	
	Roll-In Nut with Leaf Spring		Yes		
	Roll-In Nut with Spring Loaded Ball				



15 Series T-Slot Nuts						
Fits		Slot Size 8	<div>15 Series (inch)</div> <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div>			
Part Number	Part Image	Price	Nut Type	Thread Size	Pack Quantity	Drawing Link
<a href="#">161115</a>		\$17.50	Roll-In Nut	8-32 UNF	10	<a href="#">PDF</a>
<a href="#">161125</a>		\$9.50	Hammer Nut			<a href="#">PDF</a>
<a href="#">161114</a>		\$17.50	Roll-In Nut	10-32 UNF		<a href="#">PDF</a>
<a href="#">162996</a>		\$17.50				<a href="#">PDF</a>
<a href="#">162903</a>		\$9.00	Slide-In Nut			<a href="#">PDF</a>
<a href="#">161126</a>		\$8.25	Hammer Nut			<a href="#">PDF</a>










 





# FATH® T-Slotted Rail Accessories

## T-Slot Nuts - Continued

15 Series T-Slot Nuts - Continued						
<div><div><div>Fits</div><div>Slot Size</div><div>8</div></div><div><div>15 Series (inch)</div><div><div></div><div></div><div></div></div><div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div></div></div>						
Part Number	Part Image	Price	Nut Type	Thread Size	Pack Quantity	Drawing Link
<a href="#"><u>162904</u></a>		\$9.00	Slide-In Nut	1/4-20 UNC	10	<a href="#"><u>PDF</u></a>
<a href="#"><u>151097</u></a>		\$9.50	Hammer Nut			<a href="#"><u>PDF</u></a>
<a href="#"><u>162997</u></a>		\$17.50	Roll-In Nut			<a href="#"><u>PDF</u></a>
<a href="#"><u>161123</u></a>		\$5.50	Economy T-Nut	1/4-20 UNC		<a href="#"><u>PDF</u></a>
<a href="#"><u>151098</u></a>		\$20.00	Roll-In Nut			<a href="#"><u>PDF</u></a>
<a href="#"><u>151096</u></a>		\$6.50	Economy T-Nut	5/16-18 UNC		<a href="#"><u>PDF</u></a>
<a href="#"><u>148805</u></a>		\$5.50	Double Economy T-Nut		4	<a href="#"><u>PDF</u></a>
<a href="#"><u>162905</u></a>		\$9.00	Slide-In Nut		10	<a href="#"><u>PDF</u></a>
<a href="#"><u>151099</u></a>		\$20.00	Roll-In Nut			<a href="#"><u>PDF</u></a>
<a href="#"><u>162998</u></a>		\$17.50	Roll-In Nut			<a href="#"><u>PDF</u></a>
<a href="#"><u>161129</u></a>		\$8.00	Hammer Nut			M4-0.7
<a href="#"><u>161119</u></a>		\$16.75	Roll-In Nut	<a href="#"><u>PDF</u></a>		
<a href="#"><u>162999</u></a>		\$17.50		<a href="#"><u>PDF</u></a>		

# FATH® T-Slotted Rail Accessories

## T-Slot Nuts - Continued


15 Series T-Slot Nuts - Continued						
<div><div><div>Fits</div><div>Slot Size</div><div>8</div></div><div><div>15 Series (inch)</div><div><div></div><div></div><div></div></div><div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div></div></div>						
Part Number	Part Image	Price	Nut Type	Thread Size	Pack Quantity	Drawing Link
<a href="#">161130</a>		\$8.00	Hammer Nut	M5-0.8	10	<a href="#">PDF</a>
<a href="#">161120</a>		\$16.75	Roll-In Nut			<a href="#">PDF</a>
<a href="#">163000</a>		\$17.50				<a href="#">PDF</a>
<a href="#">151214</a>		\$9.00	Hammer Nut	M6-1.0		<a href="#">PDF</a>
<a href="#">162884</a>		\$9.75	Slide-In Nut			<a href="#">PDF</a>
<a href="#">151215</a>		\$19.00	Roll-In Nut			<a href="#">PDF</a>
<a href="#">163001</a>		\$17.50				<a href="#">PDF</a>
<a href="#">162885</a>		\$9.75	Slide-In Nut	M8-1.25		<a href="#">PDF</a>
<a href="#">151216</a>		\$19.00	Roll-In Nut			<a href="#">PDF</a>
<a href="#">163002</a>		\$17.50				<a href="#">PDF</a>

# FATH® T-Slotted Rail Accessories

## Fasteners

- Choose from 4 Head types in numerous lengths
- Hex socket head
- Select desired T-Slot nut style with corresponding thread size.
- Material: Black zinc plated or bright zinc plated steel, prevents corrosion better than typical black oxide coatings















15 Series Fasteners								
<div>Fits</div>		<div>Slot Size</div> <div>8</div>	<div>15 Series (inch)</div> <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div>					
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#">162994</a>		\$8.00	#8-32 UNF	3/8 in	Button head socket cap screw	Flat black	10	<a href="#">PDF</a>
<a href="#">161073</a>		\$7.75		1/2 in	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">162993</a>		\$7.50	#10-32 UNF	3/8 in	Button head socket cap screw			<a href="#">PDF</a>
<a href="#">162995</a>		\$7.75		1/2 in	Socket head cap screw			<a href="#">PDF</a>
<a href="#">161046</a>		\$4.75			5/8 in			Button head socket cap screw
<a href="#">161047</a>		\$5.00		<a href="#">PDF</a>				
<a href="#">161048</a>		\$5.75		3/4 in				
<a href="#">161074</a>		\$6.25	1/4-20 UNC	1/2 in	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">151040</a>		\$4.25			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">151041</a>		\$5.25			Flanged button head socket cap screw	Gloss black		<a href="#">PDF</a>
<a href="#">161049</a>		\$4.50		9/16 in	Button head socket cap screw	Flat black		<a href="#">PDF</a>
<a href="#">161075</a>		\$6.25		5/8 in	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161050</a>		\$4.75			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161087</a>		\$4.00			Socket head cap screw			<a href="#">PDF</a>

## Fasteners - Continued

15 Series Fasteners - Continued								
<div>Fits</div>		<div>Slot Size</div> <div>8</div>		<div>15 Series (inch)</div> <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div>				
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#">161051</a>		\$4.75	1/4-20 UNC	3/4 in	Button head socket cap screw	Flat black	10	<a href="#">PDF</a>
<a href="#">161052</a>		\$5.25		1in				<a href="#">PDF</a>
<a href="#">151100</a>		\$5.25	5/16-18 UNC	5/8 in	Button head socket cap screw	Gloss black		<a href="#">PDF</a>
<a href="#">151101</a>		\$6.00		11/16 in	Flanged button head socket cap screw			<a href="#">PDF</a>
<a href="#">161053</a>		\$5.75		1/2 in	Button head socket cap screw	Flat black		<a href="#">PDF</a>
<a href="#">161054</a>		\$6.50		3/4 in				<a href="#">PDF</a>
<a href="#">161055</a>		\$7.50		1in				<a href="#">PDF</a>
<a href="#">161088</a>		\$2.25	M4-0.7	8mm	Socket head cap screw	Bright zinc		<a href="#">PDF</a>
<a href="#">161089</a>		\$2.50		10mm				Socket head cap screw
<a href="#">161056</a>		\$1.00			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161076</a>		\$1.50	12mm	Flat head socket cap screw	<a href="#">PDF</a>			
<a href="#">161057</a>		\$1.25	M5-0.8	10mm	Button head socket cap screw		<a href="#">PDF</a>	
<a href="#">161090</a>		\$2.50			Socket head cap screw		<a href="#">PDF</a>	
<a href="#">161077</a>		\$1.75		12mm	Flat head socket cap screw		<a href="#">PDF</a>	
<a href="#">161091</a>		\$2.50			Socket head cap screw		<a href="#">PDF</a>	
















# FATH® T-Slotted Rail Accessories

## Fasteners - Continued

15 Series Fasteners - Continued								
		Fits 						
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#">161058</a>		\$1.75	M5-0.8	12mm	Button head socket cap screw	Bright zinc	10	<a href="#">PDF</a>
<a href="#">161092</a>		\$2.50	M6-1.0	10mm	Socket head cap screw			<a href="#">PDF</a>
<a href="#">161078</a>		\$2.25		12mm	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161059</a>		\$2.00			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161093</a>		\$2.75			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161079</a>		\$2.50		14mm	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161060</a>		\$2.25			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161094</a>		\$2.75			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161080</a>		\$2.50		16mm	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161061</a>		\$2.50			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161095</a>		\$2.75			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161062</a>		\$2.75		18mm	Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161096</a>		\$3.00			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161081</a>		\$2.50		20mm	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161063</a>		\$2.75			Button head socket cap screw			<a href="#">PDF</a>








# FATH® T-Slotted Rail Accessories





## Fasteners - Continued

15 Series Fasteners - Continued									
<div>Fits</div>		<div>Slot Size</div> <div>8</div>		<div>15 Series (inch)</div> <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div>					
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link	
<a href="#">161097</a>		\$3.25	M6-1.0	20mm	Socket head cap screw	Bright zinc	10	<a href="#">PDF</a>	
<a href="#">161064</a>		\$3.25		25mm	Button head socket cap screw			<a href="#">PDF</a>	
<a href="#">161082</a>		\$4.75	M8-1.25	12mm	Flat head socket cap screw			<a href="#">PDF</a>	
<a href="#">161065</a>		\$4.25			Button head socket cap screw			<a href="#">PDF</a>	
<a href="#">161098</a>		\$4.75			Socket head cap screw			<a href="#">PDF</a>	
<a href="#">161066</a>		\$4.50		14mm	Button head socket cap screw			<a href="#">PDF</a>	
<a href="#">161083</a>		\$5.00			Flat head socket cap screw			<a href="#">PDF</a>	
<a href="#">161099</a>		\$5.00	Socket head cap screw		<a href="#">PDF</a>				
<a href="#">161084</a>		\$5.50	M8-1.25	16mm	Flat head socket cap screw			Gloss black	<a href="#">PDF</a>
<a href="#">161100</a>		\$5.50			Socket head cap screw				<a href="#">PDF</a>
<a href="#">161067</a>		\$4.50			Button head socket cap screw				<a href="#">PDF</a>
<a href="#">151183</a>		\$4.75		Flanged button head socket cap screw	<a href="#">PDF</a>				
<a href="#">151184</a>		\$5.50		Flanged button head socket cap screw	<a href="#">PDF</a>				
<a href="#">161085</a>		\$5.50		18mm	Flat head socket cap screw	Bright zinc	<a href="#">PDF</a>		
<a href="#">161068</a>		\$5.00			Button head socket cap screw		<a href="#">PDF</a>		


# FATH® T-Slotted Rail Accessories

## Fasteners - Continued

15 Series Fasteners - Continued									
<div>Fits</div>		<div>Slot Size</div> <div>8</div>	<div>15 Series (inch)</div> <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div>						
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link	
<a href="#">161101</a>		\$5.50	M8-1.25	18mm	Socket head cap screw	Bright zinc	10	<a href="#">PDF</a>	
<a href="#">151241</a>		\$4.50		20mm	Button head socket cap screw			<a href="#">PDF</a>	
<a href="#">161102</a>		\$5.75			Socket head cap screw			<a href="#">PDF</a>	
<a href="#">161086</a>		\$7.00		25mm	Flat head socket cap screw			<a href="#">PDF</a>	
<a href="#">161069</a>		\$5.25			Button head socket cap screw			<a href="#">PDF</a>	
<a href="#">161070</a>		\$8.00		40mm				<a href="#">PDF</a>	
<a href="#">118284</a>		\$2.50	5/16-18 UNC	1in	Hammer head screw and flange nut		1	<a href="#">PDF</a>	

15 Series Self Forming / Tapping Screws								
		Fits		15 Series Core Hole		Works with Aluminum with hole diameter 0.256" - 0.276" [6.6 - 7.0 mm]		
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#"><u>161105</u></a>		\$17.00	S7	25mm	Self-Tapping Screw Button head socket cap	Bright zinc	10	<a href="#"><u>PDF</u></a>
<a href="#"><u>161106</u></a>		\$9.25			Self-Tapping Screw Flanged button head socket cap T-40 Torx			<a href="#"><u>PDF</u></a>
<a href="#"><u>161107</u></a>		\$17.00		40mm	Self-Tapping Screw Button head socket cap			<a href="#"><u>PDF</u></a>

### Self Forming / Tapping Screw Installation

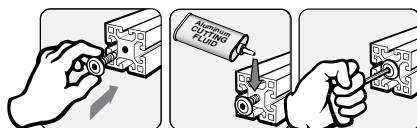



# FATH® T-Slotted Rail Accessories

## Connecting Components

- Connects two or three T-slot rails together.
- Recommended ADC Fastener based on part feature, slot depth and core hole.
- Material: varies by part









15 Series Connecting Components										
Fits		Slot Size 8	<div>15 Series (inch)</div> <div><div></div><div></div><div></div></div> <div>1.5x1.51.5x33x3</div>							
Part Number	Part Image	Price	Description	Fits Profile	Material	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Drawing Link	
						Core Hole Attachment 1	*T-Slot Attachment 2			
<a href="#">148954</a>		\$10.00	2d Cube Connector	1.5 x 1.5in	Die-cast aluminum	<a href="#">161105</a>	<a href="#">151100</a>	1	<a href="#">PDF</a>	
<a href="#">166302</a>		\$12.00							<a href="#">PDF</a>	
<a href="#">148957</a>		\$11.50	3d Cube Connector						<a href="#">PDF</a>	
<a href="#">166303</a>		\$13.00							<a href="#">PDF</a>	
<a href="#">151107</a>		\$7.50	Angle Connector			1.5 x 3in	Fasteners Included		Fasteners Included	<a href="#">PDF</a>
<a href="#">166304</a>		\$8.00					<a href="#">PDF</a>			
<a href="#">151108</a>		\$11.00		<a href="#">PDF</a>						
<a href="#">166305</a>		\$13.00		<a href="#">PDF</a>						
<a href="#">151102</a>		\$23.50	Duo Connector	All 15 Series	Steel	n/a	n/a	10	<a href="#">PDF</a>	
<a href="#">151103</a>		\$96.00	T-Matic Connector		Zinc plated steel				<a href="#">PDF</a>	
<a href="#">151104</a>		\$59.00	Automatic Connector		Steel			1	<a href="#">PDF</a>	

\*T-Slot Nut also required.

\*T-Slot Nut also required.


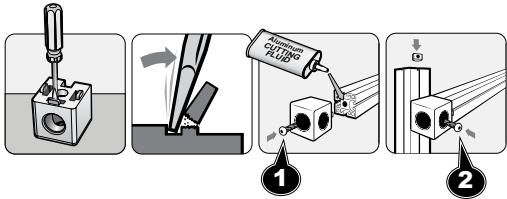
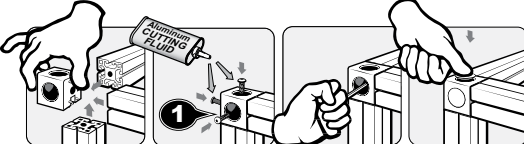
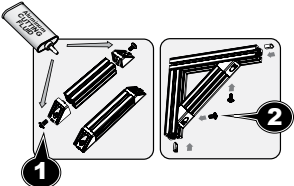
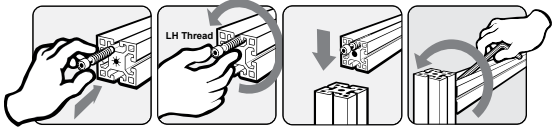
# FATH® T-Slotted Rail Accessories

## Connecting Components - Continued

15 Series Connecting Components - Continued									
		Fits		Slot Size 8		<div>15 Series (inch)</div> <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div>			
Part Number	Part Image	Price	Description	Fits Profile	Material	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Drawing Link
						Core Hole Attachment 1	*T-Slot Attachment 2		
<a href="#">151105</a>		\$9.50	Automatic Butt Connector	All 15 Series	Steel	n/a	n/a	1	<a href="#">PDF</a>
<a href="#">151106</a>		\$8.50	Milling Connector		Zinc plated steel				<a href="#">PDF</a>
<a href="#">151109</a>		\$15.50	Connecting Strip						<a href="#">PDF</a>
<a href="#">162891</a>		\$13.00	Direct Connector		Steel		Fasteners included		<a href="#">PDF</a>
<a href="#">162961</a>		\$11.50	Miter Connector		Steel		M8-1.25 x 8mm set screw (4) included		<a href="#">PDF</a>
<a href="#">163009</a>		\$13.25	Screw Connector	1.5 x 1.5in	Zinc plated steel	Designer's choice	10	<a href="#">PDF</a>	
*T-Slot Nut also required									

# FATH® T-Slotted Rail Accessories

## Connecting Components - Continued

Connecting Components Installation	
Core Hole Installation	T-Slot Installation
<b>2D Cube Connector</b> 	
<b>3D Cube Connector</b> 	n/a
<b>Angle Connector</b> 	
<b>Duo Connector</b>	

# FATH® T-Slotted Rail Accessories

## Connecting Components - Continued

Connecting Components Installation	
T-Slot Installation	
<b>T-matic Connector</b>	
<b>Automatic Connector</b>	
<b>Automatic Butt Connector</b>	
<b>Milling Connector</b>	
<b>Connecting Strip</b>	
<b>Direct Connector</b>	
<b>Screw Connector</b>	
<b>Miter Connector</b>	

# FATH® T-Slotted Rail Accessories


## Joining Plates









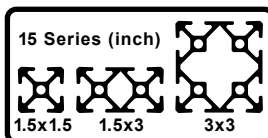





- Connects two or more T-slot rails together.
- Recommended ADC Fastener based on part feature and slot depth.
- Material: Anodized aluminum



### 15 Series Joining Plates

Fits

Slot Size  
8


Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment (ADC Part Number)	Pack Quantity	Drawing Link		
<a href="#">151110</a>		\$5.25	Straight Flat Plate	<a href="#">151100</a> or <a href="#">151101</a>	1	<a href="#">PDF</a>		
<a href="#">166306</a>		\$6.00				<a href="#">PDF</a>		
<a href="#">151111</a>		\$4.75				<a href="#">PDF</a>		
<a href="#">166307</a>		\$6.00				<a href="#">PDF</a>		
<a href="#">151112</a>		\$6.25				<a href="#">PDF</a>		
<a href="#">166308</a>		\$7.00				<a href="#">PDF</a>		
<a href="#">151113</a>		\$6.00	Square Flat Plate					<a href="#">PDF</a>
<a href="#">166309</a>		\$7.00				<a href="#">PDF</a>		
<a href="#">151114</a>		\$8.50	Rectangular Flat Plate					<a href="#">PDF</a>
<a href="#">166310</a>		\$10.00				<a href="#">PDF</a>		
<a href="#">151115</a>		\$11.00				<a href="#">PDF</a>		
<a href="#">166311</a>		\$12.00				<a href="#">PDF</a>		
<a href="#">151116</a>		\$8.50	Flat Plate					<a href="#">PDF</a>
<a href="#">166312</a>		\$10.00				<a href="#">PDF</a>		

\*T-Slot Nut also required

\*T-Slot Nut also required

# FATH® T-Slotted Rail Accessories

## Joining Plates - Continued

15 Series Joining Plates - Cont'd						
<div><div><div>Fits</div><div>Slot Size</div><div>8</div></div><div><div>15 Series (inch)</div><div><div></div><div></div><div></div></div><div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div></div></div>						
Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment (ADC Part Number)	Pack Quantity	Drawing Link
<a href="#">151117</a>		\$12.00	Flat Plate	<a href="#">151100</a> or <a href="#">151101</a>	1	<a href="#">PDF</a>
<a href="#">166313</a>		\$14.00				<a href="#">PDF</a>
<a href="#">151118</a>		\$9.25	T-Shaped Flat Plate			<a href="#">PDF</a>
<a href="#">166314</a>		\$11.00				<a href="#">PDF</a>
<a href="#">151119</a>		\$12.00				<a href="#">PDF</a>
<a href="#">166315</a>		\$14.00				<a href="#">PDF</a>
<a href="#">151120</a>		\$18.50				<a href="#">PDF</a>
<a href="#">166316</a>		\$22.00				<a href="#">PDF</a>
<a href="#">151121</a>		\$18.50	Cross Flat Plate			<a href="#">PDF</a>
<a href="#">166317</a>		\$22.00				<a href="#">PDF</a>
<a href="#">151122</a>		\$13.50	L-Shaped Flat Plate			<a href="#">PDF</a>
<a href="#">166318</a>		\$16.00				<a href="#">PDF</a>
<a href="#">151123</a>		\$14.50	T-Shaped Flat Plate			<a href="#">PDF</a>
<a href="#">166319</a>		\$17.00				<a href="#">PDF</a>

\*T-Slot Nut also required















\*T-Slot Nut also required

# FATH® T-Slotted Rail Accessories

## Brackets

- Connects two T-slot rails together at a 90° angle
- Recommended ADC Fastener based on part feature and slot depth
- Material: varies by part



15 Series Brackets													
Fits		Slot Size 8	<div>15 Series (inch)</div> <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div>										
Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link					
				Core Hole Attachment 1	*T-Slot Attachment 2								
<a href="#">148916</a>		\$4.00	Angle Bracket	n/a	<a href="#">151100</a>	1	Die-cast aluminum	<a href="#">PDF</a>					
<a href="#">166321</a>		\$4.00						<a href="#">PDF</a>					
<a href="#">151125</a>		\$7.75			<a href="#">161054</a>			<a href="#">PDF</a>					
<a href="#">166322</a>		\$9.00						<a href="#">PDF</a>					
<a href="#">151126</a>		\$11.50			<a href="#">151101</a>	1	Die-cast zinc	<a href="#">PDF</a>					
<a href="#">166323</a>		\$13.00						<a href="#">PDF</a>					
<a href="#">151124</a>		\$3.75	Inside Corner Bracket		n/a	<a href="#">151100</a> or <a href="#">151101</a>	1	Anodized aluminum	<a href="#">PDF</a>				
<a href="#">166320</a>		\$4.00							<a href="#">PDF</a>				
<a href="#">151127</a>		\$6.50	Wide Inside Corner Bracket						<a href="#">PDF</a>				
<a href="#">166324</a>		\$8.00							<a href="#">PDF</a>				
<a href="#">151128</a>		\$6.00	Tall Inside Corner Bracket						<a href="#">PDF</a>				
<a href="#">166325</a>		\$7.00							<a href="#">PDF</a>				
<a href="#">148906</a>		\$9.00	Inside Corner Bracket						<a href="#">PDF</a>				
<a href="#">166326</a>		\$11.00							<a href="#">PDF</a>				













\*T-Slot Nut also required.

\*T-Slot Nut also required.



# FATH® T-Slotted Rail Accessories

## Brackets - Continued



15 Series Brackets - Continued														
Fits		Slot Size 8	<div>15 Series (inch) <div><div>1.5x1.5</div><div>1.5x3</div><div>3x3</div></div></div>											
Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link						
				Core Hole Attachment 1	*T-Slot Attachment 2									
<a href="#">151129</a>		\$3.75	Gusseted Inside Corner Bracket			1	Anodized aluminum	<a href="#">PDF</a>						
<a href="#">166327</a>		\$4.00						<a href="#">PDF</a>						
<a href="#">151130</a>		\$7.75	Tall Gusseted Inside Corner Bracket	n/a	<a href="#">151100</a> or <a href="#">151101</a>			<a href="#">PDF</a>						
<a href="#">166328</a>		\$9.00						<a href="#">PDF</a>						
<a href="#">148910</a>		\$6.75	Wide Gusseted Inside Corner Bracket					<a href="#">PDF</a>						
<a href="#">166329</a>		\$8.00						<a href="#">PDF</a>						
<a href="#">151131</a>		\$13.00	Gusseted Inside Corner Bracket					<a href="#">PDF</a>						
<a href="#">166330</a>		\$16.00						<a href="#">PDF</a>						
<a href="#">151132</a>		\$29.50	Pivot Joint	<a href="#">161055</a>	<a href="#">151100</a>		Die-cast zinc	<a href="#">PDF</a>						
<a href="#">166331</a>		\$35.00						<a href="#">PDF</a>						
<a href="#">148933</a>		\$39.50	Pivot Joint With Locking Handle					<a href="#">PDF</a>						
<a href="#">166332</a>		\$45.00						<a href="#">PDF</a>						

\*T-Slot Nut also required.

\*T-Slot Nut also required.

# FATH<sup>®</sup> T-Slotted Rail Accessories


## Brackets - Continued

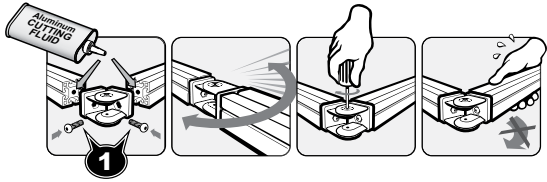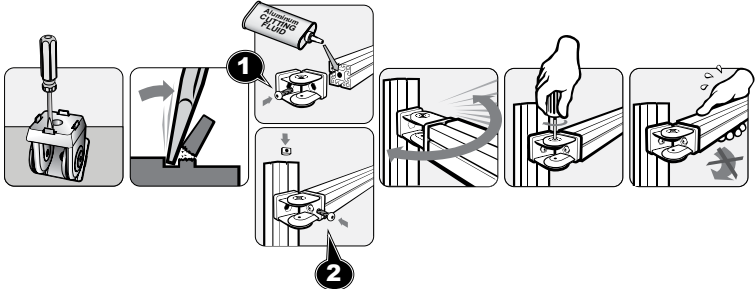Brackets Installation	
Core Hole Installation	T-Slot Installation
<b>Pivot Joint</b>	
	

# FATH® T-Slotted Rail Accessories


## Bases



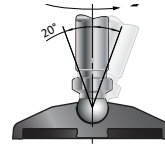





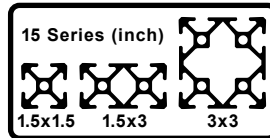




- Recommended ADC Fastener based on part feature and core hole
- Material: varies by part



### 15 Series Bases

Fits 



Part Number	Part Image	Price	Diameter	Description	Fits	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link									
							Core Hole Attachment 1	*T-Slot Attachment 2												
<a href="#">118357</a>		\$17.00	n/a	3/8-16 UNC Transport/Base Plate	1.5 x 3in	n/a	161105 (2) included with kit	n/a	1	Die-cast zinc	<a href="#">PDF</a>									
<a href="#">161043</a>		\$28.00			3 x 3in		161105 (4) included with kit				<a href="#">PDF</a>									
<a href="#">151075</a>		\$4.50		3/8-16 UNC x 1-1/2in Swivel Foot Threaded Rod with 15mm ball	Transport/Base Plate <a href="#">118357</a> and <a href="#">161043</a>	470 [1036]**	Zinc plated steel			<a href="#">PDF</a>										
<a href="#">151068</a>		\$4.00	1.57 in [39.0 mm]	Swivel Base With Anti-Slip Plate	Any 15mm ball Threaded Rod	900 [1984]	Nylon			<a href="#">PDF</a>										
<a href="#">151071</a>		\$9.50				3000 [6614]				Die-cast zinc	<a href="#">PDF</a>									
<a href="#">151072</a>		\$17.00	3.11 in [79.0 mm]								<a href="#">PDF</a>									
<a href="#">151073</a>		\$17.00									<a href="#">PDF</a>									
<a href="#">151069</a>		\$6.00	900 [1984]				Nylon			<a href="#">PDF</a>										
<a href="#">151070</a>		\$6.00								<a href="#">PDF</a>										
<a href="#">151255</a>		\$10.00	3.90 in [99.0 mm]			3500 [7716]					<a href="#">PDF</a>									
<a href="#">151256</a>		\$10.00									<a href="#">PDF</a>									
<a href="#">151257</a>		\$24.00				Die-cast zinc	<a href="#">PDF</a>													
<a href="#">151258</a>		\$24.00					<a href="#">PDF</a>													

\*T-Slot Nut also required

\*\*Based on installation with Transport / Base Plate

Load rating of a swivel foot assembly is based on the part with the lowest load rating, typically the threaded rod.

Example:









Threaded rod load rating = 210kg [463lb]

Swivel base load rating = 3000kg [6614lb]

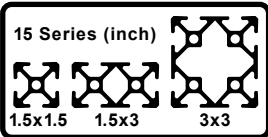Swivel foot assembly load rating = 210kg [463lb]


# FATH® T-Slotted Rail Accessories

## Bases - Continued

15 Series Bases - continued												
		Fits		Slot Size		15 Series (inch)						
				8								
Part Number	Part Image	Price	Diameter	Description	Fits	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link	
							Core Hole Attachment 1	*T-Slot Attachment 2				
<a href="#">162933</a>		\$12.50	See 2D drawing	Extended Swivel Base	Any 15mm ball Threaded Rod	1000 [2204]	n/a	n/a	1	Nylon	<a href="#">PDF</a>	
<a href="#">162934</a>		\$27.00				3000 [6613]				Die-cast zinc	<a href="#">PDF</a>	
<a href="#">166333</a>		\$30.00	n/a	Foot Console	1.5 x 1.5 in, 3 x 3in	n/a		<a href="#">161054</a>		Die-cast aluminum	<a href="#">PDF</a>	
<a href="#">166334</a>		\$30.00									<a href="#">PDF</a>	
<a href="#">166335</a>		\$30.00			1.5 x 3in, 3 x 3in						<a href="#">PDF</a>	
<a href="#">166336</a>		\$30.00									<a href="#">PDF</a>	
<a href="#">162957</a>		\$11.50		Floor Bracket	1.5 x 1.5 in, 1.5 x 3in, 3 x 3in			<a href="#">151100</a>		Anodized aluminum	<a href="#">PDF</a>	
<div>*T-Slot Nut also required</div> <div>**Based on installation with Transport / Base Plate</div> <div>Load rating of a swivel foot assembly is based on the part with the lowest load rating, typically the threaded rod.</div> <div>Example:</div> <div>Threaded rod load rating = 210kg [463lb]</div> <div>Swivel base load rating = 3000kg [6614lb]</div> <div>Swivel foot assembly load rating = 210kg [463lb]</div>												

# FATH® T-Slotted Rail Accessories



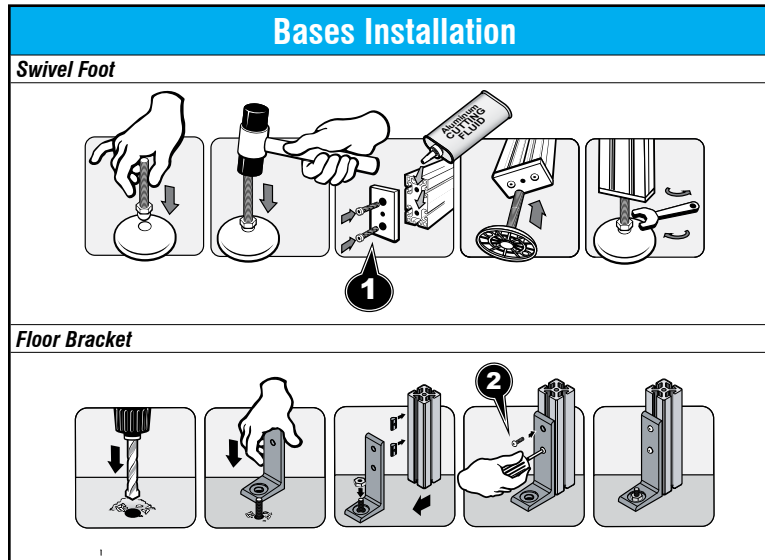











## Bases - Continued



# FATH® T-Slotted Rail Accessories

## Casters


- Recommended ADC Fastener based on part feature and attachment type
- Material: varies by part

15 Series Casters										
Fits		Slot Size 	<div>15 Series (inch)</div> <div></div> <div>1.5x1.5    1.5x3    3x3</div>							
Part Number	Part Image	Price	Description	Requires	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
						Core Hole Attachment <b>1</b>	*T-Slot Attachment <b>2</b>			
<a href="#">151134</a>		\$47.00	Swivel Caster (requires Swivel Caster Adapter Plate <a href="#">151136</a> )	n/a	122 [269]	<a href="#">161107</a>	n/a	1	Thermoplastic polyurethane/ nylon/steel	<a href="#">PDF</a>
<a href="#">151135</a>		\$40.50	Fixed Caster (requires Fixed Fixed Caster Adapter Plate <a href="#">161040</a> )			<a href="#">161106</a>				<a href="#">PDF</a>
<a href="#">151136</a>		\$4.50	<b>3</b> Swivel Caster Adapter Plate	Requires Swivel Caster <a href="#">151134</a> )	n/a	n/a	n/a		Steel	<a href="#">PDF</a>
<a href="#">161040</a>		\$3.25	<b>3</b> Fixed Fixed Caster Adapter Plate	Requires Fixed Caster <a href="#">151135</a>					Die-cast zinc	<a href="#">PDF</a>
<a href="#">151137</a>		\$62.00	Swivel Caster	n/a	122 [269]	n/a	<a href="#">161053</a>	Thermoplastic polyurethane/ nylon/steel	<a href="#">PDF</a>	
<a href="#">151138</a>		\$49.00	Fixed Caster				<a href="#">PDF</a>			
<a href="#">163010</a>		\$40.00	Leveling Caster	Transport / Base Plate with M12-1.75 threaded hole	250 [551]		n/a	Die-cast aluminum/ steel/nylon/ rubber	<a href="#">PDF</a>	
<a href="#">163011</a>		\$52.00			500 [1102]				<a href="#">PDF</a>	
<a href="#">163012</a>		\$41.00		n/a	250 [551]	<a href="#">151040</a>			<a href="#">PDF</a>	
<a href="#">163013</a>		\$56.00			500 [1102]				<a href="#">PDF</a>	
*T-Slot Nut also required										

\*T-Slot Nut also required

# FATH® T-Slotted Rail Accessories

## Casters - Continued

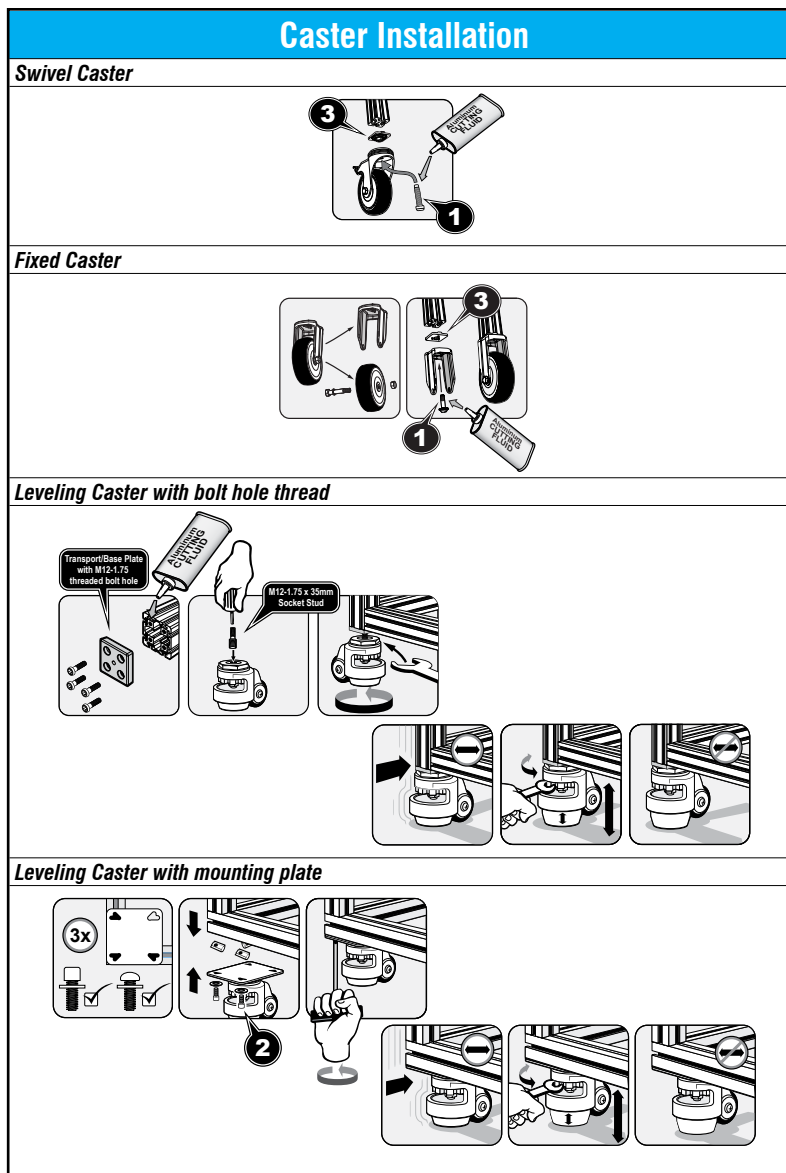





# FATH® T-Slotted Rail Accessories


## Panel and Door Elements









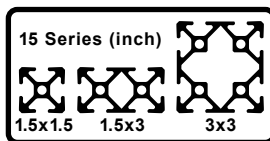



- Recommended ADC Fastener based on part feature and slot depth
- Material: varies by part



### 15 Series Panel and Door Elements

Fits Slot Size 8









Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Pack Quantity	Material	Drawing Link
<a href="#">151146</a>		\$6.00	Bridge Handle	<a href="#">161048</a>	1	Fiberglass reinforced plastic	<a href="#">PDF</a>
<a href="#">151147</a>		\$6.00		<a href="#">151100</a>			<a href="#">PDF</a>
<a href="#">151148</a>		\$6.25	Cover Cap <b>3</b>	n/a			<a href="#">PDF</a>
<a href="#">151149</a>		\$6.50	Comfort Handle	<a href="#">161054</a>			<a href="#">PDF</a>
<a href="#">151150</a>		\$2.25	Cover Cap <b>3</b>	n/a			<a href="#">PDF</a>
<a href="#">151151</a>		\$12.50	Comfort Handle	<a href="#">161054</a>			<a href="#">PDF</a>
<a href="#">151152</a>		\$3.00	Cover Cap <b>3</b>	n/a			<a href="#">PDF</a>
<a href="#">151153</a>		\$33.50	Machine Handle	<a href="#">151100</a>			<a href="#">PDF</a>
<a href="#">151154</a>		\$47.00	Compact Slam Latch	<a href="#">161050</a>		Die-cast aluminum	<a href="#">PDF</a>
<a href="#">151155</a>		\$58.00	Compact Sliding Door Latch				<a href="#">PDF</a>
<a href="#">151156</a>		\$37.00	Emergency Opener	<a href="#">161087</a>	Fiberglass reinforced plastic	<a href="#">PDF</a>	
<a href="#">151157</a>		\$7.25	Ball Catch	<a href="#">161051</a>		<a href="#">PDF</a>	

\*T-Slot Nut also required

\*T-Slot Nut also required

# FATH® T-Slotted Rail Accessories

## Panel and Door Elements - Continued


15 Series Panel and Door Elements - Continued							
<div><div>Fits</div><div><div>15 Series (inch)</div><div></div><div>1.5x1.5    1.5x3    3x3</div></div></div>							
Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Pack Quantity	Material	Drawing Link
<a href="#">151158</a>		\$14.50	Double Ball Catch	<a href="#">161076</a>	1	Brass	<a href="#">PDF</a>
<a href="#">151159</a>		\$23.00	Door Latch	<a href="#">161087</a>		Die-cast zinc	<a href="#">PDF</a>
<a href="#">162963</a>		\$8.50	Magnetic Catch	<a href="#">161048</a>		Nylon/steel	<a href="#">PDF</a>
<a href="#">162911</a>		\$5.00	Panel Holder	<a href="#">151100</a>		Anodized aluminum	<a href="#">PDF</a>
<a href="#">162916</a>		\$6.00					<a href="#">PDF</a>
<a href="#">162922</a>		\$5.75	Panel Mount Block	Fasteners included		Lacquered aluminum	<a href="#">PDF</a>
<a href="#">162923</a>		\$5.75				Powder-coated aluminum	<a href="#">PDF</a>
<a href="#">162977</a>		\$8.50	Hanger	<a href="#">161050</a>	10	Die-cast zinc	<a href="#">PDF</a>
<a href="#">162978</a>		\$3.00	Panel Uni-Block	n/a		Nylon	<a href="#">PDF</a>
<a href="#">162979</a>		\$3.00					<a href="#">PDF</a>
*T-Slot Nut also required							

# FATH® T-Slotted Rail Accessories

## Panel and Door Elements - Continued

### 15 Series Panel and Door Elements - Continued

Fits

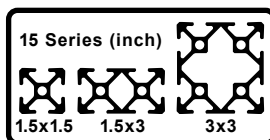


Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Pack Quantity	Material	Drawing Link
<a href="#">151160</a>		\$56.00	Sealing Strip	n/a	2	PVC/TPE	<a href="#">PDF</a>
<a href="#">151163</a>		\$25.00	Cover Profile		1	Nitrile rubber	<a href="#">PDF</a>
<a href="#">162928</a>		\$500.00	Sealing Profile			Nitrile rubber	<a href="#">PDF</a>
<a href="#">151165</a>		\$87.00	Cover Profile		25	Polypropylene	<a href="#">PDF</a>
<a href="#">151164</a>		\$110.00	Cover And Reduction Profile				<a href="#">PDF</a>


\*T-Slot Nut also required

### Panel and Door Elements Installation


#### Bridge Handle and Cover Cap

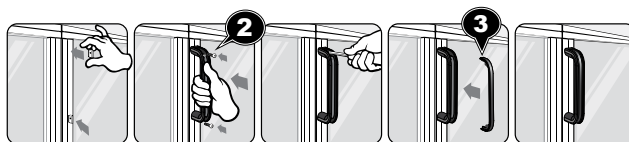


#### Comfort Handle and Cover Cap

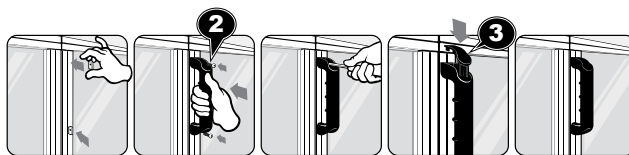

#### Slam Latch

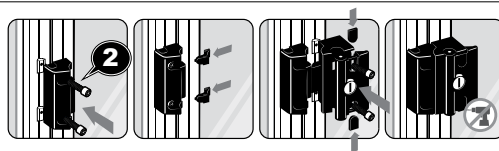

#### Sliding Door Latch

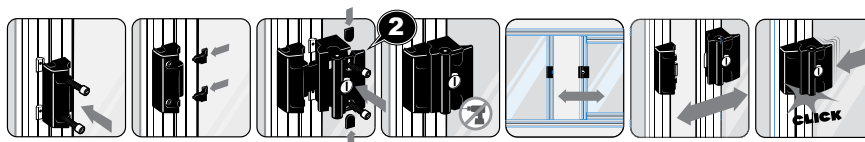


# FATH® T-Slotted Rail Accessories


## Panel and Door Elements - Continued

### Panel and Door Elements Installation - Continued


#### Emergency Opener

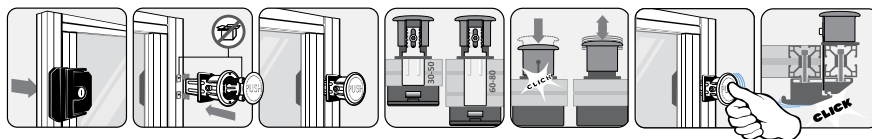


#### Ball Catch

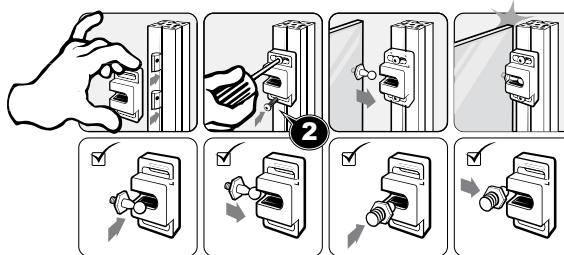


#### Magnetic Catch

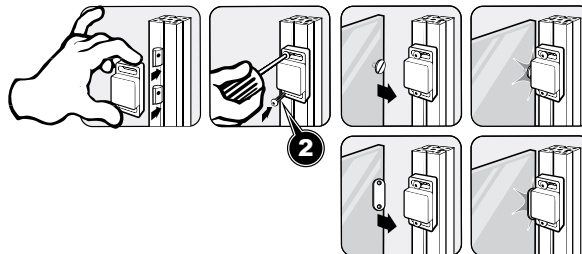


#### Panel Mount Block

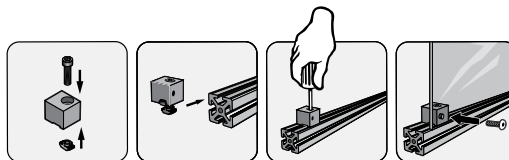


#### Door Latch

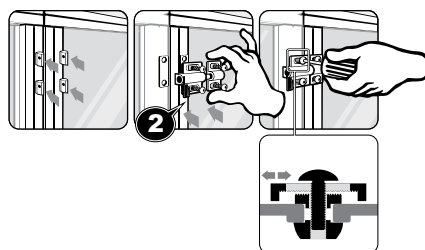

#### Cover and Reduction Profile

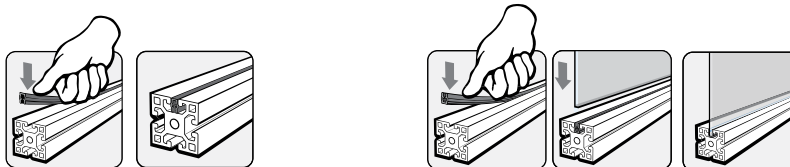


#### Sealing Profile

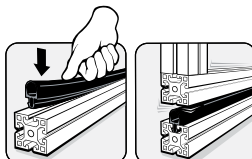

# FATH® T-Slotted Rail Accessories

## Panel and Door Elements - Continued

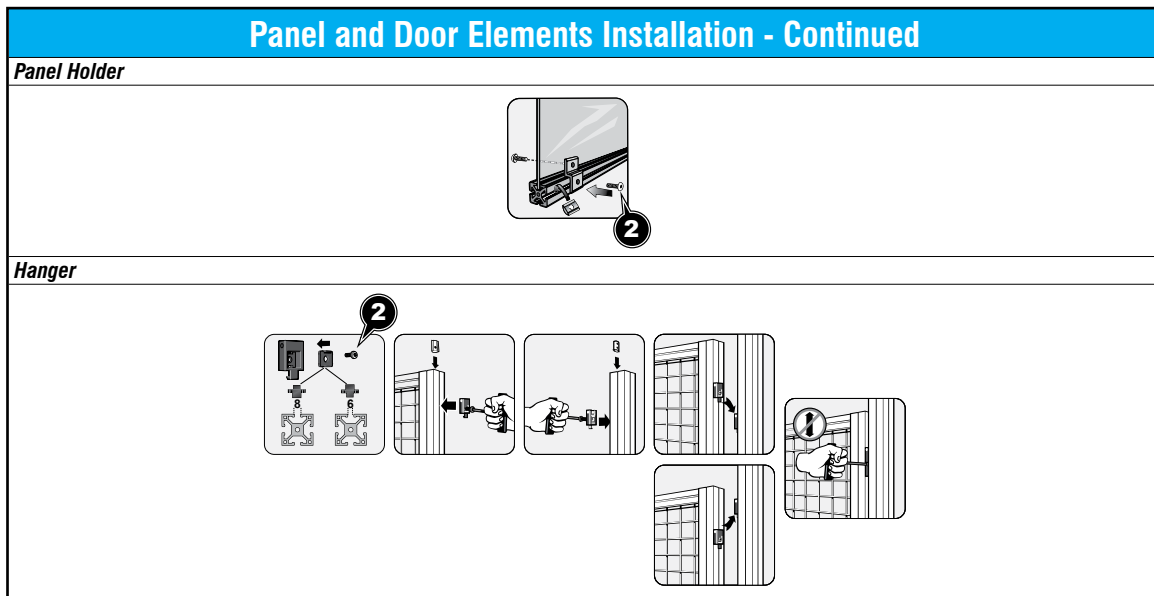

# FATH® T-Slotted Rail Accessories

## Slides and Rollers




### Linear Bearings

- No Shimming required!
- Verified fit with SureFrame 15 & 40 Series
- Static Load rating (Co) up to 4,000 N (900 lbf)
- Single and Double Flange Styles
- Available in Black or Silver
- Optional Brake Assemblies

**Note:** Not all Slot size 8 profiles are made the same, so it is important to confirm that the "a2" dimension of the profile is 3.0-4.5mm for adequate engagement and ultimate slide performance.





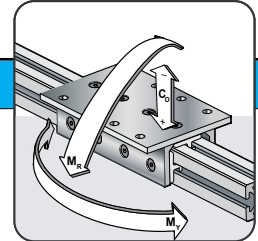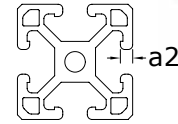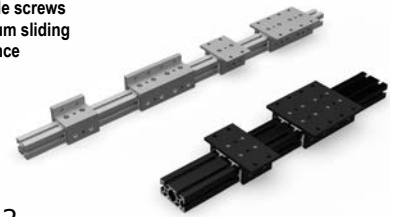









Adjust side screws  
for optimum sliding  
performance



## 15 Series Slides and Rollers

Fits  
Slot Size  
8



Part Number	Part Image	Price	Description	Fits	Pack Quantity	Load Ratings				Material	Drawing Link	
						Static (Co) N[lbf]	Reverse Static (-Co) N[lbf]	Roll Moment (Mr) N-m[lbf-ft]	Yaw Moment (My) N-m[lbf-ft]			
<a href="#">166337</a>		\$60.00	3-slot, double flange, short linear bearing	1.5 x 1.5 in, 1.5 x 3in,	1	1000 [225]	500 [112]	40 [29]	150 [111]	Aluminum/ die-cast zinc/ polyoxymethylene (POM)	<a href="#">PDF</a>	
<a href="#">166338</a>		\$60.00									<a href="#">PDF</a>	
<a href="#">166339</a>		\$120.00				3-slot, double flange, long linear bearing	2000 [450]	1000 [225]	80 [59]		200 [147]	<a href="#">PDF</a>
<a href="#">166340</a>		\$130.00										<a href="#">PDF</a>
<a href="#">166341</a>		\$80.00	4-slot, double flange, short linear bearing	1.5 x 3in, 3 x 3in		2000 [450]	1000 [225]	50 [37]	150 [111]		<a href="#">PDF</a>	
<a href="#">166342</a>		\$80.00									<a href="#">PDF</a>	
<a href="#">166343</a>		\$150.00	4-slot, double flange, long linear bearing			4000 [889]	2000 [450]	100 [74]	200 [147]		<a href="#">PDF</a>	
<a href="#">166344</a>		\$160.00									<a href="#">PDF</a>	
<a href="#">166345</a>		\$60.00	3-slot, single flange, short linear bearing	1.5 x 1.5 in, 1.5 x 3in,		1000 [225]	500 [112]	40 [29]	150 [111]		<a href="#">PDF</a>	
<a href="#">166346</a>		\$60.00									<a href="#">PDF</a>	
<a href="#">166347</a>		\$120.00	3-slot, single flange, long linear bearing			2000 [450]	1000 [225]	80 [59]	200 [147]		<a href="#">PDF</a>	
<a href="#">166348</a>		\$120.00									<a href="#">PDF</a>	




# FATH® T-Slotted Rail Accessories




## Slides and Rollers - Continued



### 15 Series Slides and Rollers - Cont'd

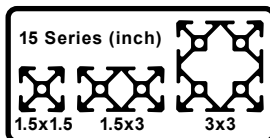Fits

Slot Size  
8


Part Number	Part Image	Price	Description	Fits	Pack Quantity	Recommended Screw Fastener T-Slot Attachment <b>2</b>	Material	Drawing Link		
<a href="#">166349</a>		\$45.00	Cam Lever Brake	All 15 Series Linear Bearings	1	n/a	Plastic/steel	<a href="#">PDF</a>		
<a href="#">166350</a>		\$28.00	L-Handle Brake					<a href="#">PDF</a>		
<a href="#">151168</a>		\$18.00	Slider	n/a		Fasteners included	Rubber/plastic/ steel	<a href="#">PDF</a>		
<a href="#">151169</a>		\$36.00	Slider With Clamp Lever					<a href="#">PDF</a>		
<a href="#">148974</a>		\$9.50	Roller					n/a	Nylon	<a href="#">PDF</a>
<a href="#">151166</a>		\$4.50	Slider							Glass-filled nylon
<a href="#">151089</a>		\$4.50	Snap Hook	Slider <a href="#">151166</a>		Fasteners included	Zinc plated steel	<a href="#">PDF</a>		
<a href="#">163020</a>		\$13.75	Roller Element With Guide	All 15 Series			Thermoplastic polyurethane/ nylon/steel	<a href="#">PDF</a>		
<a href="#">163021</a>		\$14.50	Roller Element Without Guide					<a href="#">PDF</a>		

# FATH® T-Slotted Rail Accessories

## Slides and Rollers - Continued


### Slides and Rollers Installation

#### Roller

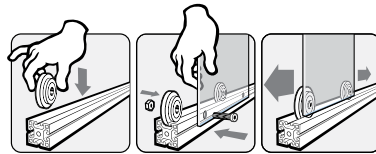


Bolt and nut not included  
and not available from  
AutomationDirect


#### Slider and Snap Hook

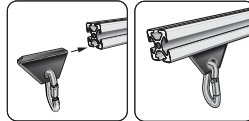


#### Slider

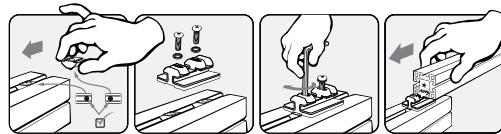


#### Slider with Clamp Lever

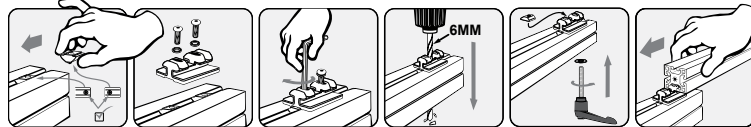


#### Roller Element

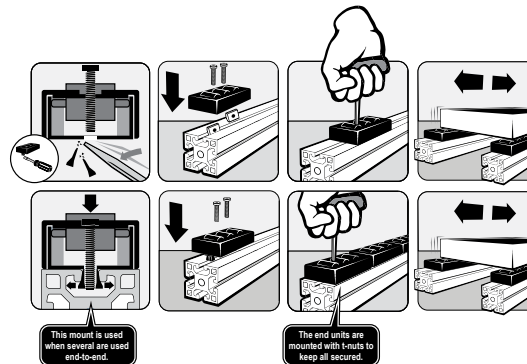

#### L-Handle Brake

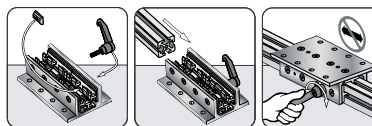

#### Cam Lever Brake

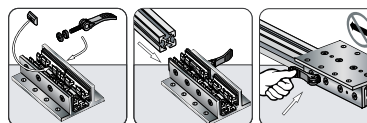

# FATH® T-Slotted Rail Accessories



## Monitor Mounts






### 15 Series Monitor Mounts

- Fits monitors with VESA mounting standard
- Durable steel construction
- Mounting hardware included for several mounting locations

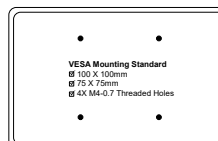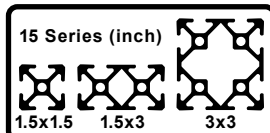Fits Slot Size 8




Part Number	Part Image	Price	Description	Load Rating kg [lb]	Pack Quantity	Installation Instructions Link	Drawing Link
<a href="#">162893</a>		\$42.00	Swivel Monitor Mount	15 [33.1]	1	<a href="#">PDF</a>	<a href="#">PDF</a>
<a href="#">162894</a>		\$50.00				<a href="#">PDF</a>	<a href="#">PDF</a>
<a href="#">162895</a>		\$58.00				<a href="#">PDF</a>	<a href="#">PDF</a>
<a href="#">162896</a>		\$92.00	Monitor Mounting Joint			<a href="#">PDF</a>	<a href="#">PDF</a>
<a href="#">162897</a>		\$92.00	Monitor Holder			<a href="#">PDF</a>	<a href="#">PDF</a>
<a href="#">162899</a>		\$325.00	4-Axis Mounting Support	10 [22.0]		<a href="#">PDF</a>	<a href="#">PDF</a>
<a href="#">162900</a>		\$375.00	5-Axis Mounting Support			<a href="#">PDF</a>	<a href="#">PDF</a>
<a href="#">162901</a>		\$600.00	4-Axis Workstation	8 [17.6]		<a href="#">PDF</a>	<a href="#">PDF</a>


# FATH® T-Slotted Rail Accessories

## Monitor Mounts - Continued


### Monitor Mounts Adjustments

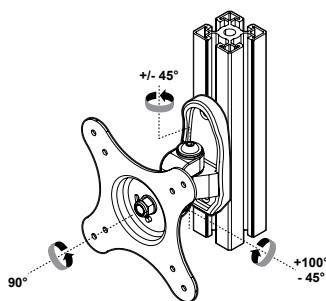


162893

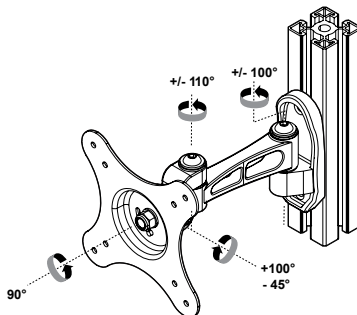


162894

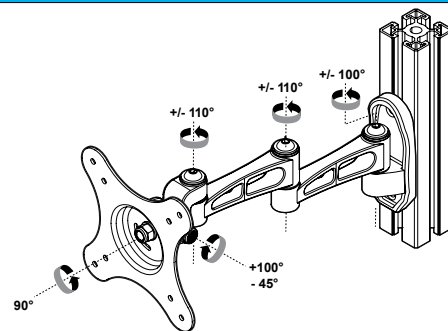


162895

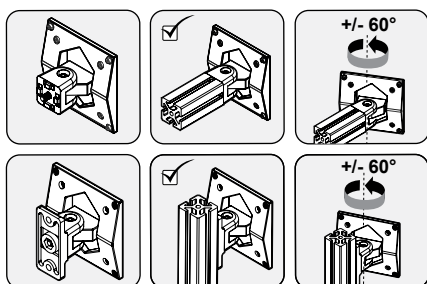


162896

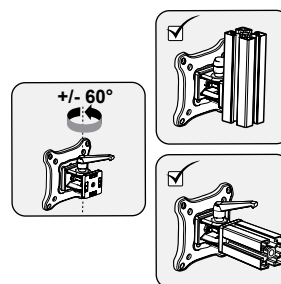


162897

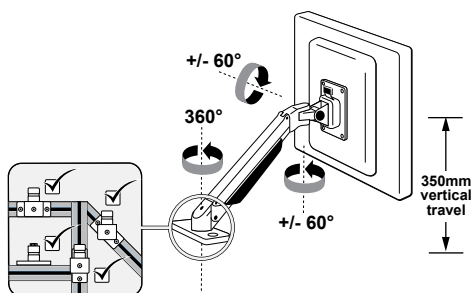

162899

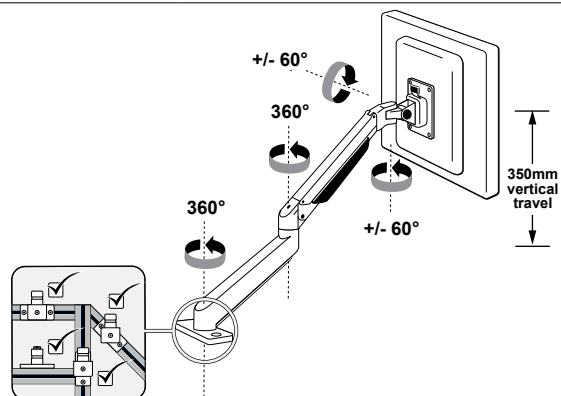

162900

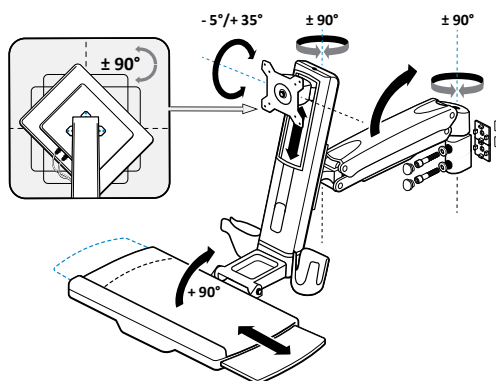

162901


# FATH® T-Slotted Rail Accessories





## Workstation Components

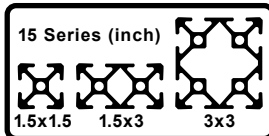

### 15 Series Workstation Components


Fits  Slot Size 8




Part Number	Part Image	Price	Description	Load Rating kg [lb]	Pack Quantity	Material	Drawing Link
<a href="#">162902</a>		\$185.00	Keyboard Holder (requires mounting solution, designer's choice)	n/a	1	Aluminum/nylon	<a href="#">PDF</a>
<a href="#">162906</a>		\$8.00	Magnetic Holder			Nylon/steel	<a href="#">PDF</a>
<a href="#">162964</a>		\$9.00	Grab Tray			Nylon	<a href="#">PDF</a>
<a href="#">162965</a>		\$2.00	Label Clip			PVC	<a href="#">PDF</a>

### Workstation Components Installation


#### Keyboard Holder (mounting example)

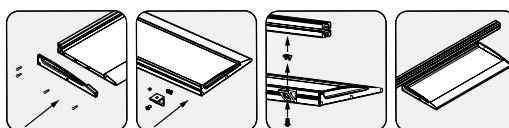


#### Magnetic Holder

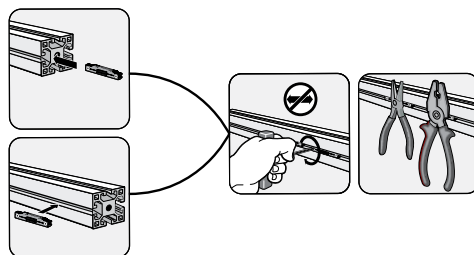

#### Grab Tray

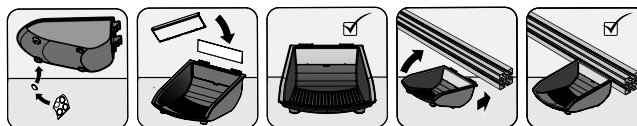

#### Label Clip

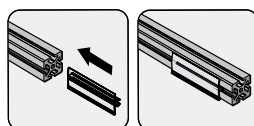


# FATH® T-Slotted Rail Accessories






## Wire Management

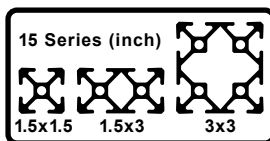

### 15 Series Wire Management

Fits Slot Size  
8




Part Number	Part Image	Price	Description	Pack Quantity	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Material	Drawing Link
<a href="#">151162</a>		\$89.00	Conduit Cover 2000mm long	2	n/a	Polypropylene	<a href="#">PDF</a>
<a href="#">151174</a>		\$15.50	Cross Cable Binding Block	10		Nylon	<a href="#">PDF</a>
<a href="#">151175</a>		\$64.00	Hook And Loop			Glass-filled nylon/ polypropylene	<a href="#">PDF</a>
<a href="#">151176</a>		\$38.50	Clip Cable Binder With Hammer			Nylon/rubber	<a href="#">PDF</a>
<a href="#">151177</a>		\$28.50	Ground Connector	1	Fasteners included	Glass-filled nylon/ copper/steel	<a href="#">PDF</a>
<a href="#">151178</a>		\$4.00	Grounding Terminal			Steel/brass	<a href="#">PDF</a>
<a href="#">162982</a>		\$7.50	Universal Cable Binder Block	10	<a href="#">161046</a>	Nylon	<a href="#">PDF</a>

\*T-Slot Nut also required

### Wire Management Installation

#### Universal Cable Binder Block

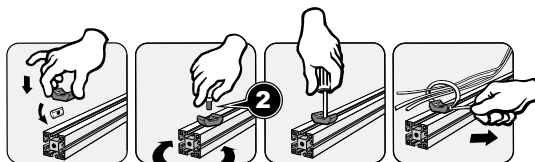


# FATH® T-Slotted Rail Accessories







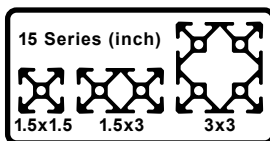


## Miscellaneous Accessories



### 15 Series Miscellaneous Accessories

Fits  Slot Size 8







Part Number	Part Image	Price	Description	Requires	Fits Profile	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Pack Quantity	Material	Drawing Link	
<a href="#">151171</a>		\$16.50	End Cap	n/a	1.5 x 1.5in	n/a	10	Glass-filled nylon	<a href="#">PDF</a>	
<a href="#">151172</a>		\$21.00			1.5 x 3in				<a href="#">PDF</a>	
<a href="#">151173</a>		\$37.00			3 x 3in				<a href="#">PDF</a>	
<a href="#">151091</a>		\$6.00	Stop Bumper	All 15 Series			1	Rubber/zinc-plated steel	<a href="#">PDF</a>	
<a href="#">151170</a>		\$9.00							<a href="#">PDF</a>	
<a href="#">162973</a>		\$3.25	Sensor Mounting Block for 8mm proximity sensor			BHCS 8-32 x 1" (not sold by ADC)	Nylon	<a href="#">PDF</a>		
<a href="#">162974</a>		\$3.25	Sensor Mounting Block for 12mm proximity sensor					<a href="#">PDF</a>		
<a href="#">162929</a>		\$240.00	Side Protection Profile			n/a	5	Thermoplastic rubber	<a href="#">PDF</a>	
<a href="#">162930</a>		\$270.00	Corner Protection Profile						<a href="#">PDF</a>	
<a href="#">162931</a>		\$28.00	Cover Cap for Side				10		<a href="#">PDF</a>	
<a href="#">162932</a>		\$20.00	Cover Cap for Corner						<a href="#">PDF</a>	

\*T-Slot Nut also required

# FATH<sup>®</sup> T-Slotted Rail Accessories

## Miscellaneous Accessories - Continued

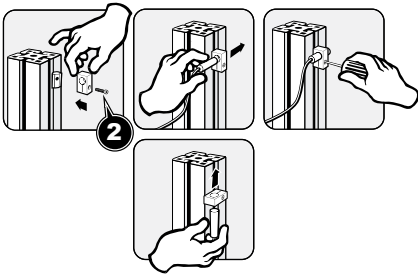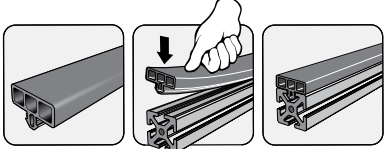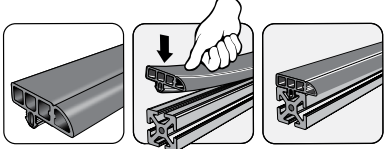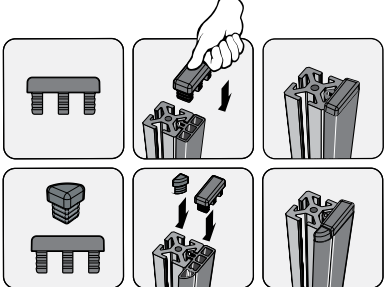Miscellaneous Installation		
<b>Sensor Mounting Block</b>		
		
<b>Side Protection Profile</b>		
		
<b>Corner Protection Profile</b>		
		
<b>Cover Cap for Side</b>		
		
<b>Cover Cap for Corner</b>		
