



# Aluminum T-Slotted Rail

## 30 Series Metric T-Slotted Aluminum Rail

SureFrame™ T-slotted aluminum rails are extruded exclusively for AutomationDirect, with features, quality, and performance you expect. SureFrame T-slotted rails are compatible with other popular brands.

- Cut to length in 0.01 cm increments
- Minimum cut length: 15.24 cm
- Maximum cut length: 228.0 cm
- Cut accuracy: +/- 0.015 cm [0.15mm]
- Corrosion and UV resistant



Properties	
<b>Material</b>	Aluminum 6063-T6
<b>Finish</b>	Clear Anodize
<b>Hardness</b>	Webster Model B 11-12
<b>Straightness</b>	0.0125 inch/ft [1.042 mm/m]
<b>Twist</b>	0.25°/ft [0.25°/305mm]



30 Series (metric)								
Slot Size  8 Core Hole Ø 7.3 mm			30 Series (mm)			2° <b>Drop Lock</b> T-Slot Drop Lock feature improves connection strength and vibration resistance		
Part Number	Part Image	Price per cm	Profile Size	Weight Class	Weight lbs/ft [kg/m]	Moment of Inertia Lx (in <sup>4</sup> [cm <sup>4</sup> ])	Moment of Inertia Ly (in <sup>4</sup> [cm <sup>4</sup> ])	Drawing Link
<a href="#">30-3030C</a>		\$0.11	30 x 30mm	Standard	0.605 [0.900]	0.068 [2.829]	0.068 [2.829]	<a href="#">PDF</a>
<a href="#">30-3060C</a>		\$0.18	30 x 60mm		1.058 [1.574]	0.130 [5.408]	0.473 [19.677]	<a href="#">PDF</a>
<a href="#">30-6060C</a>		\$0.27	60 x 60mm		1.681 [2.502]	0.871 [36.234]	0.871 [36.234]	<a href="#">PDF</a>

Extruded T-slotted rails have a thru Core Hole feature that can be used to attach various components to the end of the profile using:

- Self-tapping / thread-forming screws (no tapping needed)
- A tap to thread the core hole for a threaded fastener



Please Note: Prices on aluminum are closely tied to the market price. This allows us to offer the best savings possible if conditions are favorable; however, it also means that our prices may increase if market conditions warrant.



# Aluminum T-Slotted Rail

## Deflection Calculations

Using the calculations below, find your approximate deflection\* for a specific extrusion.  
See table below for variations.

**As always when calculating, use diligence and work only in either imperial or metric units at one time.**

"E" = Modulus of Elasticity

"F" = Force

"I" = Moment of Inertia

 
"L" = Length

"W" = Weight

*\*for reference only*


### Supported Loads

CONCENTRATED LOAD AT CENTER (simply supported)




$$\text{MAX DEFLECTION} = \frac{FL^3}{48 EI}$$

 UNIFORMLY DISTRIBUTED LOAD (simply supported)




$$\text{MAX DEFLECTION} = \frac{5}{84} \frac{WL^4}{EI}$$

 CONCENTRATED LOAD AT CENTER (between fixed supports)



$$\text{MAX DEFLECTION} = \frac{FL^3}{192 EI}$$

 UNIFORMLY DISTRIBUTED LOAD (between fixed supports)




$$\text{MAX DEFLECTION} = \frac{WL^4}{384 EI}$$

### Aluminum 6063-T6 Properties

<b>Yield Strength</b>	29,007 psi [200 MPa]
<b>Tensile Strength</b>	33,359 psi [230 MPa]
<b>Modulus of Elasticity</b>	10,000,000 psi [68.9 GPa]


### Cantilever Loads

CONCENTRATED LOAD AT CENTER (simply supported)

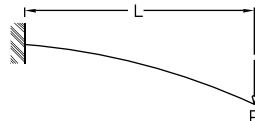

$$\text{MAX DEFLECTION} = \frac{FL^3}{3 EI}$$

UNIFORMLY DISTRIBUTED LOAD (simply supported)

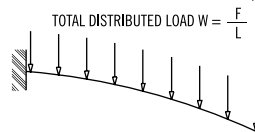









$$\text{MAX DEFLECTION} = \frac{WL^4}{8 EI}$$



# FATH® T-Slotted Rail Accessories

## T-Slot Nuts - Continued

30 Series T-Slot Nuts - Continued						
<div><div>Fits</div><div>Slot Size</div><div>8</div><div><div>30 Series (mm)</div><div><div></div><div></div><div></div></div><div><div>30x30</div><div>30x60</div><div>60x60</div></div></div></div>						
Part Number	Part Image	Price	Nut Type	Thread Size	Pack Quantity	Drawing Link
<a href="#">151179</a>		\$6.50	Economy T-Nut	M6-1.0	10	<a href="#">PDF</a>
<a href="#">151180</a>		\$5.25	Double Economy T-Nut		4	<a href="#">PDF</a>
<a href="#">151181</a>		\$9.00	Hammer Nut		10	<a href="#">PDF</a>
<a href="#">161118</a>		\$16.75	Roll-In Nut	M8-1.25		<a href="#">PDF</a>
<a href="#">151182</a>		\$19.00				<a href="#">PDF</a>

# FATH® T-Slotted Rail Accessories

## Fasteners

- Choose from 4 Head types in numerous lengths
- Hex socket head
- Select desired T-Slot nut style with corresponding thread size.
- Material: Black zinc plated or bright zinc plated steel, prevents corrosion better than typical black oxide coatings



30 Series Fasteners								
Fits		Slot Size 8	<div>30 Series (mm)</div> <div><div>30x30</div><div>30x60</div><div>60x60</div></div>					
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#">162994</a>		\$8.00	#8-32 UNF	3/8 in	Button head socket cap screw	Flat black	10	<a href="#">PDF</a>
<a href="#">161073</a>		\$7.75		1/2 in	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">162993</a>		\$7.50	#10-32 UNF	3/8 in	Button head socket cap screw			<a href="#">PDF</a>
<a href="#">162995</a>		\$7.75		1/2 in	Socket head cap screw			<a href="#">PDF</a>
<a href="#">161046</a>		\$4.75			5/8 in			Button head socket cap screw
<a href="#">161047</a>		\$5.00		<a href="#">PDF</a>				
<a href="#">161048</a>		\$5.75		3/4 in				
<a href="#">161074</a>		\$6.25	1/4-20 UNC	1/2 in	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">151040</a>		\$4.25			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">151041</a>		\$5.25			Flanged button head socket cap screw	Gloss black		<a href="#">PDF</a>
<a href="#">161049</a>		\$4.50		9/16 in	Button head socket cap screw	Flat black		<a href="#">PDF</a>
<a href="#">161075</a>		\$6.25		5/8 in	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161050</a>		\$4.75			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161087</a>		\$4.00			Socket head cap screw			<a href="#">PDF</a>



 















# FATH® T-Slotted Rail Accessories

## Fasteners - Continued

30 Series Fasteners - Continued								
<div>Fits</div>		<div>Slot Size</div> <div>8</div>	<div>30 Series (mm)</div> <div><div><div></div><div>30x30</div></div><div><div></div><div>30x60</div></div><div><div></div><div>60x60</div></div></div>					
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#">161051</a>		\$4.75	1/4-20 UNC	3/4 in	Button head socket cap screw	Flat black	10	<a href="#">PDF</a>
<a href="#">161052</a>		\$5.25		1 in				<a href="#">PDF</a>
<a href="#">161088</a>		\$2.25	M4-0.7	8mm	Socket head cap screw	<a href="#">PDF</a>		
<a href="#">161089</a>		\$2.50		10mm		<a href="#">PDF</a>		
<a href="#">161056</a>		\$1.00		10mm	Button head socket cap screw	<a href="#">PDF</a>		
<a href="#">161076</a>		\$1.50		12mm	Flat head socket cap screw	<a href="#">PDF</a>		
<a href="#">161057</a>		\$1.25	M5-0.8	10mm	Button head socket cap screw	<a href="#">PDF</a>		
<a href="#">161090</a>		\$2.50			Socket head cap screw	<a href="#">PDF</a>		
<a href="#">161077</a>		\$1.75		12mm	Flat head socket cap screw	<a href="#">PDF</a>		
<a href="#">161091</a>		\$2.50			Socket head cap screw	<a href="#">PDF</a>		
<a href="#">161058</a>		\$1.75			Button head socket cap screw	<a href="#">PDF</a>		
<a href="#">161092</a>		\$2.50	M6-1.0	10mm	Socket head cap screw	<a href="#">PDF</a>		
<a href="#">161078</a>		\$2.25		12mm	Flat head socket cap screw	<a href="#">PDF</a>		
<a href="#">161059</a>		\$2.00			Button head socket cap screw	<a href="#">PDF</a>		
<a href="#">161093</a>		\$2.75			Socket head cap screw	<a href="#">PDF</a>		














# FATH® T-Slotted Rail Accessories

## Fasteners - Continued

30 Series Fasteners - Continued								
Fits		Slot Size 8	<div> <div>30 Series (mm)</div> <div>    </div> <div>30x30 30x60 60x60</div> </div>					
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#">161079</a>		\$2.50	M6-1.0	14mm	Flat head socket cap screw	Bright zinc	10	<a href="#">PDF</a>
<a href="#">161060</a>		\$2.25			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161094</a>		\$2.75			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161080</a>		\$2.50		16mm	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161061</a>		\$2.50			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161095</a>		\$2.75			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161062</a>		\$2.75		18mm	Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161096</a>		\$3.00			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161081</a>		\$2.50		20mm	Flat head socket cap screw			<a href="#">PDF</a>
<a href="#">161063</a>		\$2.75			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161097</a>		\$3.25			Socket head cap screw			<a href="#">PDF</a>
<a href="#">161064</a>		\$3.25		25mm	Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161082</a>		\$4.75	M8-1.25	12mm	Flat head socket cap screw	Bright zinc	10	<a href="#">PDF</a>
<a href="#">161065</a>		\$4.25			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161098</a>		\$4.75			Socket head cap screw			<a href="#">PDF</a>

# FATH® T-Slotted Rail Accessories

## Fasteners - Continued

30 Series Fasteners - Continued										
<div>Fits</div>		<div>Slot Size</div> <div>8</div>	<div>30 Series (mm)</div> <div><div><div></div><div>30x30</div></div><div><div></div><div>30x60</div></div><div><div></div><div>60x60</div></div></div>							
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link		
<a href="#">161066</a>		\$4.50	M8-1.25	14mm	Button head socket cap screw	Bright zinc	10	<a href="#">PDF</a>		
<a href="#">161083</a>		\$5.00			Flat head socket cap screw			<a href="#">PDF</a>		
<a href="#">161099</a>		\$5.00			Socket head cap screw			<a href="#">PDF</a>		
<a href="#">161084</a>		\$5.50		16mm	Flat head socket cap screw			<a href="#">PDF</a>		
<a href="#">161100</a>		\$5.50			Socket head cap screw			<a href="#">PDF</a>		
<a href="#">161067</a>		\$4.50			Button head socket cap screw			Gloss black	<a href="#">PDF</a>	
<a href="#">151183</a>		\$4.75							Flanged button head socket cap screw	<a href="#">PDF</a>
<a href="#">151184</a>		\$5.50								<a href="#">PDF</a>
<a href="#">161085</a>		\$5.50		18mm	Flat head socket cap screw	Bright zinc		<a href="#">PDF</a>		
<a href="#">161068</a>		\$5.00			Button head socket cap screw			<a href="#">PDF</a>		
<a href="#">161101</a>		\$5.50			Socket head cap screw			<a href="#">PDF</a>		
<a href="#">151241</a>		\$4.50		20mm	Button head socket cap screw			<a href="#">PDF</a>		
<a href="#">161102</a>		\$5.75			Socket head cap screw			<a href="#">PDF</a>		







# FATH® T-Slotted Rail Accessories

## Fasteners - Continued

### 30 Series Fasteners - Continued

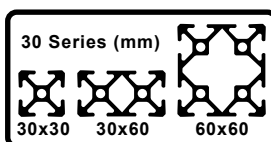
Fits



Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#">161086</a>		\$7.00	M8-1.25	25mm	Flat head socket cap screw	Bright zinc	10	<a href="#">PDF</a>
<a href="#">161069</a>		\$5.25			Button head socket cap screw			<a href="#">PDF</a>
<a href="#">161070</a>		\$8.00		40mm				<a href="#">PDF</a>

### 30 Series Self Forming / Tapping Screws


Fits

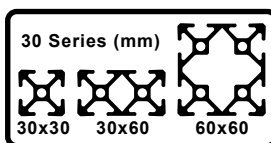

Works with Aluminum with hole diameter  
0.276" - 0.295" [7.0 - 7.5 mm]

Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
<a href="#"><u>161108</u></a>		\$9.25	S8	25mm	Self-Tapping Screw Flanged button head socket cap T-40 Torx	Bright zinc	10	<a href="#"><u>PDF</u></a>
<a href="#"><u>161109</u></a>		\$8.75			Self-Tapping Screw Flat head socket cap			<a href="#"><u>PDF</u></a>

### Self Forming / Tapping Screw Installation

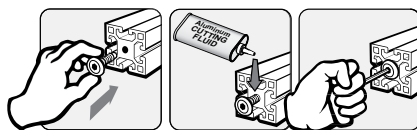

# FATH® T-Slotted Rail Accessories


## Connecting Components







- Connects two or three T-slot rails together
- Recommended ADC Fastener based on part feature, slot Depth and core hole
- Material: varies by part

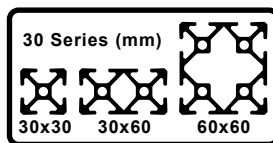

### 30 Series Connecting Components

Fits  Slot Size 8






 


Part Number	Part Image	Price	Description	Fits Profile	Material	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Drawing Link
						Core Hole Attachment 1	*T-Slot Attachment 2		
<a href="#">151185</a>		\$9.50	2d Cube Connector	30 x 30mm 30 x 60mm 60 x 60mm	Die-cast aluminum	Fasteners Included ( <a href="#">161085</a> )	<a href="#">161083</a>	1	<a href="#">PDF</a>
<a href="#">151186</a>		\$10.00	3d Cube Connector			<a href="#">161085</a>	n/a		<a href="#">PDF</a>
<a href="#">151187</a>		\$5.75	Angle Connector	30 x 30mm		<a href="#">151241</a> Requires manually tapping core hole to M8-1.25 x 20 DP	<a href="#">161066</a>		<a href="#">PDF</a>
<a href="#">151188</a>		\$9.75		30 x 60mm					<a href="#">PDF</a>
<a href="#">162961</a>		\$11.50	Miter Connector	30 x 30mm 30 x 60mm 60 x 60mm	Steel	n/a	M8-1.25 x 8mm set screw (4) included	10	<a href="#">PDF</a>
<a href="#">163008</a>		\$10.75	Screw Connector		Zinc plated steel	Designer's choice	n/a		<a href="#">PDF</a>

\*T-Slot Nut also required.

# FATH® T-Slotted Rail Accessories

## Connecting Components - Continued

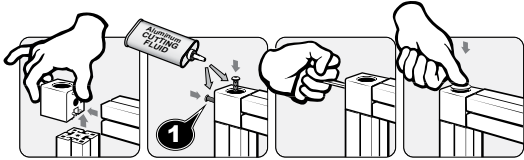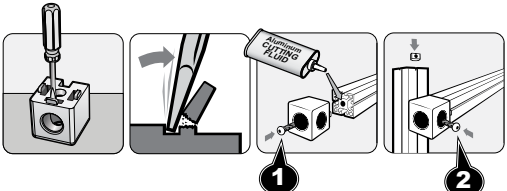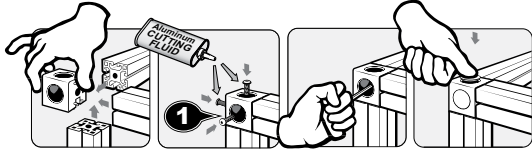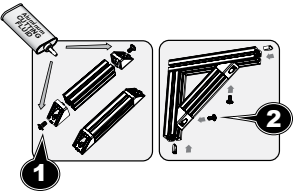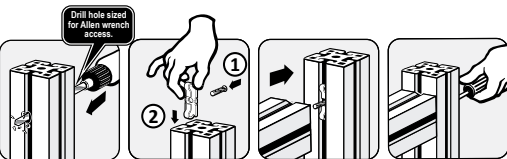







Connecting Components Installation	
Core Hole Installation	T-Slot Installation
<b>2D Cube Connector</b> 	
<b>3D Cube Connector</b> 	n/a
<b>Angle Connector</b> 	
<b>Screw Connector</b> 	
<b>Miter Connector</b> 	

# FATH® T-Slotted Rail Accessories

## Joining Plates

- Connects two or more T-slot rails together.
- Recommended ADC Fastener based on part feature and slot depth.
- Material: Anodized aluminum




 
 












30 Series Joining Plates						
Fits		Slot Size 8	<div>30 Series (mm)</div> <div><div>30x30</div><div>30x60</div><div>60x60</div></div>			
Part Number	Part Image	Price	Description	Recommended Screw Fastener - T-Slot Hole Attachment (ADC Part Number)	Pack Quantity	Drawing Link
<a href="#">151189</a>		\$4.50	Straight Flat Plate	<a href="#">161059</a>	1	<a href="#">PDF</a>
<a href="#">162985</a>		\$8.00				<a href="#">PDF</a>
<a href="#">151190</a>		\$5.50				<a href="#">PDF</a>
<a href="#">151191</a>		\$5.50	Square Flat Plate			<a href="#">PDF</a>
<a href="#">151192</a>		\$9.50	Rectangular Flat Plate			<a href="#">PDF</a>
<a href="#">151193</a>		\$9.50	Flat Plate			<a href="#">PDF</a>
<a href="#">151194</a>		\$10.00	T-Shaped Flat Plate			<a href="#">PDF</a>
<a href="#">162988</a>		\$18.00				<a href="#">PDF</a>

# FATH® T-Slotted Rail Accessories

## Brackets

- Connects two T-slot rails together at a 90° angle
- Recommended ADC Fastener based on part feature and slot depth
- Material: varies by part







30 Series Brackets								
Fits		Slot Size 8	<div>30 Series (mm)</div> <div><div>30x30</div><div>30x60</div><div>60x60</div></div>					
Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
				Core Hole Attachment 1	*T-Slot Attachment 2			
<a href="#">151195</a>		\$4.25	Inside Corner Bracket	n/a	<a href="#">161059</a>	1	Anodized aluminum	<a href="#">PDF</a>
<a href="#">151196</a>		\$5.25	Wide Inside Corner Bracket					<a href="#">PDF</a>
<a href="#">151197</a>		\$5.75	Tall Inside Corner Bracket					<a href="#">PDF</a>
<a href="#">151198</a>		\$11.00	Inside Corner Bracket					<a href="#">PDF</a>
<a href="#">162989</a>		\$2.25	Gusseted Inside Corner Bracket					<a href="#">PDF</a>
<a href="#">162990</a>		\$4.75	Tall Gusseted Inside Corner Bracket					<a href="#">PDF</a>
<a href="#">162991</a>		\$4.75	Wide Gusseted Inside Corner Bracket					<a href="#">PDF</a>
<a href="#">162992</a>		\$8.00	Gusseted Inside Corner Bracket					<a href="#">PDF</a>
<a href="#">151199</a>		\$28.50	Pivot Joint	<a href="#">161102</a> Requires manually tapping core hole to M8-1.25 x 20mm DP	<a href="#">161099</a>	1	Die-cast zinc	<a href="#">PDF</a>
<a href="#">151200</a>		\$38.50	Pivot Joint With Locking Handle					<a href="#">PDF</a>
<a href="#">163014</a>		\$27.50	1-Slot Pivot Joint	Not possible	<a href="#">161092</a>		Die-cast zinc/die-cast aluminum/nylon	<a href="#">PDF</a>
<a href="#">163017</a>		\$36.50	2-Slot Pivot Joint					<a href="#">PDF</a>

\*T-Slot Nut also required.

\*T-Slot Nut also required.

# FATH® T-Slotted Rail Accessories


## Brackets - Continued

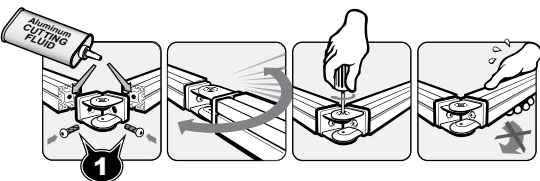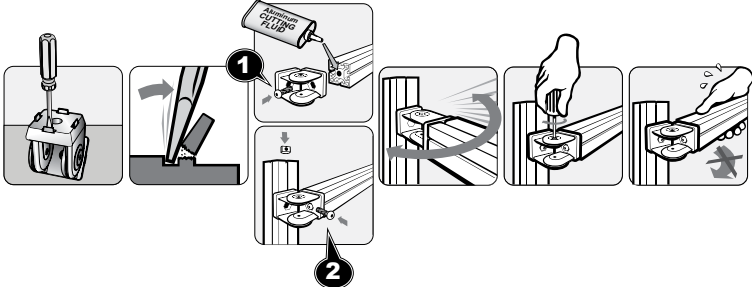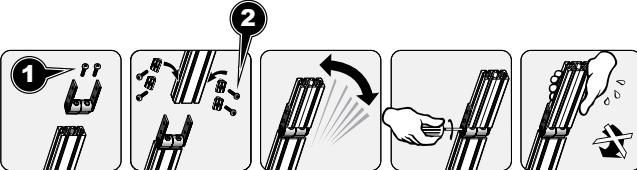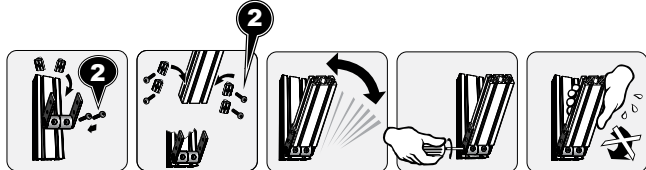Brackets Installation	
Core Hole Installation	T-Slot Installation
<p><b>Pivot Joint</b></p>  <p>Manually tap core hole for screw</p>	
<p><b>Pivot Joint</b></p> 	

# FATH® T-Slotted Rail Accessories


## Bases



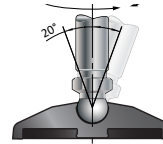





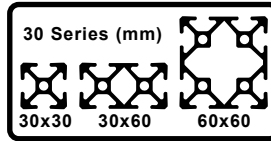


- Recommended ADC Fastener based on part feature and core hole
- Material: varies by part



### 30 Series Bases

Fits Slot Size 8



Part Number	Part Image	Price	Description	Fits	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link			
						Core Hole Attachment <b>1</b>	***T-Slot Attachment <b>2</b>						
<a href="#">162940</a>		\$11.00	M8-1.25 Transport/ Base Plate	30 x 60mm	n/a	<a href="#">161102</a> ** (2) included with kit		1	Die-cast zinc	<a href="#">PDF</a>			
<a href="#">162941</a>		\$11.00	M10-1.5 Transport/ Base Plate							<a href="#">PDF</a>			
<a href="#">162942</a>		\$11.00	M12-1.75 Transport/ Base Plate							<a href="#">PDF</a>			
<a href="#">162943</a>		\$17.50	M8-1.25 Transport/ Base Plate	60 x 60mm		<a href="#">161102</a> ** (4) included with kit				n/a			<a href="#">PDF</a>
<a href="#">162944</a>		\$17.75	M10-1.5 Transport/ Base Plate										<a href="#">PDF</a>
<a href="#">162945</a>		\$20.00	M12-1.75 Transport/ Base Plate										<a href="#">PDF</a>
<a href="#">162946</a>		\$20.00	M14-2.0 Transport/ Base Plate										<a href="#">PDF</a>
<a href="#">162947</a>		\$20.00	M16-2.0 Transport/ Base Plate										<a href="#">PDF</a>
<a href="#">151201</a>		\$3.75	M8-1.25 x 40mm Swivel Foot Threaded Rod with 15mm ball	Requires Transport / Base Plate <a href="#">162940</a> or <a href="#">162943</a>	350 [772]*	n/a			Zinc plated steel	<a href="#">PDF</a>			
<a href="#">151202</a>		\$4.00	M10-1.5 x 45mm Swivel Foot Threaded Rod with 15 mm ball	Requires Transport / Base Plate <a href="#">162941</a> or <a href="#">162944</a>	470 [1036]*					<a href="#">PDF</a>			
<a href="#">162938</a>		\$6.50	M16-2.0 x 100mm Swivel Foot Threaded Rod with 15mm ball	Requires Transport / Base Plate <a href="#">162947</a>	1450 [3197]					<a href="#">PDF</a>			

\*Based on installation with Transport / Base Plate

Load rating of a swivel foot assembly is based on the part with the lowest load rating, typically the threaded rod.

Example:

Threaded rod load rating = 210kg [463lb]

Swivel base load rating = 3000kg [6614lb]










Swivel foot assembly load rating = 210kg [463lb]

\*\*Requires tapping Core Hole (M8-1.25 x 20mm deep)

\*\*\*T-Slot Nut also required.

# FATH® T-Slotted Rail Accessories

## Bases - Continued


30 Series Bases - continued												
		Fits		Slot Size 8		<div>30 Series (mm)</div> <div><div>30x30</div><div>30x60</div><div>60x60</div></div>						
Part Number	Part Image	Price	Diameter	Description	Fits	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link	
							Core Hole Attachment 1	***T-Slot Attachment 2				
<a href="#">151068</a>		\$4.00	1.57 in [39.0 mm]	Swivel Base With Anti-Slip Plate	Any 15mm ball Threaded Rod	900 [1984]	n/a	n/a	1	Nylon	<a href="#">PDF</a>	
<a href="#">151071</a>		\$9.50								<a href="#">PDF</a>		
<a href="#">151072</a>		\$17.00	3000 [6614]			Die-cast zinc				<a href="#">PDF</a>		
<a href="#">151073</a>		\$17.00								<a href="#">PDF</a>		
<a href="#">151069</a>		\$6.00								900 [1984]	Nylon	<a href="#">PDF</a>
<a href="#">151070</a>		\$6.00										<a href="#">PDF</a>
<a href="#">162933</a>		\$12.50	see 2D drawing	Extended Swivel Base	1000 [2204]				Nylon	<a href="#">PDF</a>		
<a href="#">162934</a>		\$27.00			3000 [6613]				Die-cast zinc	<a href="#">PDF</a>		
<a href="#">162956</a>		\$11.00	n/a	Floor Bracket	30 x 30mm, 30 x 60mm, 60 x 60mm	n/a		<a href="#">161066</a>		Anodized aluminum	<a href="#">PDF</a>	

\*Based on installation with Transport / Base Plate  
Load rating of a swivel foot assembly is based on the part with the lowest load rating, typically the threaded rod.  
Example:  
Threaded rod load rating = 210kg [463lb]  
Swivel base load rating = 3000kg [6614lb]  
Swivel foot assembly load rating = 210kg [463lb]  
\*\*Requires tapping Core Hole (M8-1.25 x 20mm deep)  
\*\*\*T-Slot Nut also required.



# FATH® T-Slotted Rail Accessories



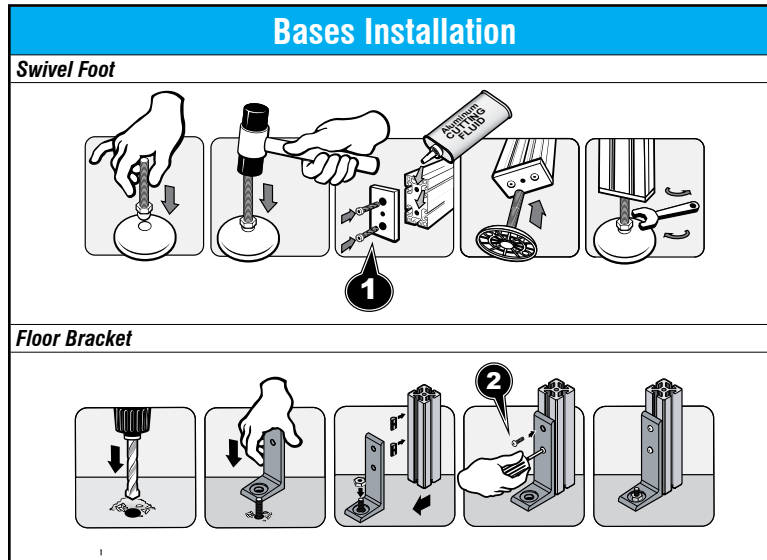

## Bases - Continued



# FATH® T-Slotted Rail Accessories

## Casters


- Recommended ADC Fastener based on part feature and attachment type
- Material: varies by part

30 Series Casters											
		Fits		Slot Size 8		<div>30 Series (mm)</div> <div><div>30x30</div><div>30x60</div><div>60x60</div></div>					
Part Number	Part Image	Price	Description	Requires	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link	
						Core Hole Attachment 1	*T-Slot Attachment 2				
<a href="#">163010</a>		\$40.00	Leveling Caster	Transport / Base Plate with M12-1.75 threaded hole	250 [551]	n/a	n/a	1	Die-cast aluminum/ steel/nylon/ rubber	<a href="#">PDF</a>	
<a href="#">163011</a>		\$52.00			500 [1102]					<a href="#">PDF</a>	
<a href="#">163012</a>		\$41.00		n/a	250 [551]		<a href="#">161059</a>			<a href="#">PDF</a>	
<a href="#">163013</a>		\$56.00			500 [1102]					<a href="#">PDF</a>	
*T-Slot Nut also required.											


\*T-Slot Nut also required.

### Caster Installation

#### Leveling Caster with bolt hole thread

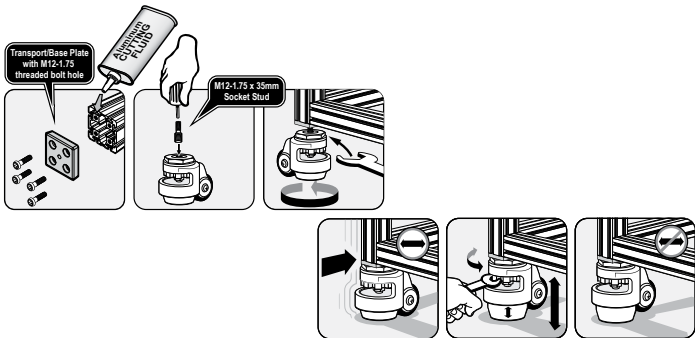

#### Leveling Caster with mounting plate

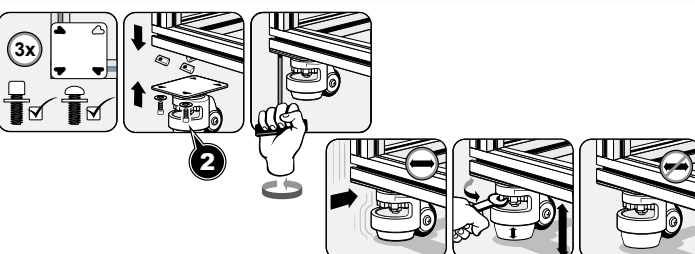











# FATH® T-Slotted Rail Accessories

## Hinges

- Recommended ADC Fastener based on part feature and slot depth
- Material: varies by part



















30 Series Hinges							
Fits		Slot Size 8	<div>30 Series (mm)</div> <div><div></div><div></div><div></div></div> <div>30x30    30x60    60x60</div>				
Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment (ADC Part Number)	Pack Quantity	Material	Drawing Link
<a href="#">151203</a>		\$6.25	Left-Hand Detachable Combination Hinge	<a href="#">161079</a>	1	Fiberglass reinforced plastic	<a href="#">PDF</a>
<a href="#">151204</a>		\$6.50	Right-Hand Detachable Combination Hinge				<a href="#">PDF</a>
<a href="#">151205</a>		\$6.50	Non-Detachable Combination Hinge				<a href="#">PDF</a>
<a href="#">151206</a>		\$11.50	Non-Detachable Combination Hinge With Locking Lever				<a href="#">PDF</a>
<a href="#">151207</a>		\$16.50	Left-Hand Detachable Combination Hinge			Die-cast aluminum	<a href="#">PDF</a>
<a href="#">151208</a>		\$16.50	Right-Hand Detachable Combination Hinge				<a href="#">PDF</a>
<a href="#">151209</a>		\$16.50	Non-Detachable Combination Hinge				<a href="#">PDF</a>
*T-Slot Nut also required							

# FATH® T-Slotted Rail Accessories

## Panel and Door Elements

- Recommended ADC Fastener based on part feature and slot depth
- Material: varies by part



30 Series Panel and Door Elements								
Fits		Slot Size 8	<div>30 Series (mm)</div> <div><div></div><div></div><div></div></div> <div>30x30 30x60 60x60</div>					
Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Pack Quantity	Material	Drawing Link	
<a href="#">151146</a>		\$6.00	Bridge Handle	<a href="#">161061</a>	1	Fiberglass reinforced plastic	<a href="#">PDF</a>	
<a href="#">151147</a>		\$6.00		<a href="#">161065</a>			<a href="#">PDF</a>	
<a href="#">151148</a>		\$6.25	Cover Cap <b>3</b>	n/a			<a href="#">PDF</a>	
<a href="#">151149</a>		\$6.50	Comfort Handle	<a href="#">151183</a>			<a href="#">PDF</a>	
<a href="#">151085</a>		\$4.50	Comfort Handle	<a href="#">161095</a>			<a href="#">PDF</a>	
<a href="#">151086</a>		\$4.00	Cover Cap <b>3</b>	n/a			<a href="#">PDF</a>	
<a href="#">151157</a>		\$7.25	Ball Catch	<a href="#">151162</a>			<a href="#">PDF</a>	
<a href="#">151158</a>		\$14.50	Double Ball Catch	FHCS M4-0.7 x 10mm**	1	Brass	<a href="#">PDF</a>	
<a href="#">162963</a>		\$8.50	Magnetic Catch	<a href="#">161062</a>		Nylon/steel	<a href="#">PDF</a>	
<a href="#">162912</a>		\$4.50	Panel Holder	<a href="#">161066</a>		Anodized aluminum	<a href="#">PDF</a>	
<a href="#">162917</a>		\$5.75					<a href="#">PDF</a>	
<a href="#">162977</a>		\$8.50	Hanger	<a href="#">161059</a>	25	Die-cast zinc	<a href="#">PDF</a>	
<a href="#">151210</a>		\$150.00	Cover And Reduction Profile	n/a		Thermoplastic elastomer	<a href="#">PDF</a>	

\*T-Slot Nut also required

\*\* Recommended fastener not available from AutomationDirect.com

\*T-Slot Nut also required


\*\* Recommended fastener not available from AutomationDirect.com

# FATH® T-Slotted Rail Accessories


## Panel and Door Elements - Continued

### Panel and Door Elements Installation


#### Bridge Handle and Cover Cap

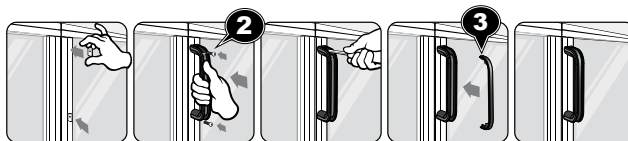


#### Comfort Handle and Cover Cap

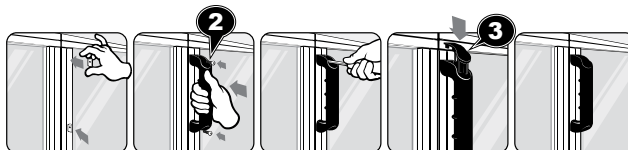


#### Cover and Reduction Profile

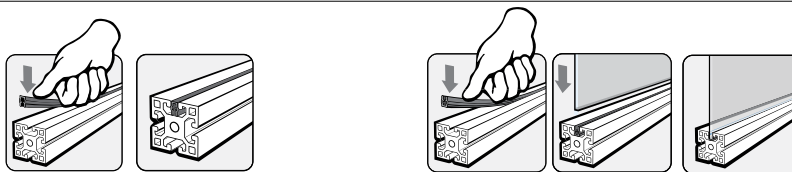


#### Magnetic Catch

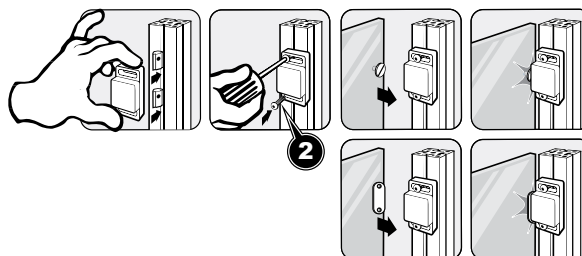

#### Hanger

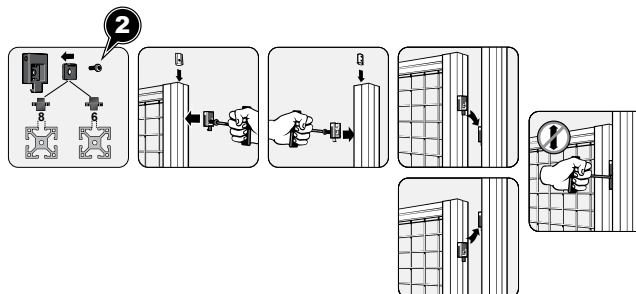

#### Panel Holder

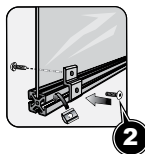


# FATH® T-Slotted Rail Accessories

## Slides and Rollers



### 30 Series Slides and Rollers


Fits Slot Size 8

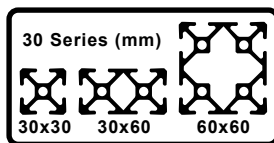

Part Number	Part Image	Price	Description	Fits	Pack Quantity	Material	Drawing Link
<a href="#"><u>148974</u></a>		\$9.50	Roller	All 30 Series	1	Nylon	<a href="#"><u>PDF</u></a>
<a href="#"><u>151211</u></a>		\$4.50	Slider			Glass-filled nylon	<a href="#"><u>PDF</u></a>
<a href="#"><u>151089</u></a>		\$4.50	Snap Hook	Slider <a href="#"><u>151211</u></a>		Zinc plated steel	<a href="#"><u>PDF</u></a>
<a href="#"><u>162968</u></a>		\$7.50	Profile Slider Center Slot	All 30 Series		Polyoxymethylene (POM)	<a href="#"><u>PDF</u></a>


### Slides and Rollers Installation

#### Roller

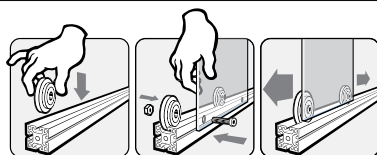


Bolt and nut not included  
and not available from  
AutomationDirect

#### Slider and Snap Hook

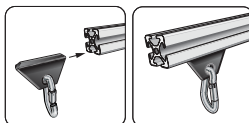

#### Profile Slider

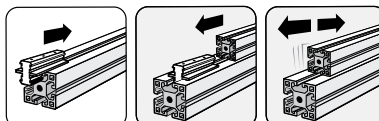

# FATH® T-Slotted Rail Accessories



## Monitor Mounts






### 30 Series Monitor Mounts


- Fits monitors with VESA mounting standard
- Durable steel construction
- Powder coat finish
- Mounting hardware included for several mounting locations

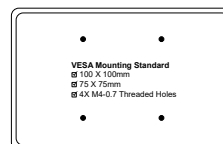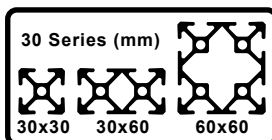Fits  Slot Size 8




Part Number	Part Image	Price	Description	Load Rating kg [lb]	Pack Quantity	Installation Instructions Link	Drawing Link
<a href="#"><u>162893</u></a>		\$42.00	Swivel Monitor Mount	15 [33.1]	1	PDF	<a href="#"><u>PDF</u></a>
<a href="#"><u>162894</u></a>		\$50.00				PDF	<a href="#"><u>PDF</u></a>
<a href="#"><u>162895</u></a>		\$58.00				PDF	<a href="#"><u>PDF</u></a>


### Monitor Mounts Adjustments

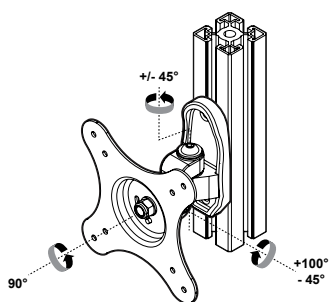

162893

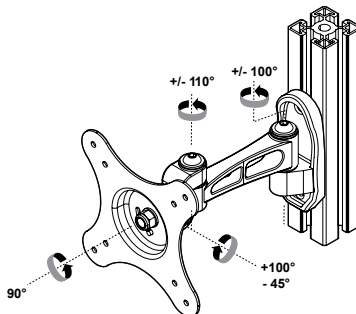

162894

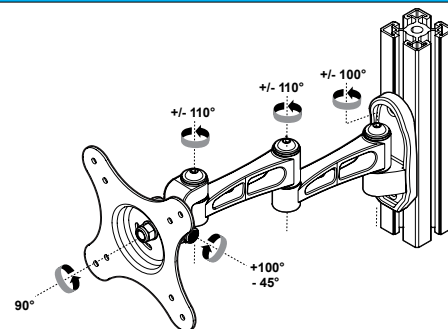

162895


# FATH® T-Slotted Rail Accessories




## Workstation Components



### 30 Series Workstation Components

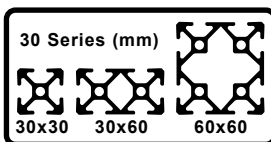
Fits  Slot Size  
8




Part Number	Part Image	Price	Description	Load Rating kg [lb]	Pack Quantity	Material	Drawing Link
<a href="#">162902</a>		\$185.00	Keyboard Holder	n/a	1	Aluminum/nylon	<a href="#">PDF</a>
<a href="#">162964</a>		\$9.00	Grab Tray			Nylon	<a href="#">PDF</a>
<a href="#">162965</a>		\$2.00	Label Clip			PVC	<a href="#">PDF</a>

### Workstation Components Installation


#### Keyboard Holder (mounting example)

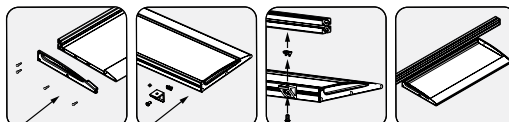

#### Grab Tray

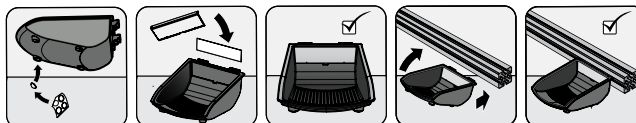

#### Label Clip

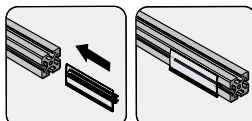




# FATH® T-Slotted Rail Accessories



## Wire Management



### 30 Series Wire Management

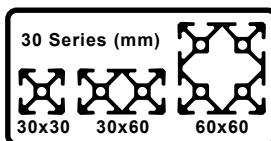Fits  Slot Size 8




Part Number	Part Image	Price	Description	Pack Quantity	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Material	Drawing Link
<a href="#">162982</a>		\$7.50	Universal Cable Binder Block	10	<a href="#">161057</a>	Nylon	<a href="#">PDF</a>
<a href="#">162983</a>		\$15.75	Cable Binder Block		n/a		<a href="#">PDF</a>

\*T-Slot Nut also required

### Wire Management Installation

#### Universal Cable Binder Block

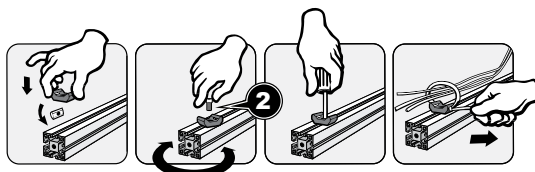


# FATH® T-Slotted Rail Accessories





## Miscellaneous Accessories

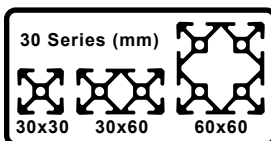

### 30 Series Miscellaneous Accessories

Fits  Slot Size 8



Part Number	Part Image	Price	Description	Fits Profile	Recommended Screw Fastener *T-Slot Attachment <b>2</b> (ADC Part Number)	Pack Quantity	Material	Drawing Link
<a href="#">151212</a>		\$9.25	End Cap	30 x 30mm	n/a	10	Glass-filled nylon	<a href="#">PDF</a>
<a href="#">151170</a>		\$9.00	Stop Bumper	All 30 Series		BHCS M4-0.7 x 20mm (not sold by ADC)	1	Rubber/zinc-plated steel
<a href="#">162973</a>		\$3.25	Sensor Mounting Block for 8mm diameter sensors		Nylon			<a href="#">PDF</a>
<a href="#">162974</a>		\$3.25	Sensor Mounting Block for 12mm diameter sensors					<a href="#">PDF</a>

\*T-Slot Nut also required

\*T-Slot Nut also required