



Aluminum T-Slotted Rail


40 Series Metric T-Slotted Aluminum Rail

SureFrame™ T-slotted aluminum rails are extruded exclusively for AutomationDirect, with features, quality, and performance you expect. SureFrame T-slotted rails are compatible with other popular brands.

- Cut to length in 0.01 cm increments
- Minimum cut length: 15.24 cm
- Maximum cut length: 228.0 cm
- Cut accuracy: +/- 0.015 cm [0.15mm]
- Corrosion and UV resistant



Properties	
Material	Aluminum 6063-T6
Finish	Clear or Black Anodize
Hardness	Webster Model B 11-12
Straightness	0.0125 inch/ft [1.042 mm/m]
Twist	0.25°/ft [0.25°/305mm]

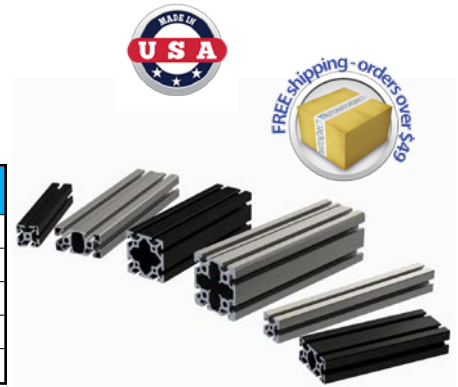

40 Series (metric)								
Slot Size 8		Core Hole Ø 6.8 mm				Drop Lock		
						T-Slot Drop Lock feature improves connection strength and vibration resistance		
Part Number	Part Image	Price per cm	Profile Size	Weight Class	Weight lbs/ft [kg/m]	Moment of Inertia Lx (in ⁴ [cm ⁴])	Moment of Inertia Ly (in ⁴ [cm ⁴])	Drawing Link
40-4040C		\$0.30	40 x 40mm	Standard	1.624 [2.417]	0.324 [13.478]	0.324 [13.478]	PDF
40-4040B		\$0.40						PDF
40-4040CL		\$0.24		Light	1.170 [1.741]	0.219 [9.110]	0.219 [9.110]	PDF
40-4040BL		\$0.31						PDF

Extruded T-slotted rails have a thru Core Hole feature that can be used to attach various components to the end of the profile using:

- Self-tapping / thread-forming screws (no tapping needed)
- A tap to thread the core hole for a threaded fastener



Please Note: Prices on aluminum are closely tied to the market price. This allows us to offer the best savings possible if conditions are favorable; however, it also means that our prices may increase if market conditions warrant.



Aluminum T-Slotted Rail

40 Series Metric T-Slotted Aluminum Rail

SureFrame™ T-slotted aluminum rails are extruded exclusively for AutomationDirect, with features, quality, and performance you expect. SureFrame T-slotted rails are compatible with other popular brands.

- Cut to length in 0.01 cm increments
- Minimum cut length: 15.24 cm
- Maximum cut length: 228.0 cm
- Cut accuracy: +/- 0.015 cm [0.15mm]
- Corrosion and UV resistant




Properties	
Material	Aluminum 6063-T6
Finish	Clear or Black Anodize
Hardness	Webster Model B 11-12
Straightness	0.0125 inch/ft [1.042 mm/m]
Twist	0.25°/ft [0.25°/305mm]



40 Series (metric) - Continued



Core Hole Ø 6.8 mm

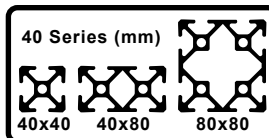

T-Slot Drop Lock feature improves connection strength and vibration resistance

Part Number	Part Image	Price per cm	Profile Size	Weight Class	Weight lbs/ft [kg/m]	Moment of Inertia Lx (in ⁴ [cm ⁴])	Moment of Inertia Ly (in ⁴ [cm ⁴])	Drawing Link
40-4080C		\$0.54	40 x 80mm	Standard	2.925 [4.353]	.0621 [25.834]	2.846 [118.477]	PDF
40-4080B		\$0.69						PDF
40-4080CL		\$0.47		Light	2.482 [3.694]	0.495 [20.592]	1.760 [73.258]	PDF
40-4080BL		\$0.59						PDF
40-8080C		\$0.78	80 x 80mm	Standard	4.281 [6.371]	4.073 [169.520]	4.073 [169.520]	PDF
40-8080B		\$0.95						PDF

Extruded T-slotted rails have a thru Core Hole feature that can be used to attach various components to the end of the profile using:

- Self-tapping / thread-forming screws (no tapping needed)
- A tap to thread the core hole for a threaded fastener



Please Note: Prices on aluminum are closely tied to the market price. This allows us to offer the best savings possible if conditions are favorable; however, it also means that our prices may increase if market conditions warrant.



Aluminum T-Slotted Rail

Deflection Calculations

Using the calculations below, find your approximate deflection* for a specific extrusion.
See table below for variations.

As always when calculating, use diligence and work only in either imperial or metric units at one time.

"E" = Modulus of Elasticity

"F" = Force

"I" = Moment of Inertia

 
"L" = Length

"W" = Weight

**for reference only*


Supported Loads

CONCENTRATED LOAD AT CENTER (simply supported)




$$\text{MAX DEFLECTION} = \frac{FL^3}{48 EI}$$

 UNIFORMLY DISTRIBUTED LOAD (simply supported)




$$\text{MAX DEFLECTION} = \frac{5}{84} \frac{WL^4}{EI}$$

 CONCENTRATED LOAD AT CENTER (between fixed supports)



$$\text{MAX DEFLECTION} = \frac{FL^3}{192 EI}$$

 UNIFORMLY DISTRIBUTED LOAD (between fixed supports)




$$\text{MAX DEFLECTION} = \frac{WL^4}{384 EI}$$

Aluminum 6063-T6 Properties

Yield Strength	29,007 psi [200 MPa]
Tensile Strength	33,359 psi [230 MPa]
Modulus of Elasticity	10,000,000 psi [68.9 GPa]


Cantilever Loads

CONCENTRATED LOAD AT CENTER (simply supported)

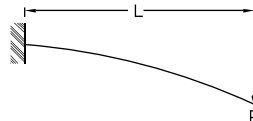

$$\text{MAX DEFLECTION} = \frac{FL^3}{3 EI}$$

UNIFORMLY DISTRIBUTED LOAD (simply supported)

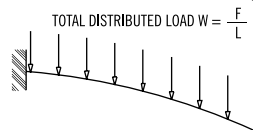
 


 

 

 



$$\text{MAX DEFLECTION} = \frac{WL^4}{8 EI}$$





FATH® T-Slotted Rail Accessories

T-Slot Nuts

- Designed to fit into the T-slot cavity of extruded aluminum rails.
- Hammer nuts provide safe electrostatic discharging (ESD) connection.
- No machining required.
- Material: zinc plated steel













T-Slot Nuts Selection					
Part Image	Nut Type	Installation	Holds Position Without Screw	ESD Connection	
	Double Economy T-Nut			No	
	Economy T-Nut				
	Hammer Nut		No	Yes	
	Slide-In Nut			No	
	Roll-In Nut with Leaf Spring		Yes		
	Roll-In Nut with Spring Loaded Ball				



40 Series T-Slot Nuts						
<div><div><div>Fits</div><div>Slot Size</div><div>8</div></div><div><div>40 Series (mm)</div><div><div></div><div></div><div></div></div><div>40x40 40x80 80x80</div></div></div>						
Part Number	Part Image	Price	Nut Type	Thread Size	Pack Quantity	Drawing Link
161126		\$8.25	Hammer Nut	10-32 UNF	10	PDF
162996		\$17.50	Roll-In Nut			PDF
162903		\$9.50	Slide-In Nut			PDF
151097		\$9.50	Hammer Nut	1/4-20 UNC		PDF
151098		\$20.00	Roll-In Nut			PDF
162997		\$17.50				PDF









FATH® T-Slotted Rail Accessories

T-Slot Nuts - Continued

40 Series T-Slot Nuts - Continued						
<div>Fits</div>		<div>Slot Size</div> <div>8</div>	<div>40 Series (mm)</div> <div><div>40x40</div><div>40x80</div><div>80x80</div></div>			
Part Number	Part Image	Price	Nut Type	Thread Size	Pack Quantity	Drawing Link
162904		\$9.50	Slide-In Nut	1/4-20 UNC	10	PDF
151099		\$20.00	Roll-In Nut	5/16-18 UNC		PDF
162998		\$17.50				PDF
161129		\$8.00	Hammer Nut	M4-0.7		PDF
162999		\$17.50	Roll-In Nut			PDF
161130		\$8.00	Hammer Nut	M5-0.8		PDF
161120		\$16.75	Roll-In Nut			PDF
163000		\$17.50				PDF
151214		\$9.00	Hammer Nut	M6-1.0		PDF
162884		\$9.75	Slide-In Nut			PDF
151215		\$19.00	Roll-In Nut			PDF
163001		\$17.50				PDF

 FATH® T-Slotted Rail Accessories

T-Slot Nuts - Continued










40 Series T-Slot Nuts - Continued						
<div><div><div>Fits</div><div>Slot Size</div><div>8</div></div><div><div>40 Series (mm)</div><div><div></div><div></div><div></div></div><div><div>40x40</div><div>40x80</div><div>80x80</div></div></div></div>						
Part Number	Part Image	Price	Nut Type	Thread Size	Pack Quantity	Drawing Link
<u>151213</u>		\$6.00	Economy T-Nut	M8-1.25	10	<u>PDF</u>
<u>148802</u>		\$5.50	Double Economy T-Nut		4	<u>PDF</u>
<u>162885</u>		\$9.75	Slide-In Nut		10	<u>PDF</u>
<u>151216</u>		\$19.00	Roll-In Nut			<u>PDF</u>
<u>163002</u>		\$17.50				<u>PDF</u>

FATH® T-Slotted Rail Accessories

Fasteners

- Choose from 4 Head types in numerous lengths
- Hex socket head
- Select desired T-Slot nut style with corresponding thread size.
- Material: Black zinc plated or bright zinc plated steel, prevents corrosion better than typical black oxide coatings



40 Series Fasteners								
<div>Fits</div>		<div>Slot Size</div> <div>8</div>	<div>40 Series (mm)</div> <div><div>40x40</div><div>40x80</div><div>80x80</div></div>					
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
162994		\$8.00	#8-32 UNF	3/8 in	Button head socket cap screw	Flat black	10	PDF
161073		\$7.75		1/2 in	Flat head socket cap screw			PDF
162993		\$7.50	#10-32 UNF	3/8 in	Button head socket cap screw			PDF
162995		\$7.75		1/2 in	Socket head cap screw			PDF
161046		\$4.75			5/8 in			Button head socket cap screw
161047		\$5.00		PDF				
161048		\$5.75		3/4 in				
161074		\$6.25	1/4-20 UNC	1/2 in	Flat head socket cap screw			PDF
151040		\$4.25			Button head socket cap screw			PDF
151041		\$5.25			Flanged button head socket cap screw	Gloss black		PDF
161049		\$4.75	1/4-20 UNC	9/16 in	Button head socket cap screw	Flat black		PDF
161075		\$6.25		5/8 in	Flat head socket cap screw			PDF
161050		\$4.75			Button head socket cap screw			PDF
161087		\$4.00			Socket head cap screw			PDF

 











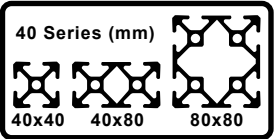



FATH® T-Slotted Rail Accessories

Fasteners - Continued

40 Series Fasteners - Continued											
<div>Fits</div>		<div>Slot Size</div> <div>8</div>		<div>40 Series (mm)</div> <div><div>40x40</div><div>40x80</div><div>80x80</div></div>							
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link			
161051		\$4.75	1/4-20 UNC	3/4 in	Button head socket cap screw	Flat black	10	PDF			
161052		\$5.25		1 in				PDF			
151100		\$5.25		5/8 in				PDF			
151101		\$6.00	5/16-18 UNC	11/16 in	Flanged button head socket cap screw	Gloss black		PDF			
161053		\$6.00		1/2 in	Button head socket cap screw	Flat black		PDF			
161054		\$6.50		3/4 in				PDF			
161055		\$7.50		1 in				PDF			
161088		\$2.25	M4-0.7	8mm	Socket head cap screw	Bright zinc		PDF			
161089		\$2.50		10mm				PDF			
161056		\$1.00		Button head socket cap screw	PDF						
161076		\$1.50		12mm	Flat head socket cap screw			PDF			
161057		\$1.25	M5-0.8	10mm	Button head socket cap screw			PDF			
161090		\$2.50			Socket head cap screw			PDF			
161077		\$1.75		12mm	Flat head socket cap screw			PDF			
161091		\$2.75			Socket head cap screw			PDF			
















FATH® T-Slotted Rail Accessories

Fasteners - Continued

40 Series Fasteners - Continued								
		Fits 						
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
161058		\$1.75	M5-0.8	12mm	Button head socket cap screw	Bright zinc	10	PDF
161092		\$2.75	M6-1.0	10mm	Socket head cap screw			PDF
161078		\$2.25		12mm	Flat head socket cap screw			PDF
161059		\$2.00			Button head socket cap screw			PDF
161093		\$2.75			Socket head cap screw			PDF
161079		\$2.50		14mm	Flat head socket cap screw			PDF
161060		\$2.25			Button head socket cap screw			PDF
161094		\$3.00			Socket head cap screw			PDF
161080		\$2.50		16mm	Flat head socket cap screw			PDF
161061		\$2.50			Button head socket cap screw			PDF
161095		\$3.00			Socket head cap screw			PDF
161062		\$3.00		18mm	Button head socket cap screw			PDF
161096		\$3.25			Socket head cap screw			PDF
161081		\$2.75		20mm	Flat head socket cap screw			PDF
161063		\$3.00			Button head socket cap screw			PDF


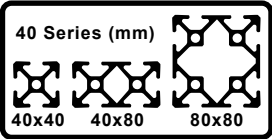








FATH® T-Slotted Rail Accessories


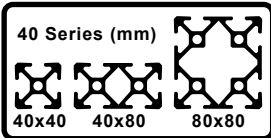



Fasteners - Continued

40 Series Fasteners - Continued									
<div>Fits</div>		<div>Slot Size</div> <div>8</div>	<div>40 Series (mm)</div> <div><div>40x40</div><div>40x80</div><div>80x80</div></div>						
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link	
161097		\$3.25	M6-1.0	20mm	Socket head cap screw	Bright zinc	10	PDF	
161064		\$3.25		25mm	Button head socket cap screw			PDF	
161082		\$4.75	12mm	Flat head socket cap screw	PDF				
161065		\$4.25		Button head socket cap screw	PDF				
161098		\$4.75		Socket head cap screw	PDF				
161066		\$4.50	14mm	Button head socket cap screw	PDF				
161083		\$5.00		Flat head socket cap screw	PDF				
161099		\$5.00		Socket head cap screw	PDF				
161084		\$5.50	M8-1.25	16mm	Flat head socket cap screw			Gloss black	PDF
161100		\$5.50			Socket head cap screw				PDF
161067		\$4.75		Button head socket cap screw	Flanged button head socket cap screw	PDF			
151183		\$4.75				PDF			
151184		\$5.50		PDF					
161085		\$5.50	18mm	Flat head socket cap screw	Bright zinc	PDF			
161068		\$5.25		Button head socket cap screw		PDF			


FATH® T-Slotted Rail Accessories

Fasteners - Continued

40 Series Fasteners - Continued								
Fits		Slot Size 8	<div>40 Series (mm)</div> <div>    </div> <div>40x40 40x80 80x80</div>					
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
161101		\$5.50	M8-1.25	18mm	Socket head cap screw	Bright zinc	10	PDF
151241		\$4.50		20mm	Button head socket cap screw			PDF
161102		\$5.75			Socket head cap screw			PDF
161086		\$7.00		25mm	Flat head socket cap screw			PDF
161069		\$5.25			Button head socket cap screw			PDF
161070		\$8.00		40mm	Button head socket cap screw			PDF
118287		\$2.50		25mm	Hammer head screw and flange nut		1	PDF

40 Series Self Forming / Tapping Screws								
<div>Fits</div> <div><div>40 Series</div><div></div><div>Core Hole</div></div>		<div><div>40 Series (mm)</div><div></div></div>			<div>Works with Aluminum with hole diameter 0.256" - 0.276" [6.6 - 7.0 mm]</div>			
Part Number	Part Image	Price	Thread	Screw Length	Head Type	Color	Pack Quantity	Drawing Link
161105		\$17.00	S7	25mm	Self-Tapping Screw Button head socket cap	Bright zinc	10	PDF
161106		\$9.25			Self-Tapping Screw Flanged button head socket cap T-40 Torx			PDF
161107		\$17.00		40mm	Self-Tapping Screw Button head socket cap			PDF

Self Forming / Tapping Screw Installation

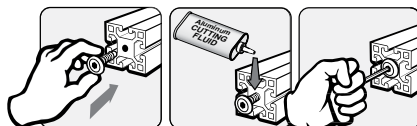

FATH® T-Slotted Rail Accessories


Connecting Components







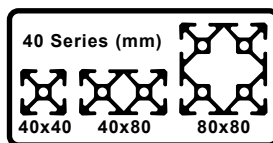

- Connects two or three T-slot rails together
- Recommended ADC Fastener based on part feature, slot Depth and core hole
- Material: varies by part



40 Series Connecting Components

Fits  Slot Size 8



Part Number	Part Image	Price	Description	Fits Profile	Material	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Drawing Link	
						Core Hole Attachment 1	*T-Slot Attachment 2			
148958		\$10.00	2d Cube Connector	40 x 40mm	Die-cast aluminum	161105	161085	1	PDF	
166369		\$12.00							PDF	
148959		\$11.50	3d Cube Connector				PDF			
166370		\$13.00					PDF			
151217		\$13.50	Angle Connector				40 x 80mm		161067	PDF
166371		\$16.00							PDF	
151218		\$13.50		PDF						
166372		\$16.50		PDF						


*T-Slot Nut **3** also required.









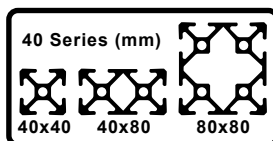


FATH® T-Slotted Rail Accessories

Connecting Components - Continued

40 Series Connecting Components - Continued

Fits  Slot Size
8



Part Number	Part Image	Price	Description	Fits Profile	Material	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Drawing Link
						Core Hole Attachment 1	*T-Slot Attachment 2		
151102		\$23.50	Duo Connector	All 40 Series	Steel	n/a	n/a	10	PDF
151103		\$96.00	T-Matic Connector		Zinc plated steel				PDF
151104		\$59.00	Automatic Connector		Steel				PDF
151105		\$9.50	Automatic Butt Connector					PDF	
151106		\$8.50	Milling Connector		Zinc plated steel			PDF	
151109		\$15.50	Connecting Strip					PDF	
162891		\$13.00	Direct Connector		Steel			Fasteners included	1
162961		\$11.50	Miter Connector		Steel	n/a	M8-1.25 x 8mm set screw (4) included	PDF	
162975		\$21.00	Clamp Profile Connector works with 162976		Die-cast zinc	161105 (2) included with kit	n/a	PDF	
162976		\$5.50	Mounting Element works with 162975		Steel	n/a	Fasteners included	PDF	
163009		\$13.25	Screw Connector			Zinc plated steel	Designer's choice	n/a	10

*T-Slot Nut also required.

FATH® T-Slotted Rail Accessories

Connecting Components - Continued

Connecting Components Installation	
Core Hole Installation	T-Slot Installation
2D Cube Connector	
3D Cube Connector	
	n/a
Angle Connector	
Screw Connector	
Miter Connector	
Direct Connector	
Clamp Profile Connector	

FATH® T-Slotted Rail Accessories

Connecting Components - Continued

Connecting Components Installation	
T-Slot Installation	
Duo Connector	
T-matic Connector	
Automatic Connector	
Automatic Butt Connector	
Milling Connector	
Connecting Strip	

FATH® T-Slotted Rail Accessories

Joining Plates








- Connects two or more T-slot rails together.
- Recommended ADC Fastener based on part feature and slot depth.
- Material: Anodized aluminum



40 Series Joining Plates							
Fits		Slot Size 8	<div>40 Series (mm)</div> <div><div></div>40x40</div> <div><div></div>40x80</div> <div><div></div>80x80</div>				
Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment (ADC Part Number)	Pack Quantity	Drawing Link	
148850		\$5.75	Straight Flat Plate	151183 or 151184	1	PDF	
166373		\$7.00				PDF	
162986		\$8.00				PDF	
166374		\$11.00				PDF	
148856		\$12.00				PDF	
166375		\$14.00				PDF	
148853		\$11.50	Square Flat Plate				PDF
166376		\$14.00				PDF	
148858		\$12.00	Rectangular Flat Plate				PDF
166377		\$15.00				PDF	
151219		\$14.50	Flat Plate				PDF
166378		\$17.00				PDF	
*T-Slot Nut also required.							

FATH® T-Slotted Rail Accessories

Joining Plates - Continued

40 Series Joining Plates - Cont'd						
<div><div>Fits</div><div>Slot Size 8</div><div><div>40 Series (mm)</div><div><div>40x40</div><div>40x80</div><div>80x80</div></div></div></div>						
Part Number	Part Image	Price	Description	Recommended Screw Fastener *T-Slot Attachment (ADC Part Number)	Pack Quantity	Drawing Link
151220		\$16.50	T-Shaped Flat Plate	151183 or 151184	1	PDF
166379		\$21.00				PDF
151221		\$27.50	T-Shaped Flat Plate			PDF
166380		\$34.00				PDF
*T-Slot Nut also required.						

FATH® T-Slotted Rail Accessories

Brackets



 












- Connects two T-slot rails together at a 90° angle
- Recommended ADC Fastener based on part feature and slot depth
- Material: varies by part



40 Series Brackets											
Fits		Slot Size 8	<div>40 Series (mm)</div> <div><div>40x40</div><div>40x80</div><div>80x80</div></div>								
Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link			
				Core Hole Attachment 1	*T-Slot Attachment 2						
151125		\$7.75	Angle Bracket	n/a	151241	1	Die-cast aluminum	PDF			
166322		\$9.00			PDF						
151126		\$11.50			161068		Die-cast zinc	PDF			
166323		\$13.00						PDF			
151222		\$4.25	Inside Corner Bracket		n/a		151183 or 151184	Anodized aluminum	PDF		
166381		\$5.00							PDF		
151223		\$6.25	Wide Inside Corner Bracket						PDF		
166382		\$7.00							PDF		
151224		\$6.25	Tall Inside Corner Bracket						PDF		
166383		\$7.00							PDF		
151225		\$11.50	Inside Corner Bracket						PDF		
166384		\$14.00							PDF		
*T-Slot Nut also required.											

FATH® T-Slotted Rail Accessories

Brackets - Continued


40 Series Brackets - Cont'd								
Fits		Slot Size 8	<div>40 Series (mm)</div> <div><div></div><div></div><div></div></div> <div>40x40 40x80 80x80</div>					
Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
				Core Hole Attachment 1	*T-Slot Attachment 2			
151226		\$3.75	Gusseted Inside Corner Bracket	n/a	151183 or 151184	1		PDF
166385		\$4.00						PDF
151227		\$9.00	Tall Gusseted Inside Corner Bracket					PDF
166386		\$11.00						PDF
148911		\$6.75	Wide Gusseted Inside Corner Bracket					PDF
166387		\$8.00						PDF
151228		\$14.50	Gusseted Inside Corner Bracket					PDF
166388		\$17.00						PDF
151229		\$29.50	Pivot Joint	161105	161066		Die-cast zinc	PDF
166389		\$36.00						PDF
151230		\$39.50	Pivot Joint With Locking Handle					PDF
166390		\$47.00						PDF
*T-Slot Nut also required.								



FATH® T-Slotted Rail Accessories

Brackets - Continued

40 Series Brackets - Continued

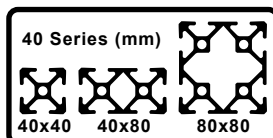Fits

Slot Size
8

Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
				Core Hole Attachment ①	*T-Slot Attachment ②			
163015		\$31.25	1-Slot Pivot Joint	161105	161068	1	Die-cast zinc/die-cast aluminum/ nylon	PDF
163018		\$41.00	2-Slot Pivot Joint					PDF



*T-Slot Nut also required.

Brackets Installation



Core Hole Installation

T-Slot Installation

Pivot Joint*

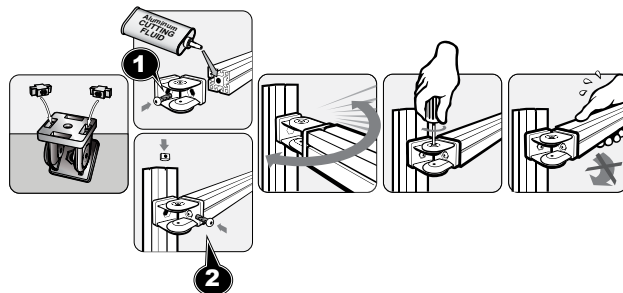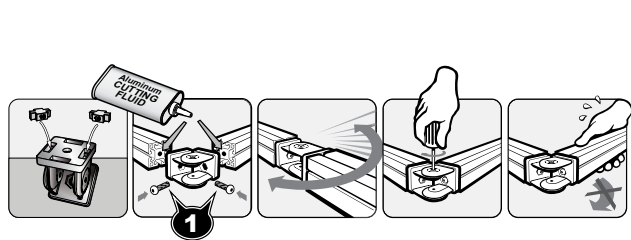

Pivot Joint

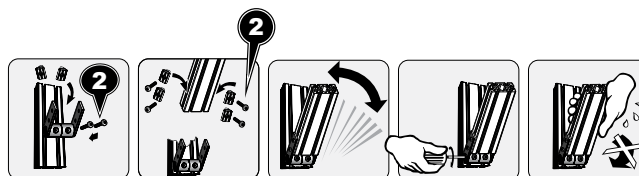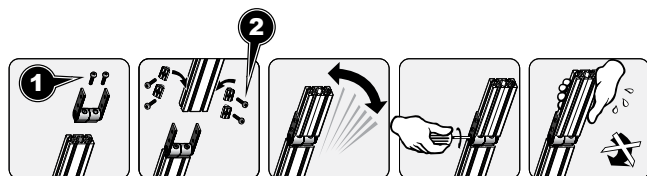


*For 45 series installation, the 10mm embossed key should face toward the aluminum extrusion upon assembly.

FATH® T-Slotted Rail Accessories


Bases



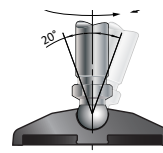





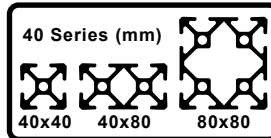

- Recommended ADC Fastener based on part features and extrusion core hole
- Material: varies by part



40 Series Bases

Fits  Slot Size 8



Part Number	Part Image	Price	Diameter	Description	Fits	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
							Core Hole Attachment ①	*T-Slot Attachment ②			
151232		\$16.50	n/a	M12-1.75 Transport/Base Plate	40 x 80mm	n/a	161105 (2) included with kit	n/a	1	Die-cast zinc	PDF
151233		\$23.00			80 x 80mm		161105 (4) included with kit				PDF
162948		\$20.00		M16-2.0 Transport/Base Plate	40 x 80mm		161105 (2) included with kit				PDF
162949		\$25.00			80 x 80mm		161105 (4) included with kit				PDF
162950		\$25.00		M20-2.5 Transport/Base Plate							PDF
151231		\$4.50	1.57 in [39.0 mm]	M12-1.75 x 66mm Swivel Foot Threaded Rod with 15mm ball	Transport/Base Plate 151232 or 151233	770 [1698]**	n/a	n/a	1	Zinc plated steel	PDF
162938		\$6.50		M16-2.0 x 100mm Swivel Foot Threaded Rod with 15mm ball	Transport/Base Plate 162948 or 162949	1450 [3197]					PDF
162939		\$11.00		M20-2.5 x 150mm Swivel Foot Threaded Rod with 15mm ball	Transport/Base Plate 162950	2430 [5357]					PDF
151068		\$4.00		Swivel Base With Anti-Slip Plate	Any 15mm ball Threaded Rod	900 [1984]				Nylon	PDF
151071		\$9.50				3000 [6614]				Die-cast zinc	PDF

*T-Slot Nut also required.

**Based on installation with Transport / Base Plate

Load rating of a swivel foot assembly is based on the part with the lowest load rating, typically the threaded rod.

Example:


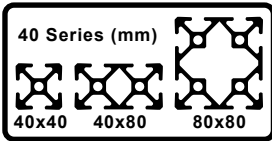








Threaded rod load rating = 210kg [463lb]

Swivel base load rating = 3000kg [6614lb]

Swivel foot assembly load rating = 210kg [463lb]







FATH® T-Slotted Rail Accessories

Bases - Continued


40 Series Bases - Continued											
		Fits 									
Part Number	Part Image	Price	Diameter	Description	Fits	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
							Core Hole Attachment 1	*T-Slot Attachment 2			
151069		\$6.00	3.11 in [79.0 mm]	Swivel Base With Anti-Slip Plate	Any 15mm ball Threaded Rod	900 [1984]	n/a	n/a	1	Nylon	PDF
151070		\$6.00									PDF
151255		\$10.00				PDF					
151256		\$10.00				PDF					
151257		\$24.00	3.90 in [99.0 mm]			3500 [7716]				Die-cast zinc	PDF
151258		\$24.00									PDF
162933		\$12.50	See 2D drawing	Extended Swivel Base	Any 15mm ball Threaded Rod	1000 [2204]	n/a			Nylon	PDF
162934		\$27.00				3000 [6613]				Die-cast zinc	PDF
<p>*T-Slot Nut also required.</p> <p>Load rating of a swivel foot assembly is based on the part with the lowest load rating, typically the threaded rod.</p> <p>Example:</p> <p>Threaded rod load rating = 210kg [463lb]</p> <p>Swivel base load rating = 3000kg [6614lb]</p> <p>Swivel foot assembly load rating = 210kg [463lb]</p>											

FATH® T-Slotted Rail Accessories

Bases - Continued

40 Series Bases - Continued											
Part Number	Part Image	Price	Diameter	Description	Fits	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
							Core Hole Attachment 1	*T-Slot Attachment 2			
162889		\$24.50	n/a	Foot Console	40 x 40mm, 40 x 80mm	n/a	n/a	161068	1	Die-cast aluminum	PDF
166391		\$33.00									PDF
162890		\$25.50									PDF
166392		\$35.00									PDF
162960		\$47.00		Support Bracket	40 x 80mm, 80 x 80mm			M8-1.25 x 30mm (not sold by ADC)			PDF
162958		\$11.50		Floor Bracket	All 40 Series			161068		Anodized aluminum	PDF



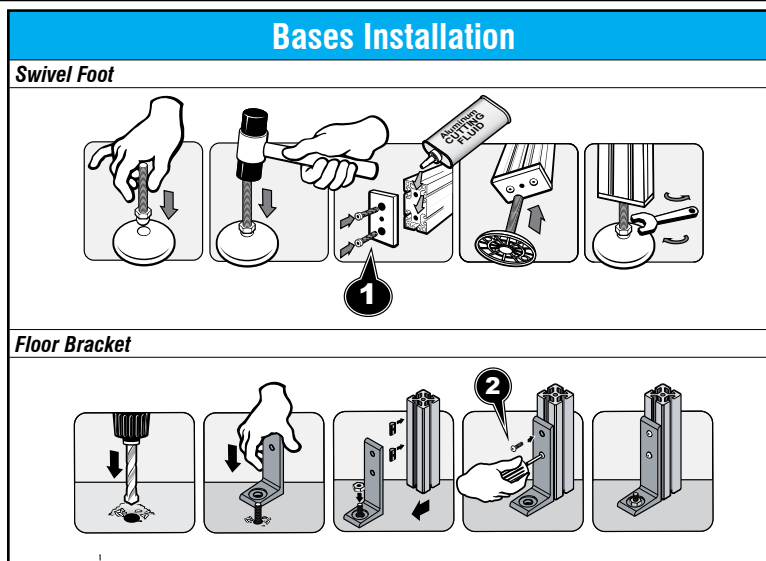







*T-Slot Nut also required.



FATH® T-Slotted Rail Accessories

Casters


- Recommended ADC Fastener based on part feature and core hole
- Material: varies by part

40 Series Casters										
Fits		Slot Size 8		40 Series (mm) <div>40x40 40x80 80x80</div>						
Part Number	Part Image	Price	Description	Requires	Load Rating kg [lb]	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
						Core Hole Attachment 1	*T-Slot Attachment 2			
151134		\$47.00	Swivel Caster (requires Swivel Caster Adapter Plate 151136)	n/a	122 [269]	161107	n/a	1	Thermoplastic polyurethane/ nylon/steel	PDF
151135		\$40.50	Fixed Caster (requires Fixed Fixed Caster Adapter Plate 161040)			161106				PDF
151136		\$4.50	3 Swivel Caster Adapter Plate	Requires Swivel Caster 151134)	n/a				Steel	PDF
161040		\$3.50	3 Fixed Fixed Caster Adapter Plate	Requires Fixed Caster 151135					Die-cast zinc	PDF
151137		\$62.00	Swivel Caster	n/a	122 [269]	n/a	161053		Thermoplastic polyurethane/ nylon/steel	PDF
151138		\$49.00	Fixed Caster				PDF			
163010		\$40.00	Leveling Caster	Transport / Base Plate with M12-1.75 threaded hole	250 [551]		n/a	Die-cast aluminum/ steel/nylon/ rubber	PDF	
163011		\$52.00			500 [1102]				PDF	
163012		\$41.00		n/a	250 [551]		161060		PDF	
163013		\$56.00			500 [1102]				PDF	
*T-Slot Nut also required										

*T-Slot Nut also required

FATH® T-Slotted Rail Accessories

Casters - Continued

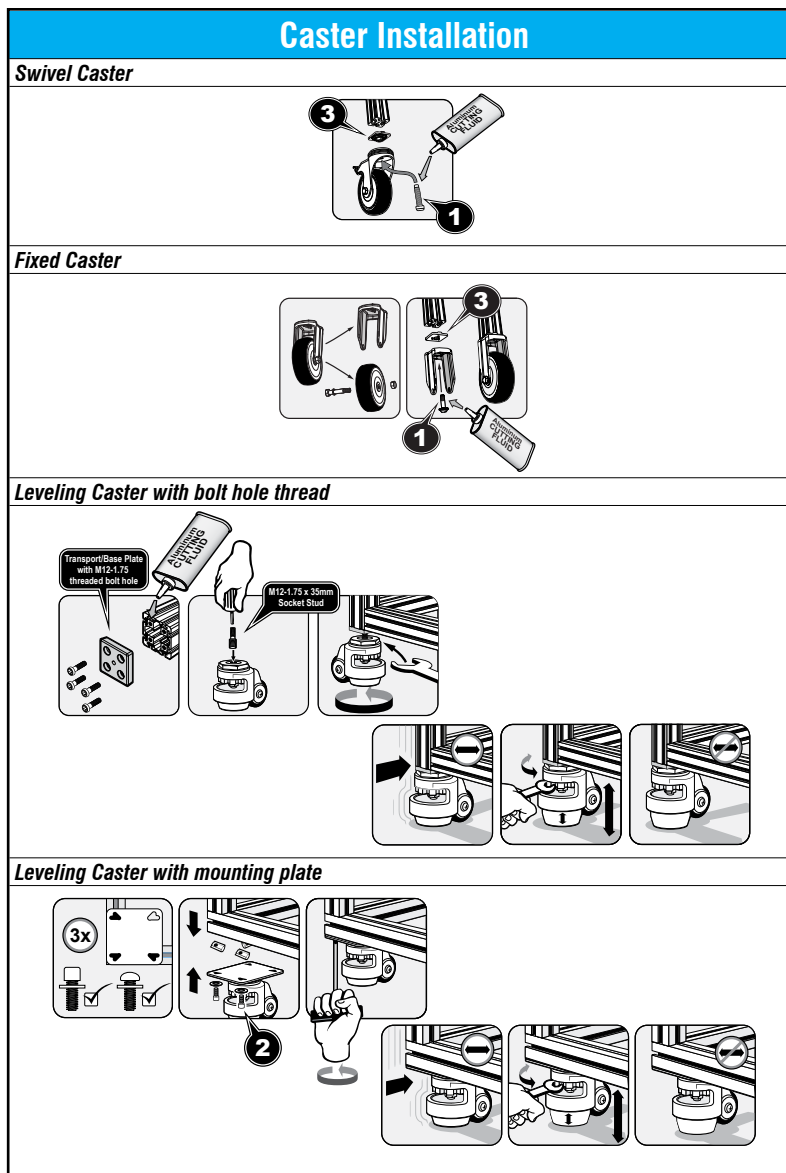

FATH® T-Slotted Rail Accessories


Panel and Door Elements









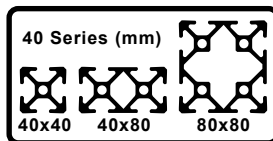



- Recommended ADC Fastener based on part feature and slot depth
- Material: varies by part



40 Series Panel and Door Elements

Fits  Slot Size 8



Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
				Core Hole Attachment 1	*T-Slot Attachment 2			
151146		\$6.00	Bridge Handle	n/a	161063	1	Fiberglass reinforced plastic	PDF
151147		\$6.00			161067			PDF
151148		\$6.25	Cover Cap 3		n/a			PDF
151149		\$6.50	Comfort Handle		161068			PDF
151150		\$2.25	Cover Cap 3		n/a			PDF
151151		\$12.50	Comfort Handle		161054			PDF
151152		\$3.00	Cover Cap 3		n/a			PDF
151153		\$33.50	Machine Handle		161099			PDF
151154		\$47.00	Compact Slam Latch		161061	1	Die-cast aluminum	PDF
151155		\$58.00	Compact Sliding Door Latch					PDF
162971		\$33.00	Sliding Door Guide	Fasteners included	n/a		Die-cast aluminum/nylon	PDF
151156		\$37.00	Emergency Opener	n/a	161060		Fiberglass reinforced plastic	PDF


*T-Slot Nut also required

FATH® T-Slotted Rail Accessories

Panel and Door Elements - Continued

40 Series Panel and Door Elements - Continued

Fits

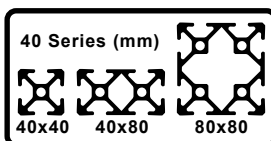


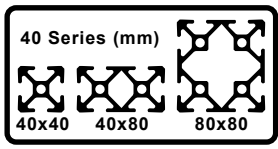




Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
				Core Hole Attachment 1	*T-Slot Attachment 2			
151157		\$7.25	Ball Catch	n/a	161063	1	Fiberglass reinforced plastic	PDF
151158		\$14.50	Double Ball Catch		161076		Brass	PDF
151159		\$23.00	Door Latch		161061		Die-cast zinc	PDF
162963		\$8.50	Magnetic Catch		161063		Nylon/steel	PDF
162913		\$5.00	Panel Holder		161068		Anodized aluminum	PDF
162918		\$6.00						PDF
162924		\$5.75	Panel Mount Block		Fasteners included	1	Lacquered aluminum	PDF
162925		\$5.75					Powder-coated aluminum	PDF
162928		\$525.00	Sealing Profile		n/a		Nitrile rubber	PDF
162977		\$8.50	Hanger		161059	1	Die-cast zinc	PDF
162978		\$3.00	Panel Uni-Block		n/a	10	Nylon	PDF
162979		\$3.00						PDF

*T-Slot Nut also required

*T-Slot Nut also required


FATH® T-Slotted Rail Accessories

Panel and Door Elements - Continued


40 Series Panel and Door Elements - Continued								
		Fits 						
Part Number	Part Image	Price	Description	Recommended Screw Fastener (ADC Part Number)		Pack Quantity	Material	Drawing Link
				Core Hole Attachment 1	*T-Slot Attachment 2			
151160		\$58.00	Sealing Strip		n/a	2	PVC/TPE	PDF
151163		\$25.00	Cover Profile			1	Nitrile rubber	PDF
151165		\$91.00				25	Polypropylene	PDF
151164		\$115.00	Cover And Reduction Profile			PDF		
*T-Slot Nut also required								

Panel and Door Elements Installation


Bridge Handle and Cover Cap

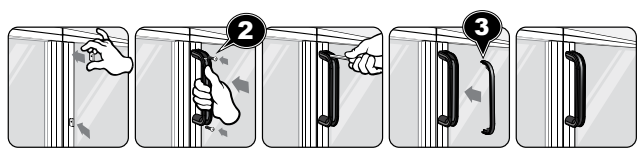


Comfort Handle and Cover Cap

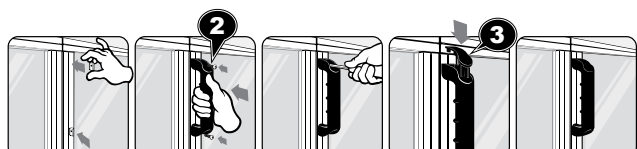

Slam Latch

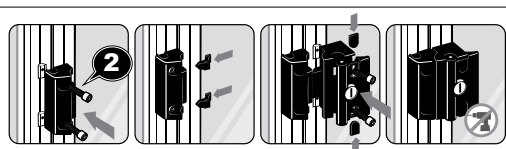

Sliding Door Latch

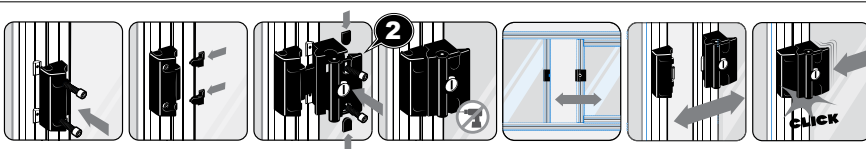


FATH® T-Slotted Rail Accessories


Panel and Door Elements - Continued

Panel and Door Elements Installation - Continued


Emergency Opener

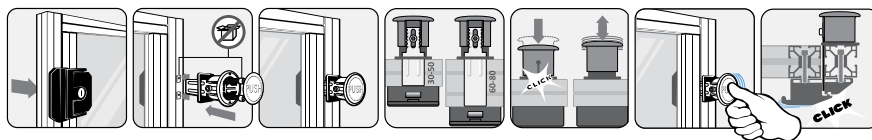


Ball Catch

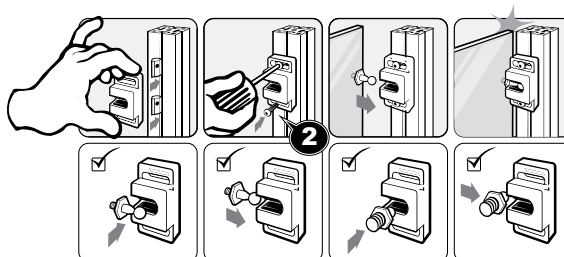


Magnetic Catch

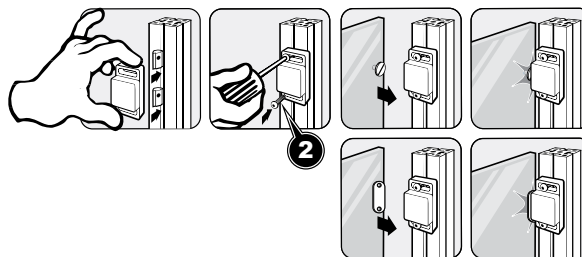


Panel Mount Block

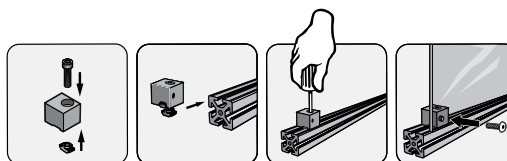


Door Latch

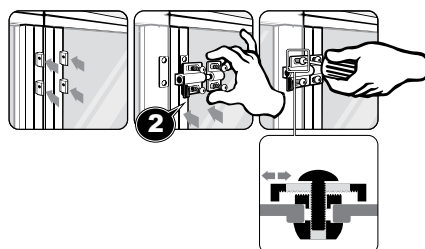

Cover and Reduction Profile



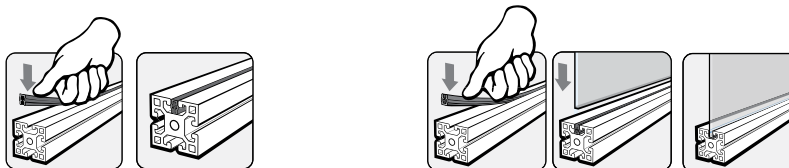


Sealing Profile

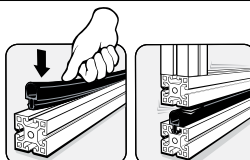

FATH[®] T-Slotted Rail Accessories

Panel and Door Elements - Continued

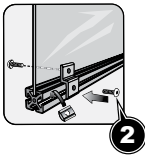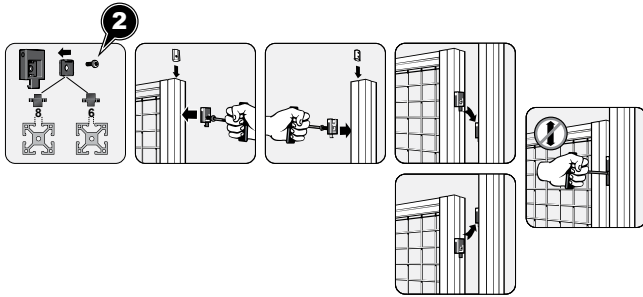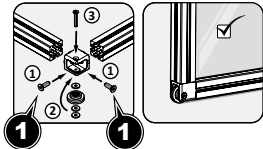Panel and Door Elements Installation - Continued	
Panel Holder	
Hanger	
Sliding Door Guide	

FATH® T-Slotted Rail Accessories

Slides and Rollers




Linear Bearings

- No Shimming required!
- Verified fit with SureFrame 15 & 40 Series
- Static Load rating (Co) up to 4,000 N (900 lbf)
- Single and Double Flange Styles
- Available in Black or Silver
- Optional Brake Assemblies

Note: Not all Slot size 8 profiles are made the same, so it is important to confirm that the "a2" dimension of the profile is 3.0-4.5mm for adequate engagement and ultimate slide performance.




Adjust side screws
for optimum sliding
performance

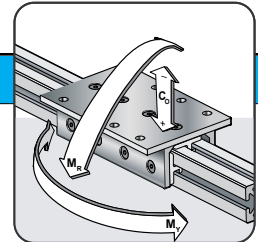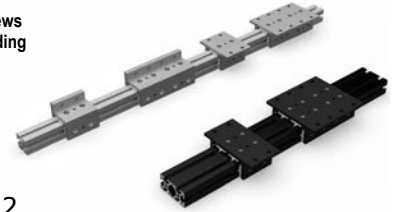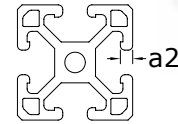

40 Series Slides and Rollers

Fits Slot Size
8

 40 Series (mm)



Part Number	Part Image	Price	Description	Fits	Pack Quantity	Load Ratings				Material	Drawing Link
						Static (Co) N[lbf]	Reverse Static (-Co) N[lbf]	Roll Moment (Mr) N-m[lbf-ft]	Yaw Moment (My) N-m[lbf-ft]		
166393		\$63.00	3-slot, double flange, short linear bearing	40 x 40mm, 40 x 80mm	1	1000 [225]	500 [112]	40 [29]	150 [111]	Aluminum/ die-cast zinc/ polyoxymethylene (POM)	PDF
166394		\$63.00									PDF
166395		\$126.00	3-slot, double flange, long linear bearing			80 [59]	200 [147]	PDF			
166396		\$130.00						PDF			
166397		\$80.00	4-slot, double flange, short linear bearing	40 x 80mm, 80 x 80mm		2000 [450]	1000 [225]	50 [37]	150 [111]		PDF
166398		\$84.00									PDF
166399		\$157.00	4-slot, double flange, long linear bearing			4000 [889]	2000 [450]	100 [74]	200 [147]		PDF
166400		\$168.00									PDF
166401		\$60.00	3-slot, single flange, short linear bearing	40 x 40mm, 80 x 80mm		1000 [225]	500 [112]	40 [29]	150 [111]		PDF
166402		\$63.00									PDF
166403		\$120.00	3-slot, single flange, long linear bearing			2000 [450]	1000 [225]	80 [59]	200 [147]		PDF
166404		\$126.00									PDF


FATH® T-Slotted Rail Accessories

Slides and Rollers - Continued



40 Series Slides and Rollers - Cont'd








Fits  Slot Size
8

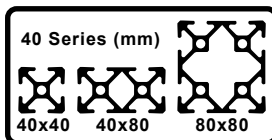

Part Number	Part Image	Price	Description	Fits	Pack Quantity	Recommended Screw Fastener T-Slot Attachment	Material	Drawing Link	
166349		\$45.00	Cam Lever Brake	All 40 Series Linear Bearings	1	n/a	Plastic/steel	PDF	
166350		\$28.00	L-Handle Brake					PDF	
151168		\$18.00	Slider	n/a		Fasteners included	Rubber/plastic/steel	PDF	
151169		\$36.00	Slider With Clamp Lever					PDF	
148974		\$9.50	Roller					Nylon	PDF
151166		\$4.50	Slider						Glass-filled nylon
151089		\$4.50	Snap Hook	Slider 151166		Zinc plated steel	PDF		
163020		\$14.50	Roller Element With Guide	All 40 Series		Fasteners included	Thermoplastic polyurethane/nylon/steel	PDF	
163021		\$14.50	Roller Element Without Guide					PDF	

FATH[®] T-Slotted Rail Accessories



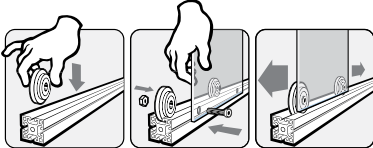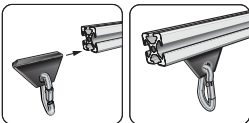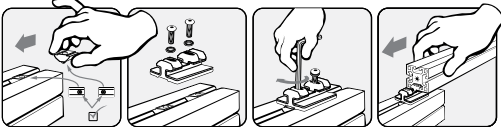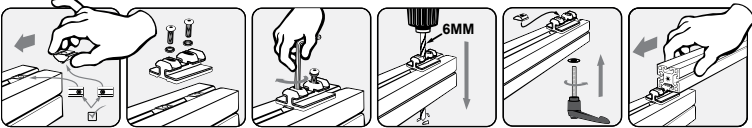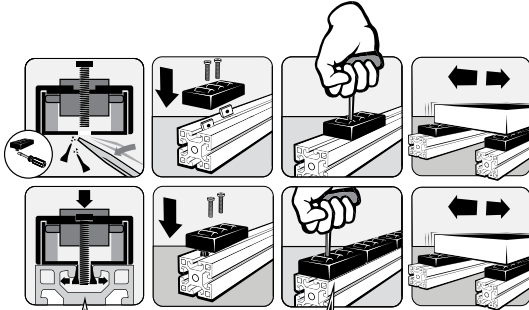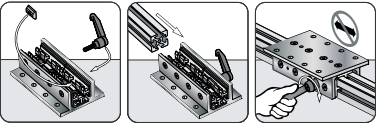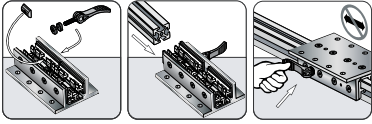








Slides and Rollers - Continued

 Slides and Rollers Installation	
Roller	 <p>Bolt and nut not included and not available from AutomationDirect</p>
Slider and Snap Hook	
Slider	
Slider with Clamp Lever	
Roller Element	 <p>This mount is used when several are used end-to-end.</p> <p>The end units are mounted with T-nuts to keep all secured.</p>
L-Handle Brake	
Cam Lever Brake	

FATH® T-Slotted Rail Accessories

Monitor Mounts




40 Series Monitor Mounts							
<ul style="list-style-type: none">Fits monitors with VESA mounting standardDurable steel constructionMounting hardware included for several mounting locations		<div>Fits</div> <div><div>Slot Size</div><div>8</div></div>	<div>40 Series (mm)</div> <div><div></div><div></div><div></div></div> <div><div>40x40</div><div>40x80</div><div>80x80</div></div>	<div><div><div><div></div><div></div><div></div><div></div></div><div>VESA Mounting Standard</div><div>Ø 100 X 100mm</div><div>Ø 75 X 75mm</div><div>Ø 4x M4-0.7 Threaded Holes</div></div></div>			
Part Number	Part Image	Price	Description	Load Rating kg [lb]	Pack Quantity	Installation Instructions Link	Drawing Link
162893		\$42.00	Swivel Monitor Mount	15 [33.1]	1	PDF	PDF
162894		\$50.00				PDF	PDF
162895		\$58.00				PDF	PDF
162896		\$92.00	Monitor Mounting Joint			PDF	PDF
162897		\$92.00	Monitor Holder			PDF	PDF
162899		\$325.00	4-Axis Mounting Support	10 [22.0]		PDF	PDF
162900		\$394.00	5-Axis Mounting Support			PDF	PDF
162901		\$630.00	4-Axis Workstation	8 [17.6]		PDF	PDF


FATH® T-Slotted Rail Accessories

Monitor Mounts - Continued


Monitor Mounts Adjustments

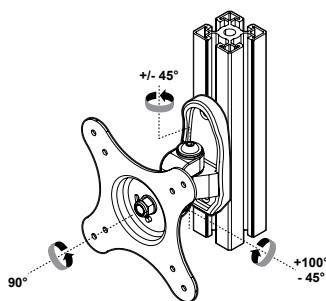


162893

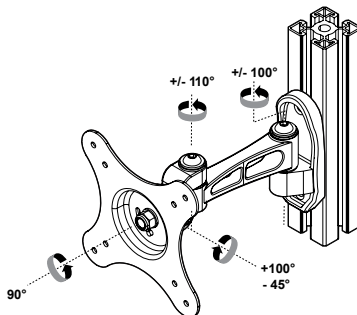


162894

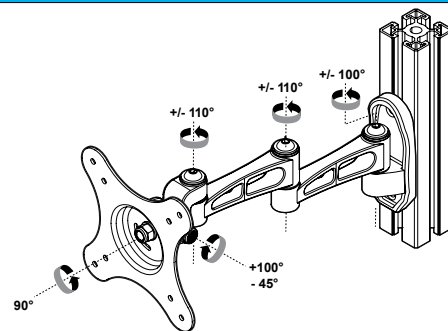


162895

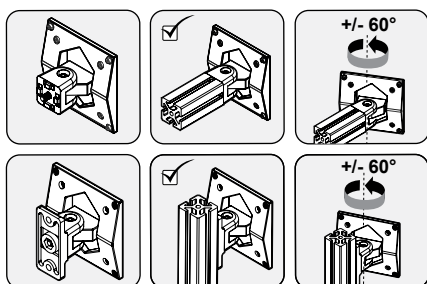


162896

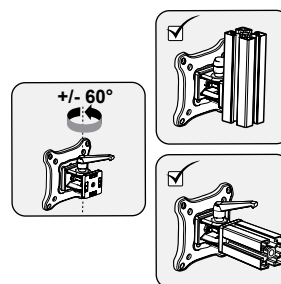


162897

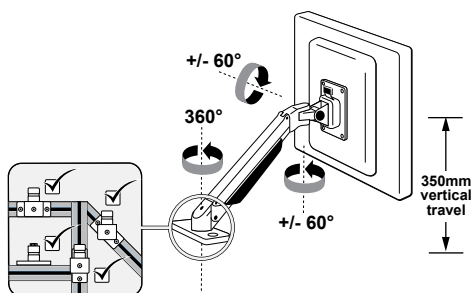

162899

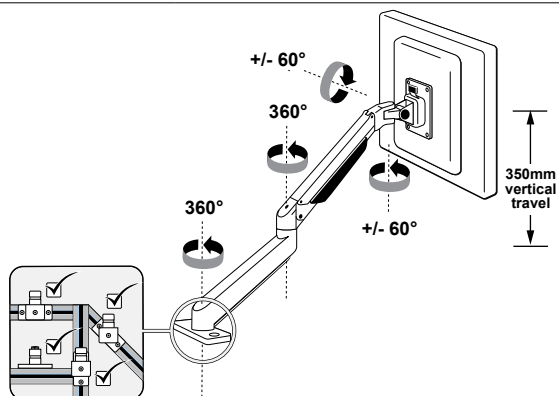

162900

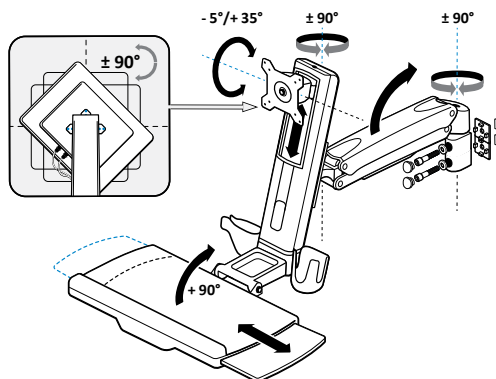

162901


FATH® T-Slotted Rail Accessories






Workstation Components

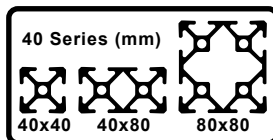

40 Series Workstation Components


Fits  Slot Size 8




Part Number	Part Image	Price	Description	Load Rating kg [lb]	Pack Quantity	Material	Drawing Link
<u>162902</u>		\$185.00	Keyboard Holder (requires mounting solution, designer's choice)	n/a	1	Aluminum/nylon	<u>PDF</u>
<u>162906</u>		\$8.00	Magnetic Holder			Nylon/steel	<u>PDF</u>
<u>162909</u>		\$5.50	Top Angle Clamp			Nylon/steel	<u>PDF</u>
<u>162964</u>		\$9.00	Grab Tray			Nylon	<u>PDF</u>
<u>162965</u>		\$2.00	Label Clip			PVC	<u>PDF</u>

Workstation Components Installation


Keyboard Holder (mounting example)

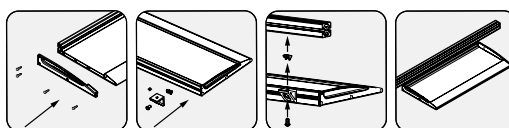


Magnetic Holder

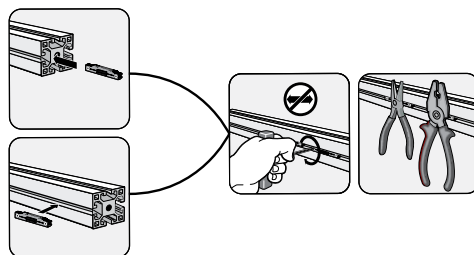

Grab Tray

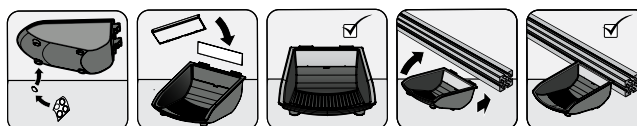



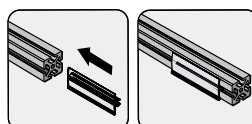


Label Clip



FATH® T-Slotted Rail Accessories


Wire Management



40 Series Wire Management							
Fits		Slot Size 8	<div>40 Series (mm)</div> <div>40x40 40x80 80x80</div>				
Part Number	Part Image	Price	Description	Pack Quantity	Recommended Screw Fastener *T-Slot Attachment 2 (ADC Part Number)	Material	Drawing Link
151162		\$93.00	Conduit Cover 2000mm long	2	n/a	Polypropylene	PDF
151174		\$15.50	Cross Cable Binding Block	10		Nylon	PDF
151175		\$64.00	Hook And Loop			Glass-filled nylon/ polypropylene	PDF
151176		\$38.50	Clip Cable Binder With Hammer			Nylon/rubber	PDF
151177		\$28.50	Ground Connector	1	Fasteners included	Glass-filled nylon/ copper/steel	PDF
151178		\$4.00	Grounding Terminal			Steel/brass	PDF
162982		\$7.50	Universal Cable Binder Block	10	161058	Nylon	PDF

*T-Slot Nut also required

*T-Slot Nut also required

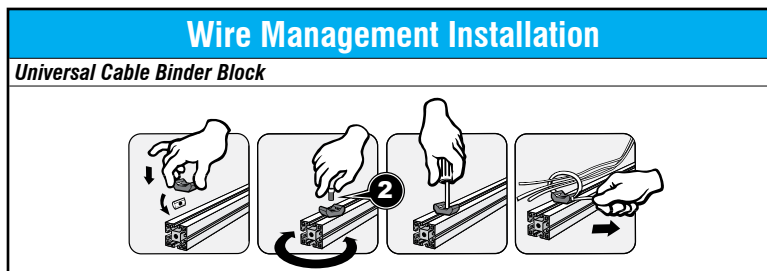


FATH® T-Slotted Rail Accessories









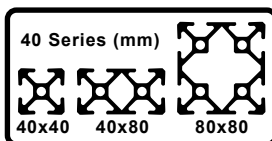

Miscellaneous Accessories



40 Series Miscellaneous Accessories

Fits Slot Size 8







Part Number	Part Image	Price	Description	Requires	Fits Profile	Recommended Screw Fastener *T-Slot Attachment 2 (ADC Part Number)	Pack Quantity	Material	Drawing Link		
151234		\$16.50	End Cap	n/a	40 x 40mm	n/a	10	Glass-filled nylon	PDF		
151235		\$20.50			40 x 80mm				PDF		
151236		\$32.00			80 x 80mm				PDF		
151091		\$6.00	Stop Bumper		All 40 Series			Rubber/zinc-plated steel	PDF		
151170		\$9.00							PDF		
162973		\$3.25	Sensor Mounting Block for 8mm proximity sensor		All 40 Series	BHCS M4-0.7 x 25mm (not sold by ADC)	1	Nylon	PDF		
162974		\$3.25	Sensor Mounting Block for 12mm proximity sensor						PDF		
162929		\$252.00	Side Protection Profile			n/a		5	Thermoplastic rubber	PDF	
162930		\$284.00	Corner Protection Profile							PDF	
162931		\$28.00	Cover Cap for Side	162929 or 162930						10	PDF
162932		\$21.00	Cover Cap for Corner	162930							PDF

*T-Slot Nut also required

FATH[®] T-Slotted Rail Accessories

Miscellaneous Accessories - Continued

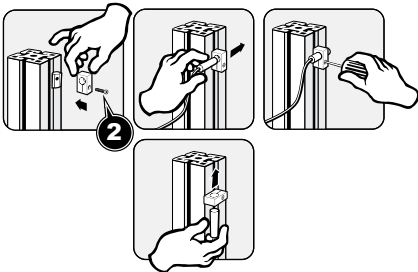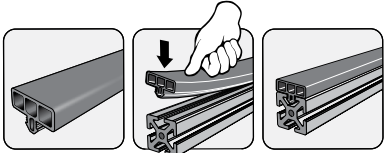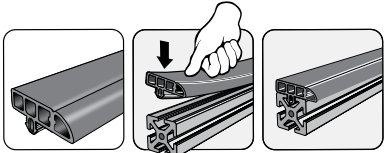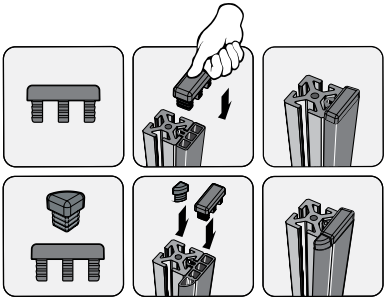Workstation Components Installation		
Sensor Mounting Block		
		
Side Protection Profile		
		
Corner Protection Profile		
		
Cover Cap for Side		
		
Cover Cap for Corner		
