

# Varioline Enclosure LED Lights



## Applications

The Varioline is a powerful and compact LED lamp capable of fully illuminating even very large enclosures. The glare-free, 360° rotatable LED tube uses mid-power LEDs with a service life of 60,000 hours. The emitted daylight color of 6,500K provides safety for the user by a natural and non-fading color reproduction.

## Features

- High luminous flux
- Integrated power unit
- Durable and maintenance-free LED technology
- Available in 15.75in [400 mm] and 23.63in [600 mm] lengths
- Up to eight units can be daisy-chained
- On/off switch, motion sensor or unswitched
- Magnet or screw mounting for easy positioning
- Uses Varioline cable and connectors

## Listings

- UL Recognized File E234324



LED 021 Movement sensor and screw mount 021000-00



LED 022 On/off switch and magnet mount 022000-30

### Varioline Enclosure LED Lights Specifications

Length	Size 1	Size 2
	15.75in [400 mm]	26.63in [600mm]
<b>Power Consumption</b>	11W Max.	16W Max.
<b>Operating Voltage</b>	AC 100 - 240V, 50/60 Hz (min. AC 90V, max. AC 265V)	
<b>Luminosity</b>	1,080 Lm	1,730 Lm
<b>Lamp Type</b>	LED	
<b>Angle of Radiation</b>	120°	
<b>Light Color</b>	Daylight	
<b>Color Temperature</b>	6,500 K	
<b>Service Life</b>	60,000 hrs. at 68°F [20°C]	
<b>Connection</b>	2-pole connector with snap lock; AC: max. 2.5A / AC 240V, color: white	
<b>Housing</b>	plastic, translucent	
<b>Mounting Hardware (screw mount only)</b>	M5 screws, 2 lb·in max. torque	
<b>Operating Temperature</b>	-22 to 104°F [-30 to 40°C]	
<b>Storage Temperature</b>	-40 to 185°F [-40 to 85°C]	
<b>Operating / Storage Humidity</b>	max. 90% RH (non-condensing)	
<b>Protection Class</b>	II (double insulated)	
<b>Protection Type</b>	IP20	
<b>Approvals</b>	UL Recognized File E234324, VDE, CE	
<b>Weight</b>	Approx. 7.1 oz [0.2 kg]	Approx. 10.6 oz [0.3 kg]

# Varioline Enclosure LED Lights




Varioline Enclosure LED Lights						
Size 1 – 15.75in [400 mm] length						
Magnet Mount	Price	Drawing Link	Screw Mount	Price	Drawing Link	Switch Type
<a href="#">021000-30</a>	\$141.00	<a href="#">PDF</a>	<a href="#">021100-00</a>	\$133.00	<a href="#">PDF</a>	on/off
<a href="#">021100-30*</a>	\$191.00	<a href="#">PDF</a>	<a href="#">021100-00</a>	\$184.00	<a href="#">PDF</a>	PIR motion sensor
<a href="#">021200-30</a>	\$137.00	<a href="#">PDF</a>	<a href="#">021200-00</a>	\$129.00	<a href="#">PDF</a>	no


\*Approximately 5 minute fixed switch-on duration.

Varioline Enclosure LED Lights						
Size 2 – 23.63in [600 mm] length						
Magnet Mount	Price	Drawing Link	Screw Mount	Price	Drawing Link	Switch Type
<a href="#">022000-30</a>	\$157.00	<a href="#">PDF</a>	<a href="#">022000-00</a>	\$149.00	<a href="#">PDF</a>	on/off
<a href="#">022100-30*</a>	\$207.00	<a href="#">PDF</a>	<a href="#">022100-00</a>	\$200.00	<a href="#">PDF</a>	PIR motion sensor
<a href="#">022200-30</a>	\$153.00	<a href="#">PDF</a>	<a href="#">022200-00</a>	\$145.00	<a href="#">PDF</a>	no

\*Approximately 5 minute fixed switch-on duration.

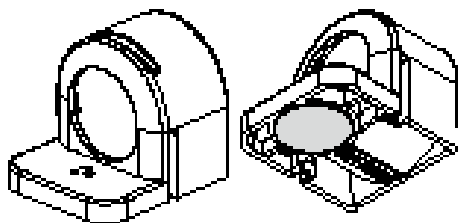

View of Magnet Mount

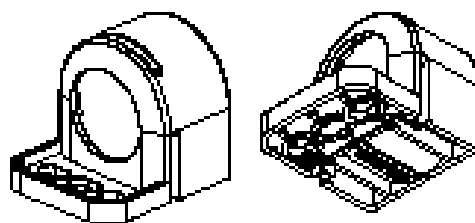

View of Screw Mount

Close up view

# Accessories – Varioline Enclosure LED Lights



## Power cable with input connector and wire leads



244357

Part Number	Price	Description	Length	Voltage	Color
<a href="#">244357</a>	\$28.00	Connection cable 2 x 16 AWG with input connector	6.5ft (2.0 m)	AC	Connectors: white; Cable: white

## Power Input and Output Connectors

(Field Wireable)



264057

Part Number	Price	Description	Voltage	Color
<a href="#">264057</a>	\$9.00	Input Connector	AC	White
<a href="#">264058</a>	\$8.50	Output Connector		

## Extension Cable with 2 Connectors (Input and Output) for Daisy Chain Connection



244359

Part Number	Price	Description	Length	Voltage	Color
<a href="#">244359</a>	\$33.50	Extension cable 2 x 15 AWG with 2 connectors	3.2 ft (1.0 m)	AC	Connectors: white; Cable: white