



## Zyklop Speed Ratchet



### Small return angle

The fine 72 tooth ratchet mechanism has a low return angle of 5°. This short stroke allows fast and precise work in small spaces.



### Swivel ratchet head


The ratchet head pivots freely and locks at 0°, 15° and 90°, making it possible to work in confined spaces with ample hand clearance.



### Simple direction change

Rotating the large thumbwheel quickly changes rotation from clockwise to counterclockwise from any position of the ratchet head.

Wera Speed Ratchets		
Part Number	Description	Price
<u><a href="#">05003500055</a></u>	Wera Zyklop Speed ratchet, 1/4 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003500.	\$81.00
<u><a href="#">05003550055</a></u>	Wera Zyklop Speed ratchet, 3/8 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003550.	\$90.00
<u><a href="#">05003600055</a></u>	Wera Zyklop Speed ratchet, 1/2 inch drive, with locking swivel head and ergonomic grip handle. Manufacturer part number 003600.	\$99.00

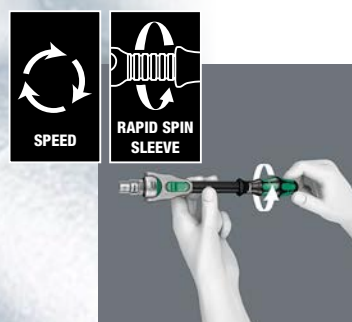

### Unbelievably fast


The gyrating mass design along with the Kraftform handle and free-turning sleeve allow for rapid rotation when used as a screwdriver.



# Zyklop Speed Ratchet and Socket Sets



## 1/4 inch Drive Imperial Ratchet Sets

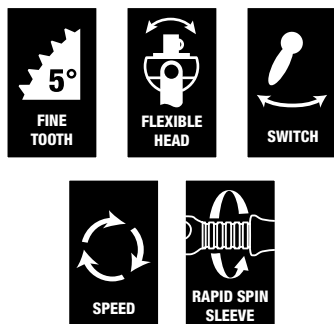

1/4 inch Drive Imperial Ratchet Sets		
Part Number	Description	Price
<b>05003535055</b>	Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, SAE. 41 pieces. Sturdy metal case included. Manufacturer part number: 003535.	Retired

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect.

Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, SAE, 41 pieces. Includes the pieces listed in the table below.



05003535055 Contents		
	1/4 Zyklop Speed ratchet	
	Sliding T-handle	1/4 x 110
	6-point socket, 23mm long	3/16, 7/32, 1/4, 9/32, 5/16, 11/32, 3/8, 7/16, 1/2, 9/16
	Wobble extension	1/4 x 56
	Universal joint	1/4 x 35.5
	Lockable extension	1/4 x 150, 1/4 x 75
	Bit adaptor	1/4 x 37
	Slotted bit, 25mm long	0.6 x 4.5, 1.0 x 5.5, 1.2 x 8.0
	Hex-Plus bit, 25mm long	5/64, 3/32, 1/8, 9/64, 5/32, 3/16, 7/32
	Phillips bit, 25mm long	PH1, PH2, PH3
	Posidriv® bit, 25mm long	PZ1, PZ2, PZ3
	Torx® bit, 25mm long	TX8, TX9, TX10, TX15, TX20, TX25, TX30, TX40

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.


**Wera**

# Zyklop Speed Ratchet and Socket Sets



## 1/4 inch Drive Metric Ratchet Sets



1/4 inch Drive Metric Ratchet Sets		
Part Number	Description	Price
<b>05003533055</b>	Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric. 42 pieces. Sturdy metal case included. Manufacturer part number 003533.	Retired
<b>05051045055</b>	Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric, 26 pieces. Durable cloth pouch included. Manufacturer part number 051045.	\$134.00
Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.		



Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric, 42 pieces. Includes the pieces listed in the table below.

05003533055 Contents		
	1/4 Zyklop Speed ratchet	
	Sliding T-handle	1/4 x 110
	6-point socket, 23mm long	4, 4.5, 5, 5.5, 6, 7, 8, 9, 10, 11, 12, 13, 14
	Wobble extension	1/4 x 56
	Universal joint	1/4 x 35.5
	Lockable extension	1/4 x 75, 1/4 x 150
	Bit adaptor	1/4 x 37
	Slotted bit, 25mm long	0.6 x 4.5, 1.0 x 5.5, 1.2 x 8
	Hex-Plus bit, 25mm long	3, 4, 5, 6, 8
	Phillips bit, 25mm long	PH1, PH2, PH3
	Posidriv® bit, 25mm long	PZ1, PZ2, PZ3
	Torx® bit, 25mm long	TX8, TX9, TX10, TX15, TX20, TX25, TX30, TX40

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.



Wera driver bit and socket set with Zyklop Speed ratchet, 1/4 inch drive, metric, 26 pieces. Includes the pieces listed in the table below.

05051045055 Contents		
	1/4 Zyklop Speed ratchet	
	6-point socket	5.5, 6, 7, 8, 10, 12, 13
	Lockable extension	1/4 x 150
	Bit adaptor	1/4 x 37
	Slotted bit	1.0 x 5.5 x 50
	Hex-Plus bit, 50mm long	3, 4, 5, 6
	Phillips bit, 50mm long	PH1, PH2, PH3
	Posidriv® bit, 50mm long	PZ1, PZ2
	Torx® bit, 50mm long	TX10, TX15, TX20, TX25, TX30, TX40

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.