




Wera Bit Drivers, Bits, & Adapters

Universal Bit Holder

The Rapidaptor universal bit holder is designed for bits with 1/4 in external hexagon drives. The Rapidaptor allows for mounting the bits without using the sleeve. The bit is removed by simply pushing it forward—for lightning-fast bit changes with just one hand.

Features

- Rapidaptor technology for rapid bit change
- Free-floating magnetic sleeve
- One-hand operation

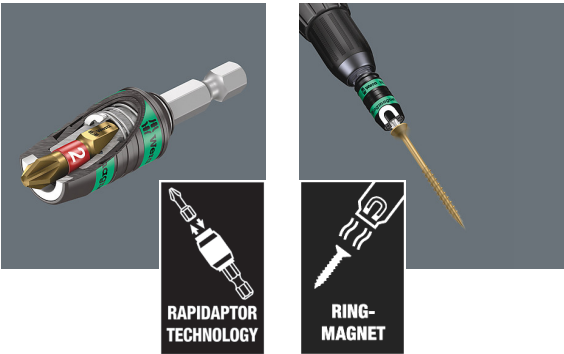

| Driver Bit Adapter | | | | |
|--------------------------------------|------------|----------------|---|---------|
| Part Number | Drive Size | Overall Length | Description | Price |
| <u>TW-DB-ADT-MAG</u> | 1/4in | 2.25in (57mm) | Wera Rapidaptor magnetic driver bit adapter, 1/4in drive, 2.25in (57mm) overall length. Rapidaptor technology for rapid bit change. | \$20.00 |

Note: Bit-holders are warranted against manufacturer defect only.




Wera Bit Drivers, Bits, & Adapters


Driver Bit, Bitholding Screwdriver, and L-key Set

This 52-piece set packs maximum screwdriving utility into a compact, lightweight set protected by an extremely robust folding textile box.

- BiTorsion bits for long service life
- Impaktor bits for extreme conditions
- Chrome-plated Hex-Plus L-keys with ball-end hex on long arm
- One Rapidaptor bit holder for quick, one-handed bit changes
- One Kraftform Kompact bitholding screwdriver for that ergonomic Kraftform feel

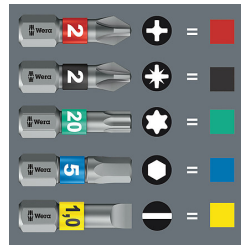

Take-it-Easy Tool Finder

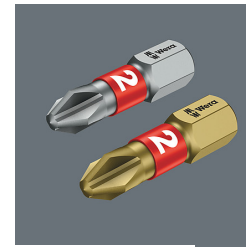











BiTorsion Bits



Impaktor Impact Bits

Screwdriver Bit Sets

| Part Number | Part Image | Number of Pieces | Type | Size (Tip Size x Length) | Quantity Included | Set Includes | Price |
|--|---|------------------|---|-----------------------------|----------------------|--|----------|
| 05057460055 |  | 52 |  Phillips | #1 x 25mm | 2 | bitholding screwdriver with Rapidaptor quick-release chuck, Rapidaptor universal bit holder, (8) BiTorsion Phillips bits ((2) #1, (4) #2, (2) #3), (3) Impaktor Phillips bits ((2) #2, #3), (8) BiTorsion Pozidriv bits ((2) #1, (4) #2, (2) #3), (3) Impaktor Pozidriv bits ((2) #2, #3), (12) BiTorsion Torx bits ((2) T10, (2) T15, (3) T20, (2) T25, (2) T30, T40), (3) Impaktor Torx bits (T25, T30, T40), (2) BiTorsion 5.5mm flat/slotted bits, (3) Impaktor hex bits (4, 5, 6mm), (8) L-keys with Hex-Plus profile (1.5, 2, 2.5, 3, 4, 5, 6, 8mm), durable cloth pouch | \$122.00 |
| | | | | #2 x 25mm | 4 | | |
| | | | | #3 x 25mm | 2 | | |
| | | |  Impact-rated Phillips | #2 x 50mm | 2 | | |
| | | | | #3 x 50mm | 1 | | |
| | | |  Slotted | 0.8 x 5.5mm x 25mm | 1 | | |
| | | | | 1 x 5.5mm x 25mm | 1 | | |
| | | |  Pozidriv | #1 x 25mm | 2 | | |
| | | | | #2 x 25mm | 4 | | |
| | | | | #3 x 25mm | 2 | | |
| | | |  Impact-rated Pozidriv | #2 x 50mm | 2 | | |
| | | | | #3 x 50mm | 1 | | |
| | | |  Torx | T10 x 25mm | 2 | | |
| | | | | T15 x 25mm | 2 | | |
| | | | | T20 x 25mm | 3 | | |
| | | | | T25 x 25mm | 2 | | |
| | | | | T30 x 25mm | 2 | | |
| | | | | T40 x 25mm | 1 | | |
| | | |  Impact-rated Torx | T25 x 50mm | 1 | | |
| | | | | T30 x 50mm | 1 | | |
| | | | | T40 x 50mm | 1 | | |
| | | |  Impact-rated Hex Plus | 4 x 50mm | 1 | | |
| | | | | 5 x 50mm | 1 | | |
| | | | | 6 x 50mm | 1 | | |
|  Hex Plus L-key | 1.5 x 50mm | 1 | | | | | |
| | 2 x 56mm | 1 | | | | | |
| | 2.5 x 63mm | 1 | | | | | |
| | 3 x 71mm | 1 | | | | | |
| | 4 x 80mm | 1 | | | | | |
| | 5 x 90mm | 1 | | | | | |
| | 6 x 100mm | 1 | | | | | |
| | 8 x 112mm | 1 | | | | | |

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.



Wera Bit Drivers, Bits, & Adapters

Standard Driver Bits

Wera bits are designed for demanding applications in trade and industry. They are able to transfer high torque loads, are safe to use, and are extremely durable.



| Standard Driver Bits | | | | | | | | |
|-----------------------------------|------------|----------|----------|------------|------------|--|------------------|---------|
| Part Number | Part Image | Type | Tip Size | Bit Length | Drive Size | Description | Package Quantity | Price |
| <u>TW-DB-PH-1</u> | | Phillips | #1 | 2.75in | 1/4in | Wera #1 Phillips general purpose driver bit, 2.75in bit length, 1/4in drive, hexagonal. Package of 10. | 10 | \$10.00 |
| <u>TW-DB-PH-2</u> | | | #2 | | | Wera #2 Phillips general purpose driver bit, 2.75in bit length, 1/4in drive, hexagonal. Package of 10. | | \$10.00 |
| <u>TW-DB-SL-1</u> | | Slotted | 3.0mm | 2in | | Wera 3.0mm slotted general purpose driver bit, 2in bit length, 1/4in drive, hexagonal. Package of 10. | | \$31.00 |

Note: Screwdriver bits are warranted against manufacturer defect only.



Wera Bit Drivers, Bits, & Adapters



| Tool-Check Socket and Driver Bit Sets | | | Bit-Check Socket and Driver Bit Sets | | |
|---|------------------------------------|---|--------------------------------------|---|---------------------------------|
| 05073220055 | | | TW-DB-SET-28R | | |
| | | | | | |
| Wera Tool-Check standard driver bit and socket set, Phillips, Pozidriv, slotted, Torx, tamperproof torx, internal hex and external hex, 38 pieces, 1in bit length, 1/4in drive, metric. | | | \$102.00 | Wera Bit-Check standard driver bit set, Phillips, Torx, tamperproof torx, external hex, slotted and square, 31 pieces, 1in bit length, 1/4in drive, imperial. | |
| Type | | Bit Size | Type | | Bit Size |
| Zyklop Mini bit ratchet | | 1/4in | Zyklop Mini bit ratchet | | 1/4in |
| Rapidaptor bit holder | | 1/4 x 50 | Rapidaptor bit holder | | 1/4in x 50mm |
| Socket adaptor | | 1/4 x 25 | Socket adaptor | | 1/4 x 25 |
| | Slotted bit 25mm long | 1.0 x 5.5mm | | Phillips bit, 25mm long | (2) PH1, (3) PH2, PH3 |
| | Hex-Plus bit 25mm long | 3, 4, 5, 6, 8mm | | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 |
| | Phillips bit, 25mm long | (2) P#, (3) #2, #3 | | Tamperproof Torx bit, 25mm long | T10, T15, T20, T25, T30 |
| | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 | | Slotted bit 25mm long | 1.0 x 5.5mm |
| | Tamperproof Torx bit, 25mm long | T10, T15, T20, T25, T30 | | Hex-Plus bit 25mm long | 3/32, 1/8, 5/32, 3/16, 1/4in |
| | Pozidriv bit 25mm long | #1, (3) #2, #3 | | Square bit 25mm long | #1, (3) #2, #3 |
| | 6-point socket | 5.5, 6.0, 7.0, 8.0 10.0, 12.0, 13.0mm | | | |

Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.



Wera Bit Drivers, Bits, & Adapters



| Tool-Check PLUS Socket and Driver Bit Sets | | | Tool-Check Socket and Driver Bit Sets | | |
|---|--------------------------------|--|--|--------------------------------|--|
| 05056490001 | | | 05056491001 | | |
| | | | | | |
| <p>Wera Tool-Check PLUS standard socket and driver bit set, Phillips, slotted, Torx, tamperproof torx, internal hex, external hex and Pozidriv, 39 pieces, 1in bit length, 1/4in drive, metric.</p> | | \$108.00 | <p>Wera Tool-Check standard socket and driver bit set, Phillips, slotted, Torx, tamperproof torx, internal hex, square and external hex, 39 pieces, 1in bit length, 1/4in drive, imperial.</p> | | \$107.00 |
| Type | Size | | Type | Size | |
| Bitholding screwdriver | 1/4in x 78mm | | Bitholding screwdriver | 1/4in x 78mm | |
| Zyklop mini bit ratchet | 1/4in | | Zyklop mini bit ratchet | 1/4in | |
| Rapidaptor bit holder | 1/4in x 50mm | | Rapidaptor bit holder | 1/4in x 50mm | |
| Socket adaptor | 1/4in x 25mm | | Socket adaptor | 1/4in x 25mm | |
| | Phillips bit, 25mm long | (2) #1, (3) #2, #3 | | Phillips bit, 25mm long | (2) #1, (3) #2, #3 |
| | Pozidriv bit, 25mm long | #1, (3) #2, #3 | | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 |
| | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 | | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 |
| | Tamperproof Torx bit 25mm long | T10, T15, T20, T25, T30 | | Tamperproof Torx bit 25mm long | T10, T15, T20, T25, T30 |
| | Slotted bit 25mm long | 1.0 x 5.5mm | | Slotted bit 25mm long | 1.0 x 5.5mm |
| | Hex-Plus bit 25mm long | 3.0, 4.0, 5.0, 6.0, 8.0mm | | Hex-Plus bit 25mm long | 3/32, 1/8, 5/32, 3/16, 1/4in |
| | 6-point socket | 5.5, 6.0, 7.0, 8.0, 10.0, 12.0, 13.0mm | | 6-point socket | 3/16, 1/4, 5/16, 11/32, 3/8, 7/16, 1/2in |

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.