



Wera Bit Drivers, Bits, & Adapters



| Tool-Check Socket and Driver Bit Sets | | | Bit-Check Socket and Driver Bit Sets | | |
|--|------------------------------------|---|--------------------------------------|--|---------------------------------|
| 05073220055 | | | TW-DB-SET-28R | | |
| | | | | | |
| <p>Wera Tool-Check standard driver bit and socket set, Phillips, Pozidriv, slotted, Torx, tamperproof torx, internal hex and external hex, 38 pieces, 1in bit length, 1/4in drive, metric.</p> | | | \$102.00 | <p>Wera Bit-Check standard driver bit set, Phillips, Torx, tamperproof torx, external hex, slotted and square, 31 pieces, 1in bit length, 1/4in drive, imperial.</p> | |
| Type | | Bit Size | Type | | Bit Size |
| Zyklop Mini bit ratchet | | 1/4in | Zyklop Mini bit ratchet | | 1/4in |
| Rapidaptor bit holder | | 1/4 x 50 | Rapidaptor bit holder | | 1/4in x 50mm |
| Socket adaptor | | 1/4 x 25 | Socket adaptor | | 1/4 x 25 |
| | Slotted bit 25mm long | 1.0 x 5.5mm | | Phillips bit, 25mm long | (2) PH1, (3) PH2, PH3 |
| | Hex-Plus bit 25mm long | 3, 4, 5, 6, 8mm | | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 |
| | Phillips bit, 25mm long | (2) P#, (3) #2, #3 | | Tamperproof Torx bit, 25mm long | T10, T15, T20, T25, T30 |
| | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 | | Slotted bit 25mm long | 1.0 x 5.5mm |
| | Tamperproof Torx bit, 25mm long | T10, T15, T20, T25, T30 | | Hex-Plus bit 25mm long | 3/32, 1/8, 5/32, 3/16, 1/4in |
| | Pozidriv bit 25mm long | #1, (3) #2, #3 | | Square bit 25mm long | #1, (3) #2, #3 |
| | 6-point socket | 5.5, 6.0, 7.0, 8.0 10.0, 12.0, 13.0mm | | | |












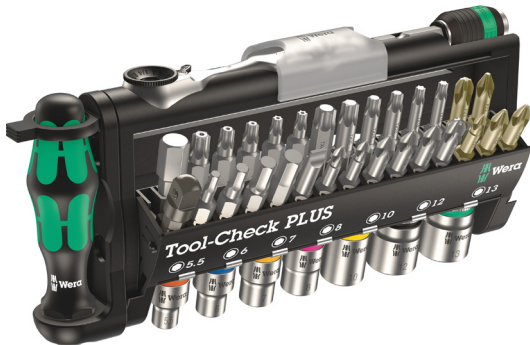




Note: Fractional dimensions are in inches. Whole and decimal dimensions are in millimeters.

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.



Wera Bit Drivers, Bits, & Adapters



| Tool-Check PLUS Socket and Driver Bit Sets | | | Tool-Check Socket and Driver Bit Sets | | |
|--|--------------------------------|--|---|---|--|
| <u>05056490001</u> | | | <u>05056491001</u> | | |
|  | | |  | | |
| Wera Tool-Check PLUS standard socket and driver bit set, Phillips, slotted, Torx, tamperproof torx, internal hex, external hex and Pozidriv, 39 pieces, 1in bit length, 1/4in drive, metric. | | | \$108.00 | Wera Tool-Check standard socket and driver bit set, Phillips, slotted, Torx, tamperproof torx, internal hex, square and external hex, 39 pieces, 1in bit length, 1/4in drive, imperial. | |
| | | | | | |
| <u>Type</u> | | | <u>Size</u> | <u>Type</u> | |
| Bitholding screwdriver | | | 1/4in x 78mm | Bitholding screwdriver | |
| Zyklop mini bit ratchet | | | 1/4in | Zyklop mini bit ratchet | |
| Rapidaptor bit holder | | | 1/4in x 50mm | Rapidaptor bit holder | |
| Socket adaptor | | | 1/4in x 25mm | Socket adaptor | |
|  | Phillips bit, 25mm long | (2) #1, (3) #2, #3 |  | Phillips bit, 25mm long | (2) #1, (3) #2, #3 |
|  | Pozidriv bit, 25mm long | #1, (3) #2, #3 | |  | Torx bit, 25mm long |
|  | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 |  | Torx bit, 25mm long | T10, T15, T20, T25, T30, T40 |
|  | Tamperproof Torx bit 25mm long | T10, T15, T20, T25, T30 | |  | Tamperproof Torx bit 25mm long |
|  | Slotted bit 25mm long | 1.0 x 5.5mm |  | Slotted bit 25mm long | 1.0 x 5.5mm |
|  | Hex-Plus bit 25mm long | 3.0, 4.0, 5.0, 6.0, 8.0mm | |  | Hex-Plus bit 25mm long |
|  | 6-point socket | 5.5, 6.0, 7.0, 8.0, 10.0, 12.0, 13.0mm |  | 6-point socket | 3/16, 1/4, 5/16, 11/32, 3/8, 7/16, 1/2in |

Note: Screwdriver bits and bit-holders are warranted against manufacturer defect only.