




# Air Prep Components

**SYNTEsi**

Metal Work Syntesi is the result of over 30 years of air prep manufacturing. Their goal is to provide high performance and low weight in a compact, affordable package. Syntesi has many standard features unavailable with other brands.

## Features

- Lightweight yet durable bodies of technopolymer and nickel plated brass
- Additional outlet ports front and back of all modules
- Available in two body sizes
- Ports sizes from 1/8" NPT to 1" NPT

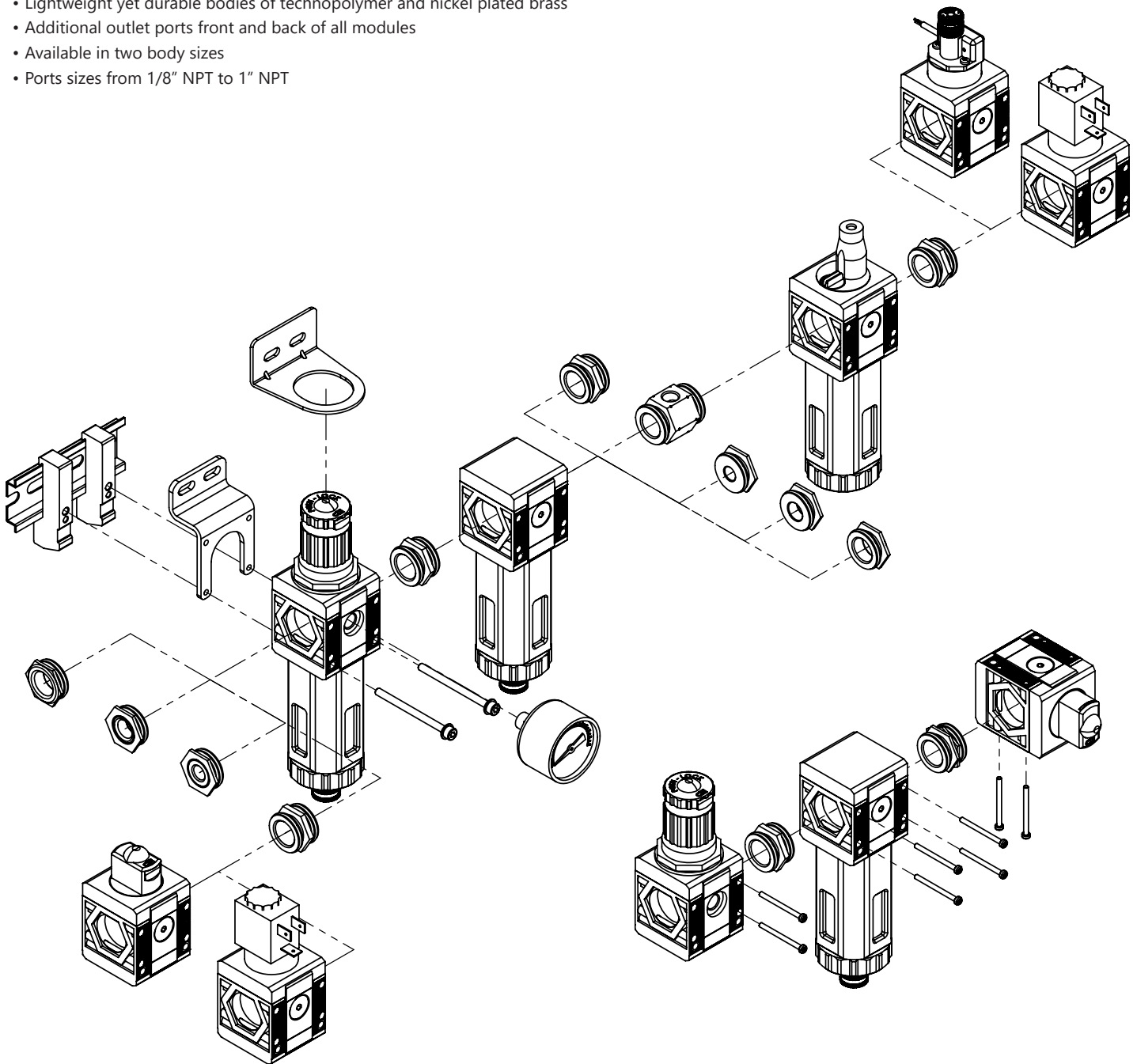



# Valve-Filter-Regulator-Lubricators

# SYNTESI®

Metal Work Syntesi combination units come pre-assembled with the most popular modules.

## Features

- Includes manual shut-off / dump valve, filter-regulator and lubricator
- Fluid - Compressed air or other inert gases
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Gauges sold separately
- Max. input pressure 217 psi (188 psi for size 2)



Part No.  
**5U23V10B24L103**



Part No.  
**5U11V10B24L101**



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

## Metal Work Syntesi Valve-Filter-Regulator-Lubricators

| Part No.                     | Price    | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl          | Drain Type                   | Shutoff Valve | Setpoint Range | Drawing Link        | Manufacturer Specs  |
|------------------------------|----------|--------------|------|------------------|------------------|---------------------|------------------------------|---------------|----------------|---------------------|---------------------|
| <b><u>5U11V10B24L101</u></b> | \$96.00  | 1.35         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer | Manual/ semi-automatic drain | Manual        | 0-120 psi      | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <b><u>5U12V10B24L102</u></b> | \$96.00  | 1.35         |      | 1/4in female NPT | 1/4in female NPT |                     |                              |               |                | <a href="#">PDF</a> |                     |
| <b><u>5U13V10B24L103</u></b> | \$96.00  | 1.30         |      | 3/8in female NPT | 3/8in female NPT |                     |                              |               |                | <a href="#">PDF</a> |                     |
| <b><u>5U23V10B24L103</u></b> | \$143.00 | 3.55         | 2    | 1/2in female NPT | 1/2in female NPT |                     |                              |               |                | <a href="#">PDF</a> |                     |
| <b><u>5U24V10B24L104</u></b> | \$143.00 | 3.50         |      | 3/4in female NPT | 3/4in female NPT |                     |                              |               |                | <a href="#">PDF</a> |                     |
| <b><u>5U25V10B24L105</u></b> | \$169.00 | 3.80         |      | 1in female NPT   | 1in female NPT   |                     |                              |               |                | <a href="#">PDF</a> |                     |
| <b><u>5U26V10B24L106</u></b> | \$169.00 | 3.80         |      | 1in female NPT   | 1in female NPT   |                     |                              |               |                | <a href="#">PDF</a> |                     |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).

Recommended Oils - ISO and UNI FD22 (Energol HPL; Spinesso; Mobil DTE; Tellus oil)



# Filter-Regulator-Lubricators

# SYNTESI®

Metal Work Syntesi combination units come pre-assembled with the most popular modules.

## Features

- Includes filter-regulator and lubricator
- Fluid - Compressed air or other inert gases
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Gauges sold separately
- Max. input pressure 217 psi (188 psi for size 2)



Part No.  
**5U23B24L103**



Part No.  
**5U11B24L101**



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options



| Metal Work Syntesi Filter-Regulator-Lubricators |          |              |      |                  |                  |                     |                              |                |                     |                     |
|---|----------|--------------|------|------------------|------------------|---------------------|------------------------------|----------------|---------------------|---------------------|
| Part No.  | Price    | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl          | Drain Type                   | Setpoint Range | Drawing Link        | Manufacturer Specs  |
| <b><u>5U11B24L101</u></b>                       | \$62.00  | 1.00         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer | Manual/ semi-automatic drain | 0-120 psi      | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <b><u>5U12B24L102</u></b>                       | \$62.00  | 1.00         |      | 1/4in female NPT | 1/4in female NPT |                     |                              |                | <a href="#">PDF</a> |                     |
| <b><u>5U13B24L103</u></b>                       | \$62.00  | 0.95         |      | 3/8in female NPT | 3/8in female NPT |                     |                              |                | <a href="#">PDF</a> |                     |
| <b><u>5U23B24L103</u></b>                       | \$95.00  | 2.60         | 2    | 1/2in female NPT | 1/2in female NPT |                     |                              |                | <a href="#">PDF</a> |                     |
| <b><u>5U24B24L104</u></b>                       | \$111.00 | 2.55         |      | 3/4in female NPT | 3/4in female NPT |                     |                              |                | <a href="#">PDF</a> |                     |
| <b><u>5U25B24L105</u></b>                       | \$111.00 | 2.60         |      | 1in female NPT   | 1in female NPT   |                     |                              |                | <a href="#">PDF</a> |                     |
| <b><u>5U26B24L106</u></b>                       | \$111.00 | 2.55         |      | 1in female NPT   | 1in female NPT   |                     |                              |                | <a href="#">PDF</a> |                     |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).

Recommended Oils - ISO and UNI FD22 (Energol HPL; Spinesso; Mobil DTE; Tellus oil)



# Filter-Lubricators

# SYNTESI®



Part No.  
**5U23F20L103**



Part No.  
**5U11F20L101**

Metal Work Syntesi combination units come pre-assembled with the most popular modules.

## Features

- Includes filter and lubricator
- Fluid - Compressed air or other inert gases
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

| Metal Work Syntesi Filter-Lubricators |         |              |      |                  |                  |                     |                              |                                      |                     |                     |
|---------------------------------------|---------|--------------|------|------------------|------------------|---------------------|------------------------------|--------------------------------------|---------------------|---------------------|
| Part No.                              | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl          | Drain Type                   | Filter                               | Drawing Link        | Manufacturer Specs  |
| <b><u>5U11F20L101</u></b>             | \$48.00 | 0.85         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer | Manual/ semi-automatic drain | Particulate filter element 20 micron | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <b><u>5U12F20L102</u></b>             | \$48.00 | 0.85         |      | 1/4in female NPT | 1/4in female NPT |                     |                              |                                      | <a href="#">PDF</a> |                     |
| <b><u>5U13F20L103</u></b>             | \$48.00 | 0.85         |      | 3/8in female NPT | 3/8in female NPT |                     |                              |                                      | <a href="#">PDF</a> |                     |
| <b><u>5U23F20L103</u></b>             | \$74.00 | 2.15         | 2    | 1/2in female NPT | 1/2in female NPT |                     |                              |                                      | <a href="#">PDF</a> |                     |
| <b><u>5U24F20L104</u></b>             | \$74.00 | 2.10         |      | 3/4in female NPT | 3/4in female NPT |                     |                              |                                      | <a href="#">PDF</a> |                     |
| <b><u>5U25F20L105</u></b>             | \$86.00 | 2.10         |      | 1in female NPT   | 1in female NPT   |                     |                              |                                      | <a href="#">PDF</a> |                     |
| <b><u>5U26F20L106</u></b>             | \$86.00 | 2.05         |      | 1in female NPT   | 1in female NPT   |                     |                              |                                      | <a href="#">PDF</a> |                     |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).

Recommended Oils - ISO and UNI FD22 (Energold HPL; Spinesso; Mobil DTE; Tellus oil)



# Filter-Coalescing Filters

# SYNTESI®



Part No.  
**5U23F10D103**



Part No.  
**5U11F10D101**

Metal Work Syntesi combination units come pre-assembled with the most popular modules.

## Features

- Includes filter and coalescing filter
- Fluid - Compressed air or other inert gases
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

| Metal Work Syntesi Filter-Coalescing Filters |          |              |      |                  |                  |                     |                              |                                     |                                       |                            |                            |
|--|----------|--------------|------|------------------|------------------|---------------------|------------------------------|-------------------------------------|---------------------------------------|----------------------------|----------------------------|
| Part No.                                     | Price    | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl          | Drain Type                   | Filter                              | Coalescing Filter                     | Drawing Link               | Manufacturer Specs         |
| <a href="#"><u>5U11F10D101</u></a>           | \$83.00  | 0.85         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer | Manual/ semi-automatic drain | Particulate filter element 5 micron | Coalescing filter element 0.01 micron | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>5U12F10D102</u></a>           | \$83.00  | 0.85         |      | 1/4in female NPT | 1/4in female NPT |                     |                              |                                     |                                       | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U13F10D103</u></a>           | \$83.00  | 0.85         |      | 3/8in female NPT | 3/8in female NPT |                     |                              |                                     |                                       | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U23F10D103</u></a>           | \$126.00 | 2.10         | 2    | 1/2in female NPT | 1/2in female NPT |                     |                              |                                     |                                       | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U24F10D104</u></a>           | \$126.00 | 2.05         |      | 3/4in female NPT | 3/4in female NPT |                     |                              |                                     |                                       | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U25F10D105</u></a>           | \$132.00 | 2.10         |      | 1in female NPT   | 1in female NPT   |                     |                              |                                     |                                       | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U26F10D106</u></a>           | \$132.00 | 2.05         |      | 1in female NPT   | 1in female NPT   |                     |                              |                                     |                                       | <a href="#"><u>PDF</u></a> |                            |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).



# Filter-Regulators

# SYNTESI®

Metal Work Syntesi filter-regulators provide particulate and moisture removal as well as pressure regulation in a compact package.

## Features

- Includes filter and 0-120 psig regulator
- Fluid - Compressed air or other inert gases
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Gauges sold separately
- Max. input pressure 217 psi (188 psi for size 2)



Part No.  
**5U23B243**



Part No.  
**5U11B241**



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options



| Metal Work Syntesi Filter-Regulators |         |              |      |                  |                  |                              |                              |                |                                      |                     |                     |
|--------------------------------------|---------|--------------|------|------------------|------------------|------------------------------|------------------------------|----------------|--------------------------------------|---------------------|---------------------|
| Part No.                             | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl                   | Drain Type                   | Setpoint Range | Filter                               | Drawing Link        | Manufacturer Specs  |
| <a href="#">5U11B241</a>             | \$35.50 | 0.60         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer w/ guard | Manual/ semi-automatic drain | 0-120 psi      | Particulate filter element 20 micron | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <a href="#">5U12B242</a>             | \$35.50 | 0.60         |      | 1/4in female NPT | 1/4in female NPT |                              |                              |                |                                      | <a href="#">PDF</a> |                     |
| <a href="#">5U13B243</a>             | \$35.50 | 0.55         |      | 3/8in female NPT | 3/8in female NPT |                              |                              |                |                                      | <a href="#">PDF</a> |                     |
| <a href="#">5U23B243</a>             | \$54.00 | 1.55         | 2    | 1/2in female NPT | 1/2in female NPT |                              |                              |                |                                      | <a href="#">PDF</a> |                     |
| <a href="#">5U24B244</a>             | \$54.00 | 1.50         |      | 3/4in female NPT | 3/4in female NPT |                              |                              |                |                                      | <a href="#">PDF</a> |                     |
| <a href="#">5U25B245</a>             | \$57.00 | 1.55         |      | 1in female NPT   | 1in female NPT   |                              |                              |                |                                      | <a href="#">PDF</a> |                     |
| <a href="#">5U26B246</a>             | \$57.00 | 1.50         |      | 1in female NPT   | 1in female NPT   |                              |                              |                |                                      | <a href="#">PDF</a> |                     |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).





# Filters

# SYNTESI®



**Part No.**  
**5U23F203**



**Part No.**  
**5U11F201**

Metal Work Syntesi filters provide particulate and moisture removal in a compact package. The technopolymer bowl is more resistant to environmental stress cracking than polycarbonate.

## Features

- Replaceable 20 micron filter element
- Fluid - Compressed air or other inert gases
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

## Metal Work Syntesi Filters

| Part No.                        | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl                   | Drain Type                   | Filter                               | Drawing Link               | Manufacturer Specs         |
|---------------------------------|---------|--------------|------|------------------|------------------|------------------------------|------------------------------|--------------------------------------|----------------------------|----------------------------|
| <a href="#"><u>5U11F201</u></a> | \$21.50 | 0.45         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer w/ guard | Manual/ semi-automatic drain | Particulate filter element 20 micron | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>5U12F202</u></a> | \$21.50 | 0.40         |      | 1/4in female NPT | 1/4in female NPT |                              |                              |                                      | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U13F203</u></a> | \$21.50 | 0.40         |      | 3/8in female NPT | 3/8in female NPT |                              |                              |                                      | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U23F203</u></a> | \$35.00 | 1.05         | 2    | 1/2in female NPT | 1/2in female NPT |                              |                              |                                      | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U24F204</u></a> | \$35.00 | 1.00         |      | 3/4in female NPT | 3/4in female NPT |                              |                              |                                      | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U25F205</u></a> | \$41.50 | 1.05         |      | 1in female NPT   | 1in female NPT   |                              |                              |                                      | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U26F206</u></a> | \$41.50 | 1.05         |      |                  |                  |                              |                              |                                      | <a href="#"><u>PDF</u></a> |                            |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).



# Coalescing Filters

**SYNTESI®**


**Part No.**  
**5U23D103**



**Part No.**  
**5U11D101**

Metal Work Syntesi coalescing filters provide oil mist removal in a compact package.

## Features

- Replaceable 0.01 micron coalescing element
- Fluid - Compressed air or other inert gases
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

## Metal Work Syntesi Coalescing Filters

| Part No.               | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl                   | Drain Type                   | Coalescing Filter                     | Drawing Link        | Manufacturer Specs  |
|------------------------|---------|--------------|------|------------------|------------------|------------------------------|------------------------------|---------------------------------------|---------------------|---------------------|
| <b><u>5U11D101</u></b> | \$62.00 | 0.45         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer w/ guard | Manual/ semi-automatic drain | Coalescing filter element 0.01 micron | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <b><u>5U12D102</u></b> | \$62.00 | 0.45         |      | 1/4in female NPT | 1/4in female NPT |                              |                              |                                       | <a href="#">PDF</a> |                     |
| <b><u>5U13D103</u></b> | \$62.00 | 0.45         |      | 3/8in female NPT | 3/8in female NPT |                              |                              |                                       | <a href="#">PDF</a> |                     |
| <b><u>5U23D103</u></b> | \$92.00 | 1.10         | 2    | 1/2in female NPT | 1/2in female NPT |                              |                              |                                       | <a href="#">PDF</a> |                     |
| <b><u>5U24D104</u></b> | \$92.00 | 1.05         |      | 3/4in female NPT | 3/4in female NPT |                              |                              |                                       | <a href="#">PDF</a> |                     |
| <b><u>5U25D105</u></b> | \$95.00 | 1.10         |      | 1in female NPT   | 1in female NPT   |                              |                              |                                       | <a href="#">PDF</a> |                     |
| <b><u>5U26D106</u></b> | \$95.00 | 1.10         |      |                  |                  |                              |                              |                                       | <a href="#">PDF</a> |                     |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).





# Regulators

# SYNTESI®



**Part No.**  
**5U23R143**



**Part No.**  
**5U11R141**

Metal Work Syntesi regulators provide pressure regulation in a compact package.

## Features

- 0-120 psig range
- Fluid - Compressed air or other inert gases
- Lockable knob
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Gauges and padlocks sold separately
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

| Metal Work Syntesi Regulators   |         |              |      |                  |                  |                              |                              |                |                            |                            |
|---------------------------------|---------|--------------|------|------------------|------------------|------------------------------|------------------------------|----------------|----------------------------|----------------------------|
| Part No.                        | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl                   | Drain Type                   | Setpoint Range | Drawing Link               | Manufacturer Specs         |
| <a href="#"><u>5U11R141</u></a> | \$26.00 | 0.45         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer w/ guard | Manual/ semi-automatic drain | 0-120 psi      | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>5U12R142</u></a> | \$26.00 | 0.45         |      | 1/4in female NPT | 1/4in female NPT |                              |                              |                | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U13R143</u></a> | \$26.00 | 0.40         |      | 3/8in female NPT | 3/8in female NPT |                              |                              |                | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U23R143</u></a> | \$40.00 | 1.20         | 2    | 1/2in female NPT | 1/2in female NPT |                              |                              |                | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U24R144</u></a> | \$40.00 | 1.20         |      | 3/4in female NPT | 3/4in female NPT |                              |                              |                | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U25R145</u></a> | \$46.50 | 1.25         |      | 1in female NPT   | 1in female NPT   |                              |                              |                | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U26R146</u></a> | \$46.50 | 1.25         |      | 1in female NPT   | 1in female NPT   |                              |                              |                | <a href="#"><u>PDF</u></a> |                            |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).



# Lubricators

# SYNTESI®



**Part No.**  
**5U23L103**



**Part No.**  
**5U11L101**

Metal Work Syntesi lubricators allow oil to be added to the downstream system in a compact package.

## Features

- Adjustable metering knob
- Fluid - Compressed air or other inert gases
- Transparent dome to view oil drops
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

## Metal Work Syntesi Lubricators

| Part No.                        | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drain Bowl                   | Drawing Link               | Manufacturer Specs         |
|---------------------------------|---------|--------------|------|------------------|------------------|------------------------------|----------------------------|----------------------------|
| <a href="#"><u>5U11L101</u></a> | \$27.00 | 0.45         | 1    | 1/8in female NPT | 1/8in female NPT | Clear technopolymer w/ guard | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>5U12L102</u></a> | \$27.00 | 0.45         |      | 1/4in female NPT | 1/4in female NPT |                              | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U13L103</u></a> | \$27.00 | 0.45         |      | 3/8in female NPT | 3/8in female NPT |                              | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U23L103</u></a> | \$43.50 | 1.10         | 2    | 1/2in female NPT | 1/2in female NPT |                              | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U24L104</u></a> | \$43.50 | 1.10         |      | 3/4in female NPT | 3/4in female NPT |                              | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U25L105</u></a> | \$48.00 | 1.10         |      | 1in female NPT   | 1in female NPT   |                              | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U26L106</u></a> | \$48.00 | 1.10         |      | 1in female NPT   | 1in female NPT   |                              | <a href="#"><u>PDF</u></a> |                            |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).

Recommended Oils - ISO and UNI FD22 (Energol HPL; Spinesso; Mobil DTE; Tellus oil)



# Shut-Off Valves

# SYNTESI®



**Part No.**  
**5U11V101**



**Part No.**  
**5U11V701**

Metal Work Syntesi shut-off valves block upstream air flow and exhaust downstream pressure.

## Features

- Manual twist valve is lockable
- Fluid - Compressed air or other inert gases
- Solenoid valve coils sold separately
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- 3-port (3-way), 2-position, N.C.
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

### Metal Work Syntesi Shut-Off Valves - Twist (N.C. Normally Closed)

| Part No.                 | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Exhaust          | Cv  | Fluid | Drawing Link        | Manufacturer Specs  |
|--------------------------|---------|--------------|------|------------------|------------------|------------------|-----|-------|---------------------|---------------------|
| <a href="#">5U11V101</a> | \$33.50 | 0.40         | 1    | 1/8in female NPT | 1/8in female NPT | G1/8 female BSPP | 1.2 | Air   | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <a href="#">5U12V102</a> | \$33.50 | 0.35         |      | 1/4in female NPT | 1/4in female NPT |                  | 1.5 |       | <a href="#">PDF</a> |                     |
| <a href="#">5U13V103</a> | \$33.50 | 0.35         |      | 3/8in female NPT | 3/8in female NPT |                  | 1.6 |       | <a href="#">PDF</a> |                     |
| <a href="#">5U23V103</a> | \$48.00 | 1.10         | 2    | 1/2in female NPT | 1/2in female NPT | G1/4 female BSPP | 4.1 |       | <a href="#">PDF</a> |                     |
| <a href="#">5U24V104</a> | \$48.50 | 1.00         |      |                  |                  |                  | 4.4 |       | <a href="#">PDF</a> |                     |
| <a href="#">5U25V105</a> | \$55.00 | 1.10         |      |                  |                  |                  |     |       | <a href="#">PDF</a> |                     |
| <a href="#">5U26V106</a> | \$56.00 | 1.05         |      |                  |                  |                  |     |       | <a href="#">PDF</a> |                     |

### Metal Work Syntesi Shut-Off Valves - Solenoid (N.C. Normally Closed)

|                          |         |      |   |                  |                  |                  |     |     |                     |                     |
|--------------------------|---------|------|---|------------------|------------------|------------------|-----|-----|---------------------|---------------------|
| <a href="#">5U11V701</a> | \$67.00 | 0.45 | 1 | 1/8in female NPT | 1/8in female NPT | G1/8 female BSPP | 1.2 | Air | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <a href="#">5U12V702</a> | \$67.00 | 0.45 |   | 1/4in female NPT | 1/4in female NPT |                  | 1.5 |     | <a href="#">PDF</a> |                     |
| <a href="#">5U13V703</a> | \$67.00 | 0.45 |   | 3/8in female NPT | 3/8in female NPT |                  | 1.6 |     | <a href="#">PDF</a> |                     |
| <a href="#">5U23V703</a> | \$79.00 | 1.10 | 2 | 1/2in female NPT | 1/2in female NPT | G1/4 female BSPP | 4.1 |     | <a href="#">PDF</a> |                     |
| <a href="#">5U24V704</a> | \$79.00 | 1.05 |   | 3/4in female NPT | 3/4in female NPT |                  | 4.4 |     | <a href="#">PDF</a> |                     |
| <a href="#">5U25V705</a> | \$85.00 | 1.10 |   | 1in female NPT   | 1in female NPT   |                  |     |     | <a href="#">PDF</a> |                     |
| <a href="#">5U26V706</a> | \$85.00 | 1.10 |   |                  |                  |                  |     |     |                     |                     |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).



# Soft Start Valves

# SYNTESI®



**Part No.**  
**5U11A701**

Metal Work Syntesi soft start valves act as a shut-off valve which gradually increase downstream pressure when opened.

## Features

- Adjustable pressure ramp-up speed
- Fluid - Compressed air or other inert gases
- Solenoid valve coils sold separately
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- 3-port (3-way), 2-position, N.C.
- Max. input pressure 217 psi (188 psi for size 2)



See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options

## Metal Work Syntesi Soft Start Valves

| Part No.                        | Price    | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Exhaust          | Cv  | Drawing Link               | Manufacturer Specs         |
|---------------------------------|----------|--------------|------|------------------|------------------|------------------|-----|----------------------------|----------------------------|
| <a href="#"><u>5U11A701</u></a> | \$88.00  | 0.50         | 1    | 1/8in female NPT | 1/8in female NPT | G1/8 female BSPP | 1.3 | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> |
| <a href="#"><u>5U12A702</u></a> | \$88.00  | 0.45         |      | 1/4in female NPT | 1/4in female NPT |                  | 1.5 | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U13A703</u></a> | \$88.00  | 0.50         |      | 3/8in female NPT | 3/8in female NPT |                  | 1.6 | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U23A703</u></a> | \$103.00 | 1.15         | 2    | 1/2in female NPT | 1/2in female NPT | G1/4 female BSPP | 4.1 | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U24A704</u></a> | \$103.00 | 1.10         |      | 3/4in female NPT | 3/4in female NPT |                  | 5.3 | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U25A705</u></a> | \$110.00 | 1.20         |      | 1in female NPT   | 1in female NPT   |                  |     | <a href="#"><u>PDF</u></a> |                            |
| <a href="#"><u>5U26A706</u></a> | \$110.00 | 1.15         |      |                  |                  |                  |     | <a href="#"><u>PDF</u></a> |                            |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).



# Pressure Switches


# SYNTESI®

Metal Work Syntesi pressure switches are a simple modular means to detect low or high pressure states in the system.

## Features

- Adjustable setpoint knob
- Fluid - Compressed air or other inert gases
- N.O./N.C. complementary outputs
- Body size 1 or 2
- Port sizes from 1/8" NPT to 1" NPT
- 7.5 to 145 psi set point
- 2 meter, 3-wire cable
- Max. input pressure 217 psi (188 psi for size 2)

## Wiring

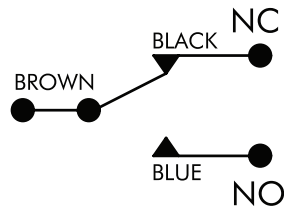

See [www.AutomationDirect.com](http://www.AutomationDirect.com) for a wide variety of fitting options



Part No.  
**5U23S103**



Part No.  
**5U11S101**

## Metal Work Syntesi Pressure Switches

| Part No.                 | Price   | Weight (lbs) | Size | Inlet(s) (NPT)   | Outlet(s) (NPT)  | Drawing Link        | Manufacturer Specs  |
|--------------------------|---------|--------------|------|------------------|------------------|---------------------|---------------------|
| <a href="#">5U11S101</a> | \$49.50 | 0.60         | 1    | 1/8in female NPT | 1/8in female NPT | <a href="#">PDF</a> | <a href="#">PDF</a> |
| <a href="#">5U12S102</a> | \$49.50 | 0.60         |      | 1/4in female NPT | 1/4in female NPT | <a href="#">PDF</a> |                     |
| <a href="#">5U13S103</a> | \$49.50 | 0.60         |      | 3/8in female NPT | 3/8in female NPT | <a href="#">PDF</a> |                     |
| <a href="#">5U23S103</a> | \$63.00 | 1.20         | 2    |                  |                  | <a href="#">PDF</a> |                     |
| <a href="#">5U24S104</a> | \$63.00 | 1.15         |      | 1/2in female NPT | 1/2in female NPT | <a href="#">PDF</a> |                     |
| <a href="#">5U25S105</a> | \$73.00 | 1.20         |      | 3/4in female NPT | 3/4in female NPT | <a href="#">PDF</a> |                     |
| <a href="#">5U26S106</a> | \$73.00 | 1.15         |      | 1in female NPT   | 1in female NPT   | <a href="#">PDF</a> |                     |

For additional details see manufacturer's technical specifications, manuals and inserts (where applicable).



# Accessories









| Metal Work Syntesi Accessories |                          |         |   |                     |                     |              |
|--------------------------------|--------------------------|---------|---|---------------------|---------------------|--------------|
| Item Photo                     | Part No.                 | Price   | Description   | Drawing Link        | Manufacturer Specs  | Weight (lbs) |
|                                | <a href="#">88257E1</a>  | \$3.25  | Metal Work mounting bracket, panel, plated steel. For use with Syntesi Size 1 regulators and filter-regulators.   | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.10         |
|                                | <a href="#">88257E2</a>  | \$4.25  | Metal Work mounting bracket, panel, plated steel. For use with Syntesi Size 2 regulators and filter-regulators.   | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.10         |
|                                | <a href="#">88257E3</a>  | \$11.25 | Metal Work mounting bracket, rear, plated steel. For use with Syntesi Size 1 air prep components. Mounting hardware included.   | <a href="#">PDF</a> | PDF                 | 0.15         |
|                                | <a href="#">88257E4</a>  | \$13.00 | Metal Work mounting bracket, rear, plated steel. For use with Syntesi Size 2 air prep components. Mounting hardware included.   | <a href="#">PDF</a> | PDF                 | 0.30         |
|                                | <a href="#">9200718X</a> | \$15.50 | Metal Work DIN rail adapter, anodized aluminum. Package of 2. For use with Syntesi Size 1 and 2 air prep components. Mounting hardware included.  | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.20         |
|                                | <a href="#">88257E5</a>  | \$2.25  | Metal Work connector nipple, anodized aluminum. For use with Syntesi Size 1 air prep components. Mounting hardware included.  | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.05         |
|                                | <a href="#">88257E6</a>  | \$5.75  | Metal Work connector nipple, anodized aluminum. For use with Syntesi Size 2 air prep components. Mounting hardware included.  | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.20         |
|                                | <a href="#">88257E7</a>  | \$3.25  | Metal Work connector nipple, 90 degree mounting, anodized aluminum. For use with Syntesi Size 1 air prep components. Mounting hardware included.  | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.05         |
|                                | <a href="#">88257E8</a>  | \$5.25  | Metal Work connector nipple, 90 degree mounting, anodized aluminum. For use with Syntesi Size 2 air prep components. Mounting hardware included.  | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.20         |
|                                | <a href="#">5U11P201</a> | \$32.00 | Metal Work pneumatic distribution block, 1/8in female NPT inlet(s), (1) 1/4in female NPT and (2) 1/8in female NPT outlet(s). For use with Syntesi Size 1 air prep components.                       | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.35         |
|                                | <a href="#">5U12P202</a> | \$32.00 | Metal Work pneumatic distribution block, 1/4in female NPT inlet(s), (1) 1/8in female NPT and (2) 1/4in female NPT outlet(s). For use with Syntesi Size 1 air prep components.                       | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.35         |
|                                | <a href="#">5U13P203</a> | \$32.00 | Metal Work pneumatic distribution block, 3/8in female NPT inlet(s), (1) 1/8in female NPT, (1) 1/4in female NPT and (1) 3/8in female NPT outlet(s). For use with Syntesi Size 1 air prep components. | <a href="#">PDF</a> | <a href="#">PDF</a> | 0.35         |
|                                | <a href="#">5U23P203</a> | \$52.00 | Metal Work pneumatic distribution block, 3/8in female NPT inlet(s), (1) 1/4in female NPT and (2) 3/8in female NPT outlet(s). For use with Syntesi Size 2 air prep components.                       | <a href="#">PDF</a> | PDF                 | 1.00         |
|                                | <a href="#">5U24P204</a> | \$52.00 | Metal Work pneumatic distribution block, 1/2in female NPT inlet(s), (1) 1/4in female NPT, (1) 3/8in female NPT and (1) 1/2in female NPT outlet(s). For use with Syntesi Size 2 air prep components. | <a href="#">PDF</a> | PDF                 | 0.95         |
|                                | <a href="#">5U25P205</a> | \$59.00 | Metal Work pneumatic distribution block, 3/4in female NPT inlet(s), (1) 1/4in female NPT, (1) 3/8in female NPT and (1) 3/4in female NPT outlet(s). For use with Syntesi Size 2 air prep components. | <a href="#">PDF</a> | PDF                 | 1.00         |
|                                | <a href="#">5U26P206</a> | \$59.00 | Metal Work pneumatic distribution block, 1in female NPT inlet(s), (1) 1/4in female NPT, (1) 3/8in female NPT and (1) 1in female NPT outlet(s). For use with Syntesi Size 2 air prep components.     | <a href="#">PDF</a> | PDF                 | 0.95         |
|                                | <a href="#">5U10P100</a> | \$7.25  | Metal Work pneumatic distribution block, 3/8in female NPT inlet(s), (1) 3/8in female NPT and (2) 1/8in female NPT outlet(s). For use with Syntesi Size 1 air prep components.                       | <a href="#">PDF</a> | PDF                 | 0.15         |
|                                | <a href="#">5U20P100</a> | \$19.50 | Metal Work pneumatic distribution block, 1/2in female NPT inlet(s), (1) 1/2in female NPT and (2) 3/8in female NPT outlet(s). For use with Syntesi Size 2 air prep components.                       | <a href="#">PDF</a> | PDF                 | 0.25         |





# Accessories

# SYNTESI®

| Metal Work Syntesi Accessories  |                                |         |  |                            |                            |              |
|---|--------------------------------|---------|--|----------------------------|----------------------------|--------------|
| Item Photo  | Part No.                       | Price   | Description  | Drawing Link               | Manufacturer Specs         | Weight (lbs) |
|    | <a href="#"><u>88257E9</u></a> | \$2.25  | Metal Work hex bushing, G1/4 male BSPP to G1/8 female BSPP, brass. For use with Syntesi Size 2 regulators and filter-regulators.           | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.05         |
|    | <a href="#"><u>88257F1</u></a> | \$1.75  | Metal Work port adapter, 1/8in female NPT, anodized aluminum. For use with Syntesi Size 1 air prep components. Mounting hardware included. | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.05         |
|   | <a href="#"><u>88257F2</u></a> | \$1.75  | Metal Work port adapter, 1/4in female NPT, anodized aluminum. For use with Syntesi Size 1 air prep components. Mounting hardware included. | <a href="#"><u>PDF</u></a> | PDF                        | 0.05         |
|   | <a href="#"><u>88257F3</u></a> | \$1.75  | Metal Work port adapter, 3/8in female NPT, anodized aluminum. For use with Syntesi Size 1 air prep components. Mounting hardware included. | <a href="#"><u>PDF</u></a> | PDF                        | 0.05         |
|    | <a href="#"><u>88257F4</u></a> | \$5.00  | Metal Work port adapter, 3/8in female NPT, anodized aluminum. For use with Syntesi Size 2 air prep components. Mounting hardware included. | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.15         |
|   | <a href="#"><u>88257F5</u></a> | \$5.00  | Metal Work port adapter, 1/2in female NPT, anodized aluminum. For use with Syntesi Size 2 air prep components. Mounting hardware included. | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.10         |
|   | <a href="#"><u>88257F6</u></a> | \$8.50  | Metal Work port adapter, 3/4in female NPT, anodized aluminum. For use with Syntesi Size 2 air prep components. Mounting hardware included. | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.10         |
|   | <a href="#"><u>88257F7</u></a> | \$8.50  | Metal Work port adapter, 1in female NPT, anodized aluminum. For use with Syntesi Size 2 air prep components. Mounting hardware included.   | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.10         |
|  | <a href="#"><u>88257F8</u></a> | \$7.50  | Metal Work pneumatic mechanical pressure gauge, 40mm diameter, 0 to 180 psi, G1/8 male BSPP process connection, center back mount.         | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.15         |
|   | <a href="#"><u>88257F9</u></a> | \$7.50  | Metal Work pneumatic mechanical pressure gauge, 40mm diameter, 0 to 60 psi, G1/8 male BSPP process connection, center back mount.          | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.15         |
|   | <a href="#"><u>88257G1</u></a> | \$7.50  | Metal Work pneumatic mechanical pressure gauge, 50mm diameter, 0 to 180 psi, G1/8 male BSPP process connection, center back mount.         | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.15         |
|   | <a href="#"><u>88257G2</u></a> | \$7.50  | Metal Work pneumatic mechanical pressure gauge, 50mm diameter, 0 to 60 psi, G1/8 male BSPP process connection, center back mount.          | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.15         |
|   | <a href="#"><u>9700110</u></a> | \$7.50  | Metal Work pneumatic mechanical pressure gauge, 40mm x 40mm, 0 to 180 psi, G1/8 male BSPP process connection, center back mount.           | <a href="#"><u>PDF</u></a> | PDF                        | 0.10         |
|   | <a href="#"><u>88257G3</u></a> | \$11.75 | Metal Work pneumatic mechanical pressure gauge, 63mm diameter, 0 to 180 psi, G1/4 male BSPP process connection, center back mount.         | <a href="#"><u>PDF</u></a> | PDF                        | 0.20         |
|  | <a href="#"><u>9210101</u></a> | \$26.50 | Metal Work automatic drain, for use with Syntesi Size 1 air prep components. Filter bowl included.   | N/A                        | PDF                        | 0.15         |
|  | <a href="#"><u>9210106</u></a> | \$32.50 | Metal Work automatic drain, for use with Syntesi Size 2 air prep components. Filter bowl included.   | N/A                        | PDF                        | 0.25         |



# Accessories





| Metal Work Syntesi Accessories  |                         |         |   |              |                     |              |
|---|-------------------------|---------|---|--------------|---------------------|--------------|
| Item Photo  | Part No.                | Price   | Description   | Drawing Link | Manufacturer Specs  | Weight (lbs) |
|    | <a href="#">9210150</a> | \$4.25  | Metal Work particulate filter element, replacement, 5 micron particles, yellow UHMWPE. For use with Syntesi Size 1 filters.                               | N/A          | <a href="#">PDF</a> | 0.05         |
|    | <a href="#">9210151</a> | \$4.25  | Metal Work particulate filter element, replacement, 20 micron particles, white UHMWPE. For use with Syntesi Size 1 filters.                               | N/A          | <a href="#">PDF</a> | 0.05         |
|    | <a href="#">9210152</a> | \$4.25  | Metal Work particulate filter element, replacement, 50 micron particles, blue HDPE. For use with Syntesi Size 1 filters.                                  | N/A          | PDF                 | 0.05         |
|    | <a href="#">9210155</a> | \$5.50  | Metal Work particulate filter element, replacement, 5 micron particles, yellow UHMWPE. For use with Syntesi Size 2 filters.                               | N/A          | PDF                 | 0.05         |
|   | <a href="#">9210156</a> | \$5.50  | Metal Work particulate filter element, replacement, 20 micron particles, white UHMWPE. For use with Syntesi Size 2 filters.                               | N/A          | <a href="#">PDF</a> | 0.05         |
|   | <a href="#">9210157</a> | \$5.50  | Metal Work particulate filter element, replacement, 50 micron particles, blue HDPE. For use with Syntesi Size 2 filters.                                  | N/A          | <a href="#">PDF</a> | 0.05         |
|  | <a href="#">9210160</a> | \$45.00 | Metal Work coalescing oil removal filter element, replacement, 0.01 micron particles, borosilicate glass microfiber. For use with Syntesi Size 1 filters. | N/A          | <a href="#">PDF</a> | 0.05         |
|   | <a href="#">9210165</a> | \$77.00 | Metal Work coalescing oil removal filter element, replacement, 0.01 micron particles, borosilicate glass microfiber. For use with Syntesi Size 2 filters. | N/A          | <a href="#">PDF</a> | 0.10         |
|  | <a href="#">9210190</a> | \$2.00  | Metal Work regulator spring, 0 to 30 psi range. For use with Syntesi Size 1 regulators.   | N/A          | <a href="#">PDF</a> | 0.05         |
|   | <a href="#">9210191</a> | \$2.00  | Metal Work regulator spring, 0 to 60 psi range. For use with Syntesi Size 1 regulators.   | N/A          | <a href="#">PDF</a> | 0.05         |
|   | <a href="#">9210192</a> | \$2.00  | Metal Work regulator spring, 0 to 120 psi range. For use with Syntesi Size 1 regulators.  | N/A          | <a href="#">PDF</a> | 0.05         |
|   | <a href="#">9210193</a> | \$2.00  | Metal Work regulator spring, 0 to 180 psi range. For use with Syntesi Size 1 regulators.  | N/A          | <a href="#">PDF</a> | 0.05         |
|   | <a href="#">9210195</a> | \$4.00  | Metal Work regulator spring, 0 to 30 psi range. For use with Syntesi Size 2 regulators.   | N/A          | PDF                 | 0.05         |
|   | <a href="#">9210196</a> | \$4.00  | Metal Work regulator spring, 0 to 60 psi range. For use with Syntesi Size 2 regulators.   | N/A          | PDF                 | 0.05         |
|   | <a href="#">9210197</a> | \$2.75  | Metal Work regulator spring, 0 to 120 psi range. For use with Syntesi Size 2 regulators.  | N/A          | PDF                 | 0.10         |
|   | <a href="#">9210198</a> | \$3.00  | Metal Work regulator spring, 0 to 180 psi range. For use with Syntesi Size 2 regulators.  | N/A          | PDF                 | 0.15         |



# Accessories



| Metal Work Syntesi Accessories  |                                  |         |   |                            |                            |              |
|---|----------------------------------|---------|---|----------------------------|----------------------------|--------------|
| Item Photo  | Part No.                         | Price   | Description   | Drawing Link               | Manufacturer Specs         | Weight (lbs) |
|  | <a href="#"><u>88257G4</u></a>   | \$11.75 | Metal Work solenoid coil, 12 VDC, 2W, 11mm DIN style wiring plug. For use with Metal Work valves.     | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.10         |
|   | <a href="#"><u>88257G5</u></a>   | \$11.75 | Metal Work solenoid coil, 24 VDC, 2W, 11mm DIN style wiring plug. For use with Metal Work valves.     | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.10         |
|   | <a href="#"><u>88257G6</u></a>   | \$11.75 | Metal Work solenoid coil, 24 VAC, 3.5VA, 11mm DIN style wiring plug. For use with Metal Work valves.  | <a href="#"><u>PDF</u></a> | PDF                        | 0.10         |
|   | <a href="#"><u>88257G7</u></a>   | \$11.75 | Metal Work solenoid coil, 110 VAC, 3.5VA, 11mm DIN style wiring plug. For use with Metal Work valves. | <a href="#"><u>PDF</u></a> | PDF                        | 0.10         |
|   | <a href="#"><u>88257G8</u></a>   | \$11.75 | Metal Work solenoid coil, 240 VAC, 3.5VA, 11mm DIN style wiring plug. For use with Metal Work valves. | <a href="#"><u>PDF</u></a> | <a href="#"><u>PDF</u></a> | 0.10         |
|  | <a href="#"><u>TAP-ACC21</u></a> | \$11.00 | NITRA padlock, replacement, brass. For use with TAP unit.   | N/A                        | N/A                        | 0.5          |